
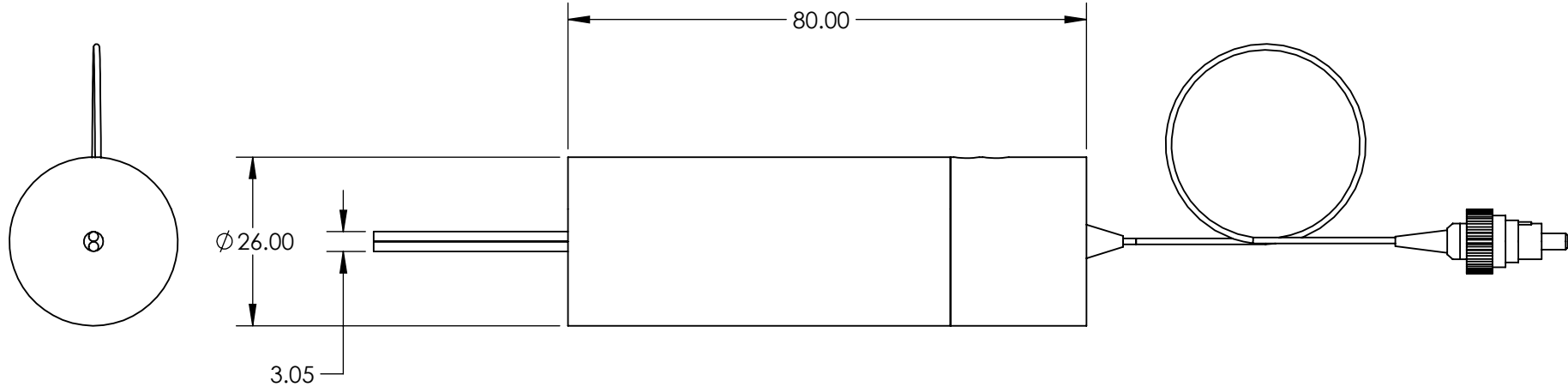


NOTES:

- 1. LASER CLASS:
IIIb
- 2. OPERATING TEMPERATURE: 15 to 30 °C
OPERATING VOLTAGE: 5V
- 3. OUTPUT POWER: 50mW
- 4. WAVELENGTH RANGE: 460±10 nm

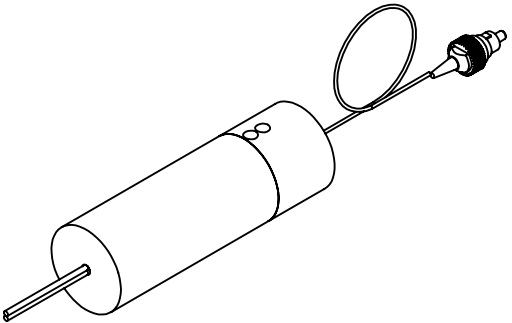

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

EO® Edmund Optics®

THIRD ANGLE PROJECTION		TITLE	460nm 50mW Pigtailed Laser Diode	
ALL DIMS IN	mm	DWG NO	23758	SHEET 1 OF 1