


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Visible Windows](#)

## High Efficiency Anti-Reflection (HEAR) Coated Windows

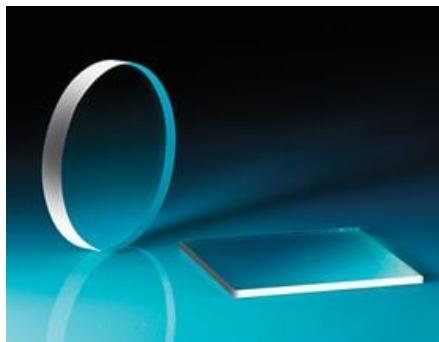


- High Transmission
- Eliminate Back Reflections and Reduce Glare
- Available in a Wide Range of Sizes

### Common Specifications

#### Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	≥90
<b>Optical Properties</b>			
Angle of Incidence (°):	0	Coating:	BBAR (425-700nm)
Coating Specification:	$R_{avg} \leq 0.5\% @ 425 - 700\text{nm}$	Substrate:	Float Glass
Surface Quality:	80-50	Wavelength Range (nm):	425 - 700

## Technical Information

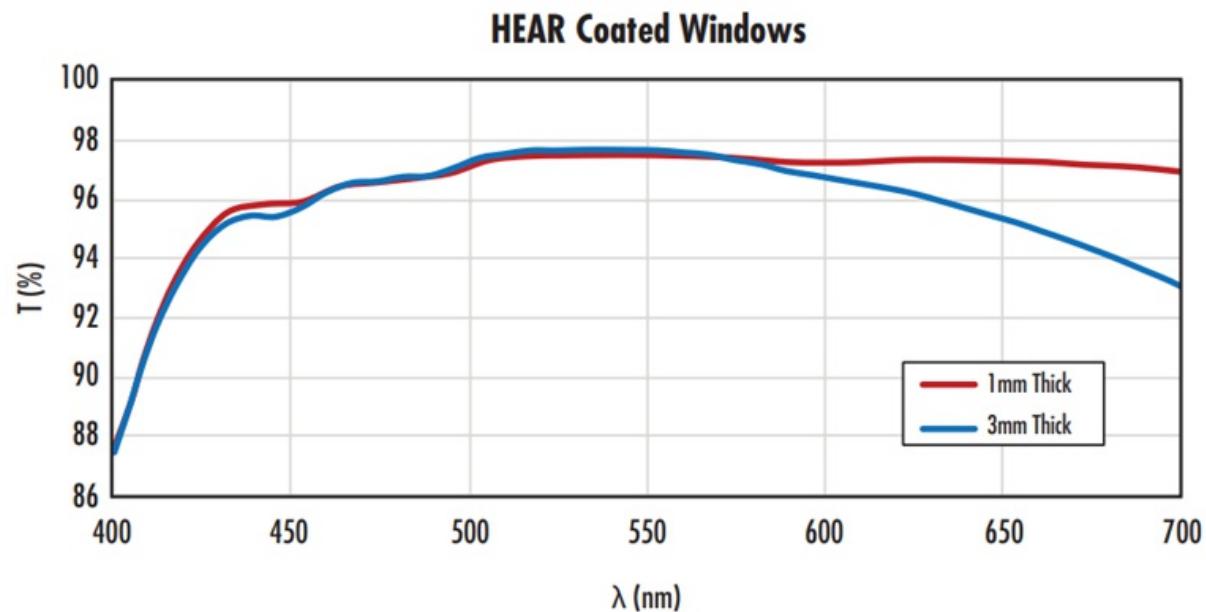

## Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
<a href="#"><u>#71-564 New</u></a>						
5.00	-	1.00	BBAR (425- 700nm)	 New  Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$32.20 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
<a href="#"><u>#71-565 New</u></a>						
5.00	-	3.00	BBAR (425- 700nm)	 New  Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$32.20 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock

[#71-566 New](#)

---

10.00	-	1.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$34.30 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock

---

[#71-567 New](#)

10.00	-	3.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$34.30 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock

---

12.50	-	1.00	BBAR (425- 700nm)	<a href="#"><u>#21-324</u></a>	C\$35.70 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
12.70	-	1.00	BBAR (425- 700nm)	<a href="#"><u>#39-279</u></a>	C\$36.40 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock

12.70	-	2.00	BBAR (425- 700nm)	<a href="#">#71-590</a>	C\$35.70 <a href="#">Volume Pricing</a>	20+ In Stock
12.70	-	3.00	BBAR (425- 700nm)	<a href="#">#39-283</a>	C\$36.40 <a href="#">Volume Pricing</a>	20+ In Stock

---

[#71-582 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

-	12.70 x 12.70	1.00	BBAR (425- 700nm)		C\$36.40 <a href="#">Volume Pricing</a>	20+ In Stock
---	---------------	------	-------------------------	--	--	--------------

---

[#71-583 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

-	12.70 x 12.70	3.00	BBAR (425- 700nm)		C\$36.05 <a href="#">Volume Pricing</a>	20+ In Stock
---	---------------	------	-------------------------	--	--	--------------

[#71-568 New](#)

---

15.00	-	1.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	C\$36.40 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
-------	---	------	-------------------------	---	---	--------------

---

[#71-569 New](#)

15.00	-	3.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	C\$36.40 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
-------	---	------	-------------------------	---	---	--------------

[#71-570 New](#)

---

20.00	-	1.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	C\$36.40 <a href="#"><u>Volume Pricing</u></a>	Contact Us
-------	---	------	-------------------------	---	---	------------

---

[#71-571 New](#)

20.00	-	3.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	C\$36.40 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
-------	---	------	-------------------------	---	---	--------------

---

25.00	-	1.00	BBAR (425- 700nm)	<a href="#"><u>#21-325</u></a>	C\$38.50 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
25.40	-	1.00	BBAR (425- 700nm)	<a href="#"><u>#48-924</u></a>	C\$38.50 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
-	25.40 x 25.40	1.00	BBAR (425- 700nm)	<a href="#"><u>#48-923</u></a>	C\$38.50 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock

25.40	-	2.00	BBAR (425- 700nm)	<a href="#">#71-591</a>	C\$38.50 <a href="#">Volume Pricing</a>	16 In Stock
25.40	-	3.00	BBAR (425- 700nm)	<a href="#">#46-098</a>	C\$38.50 <a href="#">Volume Pricing</a>	Contact Us
-	25.40 x 25.40	3.00	BBAR (425- 700nm)	<a href="#">#46-097</a>	C\$38.50 <a href="#">Volume Pricing</a>	20+ In Stock

---

[#71-584 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

-	25.40 x 50.80	1.00	BBAR (425- 700nm)	<a href="#">#71-584 New</a>	C\$39.90 <a href="#">Volume Pricing</a>	11 In Stock
---	---------------	------	-------------------------	-----------------------------	--	-------------

---

[#71-585 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

-	25.40 x 50.80	3.00	BBAR (425- 700nm)	<a href="#">#71-585 New</a>	C\$39.90 <a href="#">Volume Pricing</a>	20+ In Stock
---	---------------	------	-------------------------	-----------------------------	--	--------------

[#71-572 New](#)

---

30.00	-	1.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	C\$39.20 <a href="#"><u>Volume Pricing</u></a>	3 In Stock
-------	---	------	-------------------------	---	---	------------

---

[#71-573 New](#)

30.00	-	3.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	C\$39.20 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
-------	---	------	-------------------------	---	---	--------------

[#71-574 New](#)

---

35.00	-	1.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$38.50 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock

---

[#71-575 New](#)

35.00	-	3.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$37.80 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock

---

38.10	-	1.00	BBAR (425- 700nm)	<a href="#"><u>#39-280</u></a>	C\$38.50 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
38.10	-	2.00	BBAR (425- 700nm)	<a href="#"><u>#71-592</u></a>	C\$38.50 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock

---

38.10	-	3.00	BBAR (425- 700nm)	<a href="#">#39-284</a>	C\$38.50 <a href="#">Volume Pricing</a>	20+ In Stock
-------	---	------	-------------------------	-------------------------	--	--------------

---

[#71-576 New](#)



New

40.00	-	1.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$39.20 <a href="#">Volume Pricing</a>	20+ In Stock
-------	---	------	-------------------------	--	--	--------------

---

[#71-577 New](#)



New

40.00	-	3.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$39.20 <a href="#">Volume Pricing</a>	20+ In Stock
-------	---	------	-------------------------	--	--	--------------

---

50.00	-	3.00	BBAR (425- 700nm)	<a href="#">#21-326</a>	C\$39.90 <a href="#">Volume Pricing</a>	20+ In Stock
-------	---	------	-------------------------	-------------------------	--	--------------

---

50.80	-	1.00	BBAR (425- 700nm)	<a href="#">#48-926</a>	C\$39.90 <a href="#">Volume Pricing</a>	4 In Stock
-------	---	------	-------------------------	-------------------------	--	------------

-	50.80 x 50.80	1.00	BBAR (425- 700nm)	<a href="#">#48-925</a>	C\$39.90 <a href="#">Volume Pricing</a>	20+ In Stock
50.80	-	2.00	BBAR (425- 700nm)	<a href="#">#71-593</a>	C\$39.90 <a href="#">Volume Pricing</a>	Contact Us
-	50.80 x 50.80	2.00	BBAR (425- 700nm)	<a href="#">#71-594</a>	C\$38.50 <a href="#">Volume Pricing</a>	20+ In Stock
50.80	-	3.00	BBAR (425- 700nm)	<a href="#">#46-100</a>	C\$39.90 <a href="#">Volume Pricing</a>	20+ In Stock
-	50.80 x 50.80	3.00	BBAR (425- 700nm)	<a href="#">#46-099</a>	C\$39.90 <a href="#">Volume Pricing</a>	20+ In Stock

[#71-586 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

C\$49.00  
[Volume Pricing](#)

20+ In Stock

-	50.80 x 76.20	1.00	BBAR (425- 700nm)
---	---------------	------	-------------------------

[#71-587 New](#)



New

				Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$49.00 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
-	50.80 x 76.20	3.00	BBAR (425- 700nm)			

---

63.50	-	1.00	BBAR (425- 700nm)	<a href="#"><u>#39-281</u></a>	C\$42.70 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
63.50	-	3.00	BBAR (425- 700nm)	<a href="#"><u>#39-285</u></a>	C\$42.70 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
75.00	-	3.00	BBAR (425- 700nm)	<a href="#"><u>#21-328</u></a>	C\$49.00 <a href="#"><u>Volume Pricing</u></a>	8 In Stock
76.20	-	1.00	BBAR (425- 700nm)	<a href="#"><u>#48-928</u></a>	C\$49.00 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
-	76.20 x 76.20	1.00	BBAR (425- 700nm)	<a href="#"><u>#48-927</u></a>	C\$49.00 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
76.20	-	2.00	BBAR (425- 700nm)	<a href="#"><u>#71-595</u></a>	C\$49.00 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
-	76.20 x 76.20	2.00	BBAR (425- 700nm)	<a href="#"><u>#71-596</u></a>	C\$49.00 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
76.20	-	3.00	BBAR (425- 700nm)	<a href="#"><u>#46-102</u></a>	C\$49.00 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock

---

-	76.20 x 76.20	3.00	BBAR (425- 700nm)	<a href="#">#46-101</a>	C\$49.00 <a href="#">Volume Pricing</a>	20+ In Stock
88.90	-	1.00	BBAR (425- 700nm)	<a href="#">#39-282</a>	C\$56.70 <a href="#">Volume Pricing</a>	20+ In Stock
88.90	-	3.00	BBAR (425- 700nm)	<a href="#">#39-286</a>	C\$56.70 <a href="#">Volume Pricing</a>	20+ In Stock
101.60	-	1.00	BBAR (425- 700nm)	<a href="#">#48-930</a>	C\$64.40 <a href="#">Volume Pricing</a>	20+ In Stock
-	101.60 x 101.60	1.00	BBAR (425- 700nm)	<a href="#">#48-929</a>	C\$64.40 <a href="#">Volume Pricing</a>	20+ In Stock
101.60	-	2.00	BBAR (425- 700nm)	<a href="#">#71-597</a>	C\$64.40 <a href="#">Volume Pricing</a>	13 In Stock
-	101.60 x 101.60	2.00	BBAR (425- 700nm)	<a href="#">#71-598</a>	C\$64.40 <a href="#">Volume Pricing</a>	10 In Stock
101.60	-	3.00	BBAR (425- 700nm)	<a href="#">#46-104</a>	C\$64.40 <a href="#">Volume Pricing</a>	20+ In Stock
-	101.60 x 101.60	3.00	BBAR (425- 700nm)	<a href="#">#46-103</a>	C\$64.40 <a href="#">Volume Pricing</a>	Contact Us
-	101.60 x 127.00	3.00	BBAR (425- 700nm)	<a href="#">#21-329</a>	C\$69.30 <a href="#">Volume Pricing</a>	20+ In Stock
127.00	-	1.00	BBAR (425- 700nm)	<a href="#">#63-216</a>	C\$82.60 <a href="#">Volume Pricing</a>	20+ In Stock
-	127.00 x 177.80	1.00	BBAR (425- 700nm)	<a href="#">#63-217</a>	C\$82.60 <a href="#">Volume Pricing</a>	20+ In Stock
127.00	-	2.00	BBAR (425- 700nm)	<a href="#">#71-599</a>	C\$82.60 <a href="#">Volume Pricing</a>	20+ In Stock
-	127.00 x 177.80	2.00	BBAR (425- 700nm)	<a href="#">#71-600</a>	C\$82.60 <a href="#">Volume Pricing</a>	Contact Us

127.00	-	3.00	BBAR (425- 700nm)	<a href="#">#48-858</a>	C\$82.60 <a href="#">Volume Pricing</a>	20+ In Stock
-	127.00 x 177.80	3.00	BBAR (425- 700nm)	<a href="#">#43-973</a>	C\$82.60 <a href="#">Volume Pricing</a>	20+ In Stock

---

[#71-578 New](#)



New

152.00	-	1.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$87.50 <a href="#">Volume Pricing</a>	20+ In Stock
--------	---	------	-------------------------	--	--	--------------

---

[#71-579 New](#)



New

152.00	-	3.00	BBAR (425- 700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$87.50 <a href="#">Volume Pricing</a>	9 In Stock
--------	---	------	-------------------------	--	--	------------

[#71-580 New](#)

---

177.00	-	1.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	C\$91.00 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
--------	---	------	-------------------------	---	---	--------------

---

[#71-581 New](#)

177.00	-	3.00	BBAR (425- 700nm)	<p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>	C\$91.00 <a href="#"><u>Volume Pricing</u></a>	20+ In Stock
--------	---	------	-------------------------	---	---	--------------

---

203.20	-	1.00	BBAR (425- 700nm)	<a href="#"><u>#63-218</u></a>	C\$100.80 <a href="#"><u>Volume Pricing</u></a>	5 In Stock
-	203.20 x 203.20	3.00	BBAR (425- 700nm)	<a href="#"><u>#21-330</u></a>	C\$100.80 <a href="#"><u>Volume Pricing</u></a>	12 In Stock

-	203.20 x 254.00	1.00	BBAR (425-700nm)	<a href="#">#63-219</a>	C\$100.80 <a href="#">Volume Pricing</a>	20+ In Stock
203.20	-	3.00	BBAR (425-700nm)	<a href="#">#48-859</a>	C\$100.80 <a href="#">Volume Pricing</a>	Contact Us
-	203.20 x 254.00	3.00	BBAR (425-700nm)	<a href="#">#43-974</a>	C\$100.80 <a href="#">Volume Pricing</a>	20+ In Stock
254.00	-	1.00	BBAR (425-700nm)	<a href="#">#63-220</a>	C\$147.00 <a href="#">Volume Pricing</a>	11 In Stock
-	254.00 x 254.00	3.00	BBAR (425-700nm)	<a href="#">#21-331</a>	C\$147.00 <a href="#">Volume Pricing</a>	6 In Stock
-	254.00 x 304.80	1.00	BBAR (425-700nm)	<a href="#">#63-221</a>	C\$147.00 <a href="#">Volume Pricing</a>	14 In Stock
254.00	-	3.00	BBAR (425-700nm)	<a href="#">#48-860</a>	C\$147.00 <a href="#">Volume Pricing</a>	20+ In Stock
-	254.00 x 304.80	3.00	BBAR (425-700nm)	<a href="#">#43-975</a>	C\$147.00 <a href="#">Volume Pricing</a>	20+ In Stock
-	304.80 x 304.80	3.00	BBAR (425-700nm)	<a href="#">#21-332</a>	C\$176.40 <a href="#">Volume Pricing</a>	14 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA  
Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)