


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Visible Windows](#)

High Efficiency Anti-Reflection (HEAR) Coated Windows

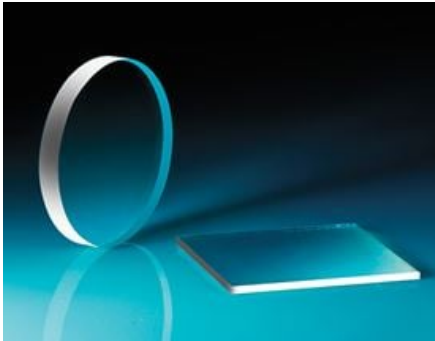


- High Transmission
- Eliminate Back Reflections and Reduce Glare
- Available in a Wide Range of Sizes

Common Specifications



Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	≥90
Optical Properties			
Angle of Incidence (°):	0	Coating:	BBAR (425-700nm)
Coating Specification:	$R_{avg} \leq 0.5\% @ 425 - 700nm$	Substrate:	Float Glass
Surface Quality:	80-50	Wavelength Range (nm):	425 - 700

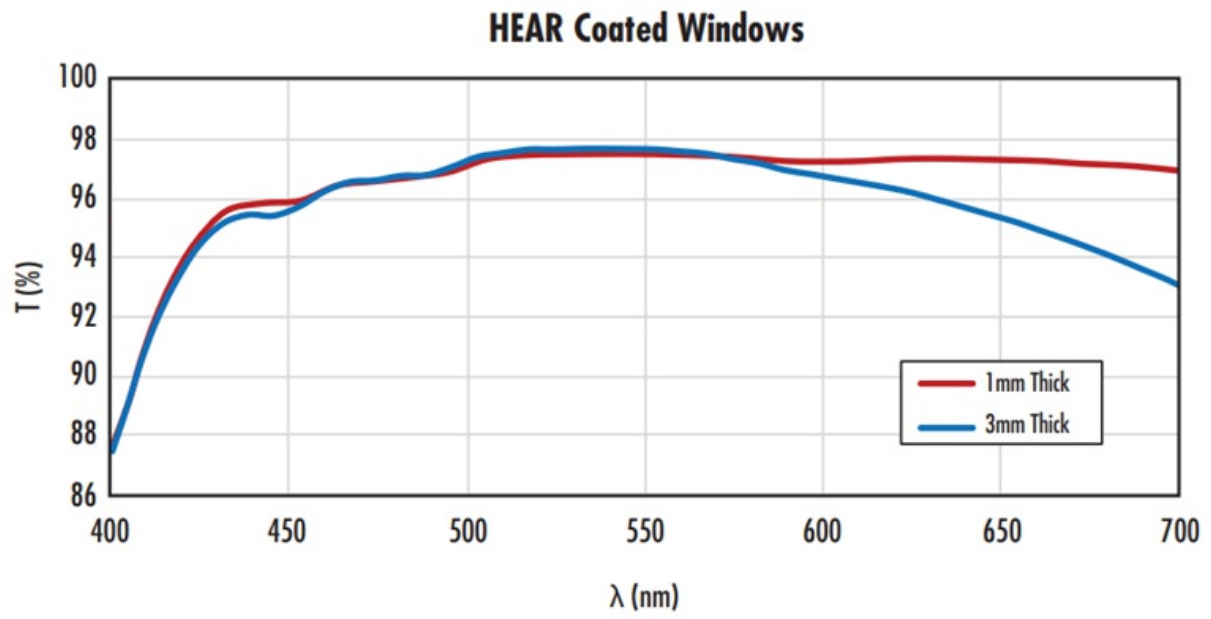Technical Information



Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
<hr/>						
#71-564 New						
						
New						
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!						
5.00	-	1.00	BBAR (425-700nm)		C\$32.20 Volume Pricing	20+ In Stock
<hr/>						
#71-565 New						
						
New						
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!						
5.00	-	3.00	BBAR (425-700nm)		C\$32.20 Volume Pricing	20+ In Stock
<hr/>						

[#71-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

10.00

-

1.00

BBAR
(425-700nm)

C\$34.30
[Volume Pricing](#)

20+ In Stock

[#71-567 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

10.00

-

3.00

BBAR
(425-700nm)

C\$34.30
[Volume Pricing](#)

20+ In Stock

12.50

-

1.00

BBAR
(425-700nm)

[#21-324](#)

C\$35.70
[Volume Pricing](#)

20+ In Stock

12.70

-

1.00

BBAR
(425-700nm)

[#39-279](#)

C\$36.40
[Volume Pricing](#)

20+ In Stock

12.70	-	2.00	BBAR (425-700nm)	#71-590	C\$35.70 Volume Pricing	20+ In Stock
-------	---	------	---------------------	-------------------------	--	--------------

12.70	-	3.00	BBAR (425-700nm)	#39-283	C\$36.40 Volume Pricing	20+ In Stock
-------	---	------	---------------------	-------------------------	--	--------------

[#71-582 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	12.70 x 12.70	1.00	BBAR (425-700nm)		C\$36.40 Volume Pricing	20+ In Stock
---	---------------	------	---------------------	--	--	--------------

[#71-583 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	12.70 x 12.70	3.00	BBAR (425-700nm)		C\$36.05 Volume Pricing	20+ In Stock
---	---------------	------	---------------------	--	--	--------------

[#71-568 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

15.00

-

1.00

BBAR
(425-700nm)

C\$36.40
[Volume Pricing](#)

20+ In Stock

[#71-569 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

15.00

-

3.00

BBAR
(425-700nm)

C\$36.40
[Volume Pricing](#)

20+ In Stock

[#71-570 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

1.00

BBAR
(425-700nm)

C\$36.40
[Volume Pricing](#)

Contact Us

[#71-571 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

3.00

BBAR
(425-700nm)

C\$36.40
[Volume Pricing](#)

20+ In Stock

25.00

-

1.00

BBAR
(425-700nm)

[#21-325](#)

C\$38.50
[Volume Pricing](#)

20+ In Stock

25.40

-

1.00

BBAR
(425-700nm)

[#48-924](#)

C\$38.50
[Volume Pricing](#)

20+ In Stock

- 25.40 x 25.40

1.00

BBAR
(425-700nm)

[#48-923](#)

C\$38.50
[Volume Pricing](#)

20+ In Stock

25.40	-	2.00	BBAR (425-700nm)	#71-591	C\$38.50 Volume Pricing	16 In Stock
25.40	-	3.00	BBAR (425-700nm)	#46-098	C\$38.50 Volume Pricing	20+ In Stock
-	25.40 x 25.40	3.00	BBAR (425-700nm)	#46-097	C\$38.50 Volume Pricing	20+ In Stock

[#71-584 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25.40 x 50.80	1.00	BBAR (425-700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$39.90 Volume Pricing	11 In Stock
---	---------------	------	---------------------	--	--	-------------

[#71-585 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	25.40 x 50.80	3.00	BBAR (425-700nm)	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	C\$39.90 Volume Pricing	20+ In Stock
---	---------------	------	---------------------	--	--	--------------

[#71-572 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

30.00

-

1.00

BBAR
(425-700nm)

C\$39.20
[Volume Pricing](#)

3 In Stock

[#71-573 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

30.00

-

3.00

BBAR
(425-700nm)

C\$39.20
[Volume Pricing](#)

20+ In Stock

[#71-574 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

1.00

BBAR
(425-700nm)

C\$38.50
[Volume Pricing](#)

20+ In Stock

[#71-575 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

3.00

BBAR
(425-700nm)

C\$37.80
[Volume Pricing](#)

20+ In Stock

38.10

-

1.00

BBAR
(425-700nm)

[#39-280](#)

C\$38.50
[Volume Pricing](#)

20+ In Stock

38.10

-



2.00

BBAR
(425-700nm)

[#71-592](#)

C\$38.50
[Volume Pricing](#)

20+ In Stock

38.10	-	3.00	BBAR (425-700nm)	#39-284	C\$38.50 Volume Pricing	20+ In Stock
<hr/>						
#71-576 New						
						
New						
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!						
40.00	-	1.00	BBAR (425-700nm)		C\$39.20 Volume Pricing	20+ In Stock
<hr/>						
#71-577 New						
						
New						
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!						
40.00	-	3.00	BBAR (425-700nm)		C\$39.20 Volume Pricing	20+ In Stock
<hr/>						
50.00	-	3.00	BBAR (425-700nm)	#21-326	C\$39.90 Volume Pricing	20+ In Stock
<hr/>						
50.80	-	1.00	BBAR (425-700nm)	#48-926	C\$39.90 Volume Pricing	6 In Stock
<hr/>						

-	50.80 x 50.80	1.00	BBAR (425-700nm)	#48-925	C\$39.90 Volume Pricing	20+ In Stock
50.80	-	2.00	BBAR (425-700nm)	#71-593	C\$39.90 Volume Pricing	Contact Us
-	50.80 x 50.80	2.00	BBAR (425-700nm)	#71-594	C\$38.50 Volume Pricing	20+ In Stock
50.80	-	3.00	BBAR (425-700nm)	#46-100	C\$39.90 Volume Pricing	20+ In Stock
-	50.80 x 50.80	3.00	BBAR (425-700nm)	#46-099	C\$39.90 Volume Pricing	20+ In Stock

[#71-586 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50.80 x 76.20	1.00	BBAR (425-700nm)		C\$49.00 Volume Pricing	20+ In Stock
---	---------------	------	---------------------	--	--	--------------

[#71-587 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	50.80 x 76.20	3.00	BBAR (425-700nm)		C\$49.00 Volume Pricing	20+ In Stock
63.50	-	1.00	BBAR (425-700nm)	#39-281	C\$42.70 Volume Pricing	20+ In Stock
63.50	-	3.00	BBAR (425-700nm)	#39-285	C\$42.70 Volume Pricing	20+ In Stock
75.00	-	3.00	BBAR (425-700nm)	#21-328	C\$49.00 Volume Pricing	8 In Stock
76.20	-	1.00	BBAR (425-700nm)	#48-928	C\$49.00 Volume Pricing	20+ In Stock
-	76.20 x 76.20	1.00	BBAR (425-700nm)	#48-927	C\$49.00 Volume Pricing	20+ In Stock
76.20	-	2.00	BBAR (425-700nm)	#71-595	C\$49.00 Volume Pricing	20+ In Stock
-	76.20 x 76.20	2.00	BBAR (425-700nm)	#71-596	C\$49.00 Volume Pricing	20+ In Stock
76.20	-	3.00	BBAR (425-700nm)	#46-102	C\$49.00 Volume Pricing	20+ In Stock

-	76.20 x 76.20	3.00	BBAR (425-700nm)	#46-101	C\$49.00 Volume Pricing	20+ In Stock
88.90	-	1.00	BBAR (425-700nm)	#39-282	C\$56.70 Volume Pricing	20+ In Stock
88.90	-	3.00	BBAR (425-700nm)	#39-286	C\$56.70 Volume Pricing	20+ In Stock
101.60	-	1.00	BBAR (425-700nm)	#48-930	C\$64.40 Volume Pricing	20+ In Stock
-	101.60 x 101.60	1.00	BBAR (425-700nm)	#48-929	C\$64.40 Volume Pricing	20+ In Stock
101.60	-	2.00	BBAR (425-700nm)	#71-597	C\$64.40 Volume Pricing	13 In Stock
-	101.60 x 101.60	2.00	BBAR (425-700nm)	#71-598	C\$64.40 Volume Pricing	10 In Stock
101.60	-	3.00	BBAR (425-700nm)	#46-104	C\$64.40 Volume Pricing	20+ In Stock
-	101.60 x 101.60	3.00	BBAR (425-700nm)	#46-103	C\$64.40 Volume Pricing	Contact Us
-	101.60 x 127.00	3.00	BBAR (425-700nm)	#21-329	C\$69.30 Volume Pricing	20+ In Stock
127.00	-	1.00	BBAR (425-700nm)	#63-216	C\$82.60 Volume Pricing	20+ In Stock
-	127.00 x 177.80	1.00	BBAR (425-700nm)	#63-217	C\$82.60 Volume Pricing	20+ In Stock
127.00	-	2.00	BBAR (425-700nm)	#71-599	C\$82.60 Volume Pricing	20+ In Stock
-	127.00 x 177.80	2.00	BBAR (425-700nm)	#71-600	C\$82.60 Volume Pricing	Contact Us

127.00	-	3.00	BBAR (425-700nm)	#48-858	C\$82.60 Volume Pricing	20+ In Stock
--------	---	------	---------------------	-------------------------	--	--------------

-	127.00 x 177.80	3.00	BBAR (425-700nm)	#43-973	C\$82.60 Volume Pricing	20+ In Stock
---	--------------------	------	---------------------	-------------------------	--	--------------

[#71-578 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

152.00	-	1.00	BBAR (425-700nm)		C\$87.50 Volume Pricing	20+ In Stock
--------	---	------	---------------------	--	--	--------------

[#71-579 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

152.00	-	3.00	BBAR (425-700nm)		C\$87.50 Volume Pricing	9 In Stock
--------	---	------	---------------------	--	--	------------

[#71-580 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

177.00

-

1.00

BBAR
(425-700nm)

C\$91.00
[Volume Pricing](#)

20+ In Stock

[#71-581 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

177.00

-

3.00

BBAR
(425-700nm)

C\$91.00
[Volume Pricing](#)

20+ In Stock

203.20

-

1.00

BBAR
(425-700nm)

[#63-218](#)

C\$100.80
[Volume Pricing](#)

5 In Stock

-

203.20 x
203.20

3.00

BBAR
(425-700nm)

[#21-330](#)

C\$100.80
[Volume Pricing](#)

12 In Stock

-	203.20 x 254.00	1.00	BBAR (425- 700nm)	#63-219	C\$100.80 Volume Pricing	20+ In Stock
203.20	-	3.00	BBAR (425- 700nm)	#48-859	C\$100.80 Volume Pricing	Contact Us
-	203.20 x 254.00	3.00	BBAR (425- 700nm)	#43-974	C\$100.80 Volume Pricing	20+ In Stock
254.00	-	1.00	BBAR (425- 700nm)	#63-220	C\$147.00 Volume Pricing	11 In Stock
-	254.00 x 254.00	3.00	BBAR (425- 700nm)	#21-331	C\$147.00 Volume Pricing	6 In Stock
-	254.00 x 304.80	1.00	BBAR (425- 700nm)	#63-221	C\$147.00 Volume Pricing	14 In Stock
254.00	-	3.00	BBAR (425- 700nm)	#48-860	C\$147.00 Volume Pricing	20+ In Stock
-	254.00 x 304.80	3.00	BBAR (425- 700nm)	#43-975	C\$147.00 Volume Pricing	20+ In Stock
-	304.80 x 304.80	3.00	BBAR (425- 700nm)	#21-332	C\$176.40 Volume Pricing	14 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
Phone: 1-800-363-1992 :
www.edmundoptics.com