


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Double-Convex \(DCX\) Lenses](#)

TECHSPEC® UV Fused Silica Double-Convex (DCX) Lenses

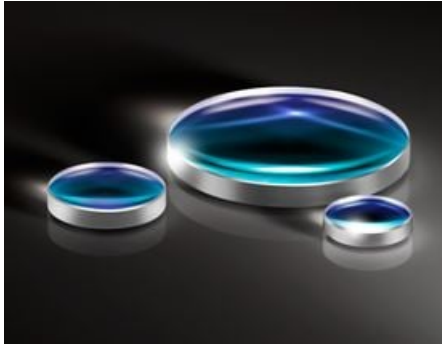

- Ideal for Imaging Applications
- Minimize Aberrations Including Spherical and Coma
- Precision Fused Silica Substrate

Common Specifications

Physical & Mechanical Properties


Bevel: Protective as needed

Optical Properties


Substrate: [Fused Silica](#) (Corning 7980)

Surface Quality:	40-20	Power (P-V) @ 632.8nm:	1.5λ
Irregularity (P-V) @ 632.8nm:	λ/4	Focal Length Specification Wavelength (nm):	587.6
Focal Length Tolerance (%):	±1		


Technical Information

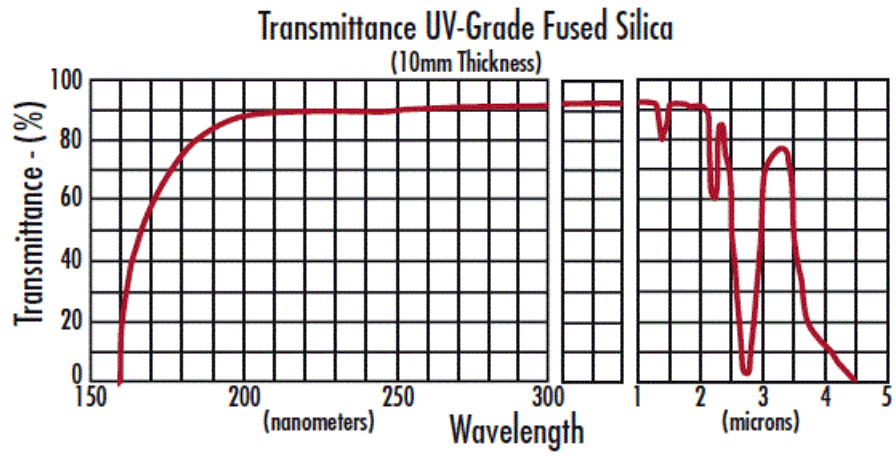


UV FS Transmission Curve

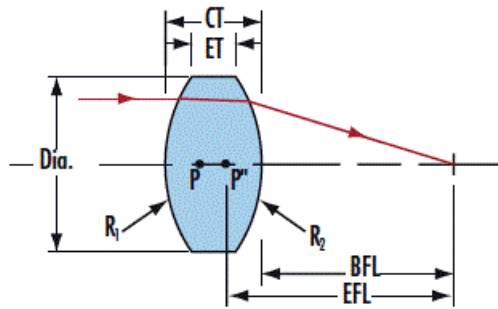

Standard Visible Anti-Reflection Coatings

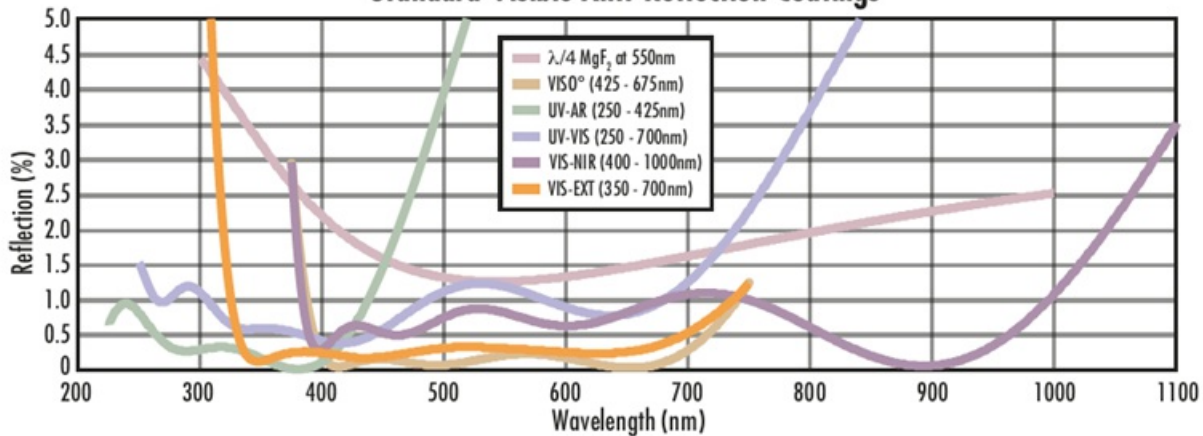

Standard Near Infrared Anti-Reflection Coatings

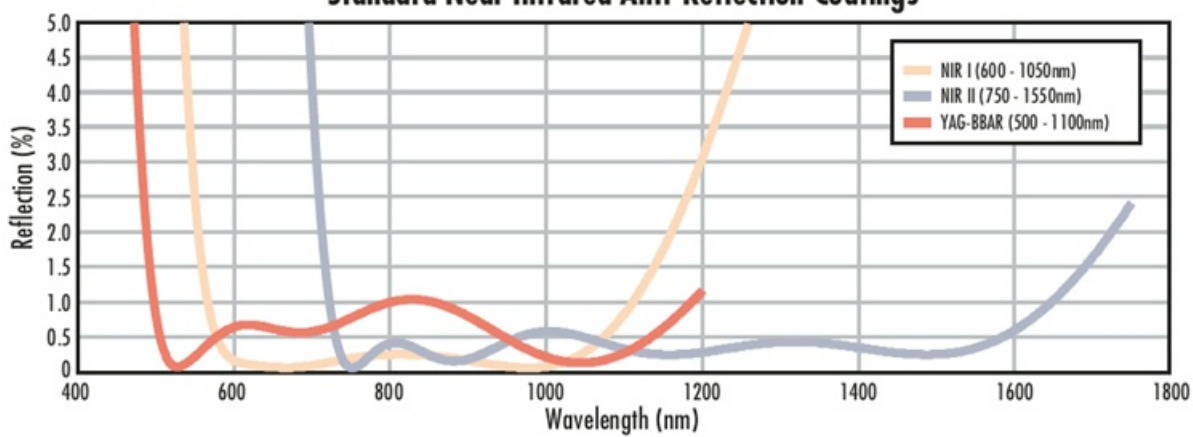

Products

Dia. (mm)	BFL (mm)	EFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	4.38	6.00	Uncoated	Fused Silica	#49-238	C\$176.40 Volume Pricing	20+ In Stock
6.00	4.38	6.00	UV-AR (250-425nm)	Fused Silica	#49-246	C\$207.20 Volume Pricing	20+ In Stock
6.00	4.38	6.00	UV-VIS (250-700nm)	Fused Silica	#49-254	C\$207.20 Volume Pricing	16 In Stock
6.00	4.38	6.00	VIS-EXT (350-700nm)	Fused Silica	#22-196	C\$207.20 Volume Pricing	8 In Stock
6.00	4.38	6.00	VIS 0° (425-675nm)	Fused Silica	#49-262	C\$204.40 Volume Pricing	Contact Us
6.00	4.38	6.00	VIS-NIR (400-1000nm)	Fused Silica	#63-817	C\$207.20 Volume Pricing	13 In Stock
6.00	4.38	6.00	NIR I (600-1050nm)	Fused Silica	#22-156	C\$204.40 Volume Pricing	7 In Stock
6.00	4.38	6.00	NIR II (750-1550nm)	Fused Silica	#22-176	C\$204.40 Volume Pricing	2 In Stock
6.00	8.02	9.00	Uncoated	Fused Silica	#49-239	C\$176.40 Volume Pricing	20+ In Stock
6.00	8.02	9.00	UV-AR (250-425nm)	Fused Silica	#49-247	C\$207.20 Volume Pricing	7 In Stock
6.00	8.02	9.00	UV-VIS (250-700nm)	Fused Silica	#49-255	C\$207.20 Volume Pricing	20+ In Stock
6.00	8.02	9.00	VIS 0° (425-675nm)	Fused Silica	#49-263	C\$204.40 Volume Pricing	20+ In Stock
6.00	8.02	9.00	VIS-NIR (400-1000nm)	Fused Silica	#63-818	C\$207.20 Volume Pricing	12 In Stock
6.00	11.23	12.00	Uncoated	Fused Silica	#49-240	C\$176.40 Volume Pricing	20+ In Stock

6.00	11.23	12.00	UV-AR (250-425nm)	Fused Silica	#49-248	C\$207.20 Volume Pricing	1 In Stock
6.00	11.23	12.00	UV-VIS (250-700nm)	Fused Silica	#49-256	C\$207.20 Volume Pricing	5 In Stock
6.00	11.23	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-195	C\$207.20 Volume Pricing	3 In Stock
6.00	11.23	12.00	VIS 0° (425-675nm)	Fused Silica	#49-264	C\$204.40 Volume Pricing	12 In Stock
6.00	11.23	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-819	C\$207.20 Volume Pricing	20+ In Stock
6.00	11.23	12.00	NIR I (600-1050nm)	Fused Silica	#22-155	C\$204.40 Volume Pricing	5 In Stock
6.00	11.23	12.00	NIR II (750-1550nm)	Fused Silica	#22-175	C\$204.40 Volume Pricing	2 In Stock
6.00	17.30	18.00	Uncoated	Fused Silica	#49-983	C\$169.40 Volume Pricing	20+ In Stock
6.00	17.30	18.00	UV-AR (250-425nm)	Fused Silica	#49-987	C\$200.20 Volume Pricing	5 In Stock
6.00	17.30	18.00	UV-VIS (250-700nm)	Fused Silica	#49-991	C\$200.20 Volume Pricing	8 In Stock
6.00	17.30	18.00	VIS 0° (425-675nm)	Fused Silica	#49-995	C\$197.40 Volume Pricing	5 In Stock
6.00	17.30	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-820	C\$200.20 Volume Pricing	16 In Stock
6.00	23.31	24.00	Uncoated	Fused Silica	#49-984	C\$169.40 Volume Pricing	20+ In Stock
6.00	23.31	24.00	UV-AR (250-425nm)	Fused Silica	#49-988	C\$200.20 Volume Pricing	4 In Stock
6.00	23.31	24.00	UV-VIS (250-700nm)	Fused Silica	#49-992	C\$200.20 Volume Pricing	Contact Us
6.00	23.31	24.00	VIS 0° (425-675nm)	Fused Silica	#49-996	C\$197.40 Volume Pricing	13 In Stock

6.00	23.31	24.00	VIS-NIR (400- 1000nm)	Fused Silica	#63-821	C\$200.20 Volume Pricing	20+ In Stock
9.00	7.12	9.00	Uncoated	Fused Silica	#49-241	C\$180.60 Volume Pricing	20+ In Stock
9.00	7.12	9.00	UV-AR (250- 425nm)	Fused Silica	#49-249	C\$212.80 Volume Pricing	20+ In Stock
9.00	7.12	9.00	UV-VIS (250- 700nm)	Fused Silica	#49-257	C\$212.80 Volume Pricing	13 In Stock
9.00	7.12	9.00	VIS-EXT (350- 700nm)	Fused Silica	#22-200	C\$212.80 Volume Pricing	4 In Stock
9.00	7.12	9.00	VIS 0° (425- 675nm)	Fused Silica	#49-265	C\$208.60 Volume Pricing	5 In Stock
9.00	7.12	9.00	VIS-NIR (400- 1000nm)	Fused Silica	#63-822	C\$212.80 Volume Pricing	7 In Stock
9.00	7.12	9.00	NIR I (600- 1050nm)	Fused Silica	#22-160	C\$208.60 Volume Pricing	2 In Stock
9.00	7.12	9.00	NIR II (750- 1550nm)	Fused Silica	#22-180	C\$208.60 Volume Pricing	4 In Stock
9.00	12.32	13.50	Uncoated	Fused Silica	#49-242	C\$180.60 Volume Pricing	20+ In Stock
9.00	12.32	13.50	UV-AR (250- 425nm)	Fused Silica	#49-250	C\$212.80 Volume Pricing	4 In Stock
9.00	12.32	13.50	UV-VIS (250- 700nm)	Fused Silica	#49-258	C\$212.80 Volume Pricing	1 In Stock
9.00	12.32	13.50	VIS-EXT (350- 700nm)	Fused Silica	#22-197	C\$212.80 Volume Pricing	1 In Stock
9.00	12.32	13.50	VIS 0° (425- 675nm)	Fused Silica	#49-266	C\$208.60 Volume Pricing	5 In Stock
9.00	12.32	13.50	VIS-NIR (400- 1000nm)	Fused Silica	#63-823	C\$212.80 Volume Pricing	20+ In Stock
9.00	12.32	13.50	NIR I (600- 1050nm)	Fused Silica	#22-157	C\$208.60 Volume Pricing	4 In Stock

9.00	12.32	13.50	NIR II (750-1550nm)	Fused Silica	#22-177	C\$208.60 Volume Pricing	5 In Stock
9.00	17.09	18.00	Uncoated	Fused Silica	#49-243	C\$180.60 Volume Pricing	20+ In Stock
9.00	17.09	18.00	UV-AR (250-425nm)	Fused Silica	#49-251	C\$212.80 Volume Pricing	20+ In Stock
9.00	17.09	18.00	UV-VIS (250-700nm)	Fused Silica	#49-259	C\$212.80 Volume Pricing	Contact Us
9.00	17.09	18.00	VIS-EXT (350-700nm)	Fused Silica	#22-198	C\$212.80 Volume Pricing	4 In Stock
9.00	17.09	18.00	VIS 0° (425-675nm)	Fused Silica	#49-267	C\$208.60 Volume Pricing	Contact Us
9.00	17.09	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-824	C\$212.80 Volume Pricing	Contact Us
9.00	17.09	18.00	NIR I (600-1050nm)	Fused Silica	#22-158	C\$208.60 Volume Pricing	5 In Stock
9.00	17.09	18.00	NIR II (750-1550nm)	Fused Silica	#22-178	C\$208.60 Volume Pricing	4 In Stock
9.00	26.13	27.00	Uncoated	Fused Silica	#49-985	C\$173.60 Volume Pricing	20+ In Stock
9.00	26.13	27.00	UV-AR (250-425nm)	Fused Silica	#49-989	C\$204.40 Volume Pricing	3 In Stock
9.00	26.13	27.00	UV-VIS (250-700nm)	Fused Silica	#49-993	C\$204.40 Volume Pricing	14 In Stock
9.00	26.13	27.00	VIS-EXT (350-700nm)	Fused Silica	#22-199	C\$204.40 Volume Pricing	5 In Stock
9.00	26.13	27.00	VIS 0° (425-675nm)	Fused Silica	#49-997	C\$200.20 Volume Pricing	7 In Stock
9.00	26.13	27.00	VIS-NIR (400-1000nm)	Fused Silica	#63-825	C\$204.40 Volume Pricing	20+ In Stock
9.00	26.13	27.00	NIR I (600-1050nm)	Fused Silica	#22-159	C\$200.20 Volume Pricing	5 In Stock

9.00	26.13	27.00	NIR II (750-1550nm)	Fused Silica	#22-179	C\$200.20 Volume Pricing	5 In Stock
9.00	35.31	36.00	Uncoated	Fused Silica	#49-986	C\$173.60 Volume Pricing	20+ In Stock
9.00	35.31	36.00	UV-AR (250-425nm)	Fused Silica	#49-990	C\$204.40 Volume Pricing	1 In Stock
9.00	35.31	36.00	UV-VIS (250-700nm)	Fused Silica	#49-994	C\$204.40 Volume Pricing	20+ In Stock
9.00	35.31	36.00	VIS 0° (425-675nm)	Fused Silica	#49-998	C\$200.20 Volume Pricing	8 In Stock
9.00	35.31	36.00	VIS-NIR (400-1000nm)	Fused Silica	#63-826	C\$204.40 Volume Pricing	20+ In Stock
12.00	9.25	12.00	Uncoated	Fused Silica	#48-034	C\$180.60 Volume Pricing	20+ In Stock
12.00	9.25	12.00	UV-AR (250-425nm)	Fused Silica	#48-040	C\$217.00 Volume Pricing	14 In Stock
12.00	9.25	12.00	UV-VIS (250-700nm)	Fused Silica	#48-834	C\$217.00 Volume Pricing	7 In Stock
12.00	9.25	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-203	C\$217.00 Volume Pricing	2 In Stock
12.00	9.25	12.00	VIS 0° (425-675nm)	Fused Silica	#48-974	C\$211.40 Volume Pricing	9 In Stock
12.00	9.25	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-827	C\$217.00 Volume Pricing	20+ In Stock
12.00	9.25	12.00	NIR I (600-1050nm)	Fused Silica	#22-163	C\$211.40 Volume Pricing	3 In Stock
12.00	9.25	12.00	NIR II (750-1550nm)	Fused Silica	#22-183	C\$211.40 Volume Pricing	7 In Stock
12.00	13.37	15.00	Uncoated	Fused Silica	#49-244	C\$180.60 Volume Pricing	20+ In Stock
12.00	13.37	15.00	UV-AR (250-425nm)	Fused Silica	#49-252	C\$217.00 Volume Pricing	5 In Stock

12.00	13.37	15.00	UV-VIS (250-700nm)	Fused Silica	#49-260	C\$217.00 Volume Pricing	7 In Stock
12.00	13.37	15.00	VIS-EXT (350-700nm)	Fused Silica	#22-204	C\$217.00 Volume Pricing	14 In Stock
12.00	13.37	15.00	VIS 0° (425-675nm)	Fused Silica	#49-268	C\$211.40 Volume Pricing	2 In Stock
12.00	13.37	15.00	VIS-NIR (400-1000nm)	Fused Silica	#63-828	C\$217.00 Volume Pricing	20+ In Stock
12.00	13.37	15.00	NIR I (600-1050nm)	Fused Silica	#22-164	C\$211.40 Volume Pricing	3 In Stock
12.00	13.37	15.00	NIR II (750-1550nm)	Fused Silica	#22-184	C\$211.40 Volume Pricing	5 In Stock
12.00	18.44	20.00	Uncoated	Fused Silica	#48-035	C\$180.60 Volume Pricing	13 In Stock
12.00	18.44	20.00	UV-AR (250-425nm)	Fused Silica	#48-041	C\$217.00 Volume Pricing	Contact Us
12.00	18.44	20.00	UV-VIS (250-700nm)	Fused Silica	#48-835	C\$217.00 Volume Pricing	Contact Us
12.00	18.44	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-205	C\$217.00 Volume Pricing	5 In Stock
12.00	18.44	20.00	VIS 0° (425-675nm)	Fused Silica	#48-975	C\$211.40 Volume Pricing	15 In Stock
12.00	18.44	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-829	C\$217.00 Volume Pricing	20+ In Stock
12.00	18.44	20.00	NIR I (600-1050nm)	Fused Silica	#22-165	C\$211.40 Volume Pricing	5 In Stock
12.00	18.44	20.00	NIR II (750-1550nm)	Fused Silica	#22-185	C\$211.40 Volume Pricing	5 In Stock
12.00	22.92	24.00	Uncoated	Fused Silica	#49-245	C\$180.60 Volume Pricing	20+ In Stock
12.00	22.92	24.00	UV-AR (250-425nm)	Fused Silica	#49-253	C\$217.00 Volume Pricing	2 In Stock

12.00	22.92	24.00	UV-VIS (250-700nm)	Fused Silica	#49-261	C\$217.00 Volume Pricing	Contact Us
12.00	22.92	24.00	VIS-EXT (350-700nm)	Fused Silica	#22-206	C\$217.00 Volume Pricing	5 In Stock
12.00	22.92	24.00	VIS 0° (425-675nm)	Fused Silica	#49-269	C\$211.40 Volume Pricing	5 In Stock
12.00	22.92	24.00	VIS-NIR (400-1000nm)	Fused Silica	#63-830	C\$217.00 Volume Pricing	20+ In Stock
12.00	22.92	24.00	NIR I (600-1050nm)	Fused Silica	#22-166	C\$211.40 Volume Pricing	4 In Stock
12.00	22.92	24.00	NIR II (750-1550nm)	Fused Silica	#22-186	C\$211.40 Volume Pricing	5 In Stock
12.00	28.77	30.00	Uncoated	Fused Silica	#48-036	C\$172.20 Volume Pricing	20+ In Stock
12.00	28.77	30.00	UV-AR (250-425nm)	Fused Silica	#48-042	C\$207.20 Volume Pricing	2 In Stock
12.00	28.77	30.00	UV-VIS (250-700nm)	Fused Silica	#48-836	C\$207.20 Volume Pricing	6 In Stock
12.00	28.77	30.00	VIS-EXT (350-700nm)	Fused Silica	#22-201	C\$207.20 Volume Pricing	4 In Stock
12.00	28.77	30.00	VIS 0° (425-675nm)	Fused Silica	#48-976	C\$203.00 Volume Pricing	8 In Stock
12.00	28.77	30.00	VIS-NIR (400-1000nm)	Fused Silica	#63-831	C\$207.20 Volume Pricing	12 In Stock
12.00	28.77	30.00	NIR I (600-1050nm)	Fused Silica	#22-161	C\$203.00 Volume Pricing	4 In Stock
12.00	28.77	30.00	NIR II (750-1550nm)	Fused Silica	#22-181	C\$203.00 Volume Pricing	5 In Stock
12.00	33.85	35.00	Uncoated	Fused Silica	#48-037	C\$172.20 Volume Pricing	20+ In Stock
12.00	33.85	35.00	UV-AR (250-425nm)	Fused Silica	#48-043	C\$207.20 Volume Pricing	Contact Us

12.00	33.85	35.00	UV-VIS (250-700nm)	Fused Silica	#48-837	C\$207.20 Volume Pricing	Contact Us
12.00	33.85	35.00	VIS-EXT (350-700nm)	Fused Silica	#22-202	C\$207.20 Volume Pricing	1 In Stock
12.00	33.85	35.00	VIS 0° (425-675nm)	Fused Silica	#48-977	C\$203.00 Volume Pricing	9 In Stock
12.00	33.85	35.00	VIS-NIR (400-1000nm)	Fused Silica	#63-832	C\$207.20 Volume Pricing	14 In Stock
12.00	33.85	35.00	NIR I (600-1050nm)	Fused Silica	#22-162	C\$203.00 Volume Pricing	3 In Stock
12.00	33.85	35.00	NIR II (750-1550nm)	Fused Silica	#22-182	C\$203.00 Volume Pricing	4 In Stock
12.00	43.96	45.00	Uncoated	Fused Silica	#48-038	C\$172.20 Volume Pricing	20+ In Stock
12.00	43.96	45.00	UV-AR (250-425nm)	Fused Silica	#48-044	C\$207.20 Volume Pricing	1 In Stock
12.00	43.96	45.00	UV-VIS (250-700nm)	Fused Silica	#48-838	C\$207.20 Volume Pricing	Contact Us
12.00	43.96	45.00	VIS 0° (425-675nm)	Fused Silica	#48-978	C\$203.00 Volume Pricing	Contact Us
12.00	43.96	45.00	VIS-NIR (400-1000nm)	Fused Silica	#63-833	C\$207.20 Volume Pricing	20+ In Stock
12.00	74.11	75.00	Uncoated	Fused Silica	#48-039	C\$172.20 Volume Pricing	7 In Stock
12.00	74.11	75.00	UV-VIS (250-700nm)	Fused Silica	#48-839	C\$207.20 Volume Pricing	12 In Stock
12.00	74.11	75.00	UV-AR (250-425nm)	Fused Silica	#48-045	C\$207.20 Volume Pricing	4 In Stock
12.00	74.11	75.00	VIS-EXT (350-700nm)	Fused Silica	#22-207	C\$207.20 Volume Pricing	2 In Stock
12.00	74.11	75.00	VIS 0° (425-675nm)	Fused Silica	#48-979	C\$203.00 Volume Pricing	15 In Stock

12.00	74.11	75.00	VIS-NIR (400-1000nm)	Fused Silica	#63-834	C\$207.20 Volume Pricing	16 In Stock
12.00	74.11	75.00	NIR I (600-1050nm)	Fused Silica	#22-167	C\$203.00 Volume Pricing	5 In Stock
12.00	74.11	75.00	NIR II (750-1550nm)	Fused Silica	#22-187	C\$203.00 Volume Pricing	4 In Stock
18.00	17.18	20.00	Uncoated	Fused Silica	#08-083	C\$193.20 Volume Pricing	Contact Us
18.00	17.18	20.00	UV-AR (250-425nm)	Fused Silica	#46-290	C\$226.80 Volume Pricing	20+ In Stock
18.00	17.18	20.00	UV-VIS (250-700nm)	Fused Silica	#48-840	C\$226.80 Volume Pricing	1 In Stock
18.00	17.18	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-208	C\$226.80 Volume Pricing	4 In Stock
18.00	17.18	20.00	VIS 0° (425-675nm)	Fused Silica	#48-980	C\$224.00 Volume Pricing	14 In Stock
18.00	17.18	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-835	C\$226.80 Volume Pricing	7 In Stock
18.00	17.18	20.00	NIR I (600-1050nm)	Fused Silica	#22-168	C\$224.00 Volume Pricing	3 In Stock
18.00	17.18	20.00	NIR II (750-1550nm)	Fused Silica	#22-188	C\$224.00 Volume Pricing	5 In Stock
18.00	38.50	40.00	Uncoated	Fused Silica	#08-084	C\$193.20 Volume Pricing	20+ In Stock
18.00	38.50	40.00	UV-AR (250-425nm)	Fused Silica	#46-291	C\$226.80 Volume Pricing	3 In Stock
18.00	38.50	40.00	UV-VIS (250-700nm)	Fused Silica	#48-841	C\$226.80 Volume Pricing	Contact Us
18.00	38.50	40.00	VIS-EXT (350-700nm)	Fused Silica	#22-209	C\$226.80 Volume Pricing	5 In Stock
18.00	38.50	40.00	VIS 0° (425-675nm)	Fused Silica	#48-981	C\$224.00 Volume Pricing	8 In Stock

18.00	38.50	40.00	VIS-NIR (400-1000nm)	Fused Silica	#63-836	C\$226.80 Volume Pricing	1 In Stock
18.00	38.50	40.00	NIR I (600-1050nm)	Fused Silica	#22-169	C\$224.00 Volume Pricing	5 In Stock
18.00	38.50	40.00	NIR II (750-1550nm)	Fused Silica	#22-189	C\$224.00 Volume Pricing	5 In Stock
25.00	20.93	25.00	Uncoated	Fused Silica	#48-293	C\$203.00 Volume Pricing	20+ In Stock
25.00	20.93	25.00	UV-AR (250-425nm)	Fused Silica	#48-304	C\$238.00 Volume Pricing	20+ In Stock
25.00	20.93	25.00	UV-VIS (250-700nm)	Fused Silica	#48-842	C\$238.00 Volume Pricing	15 In Stock
25.00	20.93	25.00	VIS-EXT (350-700nm)	Fused Silica	#22-212	C\$238.00 Volume Pricing	3 In Stock
25.00	20.93	25.00	VIS 0° (425-675nm)	Fused Silica	#48-982	C\$235.20 Volume Pricing	12 In Stock
25.00	20.93	25.00	VIS-NIR (400-1000nm)	Fused Silica	#63-837	C\$238.00 Volume Pricing	8 In Stock
25.00	20.93	25.00	NIR I (600-1050nm)	Fused Silica	#22-172	C\$235.20 Volume Pricing	9 In Stock
25.00	20.93	25.00	NIR II (750-1550nm)	Fused Silica	#22-192	C\$235.20 Volume Pricing	14 In Stock
25.00	48.02	50.00	Uncoated	Fused Silica	#48-294	C\$203.00 Volume Pricing	20+ In Stock
25.00	48.02	50.00	UV-AR (250-425nm)	Fused Silica	#48-305	C\$238.00 Volume Pricing	20+ In Stock
25.00	48.02	50.00	UV-VIS (250-700nm)	Fused Silica	#48-843	C\$238.00 Volume Pricing	7 In Stock
25.00	48.02	50.00	VIS-EXT (350-700nm)	Fused Silica	#22-213	C\$238.00 Volume Pricing	5 In Stock
25.00	48.02	50.00	VIS 0° (425-675nm)	Fused Silica	#48-983	C\$235.20 Volume Pricing	16 In Stock

25.00	48.02	50.00	VIS-NIR (400-1000nm)	Fused Silica	#63-838	C\$238.00 Volume Pricing	7 In Stock
25.00	48.02	50.00	NIR I (600-1050nm)	Fused Silica	#22-173	C\$235.20 Volume Pricing	5 In Stock
25.00	48.02	50.00	NIR II (750-1550nm)	Fused Silica	#22-193	C\$235.20 Volume Pricing	1 In Stock
25.00	58.08	60.00	Uncoated	Fused Silica	#48-295	C\$196.00 Volume Pricing	Contact Us
25.00	58.08	60.00	UV-AR (250-425nm)	Fused Silica	#48-306	C\$231.00 Volume Pricing	14 In Stock
25.00	58.08	60.00	UV-VIS (250-700nm)	Fused Silica	#48-844	C\$231.00 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS-EXT (350-700nm)	Fused Silica	#22-214	C\$229.60 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS 0° (425-675nm)	Fused Silica	#48-984	C\$226.80 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS-NIR (400-1000nm)	Fused Silica	#63-839	C\$231.00 Volume Pricing	12 In Stock
25.00	58.08	60.00	NIR I (600-1050nm)	Fused Silica	#22-174	C\$226.80 Volume Pricing	4 In Stock
25.00	58.08	60.00	NIR II (750-1550nm)	Fused Silica	#22-194	C\$226.80 Volume Pricing	4 In Stock
25.00	73.91	75.60	Uncoated	Fused Silica	#48-296	C\$196.00 Volume Pricing	20+ In Stock
25.00	73.91	75.60	UV-AR (250-425nm)	Fused Silica	#48-307	C\$231.00 Volume Pricing	6 In Stock
25.00	73.91	75.60	UV-VIS (250-700nm)	Fused Silica	#48-845	C\$231.00 Volume Pricing	2 In Stock
25.00	73.91	75.60	VIS-EXT (350-700nm)	Fused Silica	#22-210	C\$231.00 Volume Pricing	3 In Stock
25.00	73.91	75.60	VIS 0° (425-675nm)	Fused Silica	#48-985	C\$226.80 Volume Pricing	11 In Stock

25.00	73.91	75.60	VIS-NIR (400-1000nm)	Fused Silica	#63-840	C\$231.00 Volume Pricing	8 In Stock
25.00	73.91	75.60	NIR I (600-1050nm)	Fused Silica	#22-170	C\$226.80 Volume Pricing	5 In Stock
25.00	73.91	75.60	NIR II (750-1550nm)	Fused Silica	#22-190	C\$226.80 Volume Pricing	Contact Us
25.00	98.70	100.00	Uncoated	Fused Silica	#48-297	C\$196.00 Volume Pricing	15 In Stock
25.00	98.70	100.00	UV-AR (250-425nm)	Fused Silica	#48-308	C\$231.00 Volume Pricing	13 In Stock
25.00	98.70	100.00	UV-VIS (250-700nm)	Fused Silica	#48-846	C\$231.00 Volume Pricing	11 In Stock
25.00	98.70	100.00	VIS-EXT (350-700nm)	Fused Silica	#22-211	C\$231.00 Volume Pricing	8 In Stock
25.00	98.70	100.00	VIS 0° (425-675nm)	Fused Silica	#48-986	C\$226.80 Volume Pricing	7 In Stock
25.00	98.70	100.00	VIS-NIR (400-1000nm)	Fused Silica	#63-841	C\$231.00 Volume Pricing	2 In Stock
25.00	98.70	100.00	NIR I (600-1050nm)	Fused Silica	#22-171	C\$226.80 Volume Pricing	4 In Stock
25.00	98.70	100.00	NIR II (750-1550nm)	Fused Silica	#22-191	C\$226.80 Volume Pricing	3 In Stock
25.00	123.82	125.00	Uncoated	Fused Silica	#48-298	C\$186.20 Volume Pricing	20+ In Stock
25.00	123.82	125.00	UV-AR (250-425nm)	Fused Silica	#48-309	C\$222.60 Volume Pricing	2 In Stock
25.00	123.82	125.00	UV-VIS (250-700nm)	Fused Silica	#48-847	C\$222.60 Volume Pricing	10 In Stock
25.00	123.82	125.00	VIS 0° (425-675nm)	Fused Silica	#48-987	C\$218.40 Volume Pricing	14 In Stock
25.00	123.82	125.00	VIS-NIR (400-1000nm)	Fused Silica	#63-842	C\$222.60 Volume Pricing	5 In Stock

25.00	148.37	150.00	Uncoated	Fused Silica	#48-299	C\$186.20 Volume Pricing	20+ In Stock
25.00	148.37	150.00	UV-AR (250-425nm)	Fused Silica	#48-310	C\$222.60 Volume Pricing	16 In Stock
25.00	148.37	150.00	UV-VIS (250-700nm)	Fused Silica	#48-848	C\$222.60 Volume Pricing	2 In Stock
25.00	148.37	150.00	VIS 0° (425-675nm)	Fused Silica	#48-988	C\$218.40 Volume Pricing	7 In Stock
25.00	148.37	150.00	VIS-NIR (400-1000nm)	Fused Silica	#63-843	C\$222.60 Volume Pricing	4 In Stock
25.00	198.84	200.00	Uncoated	Fused Silica	#48-300	C\$186.20 Volume Pricing	5 In Stock
25.00	198.84	200.00	UV-AR (250-425nm)	Fused Silica	#48-311	C\$222.60 Volume Pricing	20+ In Stock
25.00	198.84	200.00	UV-VIS (250-700nm)	Fused Silica	#48-849	C\$222.60 Volume Pricing	Contact Us
25.00	198.84	200.00	VIS 0° (425-675nm)	Fused Silica	#48-989	C\$218.40 Volume Pricing	20+ In Stock
25.00	198.84	200.00	VIS-NIR (400-1000nm)	Fused Silica	#63-844	C\$222.60 Volume Pricing	1 In Stock
25.00	248.90	250.00	Uncoated	Fused Silica	#48-301	C\$186.20 Volume Pricing	20+ In Stock
25.00	248.90	250.00	UV-AR (250-425nm)	Fused Silica	#48-312	C\$222.60 Volume Pricing	6 In Stock
25.00	248.90	250.00	UV-VIS (250-700nm)	Fused Silica	#48-850	C\$222.60 Volume Pricing	Contact Us
25.00	248.90	250.00	VIS 0° (425-675nm)	Fused Silica	#48-990	C\$218.40 Volume Pricing	5 In Stock
25.00	248.90	250.00	VIS-NIR (400-1000nm)	Fused Silica	#63-845	C\$222.60 Volume Pricing	5 In Stock
25.00	298.94	300.00	Uncoated	Fused Silica	#48-302	C\$186.20 Volume Pricing	20+ In Stock

25.00	298.94	300.00	UV-AR (250-425nm)	Fused Silica	#48-313	C\$222.60 Volume Pricing	14 In Stock
25.00	298.94	300.00	UV-VIS (250-700nm)	Fused Silica	#48-851	C\$222.60 Volume Pricing	6 In Stock
25.00	298.94	300.00	VIS 0° (425-675nm)	Fused Silica	#48-991	C\$218.40 Volume Pricing	20+ In Stock
25.00	298.94	300.00	VIS-NIR (400-1000nm)	Fused Silica	#63-846	C\$222.60 Volume Pricing	4 In Stock
25.00	498.85	500.00	Uncoated	Fused Silica	#48-303	C\$186.20 Volume Pricing	11 In Stock
25.00	498.85	500.00	UV-AR (250-425nm)	Fused Silica	#48-314	C\$222.60 Volume Pricing	20+ In Stock
25.00	498.85	500.00	UV-VIS (250-700nm)	Fused Silica	#48-852	C\$222.60 Volume Pricing	7 In Stock
25.00	498.85	500.00	VIS 0° (425-675nm)	Fused Silica	#48-992	C\$218.40 Volume Pricing	6 In Stock
25.00	498.85	500.00	VIS-NIR (400-1000nm)	Fused Silica	#63-847	C\$222.60 Volume Pricing	3 In Stock
30.00	25.12	30.00	Uncoated	Fused Silica	#22-413	C\$233.80 Volume Pricing	5 In Stock
30.00	25.12	30.00	UV-AR (250-425nm)	Fused Silica	#26-600	C\$278.60 Volume Pricing	2 In Stock
30.00	25.12	30.00	UV-VIS (250-700nm)	Fused Silica	#26-606	C\$271.60 Volume Pricing	1 In Stock
30.00	25.12	30.00	VIS 0° (425-675nm)	Fused Silica	#26-612	C\$278.60 Volume Pricing	2 In Stock
30.00	25.12	30.00	VIS-NIR (400-1000nm)	Fused Silica	#26-618	C\$278.60 Volume Pricing	5 In Stock
40.00	33.49	40.00	Uncoated	Fused Silica	#22-420	C\$260.40 Volume Pricing	Contact Us

40.00	33.49	40.00	UV-AR (250-425nm)	Fused Silica	#26-601	C\$310.80 Volume Pricing	1 In Stock
40.00	33.49	40.00	UV-VIS (250-700nm)	Fused Silica	#26-607	C\$302.40 Volume Pricing	2 In Stock
40.00	33.49	40.00	VIS 0° (425-675nm)	Fused Silica	#26-613	C\$309.40 Volume Pricing	5 In Stock
40.00	33.49	40.00	VIS-NIR (400-1000nm)	Fused Silica	#26-619	C\$310.80 Volume Pricing	5 In Stock
50.00	41.87	50.00	Uncoated	Fused Silica	#22-426	C\$441.00 Volume Pricing	20+ In Stock
50.00	41.87	50.00	UV-AR (250-425nm)	Fused Silica	#26-602	C\$485.80 Volume Pricing	13 In Stock
50.00	41.87	50.00	UV-VIS (250-700nm)	Fused Silica	#26-608	C\$478.80 Volume Pricing	Contact Us
50.00	41.87	50.00	VIS 0° (425-675nm)	Fused Silica	#26-614	C\$485.80 Volume Pricing	5 In Stock
50.00	41.87	50.00	VIS-NIR (400-1000nm)	Fused Silica	#26-620	C\$485.80 Volume Pricing	1 In Stock
50.00	97.13	100.00	Uncoated	Fused Silica	#22-427	C\$441.00 Volume Pricing	Contact Us
50.00	97.13	100.00	UV-AR (250-425nm)	Fused Silica	#26-603	C\$485.80 Volume Pricing	1 In Stock
50.00	97.13	100.00	UV-VIS (250-700nm)	Fused Silica	#26-609	C\$478.80 Volume Pricing	3 In Stock
50.00	97.13	100.00	VIS 0° (425-675nm)	Fused Silica	#26-615	C\$485.80 Volume Pricing	3 In Stock
50.00	97.13	100.00	VIS-NIR (400-1000nm)	Fused Silica	#26-621	C\$485.80 Volume Pricing	Contact Us
50.00	148.00	150.00	Uncoated	Fused Silica	#22-428	C\$441.00 Volume Pricing	10 In Stock

50.00	148.00	150.00	UV-AR (250- 425nm)	Fused Silica	#26-604	C\$485.80 Volume Pricing	3 In Stock
50.00	148.00	150.00	UV-VIS (250- 700nm)	Fused Silica	#26-610	C\$478.80 Volume Pricing	4 In Stock
50.00	148.00	150.00	VIS 0° (425- 675nm)	Fused Silica	#26-616	C\$485.80 Volume Pricing	5 In Stock
50.00	148.00	150.00	VIS-NIR (400- 1000nm)	Fused Silica	#26-622	C\$485.80 Volume Pricing	4 In Stock
50.00	198.39	200.00	Uncoated	Fused Silica	#22-429	C\$441.00 Volume Pricing	3 In Stock
50.00	198.39	200.00	UV-AR (250- 425nm)	Fused Silica	#26-605	C\$485.80 Volume Pricing	2 In Stock
50.00	198.39	200.00	UV-VIS (250- 700nm)	Fused Silica	#26-611	C\$478.80 Volume Pricing	1 In Stock
50.00	198.39	200.00	VIS 0° (425- 675nm)	Fused Silica	#26-617	C\$485.80 Volume Pricing	5 In Stock
50.00	198.39	200.00	VIS-NIR (400- 1000nm)	Fused Silica	#26-623	C\$485.80 Volume Pricing	1 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
 Phone: 1-800-363-1992 :
www.edmundoptics.com