

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Cylinder Lenses](#) / [Illumination Grade Cylinder Lenses](#)

## TECHSPEC® Illumination Grade PCV Cylinder Lenses



- Cylinder Lenses Ideal for 1 Dimensional Laser Beam Convergence
- Circular and Rectangular Form Factors
- Multiple Coating Options Available

### Common Specifications

#### Physical & Mechanical Properties


|                                  |           |
|----------------------------------|-----------|
| Center Thickness Tolerance (mm): | $\pm 0.1$ |
|----------------------------------|-----------|

#### Optical Properties

|                             |         |
|-----------------------------|---------|
| Focal Length Tolerance (%): | $\pm 3$ |
|-----------------------------|---------|

|                  |       |
|------------------|-------|
| Surface Quality: | 60-40 |
|------------------|-------|

## Technical Information

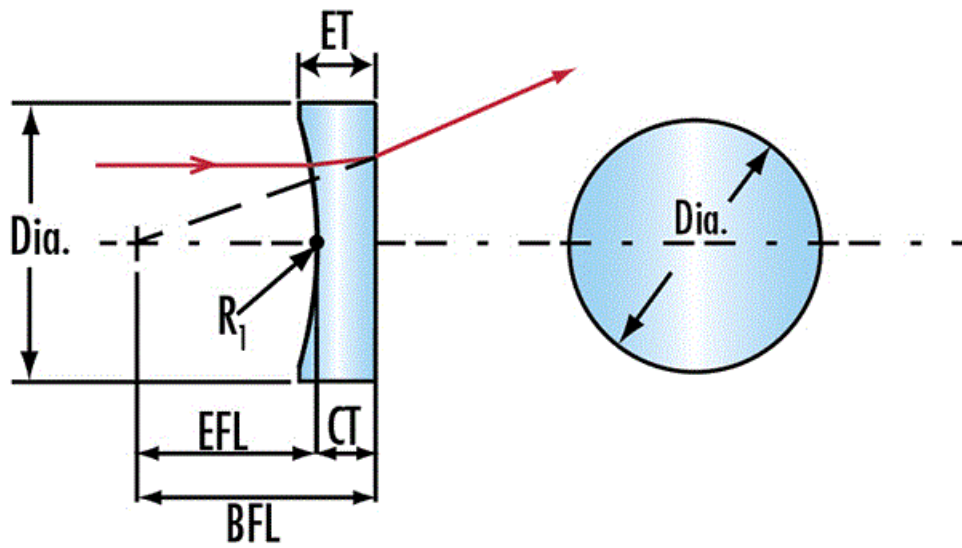

## Products

| Dia.<br>(mm) | Dimensions<br>(mm) | EFL<br>(mm) | Substrate             | Coating                         | Stock<br>Number         | Price                                       | Buy          |
|--------------|--------------------|-------------|-----------------------|---------------------------------|-------------------------|---------------------------------------------|--------------|
| 6.25         | -                  | -6.25       | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-371</a> | C\$121.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.25         | -                  | -6.25       | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#46-191</a> | C\$102.20<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.25         | -                  | -12.50      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-372</a> | C\$121.10<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.25         | -                  | -12.50      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#46-192</a> | C\$102.20<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.25         | -                  | -12.50      | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-791</a> | C\$136.50<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 6.25         | -                  | -12.50      | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-811</a> | C\$136.50<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 6.25         | -                  | -12.50      | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-831</a> | C\$136.50<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 6.25         | -                  | -25.00      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-373</a> | C\$121.10<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| 6.25         | -                  | -25.00      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#47-745</a> | C\$102.20<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.25         | -                  | -50.00      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-374</a> | C\$121.10<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 6.25         | -                  | -50.00      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#47-746</a> | C\$102.20<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 6.25         | -                  | -50.00      | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-793</a> | C\$136.50<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 6.25         | -                  | -50.00      | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-813</a> | C\$136.50<br><a href="#">Volume Pricing</a> | 4 In Stock   |

|       |   |             |                       |                                 |                         |                                             |              |
|-------|---|-------------|-----------------------|---------------------------------|-------------------------|---------------------------------------------|--------------|
| 6.25  | - | -50.00      | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-833</a> | C\$136.50<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 12.50 | - | -12.50      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-375</a> | C\$122.50<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.50 | - | -12.50      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#47-748</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.50 | - | -25.00      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-376</a> | C\$122.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.50 | - | -25.00      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#47-749</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.50 | - | -25.00      | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-794</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.50 | - | -25.00      | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-814</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 12.50 | - | -25.00      | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-834</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 12.50 | - | -50.00      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-377</a> | C\$122.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.50 | - | -50.00      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#47-750</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.50 | - | -50.00      | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-795</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | - | -50.00      | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-815</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| 12.50 | - | -50.00      | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-835</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 12.50 | - | -<br>100.00 | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-378</a> | C\$122.50<br><a href="#">Volume Pricing</a> | Contact Us   |
| 12.50 | - | -<br>100.00 | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#47-751</a> | C\$106.40<br><a href="#">Volume Pricing</a> | Contact Us   |

|       |             |             |                        |                                     |                         |                                             |              |
|-------|-------------|-------------|------------------------|-------------------------------------|-------------------------|---------------------------------------------|--------------|
| 12.50 | -           | -<br>100.00 | <a href="#">N-BK7</a>  | VIS 0°<br>(425-<br>675nm)           | <a href="#">#69-796</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 12.50 | -           | -<br>100.00 | <a href="#">N-BK7</a>  | NIR I<br>(600-<br>1050nm)           | <a href="#">#69-816</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 12.50 | -           | -<br>100.00 | <a href="#">N-BK7</a>  | VIS-NIR<br>(400-<br>1000nm)         | <a href="#">#69-836</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| -     | 12.5 x 25.0 | -12.50      | <a href="#">N-SF11</a> | MgF <sub>2</sub><br>(400-<br>700nm) | <a href="#">#68-069</a> | C\$122.50<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| -     | 12.5 x 25.0 | -12.50      | <a href="#">N-SF11</a> | Uncoated                            | <a href="#">#68-052</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -     | 12.5 x 25.0 | -15.00      | <a href="#">N-SF11</a> | MgF <sub>2</sub><br>(400-<br>700nm) | <a href="#">#68-070</a> | C\$122.50<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| -     | 12.5 x 25.0 | -15.00      | <a href="#">N-SF11</a> | Uncoated                            | <a href="#">#68-053</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -     | 12.5 x 25.0 | -20.00      | <a href="#">N-SF11</a> | Uncoated                            | <a href="#">#68-054</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -     | 12.5 x 25.0 | -20.00      | <a href="#">N-SF11</a> | MgF <sub>2</sub><br>(400-<br>700nm) | <a href="#">#68-071</a> | C\$122.50<br><a href="#">Volume Pricing</a> | Contact Us   |
| -     | 12.5 x 25.0 | -25.00      | <a href="#">N-BK7</a>  | Uncoated                            | <a href="#">#68-055</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -     | 12.5 x 25.0 | -25.00      | <a href="#">N-BK7</a>  | MgF <sub>2</sub><br>(400-<br>700nm) | <a href="#">#68-072</a> | C\$122.50<br><a href="#">Volume Pricing</a> | Contact Us   |
| -     | 12.5 x 25.0 | -25.00      | <a href="#">N-BK7</a>  | VIS 0°<br>(425-<br>675nm)           | <a href="#">#69-798</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| -     | 12.5 x 25.0 | -25.00      | <a href="#">N-BK7</a>  | NIR I<br>(600-<br>1050nm)           | <a href="#">#69-818</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| -     | 12.5 x 25.0 | -25.00      | <a href="#">N-BK7</a>  | VIS-NIR<br>(400-<br>1000nm)         | <a href="#">#69-838</a> | C\$141.40<br><a href="#">Volume Pricing</a> | Contact Us   |
| -     | 12.5 x 25.0 | -50.00      | <a href="#">N-BK7</a>  | Uncoated                            | <a href="#">#68-056</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |

|   |             |             |                       |                                 |                         |                                             |              |
|---|-------------|-------------|-----------------------|---------------------------------|-------------------------|---------------------------------------------|--------------|
| - | 12.5 x 25.0 | -50.00      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-073</a> | C\$122.50<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| - | 12.5 x 25.0 | -50.00      | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-799</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| - | 12.5 x 25.0 | -50.00      | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-819</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| - | 12.5 x 25.0 | -50.00      | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-839</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| - | 12.5 x 25.0 | -75.00      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#68-057</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| - | 12.5 x 25.0 | -75.00      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-074</a> | C\$122.50<br><a href="#">Volume Pricing</a> | 9 In Stock   |
| - | 12.5 x 25.0 | -75.00      | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-800</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| - | 12.5 x 25.0 | -75.00      | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-820</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| - | 12.5 x 25.0 | -75.00      | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-840</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| - | 12.5 x 25.0 | -<br>100.00 | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#68-058</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| - | 12.5 x 25.0 | -<br>100.00 | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-075</a> | C\$122.50<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| - | 12.5 x 25.0 | -<br>100.00 | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-801</a> | C\$141.40<br><a href="#">Volume Pricing</a> | Contact Us   |
| - | 12.5 x 25.0 | -<br>100.00 | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-821</a> | C\$141.40<br><a href="#">Volume Pricing</a> | Contact Us   |
| - | 12.5 x 25.0 | -<br>100.00 | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-841</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| - | 12.5 x 25.0 | -<br>150.00 | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#68-060</a> | C\$106.40<br><a href="#">Volume Pricing</a> | 5 In Stock   |

|       |             |             |                       |                                 |                         |                                             |              |
|-------|-------------|-------------|-----------------------|---------------------------------|-------------------------|---------------------------------------------|--------------|
| -     | 12.5 x 25.0 | -<br>150.00 | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-077</a> | C\$122.50<br><a href="#">Volume Pricing</a> | 15 In Stock  |
| -     | 12.5 x 25.0 | -<br>150.00 | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-802</a> | C\$141.40<br><a href="#">Volume Pricing</a> | Contact Us   |
| -     | 12.5 x 25.0 | -<br>150.00 | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-822</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| -     | 12.5 x 25.0 | -<br>150.00 | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-842</a> | C\$141.40<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 25.00 | -           | -25.00      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-379</a> | C\$135.80<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 25.00 | -           | -25.00      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#46-196</a> | C\$119.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | -           | -50.00      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-380</a> | C\$135.80<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 25.00 | -           | -50.00      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#46-197</a> | C\$119.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | -           | -50.00      | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-803</a> | C\$151.20<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00 | -           | -50.00      | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-823</a> | C\$151.20<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | -           | -50.00      | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-843</a> | C\$151.20<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 25.00 | -           | -75.00      | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-381</a> | C\$135.80<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | -           | -75.00      | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#47-752</a> | C\$119.70<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 25.00 | -           | -75.00      | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-804</a> | C\$151.20<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 25.00 | -           | -75.00      | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-824</a> | C\$151.20<br><a href="#">Volume Pricing</a> | 5 In Stock   |

|       |             |         |                        |                                 |                         |                                             |              |
|-------|-------------|---------|------------------------|---------------------------------|-------------------------|---------------------------------------------|--------------|
| 25.00 | -           | -75.00  | <a href="#">N-BK7</a>  | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-844</a> | C\$151.20<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 25.00 | -           | -100.00 | <a href="#">N-BK7</a>  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#48-382</a> | C\$135.80<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| 25.00 | -           | -100.00 | <a href="#">N-BK7</a>  | Uncoated                        | <a href="#">#47-753</a> | C\$119.70<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 25.00 | -           | -100.00 | <a href="#">N-BK7</a>  | VIS 0°<br>(425-675nm)           | <a href="#">#69-805</a> | C\$151.20<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| 25.00 | -           | -100.00 | <a href="#">N-BK7</a>  | NIR I<br>(600-1050nm)           | <a href="#">#69-825</a> | C\$151.20<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 25.00 | -           | -100.00 | <a href="#">N-BK7</a>  | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-845</a> | C\$151.20<br><a href="#">Volume Pricing</a> | Contact Us   |
| -     | 25.0 x 50.0 | -25.00  | <a href="#">N-SF11</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-078</a> | C\$201.60<br><a href="#">Volume Pricing</a> | Contact Us   |
| -     | 25.0 x 50.0 | -25.00  | <a href="#">N-SF11</a> | Uncoated                        | <a href="#">#68-061</a> | C\$184.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -     | 25.0 x 50.0 | -30.00  | <a href="#">N-SF11</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-079</a> | C\$201.60<br><a href="#">Volume Pricing</a> | 3 In Stock   |
| -     | 25.0 x 50.0 | -30.00  | <a href="#">N-SF11</a> | Uncoated                        | <a href="#">#68-062</a> | C\$184.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -     | 25.0 x 50.0 | -40.00  | <a href="#">N-SF11</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-080</a> | C\$201.60<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| -     | 25.0 x 50.0 | -40.00  | <a href="#">N-SF11</a> | Uncoated                        | <a href="#">#68-063</a> | C\$184.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -     | 25.0 x 50.0 | -50.00  | <a href="#">N-BK7</a>  | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-081</a> | C\$201.60<br><a href="#">Volume Pricing</a> | 8 In Stock   |
| -     | 25.0 x 50.0 | -50.00  | <a href="#">N-BK7</a>  | Uncoated                        | <a href="#">#68-064</a> | C\$184.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -     | 25.0 x 50.0 | -50.00  | <a href="#">N-BK7</a>  | VIS 0°<br>(425-675nm)           | <a href="#">#69-807</a> | C\$218.40<br><a href="#">Volume Pricing</a> | 7 In Stock   |



|   |             |         |                       |                                 |                         |                                             |              |
|---|-------------|---------|-----------------------|---------------------------------|-------------------------|---------------------------------------------|--------------|
| - | 25.0 x 50.0 | -50.00  | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-827</a> | C\$218.40<br><a href="#">Volume Pricing</a> | Contact Us   |
| - | 25.0 x 50.0 | -50.00  | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-847</a> | C\$218.40<br><a href="#">Volume Pricing</a> | 1 In Stock   |
| - | 25.0 x 50.0 | -75.00  | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-082</a> | C\$201.60<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| - | 25.0 x 50.0 | -75.00  | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#68-065</a> | C\$184.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| - | 25.0 x 50.0 | -75.00  | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-808</a> | C\$218.40<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| - | 25.0 x 50.0 | -75.00  | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-828</a> | C\$218.40<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| - | 25.0 x 50.0 | -75.00  | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-848</a> | C\$218.40<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| - | 25.0 x 50.0 | -100.00 | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-083</a> | C\$201.60<br><a href="#">Volume Pricing</a> | 17 In Stock  |
| - | 25.0 x 50.0 | -100.00 | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#68-066</a> | C\$184.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| - | 25.0 x 50.0 | -100.00 | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-809</a> | C\$218.40<br><a href="#">Volume Pricing</a> | Contact Us   |
| - | 25.0 x 50.0 | -100.00 | <a href="#">N-BK7</a> | NIR I<br>(600-1050nm)           | <a href="#">#69-829</a> | C\$218.40<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| - | 25.0 x 50.0 | -100.00 | <a href="#">N-BK7</a> | VIS-NIR<br>(400-1000nm)         | <a href="#">#69-849</a> | C\$218.40<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| - | 25.0 x 50.0 | -150.00 | <a href="#">N-BK7</a> | MgF <sub>2</sub><br>(400-700nm) | <a href="#">#68-085</a> | C\$201.60<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| - | 25.0 x 50.0 | -150.00 | <a href="#">N-BK7</a> | Uncoated                        | <a href="#">#68-068</a> | C\$184.80<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| - | 25.0 x 50.0 | -150.00 | <a href="#">N-BK7</a> | VIS 0°<br>(425-675nm)           | <a href="#">#69-810</a> | C\$218.40<br><a href="#">Volume Pricing</a> | Contact Us   |

|   |             |             |                       |                             |                         |                                             |            |
|---|-------------|-------------|-----------------------|-----------------------------|-------------------------|---------------------------------------------|------------|
| - | 25.0 x 50.0 | -<br>150.00 | <a href="#">N-BK7</a> | NIR I<br>(600-<br>1050nm)   | <a href="#">#69-830</a> | C\$218.40<br><a href="#">Volume Pricing</a> | 1 In Stock |
| - | 25.0 x 50.0 | -<br>150.00 | <a href="#">N-BK7</a> | VIS-NIR<br>(400-<br>1000nm) | <a href="#">#69-850</a> | C\$218.40<br><a href="#">Volume Pricing</a> | 2 In Stock |



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA  
 Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)