


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Cylinder Lenses](#) / [Illumination Grade Cylinder Lenses](#)

TECHSPEC®

Illumination Grade PCX Cylinder Lenses

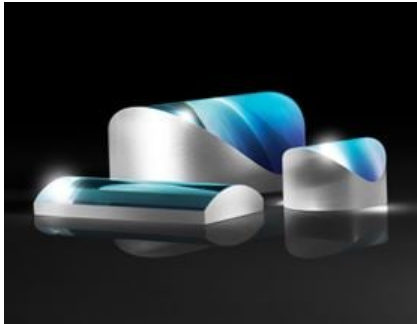

- N-BK7 Substrate for Broadband Performance
- Cost-Effective for OEM Integration
- Multiple Coating Options Available

Common Specifications


Physical & Mechanical Properties

Dimensional Tolerance (mm):	+0.0/-0.2
-----------------------------	-----------

Optical Properties



Focal Length Tolerance (%):	±3
Surface Quality:	60-40

Technical Information

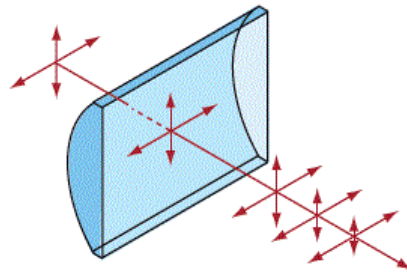

PCX Rectangular

Circular And Rectangular Cylinder Lenses

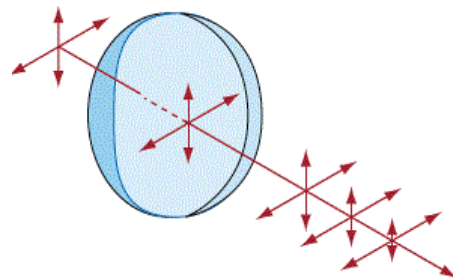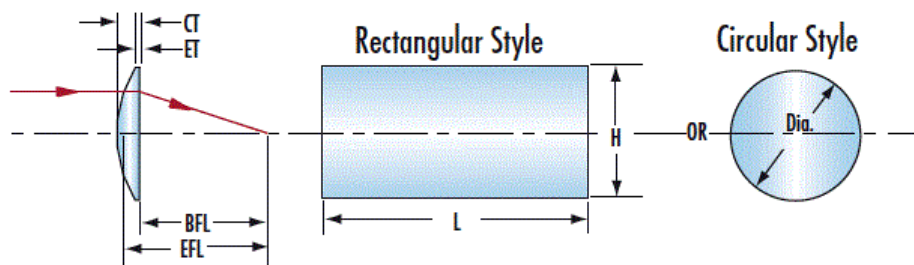

PCX Circular

Products

Dia. (mm)	Dimensions (mm)	EFL (mm)	Substrate	Coating	Stock Number	Price	Buy
5.00	-	8.00	N-BK7	Uncoated	#45-981	C\$186.59 Volume Pricing	20+ In Stock
5.00	-	8.00	N-BK7	MgF ₂ (400-700nm)	#47-760	C\$203.25 Volume Pricing	20+ In Stock
#45-982 Clearance							
Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
5.00	-	30.00	N-BK7	Uncoated		C\$91.55	14 In Stock

[#47-955 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

5.00	-	30.00	N-BK7	VIS-NIR (400-1000nm)		C\$114.87	14 In Stock
------	---	-------	-----------------------	----------------------	--	-----------	-------------

-	5.0 x 10.0	8.00	N-BK7	Uncoated	#43-856	C\$186.59 Volume Pricing	20+ In Stock
-	5.0 x 10.0	8.00	N-BK7	MgF ₂ (400-700nm)	#47-763	C\$203.25 Volume Pricing	4 In Stock
-	5.0 x 10.0	20.00	N-BK7	Uncoated	#43-857	C\$186.59 Volume Pricing	14 In Stock
-	5.0 x 10.0	20.00	N-BK7	MgF ₂ (400-700nm)	#47-764	C\$203.25 Volume Pricing	4 In Stock
-	5.0 x 10.0	20.00	N-BK7	VIS 0° (425-675nm)	#69-693	C\$214.91 Volume Pricing	3 In Stock
-	5.0 x 10.0	20.00	N-BK7	VIS-NIR (400-1000nm)	#47-958	C\$214.91 Volume Pricing	1 In Stock
-	5.0 x 10.0	20.00	N-BK7	NIR I (600-1050nm)	#69-704	C\$214.91 Volume Pricing	2 In Stock
-	5.0 x 10.0	50.00	N-BK7	Uncoated	#43-859	C\$186.59 Volume Pricing	10 In Stock
-	5.0 x 10.0	50.00	N-BK7	MgF ₂ (400-700nm)	#47-766	C\$203.25 Volume Pricing	14 In Stock

-	5.0 x 10.0	50.00	N-BK7	VIS 0° (425-675nm)	#69-695	C\$214.91 Volume Pricing	20+ In Stock
-	5.0 x 10.0	50.00	N-BK7	VIS-NIR (400-1000nm)	#47-960	C\$214.91 Volume Pricing	10 In Stock
-	5.0 x 10.0	50.00	N-BK7	NIR I (600-1050nm)	#69-706	C\$214.91 Volume Pricing	Contact Us
6.00	-	6.00	N-SF11	Uncoated	#68-024	C\$102.46 Volume Pricing	20+ In Stock
6.00	-	6.00	N-SF11	MgF ₂ (400-700nm)	#68-038	C\$120.79 Volume Pricing	20+ In Stock
6.00	-	9.00	N-SF11	Uncoated	#68-025	C\$102.46 Volume Pricing	20+ In Stock
6.00	-	9.00	N-SF11	MgF ₂ (400-700nm)	#68-039	C\$120.79 Volume Pricing	20+ In Stock
6.00	-	12.00	N-BK7	Uncoated	#68-026	C\$102.46 Volume Pricing	20+ In Stock
6.00	-	12.00	N-BK7	MgF ₂ (400-700nm)	#68-040	C\$120.79 Volume Pricing	Contact Us
6.00	-	12.00	N-BK7	VIS 0° (425-675nm)	#69-714	C\$136.61 Volume Pricing	14 In Stock
6.00	-	12.00	N-BK7	VIS-NIR (400-1000nm)	#69-766	C\$136.61 Volume Pricing	5 In Stock
6.00	-	12.00	N-BK7	NIR I (600-1050nm)	#69-740	C\$136.61 Volume Pricing	5 In Stock
6.00	-	18.00	N-BK7	Uncoated	#68-027	C\$102.46 Volume Pricing	20+ In Stock
6.00	-	18.00	N-BK7	MgF ₂ (400-700nm)	#68-041	C\$120.79 Volume Pricing	20+ In Stock
6.00	-	18.00	N-BK7	VIS 0° (425-675nm)	#69-715	C\$136.61 Volume Pricing	20+ In Stock
6.00	-	18.00	N-BK7	VIS-NIR (400-1000nm)	#69-767	C\$136.61 Volume Pricing	Contact Us

6.00	-	18.00	N-BK7	NIR I (600-1050nm)	#69-741	C\$136.61 Volume Pricing	4 In Stock
6.00	-	24.00	N-BK7	Uncoated	#68-028	C\$102.46 Volume Pricing	20+ In Stock
6.00	-	24.00	N-BK7	MgF ₂ (400-700nm)	#68-042	C\$120.79 Volume Pricing	4 In Stock
6.00	-	24.00	N-BK7	VIS 0° (425-675nm)	#69-716	C\$136.61 Volume Pricing	2 In Stock
6.00	-	24.00	N-BK7	VIS-NIR (400-1000nm)	#69-768	C\$136.61 Volume Pricing	Contact Us
6.00	-	24.00	N-BK7	NIR I (600-1050nm)	#69-742	C\$136.61 Volume Pricing	20+ In Stock
-	10.0 x 10.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-484	C\$140.78 Volume Pricing	2 In Stock
-	10.0 x 10.0	25.00	N-BK7	NIR I (600-1050nm)	#25-485	C\$140.78 Volume Pricing	1 In Stock
10.00	-	15.00	N-BK7	Uncoated	#47-754	C\$204.92 Volume Pricing	4 In Stock
10.00	-	15.00	N-BK7	MgF ₂ (400-700nm)	#47-767	C\$223.24 Volume Pricing	13 In Stock

[#69-696 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

10.00	-	20.00	N-BK7	VIS 0° (425-675nm)		C\$114.87	8 In Stock
-------	---	-------	-----------------------	-----------------------	--	-----------	------------

10.00	-	30.00	N-BK7	Uncoated	#47-756	C\$204.92 Volume Pricing	20+ In Stock
-------	---	-------	-----------------------	----------	-------------------------	---	--------------

10.00	-	30.00	N-BK7	MgF ₂ (400-700nm)	#47-769	C\$223.24 Volume Pricing	5 In Stock
-------	---	-------	-----------------------	---------------------------------	-------------------------	---	------------

10.00	-	30.00	N-BK7	VIS 0° (425-675nm)	#69-697	C\$234.91 Volume Pricing	1 In Stock
-------	---	-------	-----------------------	-----------------------	-------------------------	---	------------

10.00	-	30.00	N-BK7	VIS-NIR (400-1000nm)	#47-963	C\$234.91 Volume Pricing	2 In Stock
-------	---	-------	-----------------------	-------------------------	-------------------------	---	------------

10.00	-	30.00	N-BK7	NIR I (600-1050nm)	#69-708	C\$234.91 Volume Pricing	7 In Stock
-------	---	-------	-----------------------	-----------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	Uncoated	#47-757	C\$204.92 Volume Pricing	20+ In Stock
-------	---	-------	-----------------------	----------	-------------------------	---	--------------

10.00	-	50.00	N-BK7	MgF ₂ (400-700nm)	#47-770	C\$223.24 Volume Pricing	3 In Stock
-------	---	-------	-----------------------	---------------------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	VIS 0° (425-675nm)	#69-698	C\$234.91 Volume Pricing	1 In Stock
-------	---	-------	-----------------------	-----------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	VIS-NIR (400-1000nm)	#47-964	C\$234.91 Volume Pricing	5 In Stock
-------	---	-------	-----------------------	-------------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	NIR I (600-1050nm)	#69-709	C\$234.91 Volume Pricing	Contact Us
-	10.0 x 10.0	25.00	N-BK7	Uncoated	#25-483	C\$106.62 Volume Pricing	20+ In Stock
-	10.0 x 20.0	25.00	N-BK7	Uncoated	#25-486	C\$130.78 Volume Pricing	20+ In Stock
-	10.0 x 20.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-487	C\$164.93 Volume Pricing	2 In Stock
-	10.0 x 20.0	25.00	N-BK7	NIR I (600-1050nm)	#25-488	C\$164.93 Volume Pricing	5 In Stock

[#47-775 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

12.50	-	12.50	N-BK7	Uncoated	#46-193	C\$106.62 Volume Pricing	20+ In Stock
12.50	-	12.50	N-BK7	MgF ₂ (400-700nm)	#48-352	C\$122.45 Volume Pricing	20+ In Stock
12.50	-	25.00	N-BK7	Uncoated	#46-194	C\$106.62 Volume Pricing	20+ In Stock
12.50	-	25.00	N-BK7	MgF ₂ (400-700nm)	#48-353	C\$122.45 Volume Pricing	20+ In Stock
12.50	-	25.00	N-BK7	VIS 0° (425-675nm)	#69-717	C\$140.78 Volume Pricing	20+ In Stock

12.50	-	25.00	N-BK7	VIS-NIR (400-1000nm)	#69-769	C\$140.78 Volume Pricing	3 In Stock
12.50	-	25.00	N-BK7	NIR I (600-1050nm)	#69-743	C\$140.78 Volume Pricing	1 In Stock
12.50	-	50.00	N-BK7	Uncoated	#46-195	C\$106.62 Volume Pricing	20+ In Stock
12.50	-	50.00	N-BK7	MgF ₂ (400-700nm)	#48-354	C\$122.45 Volume Pricing	20+ In Stock
12.50	-	50.00	N-BK7	VIS 0° (425-675nm)	#69-718	C\$140.78 Volume Pricing	1 In Stock
12.50	-	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-770	C\$140.78 Volume Pricing	20+ In Stock
12.50	-	50.00	N-BK7	NIR I (600-1050nm)	#69-744	C\$140.78 Volume Pricing	Contact Us
12.50	-	75.00	N-BK7	Uncoated	#47-742	C\$106.62 Volume Pricing	20+ In Stock
12.50	-	75.00	N-BK7	MgF ₂ (400-700nm)	#48-355	C\$122.45 Volume Pricing	20+ In Stock
12.50	-	75.00	N-BK7	VIS 0° (425-675nm)	#69-719	C\$140.78 Volume Pricing	11 In Stock
12.50	-	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-771	C\$140.78 Volume Pricing	Contact Us
12.50	-	75.00	N-BK7	NIR I (600-1050nm)	#69-745	C\$140.78 Volume Pricing	Contact Us
12.50	-	100.00	N-BK7	Uncoated	#47-743	C\$106.62 Volume Pricing	20+ In Stock
12.50	-	100.00	N-BK7	MgF ₂ (400-700nm)	#48-356	C\$122.45 Volume Pricing	20+ In Stock
12.50	-	100.00	N-BK7	VIS 0° (425-675nm)	#69-720	C\$140.78 Volume Pricing	9 In Stock
-	12.5 x 25.0	12.50	N-SF11	Uncoated	#68-029	C\$106.62 Volume Pricing	20+ In Stock

-	12.5 x 25.0	12.50	N-SF11	MgF ₂ (400-700nm)	#68-043	C\$122.45 Volume Pricing	5 In Stock
-	12.5 x 25.0	15.00	N-SF11	Uncoated	#68-030	C\$106.62 Volume Pricing	20+ In Stock
-	12.5 x 25.0	15.00	N-SF11	MgF ₂ (400-700nm)	#68-044	C\$122.45 Volume Pricing	6 In Stock
-	12.5 x 25.0	20.00	N-BK7	Uncoated	#68-031	C\$106.62 Volume Pricing	20+ In Stock
-	12.5 x 25.0	20.00	N-BK7	MgF ₂ (400-700nm)	#68-045	C\$122.45 Volume Pricing	1 In Stock
-	12.5 x 25.0	20.00	N-BK7	VIS 0° (425-675nm)	#69-721	C\$140.78 Volume Pricing	Contact Us
-	12.5 x 25.0	20.00	N-BK7	VIS-NIR (400-1000nm)	#69-773	C\$140.78 Volume Pricing	4 In Stock
-	12.5 x 25.0	20.00	N-BK7	NIR I (600-1050nm)	#69-747	C\$140.78 Volume Pricing	4 In Stock
-	12.5 x 25.0	25.00	N-BK7	Uncoated	#68-032	C\$106.62 Volume Pricing	20+ In Stock
-	12.5 x 25.0	25.00	N-BK7	MgF ₂ (400-700nm)	#68-046	C\$122.45 Volume Pricing	20+ In Stock
-	12.5 x 25.0	25.00	N-BK7	VIS 0° (425-675nm)	#69-722	C\$140.78 Volume Pricing	10 In Stock
-	12.5 x 25.0	25.00	N-BK7	VIS-NIR (400-1000nm)	#69-774	C\$140.78 Volume Pricing	6 In Stock
-	12.5 x 25.0	25.00	N-BK7	NIR I (600-1050nm)	#69-748	C\$140.78 Volume Pricing	8 In Stock
-	12.5 x 25.0	50.00	N-BK7	Uncoated	#68-033	C\$106.62 Volume Pricing	20+ In Stock
-	12.5 x 25.0	50.00	N-BK7	MgF ₂ (400-700nm)	#68-047	C\$122.45 Volume Pricing	20+ In Stock
-	12.5 x 25.0	50.00	N-BK7	VIS 0° (425-675nm)	#69-723	C\$140.78 Volume Pricing	20+ In Stock

-	12.5 x 25.0	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-775	C\$140.78 Volume Pricing	5 In Stock
-	12.5 x 25.0	50.00	N-BK7	NIR I (600-1050nm)	#69-749	C\$140.78 Volume Pricing	4 In Stock
-	12.5 x 25.0	75.00	N-BK7	Uncoated	#68-034	C\$106.62 Volume Pricing	20+ In Stock
-	12.5 x 25.0	75.00	N-BK7	MgF ₂ (400-700nm)	#68-048	C\$122.45 Volume Pricing	8 In Stock
-	12.5 x 25.0	75.00	N-BK7	VIS 0° (425-675nm)	#69-724	C\$140.78 Volume Pricing	16 In Stock
-	12.5 x 25.0	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-776	C\$140.78 Volume Pricing	13 In Stock
-	12.5 x 25.0	75.00	N-BK7	NIR I (600-1050nm)	#69-750	C\$140.78 Volume Pricing	3 In Stock
-	12.5 x 25.0	100.00	N-BK7	Uncoated	#68-035	C\$106.62 Volume Pricing	20+ In Stock
-	12.5 x 25.0	100.00	N-BK7	MgF ₂ (400-700nm)	#68-049	C\$122.45 Volume Pricing	5 In Stock
-	12.5 x 25.0	100.00	N-BK7	VIS 0° (425-675nm)	#69-725	C\$140.78 Volume Pricing	5 In Stock
-	12.5 x 25.0	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-777	C\$140.78 Volume Pricing	20+ In Stock
-	12.5 x 25.0	100.00	N-BK7	NIR I (600-1050nm)	#69-751	C\$140.78 Volume Pricing	Contact Us
-	12.5 x 25.0	150.00	N-BK7	Uncoated	#68-037	C\$106.62 Volume Pricing	20+ In Stock
-	12.5 x 25.0	150.00	N-BK7	MgF ₂ (400-700nm)	#68-051	C\$122.45 Volume Pricing	5 In Stock
-	12.5 x 25.0	150.00	N-BK7	VIS 0° (425-675nm)	#69-726	C\$140.78 Volume Pricing	Contact Us
-	12.5 x 25.0	150.00	N-BK7	VIS-NIR (400-1000nm)	#69-778	C\$140.78 Volume Pricing	9 In Stock

-	12.5 x 25.0	150.00	N-BK7	NIR I (600-1050nm)	#69-752	C\$140.78 Volume Pricing	3 In Stock
-	12.7 x 12.7	12.50	N-BK7	Uncoated	#35-020	C\$106.62 Volume Pricing	20+ In Stock
-	12.7 x 12.7	12.50	N-BK7	VIS 0° (425-675nm)	#36-208	C\$140.78 Volume Pricing	Contact Us
-	12.7 x 12.7	12.50	N-BK7	VIS-NIR (400-1000nm)	#36-217	C\$140.78 Volume Pricing	1 In Stock
-	12.7 x 12.7	12.50	N-BK7	NIR I (600-1050nm)	#36-227	C\$140.78 Volume Pricing	1 In Stock
-	12.7 x 12.7	25.00	N-BK7	Uncoated	#35-021	C\$106.62 Volume Pricing	20+ In Stock
-	12.7 x 12.7	25.00	N-BK7	VIS 0° (425-675nm)	#36-209	C\$140.78 Volume Pricing	2 In Stock
-	12.7 x 12.7	25.00	N-BK7	VIS-NIR (400-1000nm)	#36-218	C\$140.78 Volume Pricing	Contact Us
-	12.7 x 12.7	25.00	N-BK7	NIR I (600-1050nm)	#36-228	C\$140.78 Volume Pricing	2 In Stock
-	12.7 x 12.7	100.00	N-BK7	Uncoated	#35-022	C\$106.62 Volume Pricing	20+ In Stock
-	12.7 x 12.7	100.00	N-BK7	VIS 0° (425-675nm)	#36-210	C\$140.78 Volume Pricing	2 In Stock
-	12.7 x 12.7	100.00	N-BK7	VIS-NIR (400-1000nm)	#36-219	C\$140.78 Volume Pricing	20+ In Stock
-	12.7 x 12.7	100.00	N-BK7	NIR I (600-1050nm)	#36-229	C\$140.78 Volume Pricing	5 In Stock
-	12.7 x 12.7	150.00	N-BK7	Uncoated	#35-023	C\$106.62 Volume Pricing	20+ In Stock
-	12.7 x 12.7	150.00	N-BK7	VIS 0° (425-675nm)	#36-211	C\$140.78 Volume Pricing	5 In Stock
-	12.7 x 12.7	150.00	N-BK7	VIS-NIR (400-1000nm)	#36-220	C\$140.78 Volume Pricing	3 In Stock

-	12.7 x 12.7	150.00	N-BK7	NIR I (600-1050nm)	#36-230	C\$140.78 Volume Pricing	4 In Stock
-	20.0 x 20.0	25.00	N-BK7	Uncoated	#25-489	C\$159.94 Volume Pricing	20+ In Stock
-	20.0 x 20.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-490	C\$193.26 Volume Pricing	5 In Stock
-	20.0 x 20.0	25.00	N-BK7	NIR I (600-1050nm)	#25-491	C\$193.26 Volume Pricing	5 In Stock
-	20.0 x 20.0	50.00	N-BK7	Uncoated	#25-495	C\$159.94 Volume Pricing	9 In Stock
-	20.0 x 20.0	50.00	N-BK7	VIS 0° (425-675nm)	#25-496	C\$193.26 Volume Pricing	5 In Stock
-	20.0 x 20.0	50.00	N-BK7	NIR I (600-1050nm)	#25-497	C\$193.26 Volume Pricing	5 In Stock
-	20.0 x 40.0	25.00	N-BK7	Uncoated	#25-492	C\$196.59 Volume Pricing	20+ In Stock
-	20.0 x 40.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-493	C\$231.57 Volume Pricing	5 In Stock
-	20.0 x 40.0	25.00	N-BK7	NIR I (600-1050nm)	#25-494	C\$231.57 Volume Pricing	4 In Stock
-	20.0 x 40.0	50.00	N-BK7	Uncoated	#25-498	C\$196.59 Volume Pricing	20+ In Stock
-	20.0 x 40.0	50.00	N-BK7	VIS 0° (425-675nm)	#25-499	C\$231.57 Volume Pricing	4 In Stock
-	20.0 x 40.0	50.00	N-BK7	NIR I (600-1050nm)	#25-500	C\$231.57 Volume Pricing	2 In Stock
25.00	-	25.00	N-BK7	Uncoated	#46-015	C\$119.95 Volume Pricing	20+ In Stock
25.00	-	25.00	N-BK7	MgF ₂ (400-700nm)	#48-357	C\$135.78 Volume Pricing	16 In Stock
25.00	-	50.00	N-BK7	Uncoated	#46-016	C\$119.95 Volume Pricing	20+ In Stock
25.00	-	50.00	N-BK7	MgF ₂ (400-700nm)	#48-358	C\$135.78 Volume Pricing	20+ In Stock

25.00	-	50.00	N-BK7	VIS 0° (425-675nm)	#69-727	C\$150.77 Volume Pricing	20+ In Stock
25.00	-	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-779	C\$150.77 Volume Pricing	3 In Stock
25.00	-	50.00	N-BK7	NIR I (600-1050nm)	#69-753	C\$150.77 Volume Pricing	20+ In Stock
25.00	-	75.00	N-BK7	Uncoated	#46-017	C\$119.95 Volume Pricing	20+ In Stock
25.00	-	75.00	N-BK7	MgF ₂ (400-700nm)	#48-359	C\$135.78 Volume Pricing	7 In Stock
25.00	-	75.00	N-BK7	VIS 0° (425-675nm)	#69-728	C\$150.77 Volume Pricing	5 In Stock
25.00	-	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-780	C\$135.78 Volume Pricing	1 In Stock
25.00	-	75.00	N-BK7	NIR I (600-1050nm)	#69-754	C\$150.77 Volume Pricing	2 In Stock
25.00	-	100.00	N-BK7	Uncoated	#46-018	C\$119.95 Volume Pricing	20+ In Stock
25.00	-	100.00	N-BK7	MgF ₂ (400-700nm)	#48-360	C\$135.78 Volume Pricing	11 In Stock
25.00	-	100.00	N-BK7	VIS 0° (425-675nm)	#69-729	C\$150.77 Volume Pricing	6 In Stock
25.00	-	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-781	C\$150.77 Volume Pricing	Contact Us
25.00	-	100.00	N-BK7	NIR I (600-1050nm)	#69-755	C\$150.77 Volume Pricing	Contact Us
25.00	-	125.00	N-BK7	Uncoated	#47-744	C\$119.95 Volume Pricing	20+ In Stock
25.00	-	125.00	N-BK7	MgF ₂ (400-700nm)	#48-361	C\$135.78 Volume Pricing	8 In Stock
25.00	-	125.00	N-BK7	VIS 0° (425-675nm)	#69-730	C\$150.77 Volume Pricing	6 In Stock

25.00	-	125.00	N-BK7	VIS-NIR (400-1000nm)	#69-782	C\$150.77 Volume Pricing	5 In Stock
25.00	-	125.00	N-BK7	NIR I (600-1050nm)	#69-756	C\$150.77 Volume Pricing	7 In Stock
25.00	-	150.00	N-BK7	Uncoated	#46-019	C\$119.95 Volume Pricing	20+ In Stock
25.00	-	150.00	N-BK7	MgF ₂ (400-700nm)	#48-362	C\$135.78 Volume Pricing	20+ In Stock
25.00	-	150.00	N-BK7	VIS 0° (425-675nm)	#69-731	C\$150.77 Volume Pricing	5 In Stock
25.00	-	150.00	N-BK7	VIS-NIR (400-1000nm)	#69-783	C\$150.77 Volume Pricing	3 In Stock
25.00	-	150.00	N-BK7	NIR I (600-1050nm)	#69-757	C\$150.77 Volume Pricing	7 In Stock
-	25.0 x 50.0	25.00	N-BK7	Uncoated	#46-020	C\$188.26 Volume Pricing	20+ In Stock
-	25.0 x 50.0	25.00	N-BK7	MgF ₂ (400-700nm)	#48-363	C\$206.58 Volume Pricing	11 In Stock
-	25.0 x 50.0	50.00	N-BK7	Uncoated	#46-021	C\$188.26 Volume Pricing	20+ In Stock
-	25.0 x 50.0	50.00	N-BK7	MgF ₂ (400-700nm)	#48-364	C\$206.58 Volume Pricing	20+ In Stock
-	25.0 x 50.0	50.00	N-BK7	VIS 0° (425-675nm)	#69-732	C\$221.58 Volume Pricing	2 In Stock
-	25.0 x 50.0	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-784	C\$221.58 Volume Pricing	2 In Stock
-	25.0 x 50.0	50.00	N-BK7	NIR I (600-1050nm)	#69-758	C\$221.58 Volume Pricing	2 In Stock
-	25.0 x 50.0	75.00	N-BK7	Uncoated	#46-022	C\$188.26 Volume Pricing	20+ In Stock
-	25.0 x 50.0	75.00	N-BK7	MgF ₂ (400-700nm)	#48-365	C\$206.58 Volume Pricing	1 In Stock

-	25.0 x 50.0	75.00	N-BK7	VIS 0° (425-675nm)	#69-733	C\$221.58 Volume Pricing	6 In Stock
-	25.0 x 50.0	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-785	C\$221.58 Volume Pricing	1 In Stock
-	25.0 x 50.0	75.00	N-BK7	NIR I (600-1050nm)	#69-759	C\$221.58 Volume Pricing	20+ In Stock
-	25.0 x 50.0	100.00	N-BK7	Uncoated	#46-023	C\$188.26 Volume Pricing	20+ In Stock
-	25.0 x 50.0	100.00	N-BK7	MgF ₂ (400-700nm)	#48-366	C\$206.58 Volume Pricing	3 In Stock
-	25.0 x 50.0	100.00	N-BK7	VIS 0° (425-675nm)	#69-734	C\$221.58 Volume Pricing	4 In Stock
-	25.0 x 50.0	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-786	C\$221.58 Volume Pricing	3 In Stock
-	25.0 x 50.0	100.00	N-BK7	NIR I (600-1050nm)	#69-760	C\$221.58 Volume Pricing	8 In Stock
-	25.0 x 50.0	150.00	N-BK7	Uncoated	#46-024	C\$188.26 Volume Pricing	20+ In Stock
-	25.0 x 50.0	150.00	N-BK7	MgF ₂ (400-700nm)	#48-367	C\$206.58 Volume Pricing	5 In Stock
-	25.0 x 50.0	150.00	N-BK7	VIS 0° (425-675nm)	#69-735	C\$221.58 Volume Pricing	5 In Stock
-	25.0 x 50.0	150.00	N-BK7	VIS-NIR (400-1000nm)	#69-787	C\$221.58 Volume Pricing	1 In Stock
-	25.0 x 50.0	150.00	N-BK7	NIR I (600-1050nm)	#69-761	C\$221.58 Volume Pricing	1 In Stock
-	25.4 x 25.4	50.00	N-BK7	Uncoated	#35-024	C\$119.95 Volume Pricing	20+ In Stock
-	25.4 x 25.4	50.00	N-BK7	VIS 0° (425-675nm)	#36-212	C\$150.77 Volume Pricing	2 In Stock
-	25.4 x 25.4	50.00	N-BK7	VIS-NIR (400-1000nm)	#36-222	C\$150.77 Volume Pricing	3 In Stock

-	25.4 x 25.4	50.00	N-BK7	NIR I (600-1050nm)	#36-231	C\$150.77 Volume Pricing	1 In Stock
-	25.4 x 25.4	100.00	N-BK7	Uncoated	#35-025	C\$119.95 Volume Pricing	20+ In Stock
-	25.4 x 25.4	100.00	N-BK7	VIS 0° (425-675nm)	#36-213	C\$150.77 Volume Pricing	6 In Stock
-	25.4 x 25.4	100.00	N-BK7	VIS-NIR (400-1000nm)	#36-223	C\$150.77 Volume Pricing	2 In Stock
-	25.4 x 25.4	100.00	N-BK7	NIR I (600-1050nm)	#36-232	C\$150.77 Volume Pricing	3 In Stock
-	25.4 x 25.4	150.00	N-BK7	Uncoated	#35-026	C\$119.95 Volume Pricing	20+ In Stock
-	25.4 x 25.4	150.00	N-BK7	VIS 0° (425-675nm)	#36-214	C\$150.77 Volume Pricing	1 In Stock
-	25.4 x 25.4	150.00	N-BK7	VIS-NIR (400-1000nm)	#36-224	C\$150.77 Volume Pricing	2 In Stock
-	25.4 x 25.4	150.00	N-BK7	NIR I (600-1050nm)	#36-233	C\$150.77 Volume Pricing	5 In Stock
-	25.4 x 25.4	200.00	N-BK7	Uncoated	#35-027	C\$119.95 Volume Pricing	20+ In Stock
-	25.4 x 25.4	200.00	N-BK7	VIS 0° (425-675nm)	#36-215	C\$150.77 Volume Pricing	Contact Us
-	25.4 x 25.4	200.00	N-BK7	VIS-NIR (400-1000nm)	#36-225	C\$150.77 Volume Pricing	3 In Stock
-	25.4 x 25.4	200.00	N-BK7	NIR I (600-1050nm)	#36-234	C\$150.77 Volume Pricing	5 In Stock
-	25.4 x 25.4	250.00	N-BK7	Uncoated	#35-028	C\$119.95 Volume Pricing	20+ In Stock
-	25.4 x 25.4	250.00	N-BK7	VIS 0° (425-675nm)	#36-216	C\$150.77 Volume Pricing	2 In Stock
-	25.4 x 25.4	250.00	N-BK7	VIS-NIR (400-1000nm)	#36-226	C\$150.77 Volume Pricing	11 In Stock

-	25.4 x 25.4	250.00	N-BK7	NIR I (600-1050nm)	#36-235	C\$150.77 Volume Pricing	2 In Stock
-	30.0 x 30.0	50.00	N-BK7	Uncoated	#25-501	C\$223.24 Volume Pricing	20+ In Stock
-	30.0 x 30.0	50.00	N-BK7	VIS 0° (425-675nm)	#25-502	C\$258.23 Volume Pricing	4 In Stock
-	30.0 x 30.0	50.00	N-BK7	NIR I (600-1050nm)	#25-503	C\$258.23 Volume Pricing	11 In Stock
-	30.0 x 30.0	100.00	N-BK7	Uncoated	#25-504	C\$223.24 Volume Pricing	7 In Stock
-	30.0 x 30.0	100.00	N-BK7	NIR I (600-1050nm)	#25-506	C\$258.23 Volume Pricing	5 In Stock
-	30.0 x 30.0	100.00	N-BK7	VIS 0° (425-675nm)	#25-505	C\$258.23 Volume Pricing	5 In Stock
-	50.0 x 25.0	75.00	N-BK7	Uncoated	#46-198	C\$188.26 Volume Pricing	20+ In Stock
-	50.0 x 25.0	75.00	N-BK7	MgF ₂ (400-700nm)	#48-368	C\$206.58 Volume Pricing	8 In Stock
-	50.0 x 25.0	75.00	N-BK7	VIS 0° (425-675nm)	#69-736	C\$221.58 Volume Pricing	1 In Stock
-	50.0 x 25.0	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-788	C\$221.58 Volume Pricing	2 In Stock
-	50.0 x 25.0	75.00	N-BK7	NIR I (600-1050nm)	#69-762	C\$221.58 Volume Pricing	5 In Stock
-	50.0 x 25.0	100.00	N-BK7	Uncoated	#46-199	C\$188.26 Volume Pricing	20+ In Stock
-	50.0 x 25.0	100.00	N-BK7	MgF ₂ (400-700nm)	#48-369	C\$206.58 Volume Pricing	2 In Stock
-	50.0 x 25.0	100.00	N-BK7	VIS 0° (425-675nm)	#69-737	C\$221.58 Volume Pricing	5 In Stock
-	50.0 x 25.0	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-789	C\$221.58 Volume Pricing	3 In Stock

-	50.0 x 25.0	100.00	N-BK7	NIR I (600-1050nm)	#69-763	C\$221.58 Volume Pricing	3 In Stock
-	50.0 x 25.0	150.00	N-BK7	Uncoated	#46-200	C\$188.26 Volume Pricing	20+ In Stock
-	50.0 x 25.0	150.00	N-BK7	MgF ₂ (400-700nm)	#48-370	C\$206.58 Volume Pricing	Contact Us
-	50.0 x 25.0	150.00	N-BK7	VIS 0° (425-675nm)	#69-738	C\$221.58 Volume Pricing	3 In Stock
				VIS-NIR (400-1000nm)	#69-790	C\$221.58 Volume Pricing	5 In Stock
Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA Phone: 1-800-363-1992 : www.edmundoptics.com							
-	50.0 x 25.0	150.00	N-BK7	NIR I (600-1050nm)	#69-764	C\$221.58 Volume Pricing	3 In Stock