

[All Products](#) /
 [Optics](#) /
 [Optical Lenses](#) /
 [Ball and Condenser Lenses](#)

TECHSPEC® N-BK7 Half-Ball Lenses



- Fiber Coupling Half-Spheres
- Collimating Lenses

Common Specifications

Physical & Mechanical Properties

Center Thickness
 Tolerance (mm): ± 0.05

Diameter Tolerance
 (μm): ± 2.5


Optical Properties

Substrate: [N-BK7](#)

Coating: Uncoated

Wavelength Range
 (nm): 350 - 2200

Technical Information

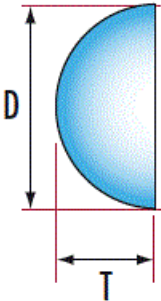

Products

Dia. (mm)	Substrate	Type	Coating	Stock Number	Price	Buy
0.50	N-BK7	Half-Ball Lens	Uncoated	#49-567	C\$79.00 Volume Pricing	20+ In Stock
1.00	N-BK7	Half-Ball Lens	Uncoated	#49-568	C\$79.00 Volume Pricing	16 In Stock
2.00	N-BK7	Half-Ball Lens	Uncoated	#45-933	C\$73.82 Volume Pricing	20+ In Stock
3.00	N-BK7	Half-Ball Lens	Uncoated	#47-269	C\$73.82 Volume Pricing	20+ In Stock
4.00	N-BK7	Half-Ball Lens	Uncoated	#45-934	C\$73.82 Volume Pricing	20+ In Stock
5.00	N-BK7	Half-Ball Lens	Uncoated	#47-270	C\$76.61 Volume Pricing	20+ In Stock
6.00	N-BK7	Half-Ball Lens	Uncoated	#45-935	C\$79.00 Volume Pricing	20+ In Stock
8.00	N-BK7	Half-Ball Lens	Uncoated	#45-936	C\$86.18 Volume Pricing	20+ In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com