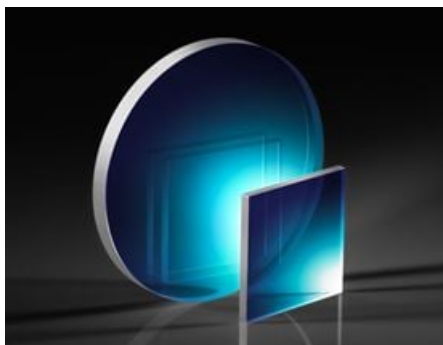


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)
TECHSPEC® $\lambda/10$ UV Fused Silica Windows


- UV, Visible, and NIR Anti-Reflection Coated Versions Available
- $\lambda/10$ Transmitted Wavefront Distortion
- Circular and Square Sizes from 2mm to 150mm
- [1 \$\lambda\$](#) or [\$\lambda/4\$](#) UV Fused Silica Windows Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Edges:	Fine Ground
Knoop Hardness (kg/mm²):	522.00	Poisson's Ratio:	0.16
Young's Modulus (GPa):	73		



Optical Properties

Abbe Number (v_d):	67.8
Index of Refraction (n_d):	1.458

Material Properties

Density (g/cm³):	2.20
------------------------------------	------

Technical Information

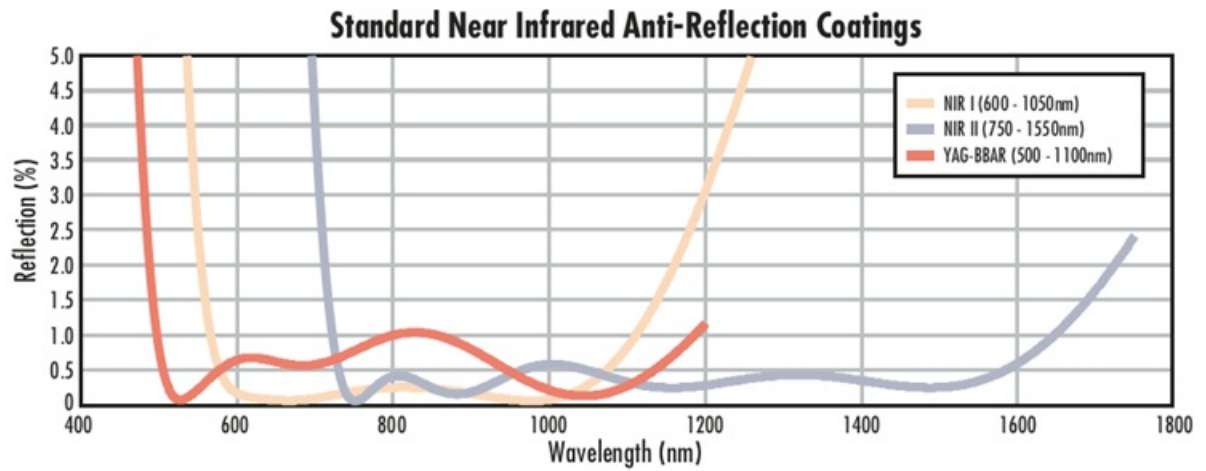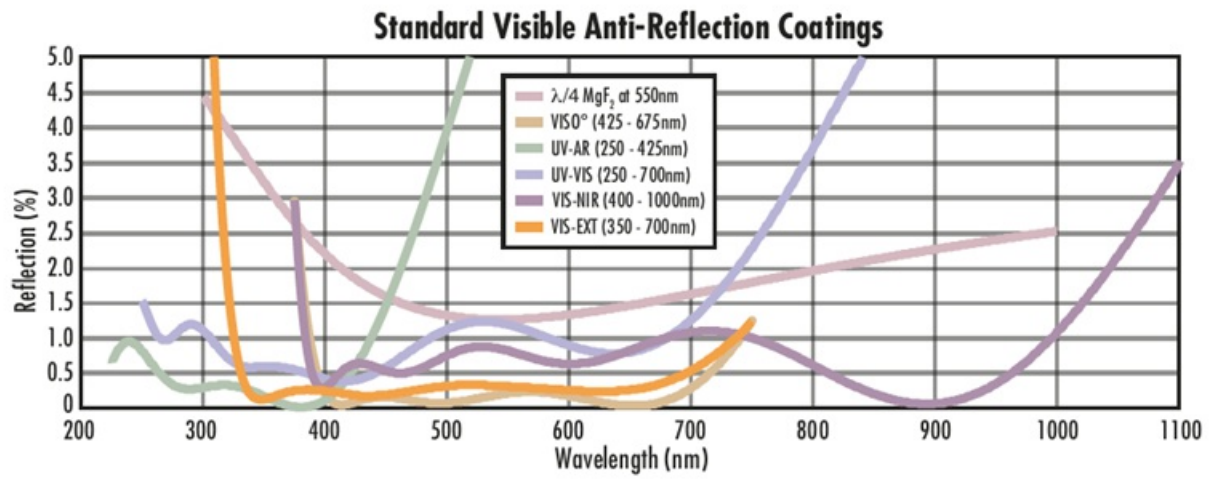

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
2.00	-	1.00	Uncoated	#27-669	C\$147.00 Volume Pricing	5 In Stock
2.50	-	1.00	Uncoated	#27-670	C\$147.00 Volume Pricing	20+ In Stock
3.00	-	1.00	Uncoated	#27-671	C\$155.40 Volume Pricing	20+ In Stock
4.00	-	1.00	Uncoated	#27-672	C\$165.20 Volume Pricing	20+ In Stock
5.00	-	1.00	Uncoated	#47-833	C\$184.80 Volume Pricing	Contact Us
10.00	-	1.25	Uncoated	#47-192	C\$184.80 Volume Pricing	20+ In Stock
12.50	-	1.50	Uncoated	#47-193	C\$189.00 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	Uncoated	#23-136	C\$179.20 Volume Pricing	20+ In Stock
12.50	-	2.00	Uncoated	#63-107	C\$189.00 Volume Pricing	20+ In Stock
12.70	-	1.50	Uncoated	#15-402	C\$179.20 Volume Pricing	Contact Us
15.00	-	2.00	Uncoated	#47-194	C\$197.40 Volume Pricing	20+ In Stock
20.00	-	2.00	Uncoated	#63-204	C\$210.00 Volume Pricing	20+ In Stock
25.00	-	1.00	Uncoated	#11-876	C\$224.00 Volume Pricing	12 In Stock
25.00	-	2.00	Uncoated	#11-877	C\$224.00 Volume Pricing	20+ In Stock
25.00	-	3.00	Uncoated	#47-195	C\$224.00 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	Uncoated	#23-137	C\$224.00 Volume Pricing	20+ In Stock
25.00	-	5.00	Uncoated	#11-878	C\$224.00 Volume Pricing	20+ In Stock

25.40	-	3.00	Uncoated	#15-403	C\$224.00 Volume Pricing	1 In Stock
30.00	-	4.00	Uncoated	#47-834	C\$284.20 Volume Pricing	20+ In Stock
40.00	-	4.00	Uncoated	#47-835	C\$323.40 Volume Pricing	20+ In Stock
50.00	-	1.00	Uncoated	#34-599	C\$392.00 Volume Pricing	20+ In Stock
50.00	-	2.00	Uncoated	#34-600	C\$392.00 Volume Pricing	Contact Us
50.00	-	3.00	Uncoated	#34-601	C\$392.00 Volume Pricing	20+ In Stock
50.00	-	5.00	Uncoated	#47-836	C\$392.00 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	Uncoated	#23-138	C\$392.00 Volume Pricing	2 In Stock
50.00	-	6.00	Uncoated	#34-602	C\$392.00 Volume Pricing	5 In Stock
50.80	-	5.00	Uncoated	#15-404	C\$392.00 Volume Pricing	16 In Stock
75.00	-	3.00	Uncoated	#36-935	C\$653.80 Volume Pricing	20+ In Stock
75.00	-	5.00	Uncoated	#36-936	C\$653.80 Volume Pricing	Contact Us
100.00	-	5.00	Uncoated	#17-561	C\$833.00 Volume Pricing	15 In Stock
125.00	-	6.00	Uncoated	#17-562	C\$1,050.00 Volume Pricing	20+ In Stock
150.00	-	8.00	Uncoated	#17-563	C\$1,463.00 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-AR (250-425nm)	#65-870	C\$240.80 Volume Pricing	11 In Stock
10.00	-	1.25	UV-AR (250-425nm)	#65-871	C\$232.40 Volume Pricing	6 In Stock
12.50	-	1.50	UV-AR (250-425nm)	#65-872	C\$236.60 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	UV-AR (250-425nm)	#24-296	C\$236.60 Volume Pricing	2 In Stock

12.50	-	2.00	UV-AR (250-425nm)	#68-487	C\$236.60 Volume Pricing	17 In Stock
12.70	-	1.50	UV-AR (250-425nm)	#15-405	C\$236.60 Volume Pricing	Contact Us
15.00	-	2.00	UV-AR (250-425nm)	#65-873	C\$245.00 Volume Pricing	20+ In Stock
20.00	-	2.00	UV-AR (250-425nm)	#65-874	C\$257.60 Volume Pricing	20+ In Stock
25.00	-	1.00	UV-AR (250-425nm)	#11-879	C\$270.20 Volume Pricing	1 In Stock
25.00	-	2.00	UV-AR (250-425nm)	#11-880	C\$270.20 Volume Pricing	5 In Stock
25.00	-	3.00	UV-AR (250-425nm)	#65-875	C\$270.20 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	UV-AR (250-425nm)	#24-304	C\$270.20 Volume Pricing	8 In Stock
25.00	-	5.00	UV-AR (250-425nm)	#11-881	C\$270.20 Volume Pricing	6 In Stock
25.40	-	3.00	UV-AR (250-425nm)	#15-406	C\$270.20 Volume Pricing	8 In Stock
30.00	-	4.00	UV-AR (250-425nm)	#65-876	C\$338.80 Volume Pricing	8 In Stock
40.00	-	4.00	UV-AR (250-425nm)	#65-877	C\$378.00 Volume Pricing	Contact Us
50.00	-	1.00	UV-AR (250-425nm)	#36-938	C\$446.60 Volume Pricing	3 In Stock
50.00	-	2.00	UV-AR (250-425nm)	#36-943	C\$446.60 Volume Pricing	Contact Us
50.00	-	3.00	UV-AR (250-425nm)	#36-948	C\$446.60 Volume Pricing	6 In Stock
50.00	-	5.00	UV-AR (250-425nm)	#65-878	C\$446.60 Volume Pricing	9 In Stock
-	50.00 x 50.00	5.00	UV-AR (250-425nm)	#24-312	C\$446.60 Volume Pricing	1 In Stock
50.00	-	6.00	UV-AR (250-425nm)	#36-953	C\$446.60 Volume Pricing	5 In Stock
50.80	-	5.00	UV-AR (250-425nm)	#15-407	C\$446.60 Volume Pricing	1 In Stock

75.00	-	3.00	UV-AR (250-425nm)	#36-958	C\$763.00 Volume Pricing	3 In Stock
75.00	-	5.00	UV-AR (250-425nm)	#36-963	C\$763.00 Volume Pricing	4 In Stock
5.00	-	1.00	UV-VIS (250-700nm)	#48-062	C\$240.80 Volume Pricing	15 In Stock
10.00	-	1.25	UV-VIS (250-700nm)	#48-063	C\$232.40 Volume Pricing	20+ In Stock
12.50	-	1.50	UV-VIS (250-700nm)	#48-064	C\$236.60 Volume Pricing	14 In Stock
-	12.50 x 12.50	1.50	UV-VIS (250-700nm)	#24-297	C\$236.60 Volume Pricing	1 In Stock
12.50	-	2.00	UV-VIS (250-700nm)	#68-488	C\$236.60 Volume Pricing	1 In Stock
12.70	-	1.50	UV-VIS (250-700nm)	#15-408	C\$236.60 Volume Pricing	1 In Stock
15.00	-	2.00	UV-VIS (250-700nm)	#48-065	C\$245.00 Volume Pricing	3 In Stock
20.00	-	2.00	UV-VIS (250-700nm)	#63-206	C\$257.60 Volume Pricing	12 In Stock
25.00	-	1.00	UV-VIS (250-700nm)	#11-882	C\$270.20 Volume Pricing	7 In Stock
25.00	-	2.00	UV-VIS (250-700nm)	#11-883	C\$270.20 Volume Pricing	17 In Stock
25.00	-	3.00	UV-VIS (250-700nm)	#48-066	C\$270.20 Volume Pricing	7 In Stock
-	25.00 x 25.00	3.00	UV-VIS (250-700nm)	#24-305	C\$270.20 Volume Pricing	4 In Stock
25.00	-	5.00	UV-VIS (250-700nm)	#11-884	C\$270.20 Volume Pricing	11 In Stock
25.40	-	3.00	UV-VIS (250-700nm)	#15-409	C\$270.20 Volume Pricing	5 In Stock
30.00	-	4.00	UV-VIS (250-700nm)	#48-067	C\$338.80 Volume Pricing	10 In Stock
40.00	-	4.00	UV-VIS (250-700nm)	#48-068	C\$378.00 Volume Pricing	2 In Stock
50.00	-	1.00	UV-VIS (250-700nm)	#36-939	C\$446.60 Volume Pricing	Contact Us

50.00	-	2.00	UV-VIS (250-700nm)	#36-944	C\$446.60 Volume Pricing	Contact Us
50.00	-	3.00	UV-VIS (250-700nm)	#36-949	C\$446.60 Volume Pricing	7 In Stock
50.00	-	5.00	UV-VIS (250-700nm)	#48-069	C\$446.60 Volume Pricing	5 In Stock
-	50.00 x 50.00	5.00	UV-VIS (250-700nm)	#24-313	C\$446.60 Volume Pricing	6 In Stock
50.00	-	6.00	UV-VIS (250-700nm)	#36-954	C\$446.60 Volume Pricing	1 In Stock
50.80	-	5.00	UV-VIS (250-700nm)	#15-410	C\$446.60 Volume Pricing	3 In Stock
75.00	-	3.00	UV-VIS (250-700nm)	#36-959	C\$763.00 Volume Pricing	20+ In Stock
75.00	-	5.00	UV-VIS (250-700nm)	#36-964	C\$763.00 Volume Pricing	Contact Us
100.00	-	5.00	UV-VIS (250-700nm)	#22-064	C\$1,288.00 Volume Pricing	8 In Stock
125.00	-	6.00	UV-VIS (250-700nm)	#22-065	C\$1,659.00 Volume Pricing	5 In Stock
150.00	-	8.00	UV-VIS (250-700nm)	#22-066	C\$2,198.00 Volume Pricing	2 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#13-330	C\$245.00 Volume Pricing	5 In Stock
10.00	-	1.25	VIS-EXT (350-700nm)	#13-331	C\$236.60 Volume Pricing	7 In Stock
-	12.50 x 12.50	1.50	VIS-EXT (350-700nm)	#24-301	C\$240.80 Volume Pricing	4 In Stock
12.50	-	1.50	VIS-EXT (350-700nm)	#13-332	C\$240.80 Volume Pricing	7 In Stock
12.50	-	2.00	VIS-EXT (350-700nm)	#13-333	C\$240.80 Volume Pricing	5 In Stock
12.70	-	1.50	VIS-EXT (350-700nm)	#15-781	C\$240.80 Volume Pricing	11 In Stock
15.00	-	2.00	VIS-EXT (350-700nm)	#13-334	C\$249.20 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#13-335	C\$263.20 Volume Pricing	9 In Stock

25.00	-	1.00	VIS-EXT (350-700nm)	#13-336	C\$275.80 Volume Pricing	Contact Us
25.00	-	2.00	VIS-EXT (350-700nm)	#13-337	C\$275.80 Volume Pricing	Contact Us
-	25.00 x 25.00	3.00	VIS-EXT (350-700nm)	#24-309	C\$275.80 Volume Pricing	1 In Stock
25.00	-	3.00	VIS-EXT (350-700nm)	#13-338	C\$275.80 Volume Pricing	5 In Stock
25.00	-	5.00	VIS-EXT (350-700nm)	#13-339	C\$275.80 Volume Pricing	8 In Stock
25.40	-	3.00	VIS-EXT (350-700nm)	#15-782	C\$275.80 Volume Pricing	4 In Stock
30.00	-	4.00	VIS-EXT (350-700nm)	#16-461	C\$344.40 Volume Pricing	2 In Stock
40.00	-	4.00	VIS-EXT (350-700nm)	#13-341	C\$383.60 Volume Pricing	Contact Us
50.00	-	1.00	VIS-EXT (350-700nm)	#13-342	C\$452.20 Volume Pricing	3 In Stock
50.00	-	2.00	VIS-EXT (350-700nm)	#13-343	C\$452.20 Volume Pricing	Contact Us
50.00	-	3.00	VIS-EXT (350-700nm)	#13-344	C\$452.20 Volume Pricing	2 In Stock
50.00	-	5.00	VIS-EXT (350-700nm)	#13-345	C\$452.20 Volume Pricing	5 In Stock
-	50.00 x 50.00	5.00	VIS-EXT (350-700nm)	#24-317	C\$452.20 Volume Pricing	7 In Stock
50.00	-	6.00	VIS-EXT (350-700nm)	#13-346	C\$452.20 Volume Pricing	Contact Us
50.80	-	5.00	VIS-EXT (350-700nm)	#15-783	C\$452.20 Volume Pricing	Contact Us
75.00	-	3.00	VIS-EXT (350-700nm)	#15-799	C\$777.00 Volume Pricing	2 In Stock
75.00	-	5.00	VIS-EXT (350-700nm)	#15-800	C\$777.00 Volume Pricing	Contact Us
5.00	-	1.00	VIS-NIR (400-1000nm)	#84-449	C\$245.00 Volume Pricing	4 In Stock

10.00	-	1.25	VIS-NIR (400-1000nm)	#84-450	C\$236.60 Volume Pricing	9 In Stock
12.50	-	1.50	VIS-NIR (400-1000nm)	#84-451	C\$240.80 Volume Pricing	11 In Stock
-	12.50 x 12.50	1.50	VIS-NIR (400-1000nm)	#24-302	C\$240.80 Volume Pricing	1 In Stock
12.50	-	2.00	VIS-NIR (400-1000nm)	#84-452	C\$240.80 Volume Pricing	1 In Stock
12.70	-	1.50	VIS-NIR (400-1000nm)	#15-414	C\$240.80 Volume Pricing	1 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#84-453	C\$249.20 Volume Pricing	Contact Us
20.00	-	2.00	VIS-NIR (400-1000nm)	#84-454	C\$263.20 Volume Pricing	20+ In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#11-888	C\$275.80 Volume Pricing	20+ In Stock
25.00	-	2.00	VIS-NIR (400-1000nm)	#11-889	C\$275.80 Volume Pricing	9 In Stock
-	25.00 x 25.00	3.00	VIS-NIR (400-1000nm)	#24-310	C\$275.80 Volume Pricing	5 In Stock
25.00	-	3.00	VIS-NIR (400-1000nm)	#84-455	C\$275.80 Volume Pricing	20+ In Stock
25.00	-	5.00	VIS-NIR (400-1000nm)	#11-890	C\$275.80 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-NIR (400-1000nm)	#15-415	C\$275.80 Volume Pricing	6 In Stock
30.00	-	4.00	VIS-NIR (400-1000nm)	#84-456	C\$344.40 Volume Pricing	10 In Stock

40.00	-	4.00	VIS-NIR (400-1000nm)	#84-457	C\$383.60 Volume Pricing	13 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#36-941	C\$452.20 Volume Pricing	6 In Stock
50.00	-	2.00	VIS-NIR (400-1000nm)	#36-946	C\$452.20 Volume Pricing	7 In Stock
50.00	-	3.00	VIS-NIR (400-1000nm)	#36-951	C\$452.20 Volume Pricing	1 In Stock
50.00	-	5.00	VIS-NIR (400-1000nm)	#84-458	C\$452.20 Volume Pricing	20+ In Stock
-	50.00 x 50.00	5.00	VIS-NIR (400-1000nm)	#24-318	C\$452.20 Volume Pricing	1 In Stock
50.00	-	6.00	VIS-NIR (400-1000nm)	#36-956	C\$452.20 Volume Pricing	13 In Stock
50.80	-	5.00	VIS-NIR (400-1000nm)	#15-416	C\$452.20 Volume Pricing	4 In Stock
75.00	-	3.00	VIS-NIR (400-1000nm)	#36-961	C\$777.00 Volume Pricing	5 In Stock
75.00	-	5.00	VIS-NIR (400-1000nm)	#36-966	C\$777.00 Volume Pricing	13 In Stock
100.00	-	5.00	VIS-NIR (400-1000nm)	#22-070	C\$1,288.00 Volume Pricing	4 In Stock
125.00	-	6.00	VIS-NIR (400-1000nm)	#22-071	C\$1,659.00 Volume Pricing	15 In Stock
150.00	-	8.00	VIS-NIR (400-1000nm)	#22-072	C\$2,198.00 Volume Pricing	7 In Stock
5.00	-	1.00	VIS 0° (425-675nm)	#47-837	C\$236.60 Volume Pricing	20+ In Stock

10.00	-	1.25	VIS 0° (425-675nm)	#47-196	C\$228.20 Volume Pricing	20+ In Stock
-	12.50 x 12.50	1.50	VIS 0° (425-675nm)	#24-298	C\$232.40 Volume Pricing	1 In Stock
12.50	-	1.50	VIS 0° (425-675nm)	#47-197	C\$232.40 Volume Pricing	20+ In Stock
12.50	-	2.00	VIS 0° (425-675nm)	#68-489	C\$232.40 Volume Pricing	10 In Stock
12.70	-	1.50	VIS 0° (425-675nm)	#15-411	C\$232.40 Volume Pricing	4 In Stock
15.00	-	2.00	VIS 0° (425-675nm)	#47-198	C\$240.80 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS 0° (425-675nm)	#63-205	C\$254.80 Volume Pricing	7 In Stock
25.00	-	1.00	VIS 0° (425-675nm)	#11-885	C\$267.40 Volume Pricing	8 In Stock
25.00	-	2.00	VIS 0° (425-675nm)	#11-886	C\$267.40 Volume Pricing	17 In Stock
25.00	-	3.00	VIS 0° (425-675nm)	#47-199	C\$267.40 Volume Pricing	20+ In Stock
-	25.00 x 25.00	3.00	VIS 0° (425-675nm)	#24-306	C\$267.40 Volume Pricing	4 In Stock
25.00	-	5.00	VIS 0° (425-675nm)	#11-887	C\$267.40 Volume Pricing	13 In Stock
25.40	-	3.00	VIS 0° (425-675nm)	#15-412	C\$267.40 Volume Pricing	20+ In Stock
30.00	-	4.00	VIS 0° (425-675nm)	#47-838	C\$336.00 Volume Pricing	8 In Stock
40.00	-	4.00	VIS 0° (425-675nm)	#47-839	C\$373.80 Volume Pricing	13 In Stock
50.00	-	1.00	VIS 0° (425-675nm)	#36-940	C\$443.80 Volume Pricing	10 In Stock
50.00	-	2.00	VIS 0° (425-675nm)	#36-945	C\$443.80 Volume Pricing	14 In Stock
50.00	-	3.00	VIS 0° (425-675nm)	#36-950	C\$443.80 Volume Pricing	11 In Stock
50.00	-	5.00	VIS 0° (425-675nm)	#47-840	C\$443.80 Volume Pricing	20+ In Stock

-	50.00 x 50.00	5.00	VIS 0° (425-675nm)	#24-314	C\$443.80 Volume Pricing	2 In Stock
50.00	-	6.00	VIS 0° (425-675nm)	#36-955	C\$443.80 Volume Pricing	9 In Stock
50.80	-	5.00	VIS 0° (425-675nm)	#15-413	C\$443.80 Volume Pricing	4 In Stock
75.00	-	3.00	VIS 0° (425-675nm)	#36-960	C\$756.00 Volume Pricing	2 In Stock
75.00	-	5.00	VIS 0° (425-675nm)	#36-965	C\$756.00 Volume Pricing	2 In Stock
100.00	-	5.00	VIS 0° (425-675nm)	#22-067	C\$1,267.00 Volume Pricing	10 In Stock
125.00	-	6.00	VIS 0° (425-675nm)	#22-068	C\$1,610.00 Volume Pricing	4 In Stock
150.00	-	8.00	VIS 0° (425-675nm)	#22-069	C\$2,156.00 Volume Pricing	3 In Stock
5.00	-	1.00	YAG-BBAR (500-1100nm)	#13-347	C\$245.00 Volume Pricing	15 In Stock
10.00	-	1.25	YAG-BBAR (500-1100nm)	#13-348	C\$236.60 Volume Pricing	13 In Stock
-	12.50 x 12.50	1.50	YAG-BBAR (500-1100nm)	#24-303	C\$240.80 Volume Pricing	8 In Stock
12.50	-	1.50	YAG-BBAR (500-1100nm)	#13-349	C\$240.80 Volume Pricing	1 In Stock
12.50	-	2.00	YAG-BBAR (500-1100nm)	#13-350	C\$240.80 Volume Pricing	9 In Stock
12.70	-	1.50	YAG-BBAR (500-1100nm)	#15-784	C\$240.80 Volume Pricing	4 In Stock
15.00	-	2.00	YAG-BBAR (500-1100nm)	#13-351	C\$249.20 Volume Pricing	1 In Stock
20.00	-	2.00	YAG-BBAR (500-1100nm)	#13-352	C\$263.20 Volume Pricing	9 In Stock

25.00	-	1.00	YAG-BBAR (500-1100nm)	#13-353	C\$275.80 Volume Pricing	Contact Us
25.00	-	2.00	YAG-BBAR (500-1100nm)	#13-354	C\$275.80 Volume Pricing	6 In Stock
-	25.00 x 25.00	3.00	YAG-BBAR (500-1100nm)	#24-311	C\$275.80 Volume Pricing	3 In Stock
25.00	-	3.00	YAG-BBAR (500-1100nm)	#13-355	C\$275.80 Volume Pricing	3 In Stock
25.00	-	5.00	YAG-BBAR (500-1100nm)	#13-356	C\$275.80 Volume Pricing	3 In Stock
25.40	-	3.00	YAG-BBAR (500-1100nm)	#15-785	C\$275.80 Volume Pricing	9 In Stock
30.00	-	4.00	YAG-BBAR (500-1100nm)	#13-357	C\$344.40 Volume Pricing	17 In Stock
40.00	-	4.00	YAG-BBAR (500-1100nm)	#13-358	C\$383.60 Volume Pricing	15 In Stock
50.00	-	1.00	YAG-BBAR (500-1100nm)	#13-359	C\$452.20 Volume Pricing	Contact Us
50.00	-	2.00	YAG-BBAR (500-1100nm)	#13-360	C\$452.20 Volume Pricing	Contact Us
50.00	-	3.00	YAG-BBAR (500-1100nm)	#13-361	C\$452.20 Volume Pricing	13 In Stock
50.00	-	5.00	YAG-BBAR (500-1100nm)	#13-362	C\$452.20 Volume Pricing	14 In Stock
-	50.00 x 50.00	5.00	YAG-BBAR (500-1100nm)	#24-319	C\$452.20 Volume Pricing	5 In Stock
50.00	-	6.00	YAG-BBAR (500-1100nm)	#13-363	C\$452.20 Volume Pricing	12 In Stock

50.80	-	5.00	YAG-BBAR (500-1100nm)	#15-786	C\$452.20 Volume Pricing	4 In Stock
75.00	-	3.00	YAG-BBAR (500-1100nm)	#15-801	C\$777.00 Volume Pricing	2 In Stock
75.00	-	5.00	YAG-BBAR (500-1100nm)	#15-802	C\$777.00 Volume Pricing	20+ In Stock
5.00	-	1.00	NIR I (600-1050nm)	#84-459	C\$236.60 Volume Pricing	Contact Us
10.00	-	1.25	NIR I (600-1050nm)	#84-460	C\$228.20 Volume Pricing	20+ In Stock
12.50	-	1.50	NIR I (600-1050nm)	#84-461	C\$232.40 Volume Pricing	7 In Stock
-	12.50 x 12.50	1.50	NIR I (600-1050nm)	#24-299	C\$232.40 Volume Pricing	5 In Stock
12.50	-	2.00	NIR I (600-1050nm)	#84-462	C\$232.40 Volume Pricing	20+ In Stock
12.70	-	1.50	NIR I (600-1050nm)	#15-417	C\$232.40 Volume Pricing	2 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#84-463	C\$240.80 Volume Pricing	20+ In Stock
20.00	-	2.00	NIR I (600-1050nm)	#84-464	C\$254.80 Volume Pricing	20+ In Stock
25.00	-	1.00	NIR I (600-1050nm)	#11-891	C\$267.40 Volume Pricing	15 In Stock
25.00	-	2.00	NIR I (600-1050nm)	#11-892	C\$267.40 Volume Pricing	2 In Stock
25.00	-	3.00	NIR I (600-1050nm)	#84-465	C\$267.40 Volume Pricing	5 In Stock
25.00	-	5.00	NIR I (600-1050nm)	#11-893	C\$267.40 Volume Pricing	1 In Stock
25.40	-	3.00	NIR I (600-1050nm)	#15-418	C\$267.40 Volume Pricing	5 In Stock
-	25.00 x 25.00	3.00	NIR I (600-1050nm)	#24-307	C\$267.40 Volume Pricing	Contact Us
30.00	-	4.00	NIR I (600-1050nm)	#84-466	C\$336.00 Volume Pricing	10 In Stock

40.00	-	4.00	NIR I (600-1050nm)	#84-467	C\$373.80 Volume Pricing	4 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#36-937	C\$443.80 Volume Pricing	5 In Stock
50.00	-	2.00	NIR I (600-1050nm)	#36-942	C\$443.80 Volume Pricing	14 In Stock
50.00	-	3.00	NIR I (600-1050nm)	#36-947	C\$443.80 Volume Pricing	5 In Stock
50.00	-	5.00	NIR I (600-1050nm)	#84-468	C\$443.80 Volume Pricing	Contact Us
-	50.00 x 50.00	5.00	NIR I (600-1050nm)	#24-315	C\$443.80 Volume Pricing	2 In Stock
50.00	-	6.00	NIR I (600-1050nm)	#36-952	C\$443.80 Volume Pricing	20+ In Stock
50.80	-	5.00	NIR I (600-1050nm)	#15-419	C\$443.80 Volume Pricing	2 In Stock
75.00	-	3.00	NIR I (600-1050nm)	#36-957	C\$756.00 Volume Pricing	Contact Us
75.00	-	5.00	NIR I (600-1050nm)	#36-962	C\$756.00 Volume Pricing	Contact Us
5.00	-	1.00	NIR II (750-1550nm)	#11-894	C\$236.60 Volume Pricing	Contact Us
10.00	-	1.25	NIR II (750-1550nm)	#11-895	C\$228.20 Volume Pricing	5 In Stock
12.50	-	1.50	NIR II (750-1550nm)	#11-896	C\$232.40 Volume Pricing	1 In Stock
-	12.50 x 12.50	1.50	NIR II (750-1550nm)	#24-300	C\$232.40 Volume Pricing	2 In Stock
12.50	-	2.00	NIR II (750-1550nm)	#11-897	C\$232.40 Volume Pricing	1 In Stock
12.70	-	1.50	NIR II (750-1550nm)	#15-420	C\$232.40 Volume Pricing	Contact Us
15.00	-	2.00	NIR II (750-1550nm)	#11-898	C\$240.80 Volume Pricing	11 In Stock
20.00	-	2.00	NIR II (750-1550nm)	#11-899	C\$254.80 Volume Pricing	17 In Stock
25.00	-	1.00	NIR II (750-1550nm)	#11-900	C\$267.40 Volume Pricing	20+ In Stock

25.00	-	2.00	NIR II (750-1550nm)	#11-901	C\$267.40 Volume Pricing	6 In Stock
-	25.00 x 25.00	3.00	NIR II (750-1550nm)	#24-308	C\$267.40 Volume Pricing	5 In Stock
25.00	-	3.00	NIR II (750-1550nm)	#11-902	C\$267.40 Volume Pricing	16 In Stock
25.00	-	5.00	NIR II (750-1550nm)	#11-903	C\$267.40 Volume Pricing	8 In Stock
25.40	-	3.00	NIR II (750-1550nm)	#15-421	C\$267.40 Volume Pricing	5 In Stock
30.00	-	4.00	NIR II (750-1550nm)	#11-904	C\$336.00 Volume Pricing	5 In Stock
40.00	-	4.00	NIR II (750-1550nm)	#11-905	C\$373.80 Volume Pricing	1 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#11-906	C\$443.80 Volume Pricing	7 In Stock
50.00	-	2.00	NIR II (750-1550nm)	#11-907	C\$443.80 Volume Pricing	12 In Stock
50.00	-	3.00	NIR II (750-1550nm)	#11-908	C\$443.80 Volume Pricing	20+ In Stock
50.00	-	5.00	NIR II (750-1550nm)	#11-909	C\$443.80 Volume Pricing	4 In Stock
-	50.00 x 50.00	5.00	NIR II (750-1550nm)	#24-316	C\$443.80 Volume Pricing	6 In Stock
50.00	-	6.00	NIR II (750-1550nm)	#11-910	C\$443.80 Volume Pricing	14 In Stock
50.80	-	5.00	NIR II (750-1550nm)	#15-422	C\$443.80 Volume Pricing	6 In Stock
75.00	-	3.00	NIR II (750-1550nm)	#11-911	C\$756.00 Volume Pricing	20+ In Stock
75.00	-	5.00	NIR II (750-1550nm)	#11-912	C\$756.00 Volume Pricing	6 In Stock
100.00	-	5.00	UV-AR (250-425nm)	#29-604	C\$1,288.00 Volume Pricing	Contact Us
100.00	-	5.00	VIS-EXT (350-700nm)	#29-607	C\$1,288.00 Volume Pricing	Contact Us
100.00	-	5.00	NIR I (600-1050nm)	#29-605	C\$1,267.00 Volume Pricing	Contact Us

100.00	-	5.00	NIR II (750-1550nm)	#29-606	C\$1,267.00 Volume Pricing	16 In Stock
100.00	-	5.00	YAG-BBAR (500-1100nm)	#29-608	C\$1,288.00 Volume Pricing	Contact Us
100.00	-	10.00	Uncoated	#29-508	C\$1,001.00 Volume Pricing	20+ In Stock
125.00	-	6.00	UV-AR (250-425nm)	#29-609	C\$1,659.00 Volume Pricing	2 In Stock
125.00	-	6.00	VIS-EXT (350-700nm)	#29-612	C\$1,659.00 Volume Pricing	Contact Us
125.00	-	6.00	NIR I (600-1050nm)	#29-610	C\$1,610.00 Volume Pricing	1 In Stock
125.00	-	6.00	NIR II (750-1550nm)	#29-611	C\$1,610.00 Volume Pricing	5 In Stock
125.00	-	6.00	YAG-BBAR (500-1100nm)	#29-613	C\$1,659.00 Volume Pricing	2 In Stock
125.00	-	12.50	Uncoated	#29-509	C\$1,288.00 Volume Pricing	1 In Stock
150.00	-	8.00	UV-AR (250-425nm)	#29-614	C\$2,198.00 Volume Pricing	1 In Stock
150.00	-	8.00	VIS-EXT (350-700nm)	#29-617	C\$2,198.00 Volume Pricing	1 In Stock
150.00	-	8.00	NIR I (600-1050nm)	#29-615	C\$2,156.00 Volume Pricing	Contact Us
150.00	-	8.00	NIR II (750-1550nm)	#29-616	C\$2,156.00 Volume Pricing	3 In Stock
150.00	-	8.00	YAG-BBAR (500-1100nm)	#29-618	C\$2,198.00 Volume Pricing	1 In Stock
150.00	-	15.00	Uncoated	#29-510	C\$2,037.00 Volume Pricing	5 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com