

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® VIS 0° Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <0.4% Reflectance per Surface for 425 - 675nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), [VIS-EXT](#), and [YAG-BBAR](#)

Common Specifications

Physical & Mechanical Properties



Bevel:	Protective as needed
--------	----------------------

Optical Properties

Focal Length Tolerance (%):	±1
-----------------------------	----

Wavelength Range (nm):	425 - 675
------------------------	-----------

Technical Information

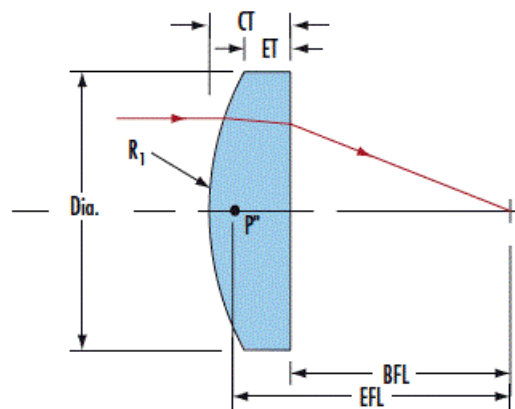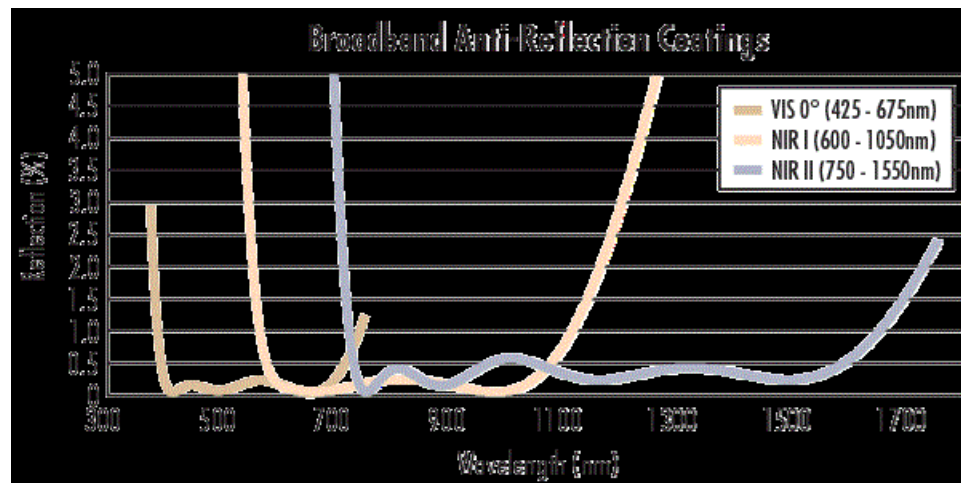

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	VIS 0° (425-675nm)	N-LASF9	#65-273	C\$123.90 Volume Pricing	5 In Stock
1.00	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-274	C\$123.90 Volume Pricing	Contact Us
1.00	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-275	C\$123.90 Volume Pricing	Contact Us
1.00	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-276	C\$123.90 Volume Pricing	Contact Us
1.50	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-277	C\$123.90 Volume Pricing	8 In Stock
1.50	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-278	C\$123.90 Volume Pricing	6 In Stock
1.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-279	C\$123.90 Volume Pricing	12 In Stock
2.00	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-280	C\$122.50 Volume Pricing	5 In Stock
2.00	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-281	C\$122.50 Volume Pricing	Contact Us
2.00	3.00	2.57	VIS 0° (425-675nm)	N-LASF9	#65-282	C\$122.50 Volume Pricing	3 In Stock
2.00	4.00	3.57	VIS 0° (425-675nm)	N-LASF9	#65-283	C\$122.50 Volume Pricing	8 In Stock
2.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-284	C\$122.50 Volume Pricing	17 In Stock
2.50	2.50	2.05	VIS 0° (425-675nm)	N-LASF9	#65-285	C\$122.50 Volume Pricing	3 In Stock
2.50	3.00	2.57	VIS 0° (425-675nm)	N-LASF9	#65-286	C\$122.50 Volume Pricing	Contact Us
2.50	4.00	3.57	VIS 0° (425-675nm)	N-LASF9	#65-287	C\$122.50 Volume Pricing	5 In Stock
2.50	5.00	4.57	VIS 0° (425-675nm)	N-LASF9	#65-288	C\$122.50 Volume Pricing	20+ In Stock

3.00	3.00	1.88	VIS 0° (425-675nm)	N-SF11	#49-167	C\$102.90 Volume Pricing	20+ In Stock
3.00	4.50	3.50	VIS 0° (425-675nm)	N-LASF44	#49-168	C\$102.90 Volume Pricing	4 In Stock
3.00	6.00	4.81	VIS 0° (425-675nm)	N-BK7	#49-169	C\$95.20 Volume Pricing	20+ In Stock
3.00	7.50	6.51	VIS 0° (425-675nm)	N-BK7	#49-170	C\$95.20 Volume Pricing	5 In Stock
3.00	9.00	8.01	VIS 0° (425-675nm)	N-BK7	#49-171	C\$95.20 Volume Pricing	14 In Stock
3.00	12.00	11.29	VIS 0° (425-675nm)	N-BK7	#49-172	C\$95.20 Volume Pricing	11 In Stock
3.00	15.00	14.17	VIS 0° (425-675nm)	N-BK7	#49-173	C\$95.20 Volume Pricing	10 In Stock
4.00	4.00	3.06	VIS 0° (425-675nm)	N-LASF44	#47-861	C\$98.70 Volume Pricing	20+ In Stock
4.00	6.00	4.51	VIS 0° (425-675nm)	N-BK7	#47-862	C\$98.70 Volume Pricing	5 In Stock
4.00	8.00	7.17	VIS 0° (425-675nm)	N-BAF10	#47-863	C\$92.40 Volume Pricing	11 In Stock
4.00	10.00	8.92	VIS 0° (425-675nm)	N-BK7	#47-864	C\$92.40 Volume Pricing	5 In Stock
4.00	12.00	11.00	VIS 0° (425-675nm)	N-BK7	#47-865	C\$92.40 Volume Pricing	2 In Stock
4.50	4.50	3.05	VIS 0° (425-675nm)	N-LASF44	#47-866	C\$98.70 Volume Pricing	20+ In Stock
4.50	9.00	7.41	VIS 0° (425-675nm)	N-BK7	#47-867	C\$92.40 Volume Pricing	20+ In Stock
5.00	5.00	3.96	VIS 0° (425-675nm)	N-LASF44	#47-868	C\$74.90 Volume Pricing	7 In Stock
5.00	7.50	6.43	VIS 0° (425-675nm)	N-SF11	#48-658	C\$74.20 Volume Pricing	8 In Stock
5.00	10.00	8.91	VIS 0° (425-675nm)	N-BK7	#47-869	C\$74.20 Volume Pricing	1 In Stock
5.00	12.00	10.83	VIS 0° (425-675nm)	N-BK7	#47-870	C\$74.20 Volume Pricing	20+ In Stock
5.00	15.00	13.94	VIS 0° (425-675nm)	N-BK7	#47-871	C\$74.20 Volume Pricing	5 In Stock

5.00	20.00	19.02	VIS 0° (425-675nm)	N-BK7	#49-893	C\$74.20 Volume Pricing	4 In Stock
5.00	25.00	23.95	VIS 0° (425-675nm)	N-BK7	#87-915	C\$74.20 Volume Pricing	20+ In Stock
5.00	30.00	28.95	VIS 0° (425-675nm)	N-BK7	#87-916	C\$74.20 Volume Pricing	14 In Stock
6.00	6.00	4.60	VIS 0° (425-675nm)	N-SF11	#47-460	C\$61.95 Volume Pricing	20+ In Stock
6.00	7.50	6.10	VIS 0° (425-675nm)	N-SF11	#49-894	C\$60.90 Volume Pricing	20+ In Stock
6.00	9.00	7.95	VIS 0° (425-675nm)	N-SF5	#47-461	C\$60.90 Volume Pricing	20+ In Stock
6.00	10.00	8.82	VIS 0° (425-675nm)	N-BK7	#38-272	C\$60.90 Volume Pricing	11 In Stock
6.00	12.00	10.94	VIS 0° (425-675nm)	N-BK7	#47-462	C\$59.50 Volume Pricing	20+ In Stock
6.00	15.00	13.68	VIS 0° (425-675nm)	N-BK7	#47-463	C\$59.50 Volume Pricing	20+ In Stock
6.00	18.00	17.07	VIS 0° (425-675nm)	N-BK7	#47-464	C\$59.50 Volume Pricing	20+ In Stock
6.00	20.00	19.04	VIS 0° (425-675nm)	N-BK7	#38-273	C\$59.50 Volume Pricing	3 In Stock
6.00	21.00	20.06	VIS 0° (425-675nm)	N-BK7	#47-465	C\$59.50 Volume Pricing	20+ In Stock
6.00	24.00	23.01	VIS 0° (425-675nm)	N-BK7	#47-466	C\$59.50 Volume Pricing	20+ In Stock
6.00	25.00	24.04	VIS 0° (425-675nm)	N-BK7	#38-275	C\$59.50 Volume Pricing	20+ In Stock
6.00	30.00	29.14	VIS 0° (425-675nm)	N-BK7	#47-467	C\$59.50 Volume Pricing	20+ In Stock
6.00	36.00	34.95	VIS 0° (425-675nm)	N-BK7	#47-468	C\$59.50 Volume Pricing	20+ In Stock
6.00	48.00	46.95	VIS 0° (425-675nm)	N-BK7	#47-469	C\$59.50 Volume Pricing	20+ In Stock
6.00	60.00	58.95	VIS 0° (425-675nm)	N-BK7	#67-162	C\$59.50 Volume Pricing	3 In Stock
6.00	72.00	70.97	VIS 0° (425-675nm)	N-BK7	#47-470	C\$59.50 Volume Pricing	20+ In Stock

7.00	7.00	5.50	VIS 0° (425-675nm)	N-SF11	#71-294	C\$61.95 Volume Pricing	Contact Us
7.00	10.00	8.10	VIS 0° (425-675nm)	N-BK7	#71-301	C\$60.90 Volume Pricing	2 In Stock
7.00	12.00	10.30	VIS 0° (425-675nm)	N-BK7	#71-308	C\$60.90 Volume Pricing	5 In Stock
8.00	8.00	6.40	VIS 0° (425-675nm)	N-SF11	#71-315	C\$61.95 Volume Pricing	Contact Us
8.00	10.00	7.60	VIS 0° (425-675nm)	N-BK7	#71-322	C\$60.90 Volume Pricing	5 In Stock
8.00	12.00	10.00	VIS 0° (425-675nm)	N-BK7	#71-329	C\$60.90 Volume Pricing	3 In Stock
9.00	9.00	7.32	VIS 0° (425-675nm)	N-SF11	#47-471	C\$62.65 Volume Pricing	Contact Us
9.00	10.00	8.49	VIS 0° (425-675nm)	N-SF11	#38-276	C\$62.65 Volume Pricing	3 In Stock
9.00	12.00	10.60	VIS 0° (425-675nm)	N-SF11	#49-895	C\$62.65 Volume Pricing	20+ In Stock
9.00	13.50	11.94	VIS 0° (425-675nm)	N-SF5	#47-472	C\$62.65 Volume Pricing	20+ In Stock
9.00	15.00	13.02	VIS 0° (425-675nm)	N-BK7	#49-896	C\$62.65 Volume Pricing	20+ In Stock
9.00	18.00	16.41	VIS 0° (425-675nm)	N-BK7	#47-473	C\$60.90 Volume Pricing	7 In Stock
9.00	20.00	18.55	VIS 0° (425-675nm)	N-BK7	#38-277	C\$60.90 Volume Pricing	3 In Stock
9.00	22.00	20.73	VIS 0° (425-675nm)	N-BK7	#47-474	C\$60.90 Volume Pricing	20+ In Stock
9.00	25.00	23.68	VIS 0° (425-675nm)	N-BK7	#38-278	C\$60.90 Volume Pricing	5 In Stock
9.00	27.00	25.34	VIS 0° (425-675nm)	N-BK7	#47-475	C\$60.90 Volume Pricing	20+ In Stock
9.00	36.00	34.48	VIS 0° (425-675nm)	N-BK7	#47-476	C\$60.90 Volume Pricing	20+ In Stock
9.00	45.00	43.98	VIS 0° (425-675nm)	N-BK7	#47-477	C\$60.90 Volume Pricing	1 In Stock
9.00	54.00	52.69	VIS 0° (425-675nm)	N-BK7	#67-163	C\$60.90 Volume Pricing	6 In Stock

9.00	72.00	70.68	VIS 0° (425-675nm)	N-BK7	#67-164	C\$60.90 Volume Pricing	6 In Stock
9.00	90.00	88.68	VIS 0° (425-675nm)	N-BK7	#67-165	C\$60.90 Volume Pricing	13 In Stock
10.00	10.00	8.18	VIS 0° (425-675nm)	N-SF11	#63-497	C\$62.65 Volume Pricing	20+ In Stock
10.00	12.50	10.99	VIS 0° (425-675nm)	N-SF11	#38-279	C\$62.65 Volume Pricing	6 In Stock
10.00	15.00	13.32	VIS 0° (425-675nm)	N-SF11	#63-498	C\$62.65 Volume Pricing	Contact Us
10.00	17.50	15.66	VIS 0° (425-675nm)	N-BK7	#38-280	C\$60.90 Volume Pricing	1 In Stock
10.00	20.00	18.03	VIS 0° (425-675nm)	N-BK7	#63-499	C\$60.90 Volume Pricing	Contact Us
10.00	25.00	23.02	VIS 0° (425-675nm)	N-BK7	#63-500	C\$60.90 Volume Pricing	20+ In Stock
10.00	30.00	28.01	VIS 0° (425-675nm)	N-BK7	#63-501	C\$60.90 Volume Pricing	20+ In Stock
10.00	40.00	38.02	VIS 0° (425-675nm)	N-BK7	#63-502	C\$60.90 Volume Pricing	20+ In Stock
10.00	50.00	48.02	VIS 0° (425-675nm)	N-BK7	#63-503	C\$60.90 Volume Pricing	20+ In Stock
10.00	75.00	73.02	VIS 0° (425-675nm)	N-BK7	#63-504	C\$60.90 Volume Pricing	20+ In Stock
10.00	100.00	98.02	VIS 0° (425-675nm)	N-BK7	#63-505	C\$60.90 Volume Pricing	Contact Us
12.00	12.00	9.76	VIS 0° (425-675nm)	N-SF11	#47-329	C\$67.90 Volume Pricing	20+ In Stock
12.00	15.00	12.03	VIS 0° (425-675nm)	N-BK7	#47-330	C\$67.90 Volume Pricing	15 In Stock
12.00	18.00	16.22	VIS 0° (425-675nm)	N-SF5	#47-331	C\$67.90 Volume Pricing	Contact Us
12.00	20.00	17.69	VIS 0° (425-675nm)	N-BK7	#49-897	C\$67.90 Volume Pricing	20+ In Stock
12.00	24.00	22.15	VIS 0° (425-675nm)	N-BK7	#47-332	C\$66.50 Volume Pricing	20+ In Stock
12.00	25.00	23.22	VIS 0° (425-675nm)	N-BK7	#38-281	C\$66.50 Volume Pricing	8 In Stock

12.00	30.00	28.02	VIS 0° (425-675nm)	N-BK7	#47-333	C\$66.50 Volume Pricing	20+ In Stock
12.00	36.00	34.02	VIS 0° (425-675nm)	N-BK7	#33-354	C\$66.50 Volume Pricing	6 In Stock
12.00	42.00	40.22	VIS 0° (425-675nm)	N-BK7	#47-335	C\$66.50 Volume Pricing	12 In Stock
12.00	48.00	46.36	VIS 0° (425-675nm)	N-BK7	#47-336	C\$66.50 Volume Pricing	20+ In Stock
12.00	50.00	48.75	VIS 0° (425-675nm)	N-BK7	#38-282	C\$66.50 Volume Pricing	9 In Stock
12.00	54.00	52.02	VIS 0° (425-675nm)	N-BK7	#47-337	C\$66.50 Volume Pricing	20+ In Stock
12.00	60.00	58.37	VIS 0° (425-675nm)	N-BK7	#47-338	C\$66.50 Volume Pricing	20+ In Stock
12.00	72.00	70.42	VIS 0° (425-675nm)	N-BK7	#47-339	C\$66.50 Volume Pricing	20+ In Stock
12.00	84.00	82.39	VIS 0° (425-675nm)	N-BK7	#47-340	C\$66.50 Volume Pricing	20+ In Stock
12.00	100.00	98.35	VIS 0° (425-675nm)	N-BK7	#47-341	C\$66.50 Volume Pricing	20+ In Stock
12.50	12.50	10.40	VIS 0° (425-675nm)	N-SF11	#38-283	C\$66.50 Volume Pricing	20+ In Stock
12.50	15.00	13.26	VIS 0° (425-675nm)	N-SF11	#38-285	C\$66.50 Volume Pricing	20+ In Stock
12.50	17.50	15.00	VIS 0° (425-675nm)	N-BK7	#38-287	C\$66.50 Volume Pricing	4 In Stock
12.50	20.00	17.69	VIS 0° (425-675nm)	N-BK7	#38-288	C\$66.50 Volume Pricing	8 In Stock
12.50	25.00	22.96	VIS 0° (425-675nm)	N-BK7	#38-290	C\$64.75 Volume Pricing	Contact Us
12.50	30.00	28.22	VIS 0° (425-675nm)	N-BK7	#38-291	C\$64.75 Volume Pricing	2 In Stock
12.50	35.00	33.42	VIS 0° (425-675nm)	N-BK7	#38-292	C\$64.75 Volume Pricing	20+ In Stock
12.50	40.00	38.55	VIS 0° (425-675nm)	N-BK7	#38-293	C\$64.75 Volume Pricing	1 In Stock
12.50	45.00	43.68	VIS 0° (425-675nm)	N-BK7	#38-294	C\$64.75 Volume Pricing	3 In Stock

12.50	50.00	48.68	VIS 0° (425-675nm)	N-BK7	#38-296	C\$64.75 Volume Pricing	4 In Stock
12.50	75.00	73.88	VIS 0° (425-675nm)	N-BK7	#38-297	C\$64.75 Volume Pricing	4 In Stock
12.50	100.00	98.95	VIS 0° (425-675nm)	N-BK7	#38-298	C\$64.75 Volume Pricing	5 In Stock
12.70	12.70	10.46	VIS 0° (425-675nm)	N-SF11	#62-561	C\$66.50 Volume Pricing	13 In Stock
12.70	15.00	11.53	VIS 0° (425-675nm)	N-BK7	#62-562	C\$66.50 Volume Pricing	20+ In Stock
12.70	19.10	16.46	VIS 0° (425-675nm)	N-BK7	#62-563	C\$66.50 Volume Pricing	20+ In Stock
12.70	20.00	17.49	VIS 0° (425-675nm)	N-BK7	#38-299	C\$66.50 Volume Pricing	5 In Stock
12.70	25.40	23.43	VIS 0° (425-675nm)	N-BK7	#62-564	C\$64.75 Volume Pricing	7 In Stock
12.70	30.00	28.22	VIS 0° (425-675nm)	N-BK7	#38-300	C\$64.75 Volume Pricing	3 In Stock
12.70	31.80	29.81	VIS 0° (425-675nm)	N-BK7	#62-565	C\$64.75 Volume Pricing	4 In Stock
12.70	38.10	36.12	VIS 0° (425-675nm)	N-BK7	#62-566	C\$64.75 Volume Pricing	7 In Stock
12.70	40.00	38.48	VIS 0° (425-675nm)	N-BK7	#38-309	C\$64.75 Volume Pricing	13 In Stock
12.70	44.50	42.69	VIS 0° (425-675nm)	N-BK7	#62-567	C\$64.75 Volume Pricing	Contact Us
12.70	50.80	49.15	VIS 0° (425-675nm)	N-BK7	#62-568	C\$64.75 Volume Pricing	16 In Stock
12.70	100.00	98.88	VIS 0° (425-675nm)	N-BK7	#38-310	C\$64.75 Volume Pricing	Contact Us
15.00	15.00	11.71	VIS 0° (425-675nm)	N-SF5	#47-872	C\$67.90 Volume Pricing	20+ In Stock
15.00	18.00	15.61	VIS 0° (425-675nm)	N-SF5	#49-898	C\$67.90 Volume Pricing	20+ In Stock
15.00	20.00	17.74	VIS 0° (425-675nm)	N-SF5	#63-506	C\$67.90 Volume Pricing	Contact Us
15.00	22.50	20.50	VIS 0° (425-675nm)	N-SF5	#47-873	C\$67.90 Volume Pricing	20+ In Stock

15.00	25.00	22.50	VIS 0° (425-675nm)	N-BK7	#38-311	C\$66.50 Volume Pricing	4 In Stock
15.00	30.00	27.90	VIS 0° (425-675nm)	N-BK7	#47-874	C\$66.50 Volume Pricing	20+ In Stock
15.00	40.00	38.02	VIS 0° (425-675nm)	N-BK7	#47-875	C\$66.50 Volume Pricing	20+ In Stock
15.00	45.00	43.35	VIS 0° (425-675nm)	N-BK7	#49-899	C\$66.50 Volume Pricing	Contact Us
15.00	50.00	48.35	VIS 0° (425-675nm)	N-BK7	#38-312	C\$66.50 Volume Pricing	2 In Stock
15.00	60.00	58.65	VIS 0° (425-675nm)	N-BK7	#47-876	C\$66.50 Volume Pricing	15 In Stock
15.00	75.00	73.79	VIS 0° (425-675nm)	N-BK7	#47-877	C\$66.50 Volume Pricing	7 In Stock
15.00	100.00	98.02	VIS 0° (425-675nm)	N-BK7	#47-878	C\$66.50 Volume Pricing	20+ In Stock
15.00	200.00	197.89	VIS 0° (425-675nm)	N-BK7	#14-376	C\$66.50 Volume Pricing	4 In Stock
15.00	250.00	248.02	VIS 0° (425-675nm)	N-BK7	#14-384	C\$66.50 Volume Pricing	Contact Us
18.00	18.00	15.20	VIS 0° (425-675nm)	N-SF11	#48-425	C\$68.95 Volume Pricing	7 In Stock
18.00	20.00	17.59	VIS 0° (425-675nm)	N-SF11	#38-313	C\$67.90 Volume Pricing	11 In Stock
18.00	22.50	20.26	VIS 0° (425-675nm)	N-SF11	#49-900	C\$67.90 Volume Pricing	20+ In Stock
18.00	25.00	21.51	VIS 0° (425-675nm)	N-BK7	#38-314	C\$67.90 Volume Pricing	Contact Us
18.00	27.00	24.73	VIS 0° (425-675nm)	N-SF5	#47-880	C\$67.90 Volume Pricing	20+ In Stock
18.00	30.00	27.10	VIS 0° (425-675nm)	N-BK7	#38-315	C\$65.80 Volume Pricing	8 In Stock
18.00	36.00	33.65	VIS 0° (425-675nm)	N-BK7	#47-881	C\$65.80 Volume Pricing	10 In Stock
18.00	50.00	48.09	VIS 0° (425-675nm)	N-BK7	#38-316	C\$65.80 Volume Pricing	1 In Stock
18.00	54.00	52.02	VIS 0° (425-675nm)	N-BK7	#47-882	C\$65.80 Volume Pricing	Contact Us

18.00	72.00	70.05	VIS 0° (425-675nm)	N-BK7	#47-883	C\$65.80 Volume Pricing	11 In Stock
20.00	20.00	17.42	VIS 0° (425-675nm)	N-SF11	#47-884	C\$69.65 Volume Pricing	20+ In Stock
20.00	25.00	22.76	VIS 0° (425-675nm)	N-SF11	#49-901	C\$68.95 Volume Pricing	20+ In Stock
20.00	30.00	27.30	VIS 0° (425-675nm)	N-BAF10	#47-885	C\$68.95 Volume Pricing	20+ In Stock
20.00	35.00	32.04	VIS 0° (425-675nm)	N-BK7	#49-902	C\$68.95 Volume Pricing	20+ In Stock
20.00	40.00	36.77	VIS 0° (425-675nm)	N-BK7	#47-886	C\$66.50 Volume Pricing	20+ In Stock
20.00	50.00	47.87	VIS 0° (425-675nm)	N-BK7	#47-887	C\$66.50 Volume Pricing	2 In Stock
20.00	60.00	57.03	VIS 0° (425-675nm)	N-BK7	#47-888	C\$66.50 Volume Pricing	20+ In Stock
20.00	70.00	68.03	VIS 0° (425-675nm)	N-BK7	#47-889	C\$66.50 Volume Pricing	8 In Stock
20.00	80.00	78.45	VIS 0° (425-675nm)	N-BK7	#47-890	C\$66.50 Volume Pricing	20+ In Stock
20.00	100.00	97.13	VIS 0° (425-675nm)	N-BK7	#47-891	C\$66.50 Volume Pricing	7 In Stock
20.00	150.00	148.02	VIS 0° (425-675nm)	N-BK7	#47-892	C\$66.50 Volume Pricing	20+ In Stock
25.00	25.00	20.22	VIS 0° (425-675nm)	N-SF5	#47-342	C\$69.65 Volume Pricing	20+ In Stock
25.00	30.00	24.69	VIS 0° (425-675nm)	N-BK7	#47-343	C\$69.65 Volume Pricing	20+ In Stock
25.00	35.00	30.42	VIS 0° (425-675nm)	N-BK7	#47-344	C\$69.65 Volume Pricing	20+ In Stock
25.00	40.00	36.31	VIS 0° (425-675nm)	N-BK7	#47-345	C\$69.65 Volume Pricing	20+ In Stock
25.00	50.00	46.75	VIS 0° (425-675nm)	N-BK7	#47-346	C\$66.50 Volume Pricing	20+ In Stock
25.00	60.00	56.90	VIS 0° (425-675nm)	N-BK7	#47-347	C\$66.50 Volume Pricing	20+ In Stock
25.00	75.00	72.00	VIS 0° (425-675nm)	N-BK7	#47-348	C\$66.50 Volume Pricing	20+ In Stock

25.00	85.00	82.17	VIS 0° (425-675nm)	N-BK7	#47-349	C\$66.50 Volume Pricing	20+ In Stock
25.00	100.00	97.17	VIS 0° (425-675nm)	N-BK7	#47-350	C\$66.50 Volume Pricing	20+ In Stock
25.00	125.00	122.70	VIS 0° (425-675nm)	N-BK7	#47-351	C\$66.50 Volume Pricing	20+ In Stock
25.00	150.00	147.81	VIS 0° (425-675nm)	N-BK7	#47-352	C\$66.50 Volume Pricing	Contact Us
25.00	175.00	172.85	VIS 0° (425-675nm)	N-BK7	#47-353	C\$66.50 Volume Pricing	20+ In Stock
25.00	200.00	197.89	VIS 0° (425-675nm)	N-BK7	#33-360	C\$66.50 Volume Pricing	20+ In Stock
25.00	250.00	248.02	VIS 0° (425-675nm)	N-BK7	#67-166	C\$66.50 Volume Pricing	20+ In Stock
25.00	300.00	298.02	VIS 0° (425-675nm)	N-BK7	#67-167	C\$66.50 Volume Pricing	11 In Stock
25.00	400.00	397.89	VIS 0° (425-675nm)	N-BK7	#33-366	C\$66.50 Volume Pricing	20+ In Stock
25.00	500.00	497.89	VIS 0° (425-675nm)	N-BK7	#47-356	C\$66.50 Volume Pricing	20+ In Stock
25.00	750.00	747.89	VIS 0° (425-675nm)	N-BK7	#47-357	C\$66.50 Volume Pricing	20+ In Stock
25.40	25.40	21.48	VIS 0° (425-675nm)	N-SF11	#62-569	C\$69.65 Volume Pricing	20+ In Stock
25.40	35.00	30.46	VIS 0° (425-675nm)	N-BK7	#38-317	C\$69.65 Volume Pricing	2 In Stock
25.40	38.10	33.48	VIS 0° (425-675nm)	N-BK7	#62-570	C\$69.65 Volume Pricing	4 In Stock
25.40	40.00	36.11	VIS 0° (425-675nm)	N-BK7	#38-318	C\$69.65 Volume Pricing	11 In Stock
25.40	50.80	47.50	VIS 0° (425-675nm)	N-BK7	#62-571	C\$66.50 Volume Pricing	1 In Stock
25.40	63.50	60.37	VIS 0° (425-675nm)	N-BK7	#62-572	C\$66.50 Volume Pricing	20+ In Stock
25.40	75.00	72.69	VIS 0° (425-675nm)	N-BK7	#38-319	C\$66.50 Volume Pricing	2 In Stock
25.40	76.20	73.56	VIS 0° (425-675nm)	N-BK7	#62-573	C\$66.50 Volume Pricing	1 In Stock

25.40	88.90	86.26	VIS 0° (425-675nm)	N-BK7	#62-574	C\$66.50 Volume Pricing	3 In Stock
25.40	100.00	98.02	VIS 0° (425-675nm)	N-BK7	#38-321	C\$66.50 Volume Pricing	1 In Stock
25.40	101.60	98.97	VIS 0° (425-675nm)	N-BK7	#62-575	C\$66.50 Volume Pricing	7 In Stock
25.40	125.00	123.02	VIS 0° (425-675nm)	N-BK7	#38-322	C\$66.50 Volume Pricing	Contact Us
25.40	150.00	148.02	VIS 0° (425-675nm)	N-BK7	#38-323	C\$66.50 Volume Pricing	3 In Stock
30.00	30.00	26.13	VIS 0° (425-675nm)	N-SF11	#48-659	C\$86.10 Volume Pricing	4 In Stock
30.00	40.00	37.20	VIS 0° (425-675nm)	N-SF11	#67-168	C\$82.60 Volume Pricing	20+ In Stock
30.00	50.00	46.17	VIS 0° (425-675nm)	N-SF5	#48-233	C\$82.60 Volume Pricing	20+ In Stock
30.00	60.00	56.03	VIS 0° (425-675nm)	N-BK7	#48-234	C\$80.50 Volume Pricing	20+ In Stock
30.00	75.00	70.95	VIS 0° (425-675nm)	N-BK7	#48-235	C\$80.50 Volume Pricing	17 In Stock
30.00	100.00	96.01	VIS 0° (425-675nm)	N-BK7	#48-236	C\$80.50 Volume Pricing	6 In Stock
30.00	120.00	116.04	VIS 0° (425-675nm)	N-BK7	#48-237	C\$80.50 Volume Pricing	20+ In Stock
35.00	35.00	30.52	VIS 0° (425-675nm)	N-SF11	#38-324	C\$88.20 Volume Pricing	20+ In Stock
35.00	50.00	44.40	VIS 0° (425-675nm)	N-BK7	#38-325	C\$86.10 Volume Pricing	5 In Stock
35.00	70.00	66.04	VIS 0° (425-675nm)	N-BK7	#38-326	C\$86.10 Volume Pricing	4 In Stock
35.00	100.00	97.03	VIS 0° (425-675nm)	N-BK7	#38-327	C\$86.10 Volume Pricing	1 In Stock
40.00	40.00	35.13	VIS 0° (425-675nm)	N-SF11	#48-660	C\$95.90 Volume Pricing	20+ In Stock
40.00	60.00	53.90	VIS 0° (425-675nm)	N-BK7	#48-238	C\$95.90 Volume Pricing	10 In Stock
40.00	80.00	74.73	VIS 0° (425-675nm)	N-BK7	#33-384	C\$94.50 Volume Pricing	6 In Stock

40.00	100.00	95.39	VIS 0° (425-675nm)	N-BK7	#33-372	C\$94.50 Volume Pricing	12 In Stock
40.00	200.00	196.7	VIS 0° (425-675nm)	N-BK7	#33-378	C\$94.50 Volume Pricing	12 In Stock
40.00	300.00	296.70	VIS 0° (425-675nm)	N-BK7	#48-242	C\$94.50 Volume Pricing	20+ In Stock
40.00	400.00	396.70	VIS 0° (425-675nm)	N-BK7	#48-243	C\$94.50 Volume Pricing	2 In Stock
50.00	50.00	43.28	VIS 0° (425-675nm)	N-SF11	#48-244	C\$105.00 Volume Pricing	20+ In Stock
50.00	75.00	67.75	VIS 0° (425-675nm)	N-BK7	#48-245	C\$101.50 Volume Pricing	20+ In Stock
50.00	100.00	93.41	VIS 0° (425-675nm)	N-BK7	#48-246	C\$98.00 Volume Pricing	20+ In Stock
50.00	125.00	118.39	VIS 0° (425-675nm)	N-BK7	#48-247	C\$98.00 Volume Pricing	9 In Stock
50.00	150.00	144.07	VIS 0° (425-675nm)	N-BK7	#48-248	C\$98.00 Volume Pricing	20+ In Stock
50.00	175.00	169.05	VIS 0° (425-675nm)	N-BK7	#48-249	C\$98.00 Volume Pricing	20+ In Stock
50.00	200.00	196.66	VIS 0° (425-675nm)	N-BK7	#48-250	C\$98.00 Volume Pricing	5 In Stock
50.00	250.00	246.74	VIS 0° (425-675nm)	N-BK7	#48-251	C\$98.00 Volume Pricing	20+ In Stock
50.00	500.00	496.70	VIS 0° (425-675nm)	N-BK7	#48-252	C\$98.00 Volume Pricing	6 In Stock
50.80	50.81	44.08	VIS 0° (425-675nm)	N-SF11	#71-336	C\$105.00 Volume Pricing	3 In Stock
50.80	76.20	68.95	VIS 0° (425-675nm)	N-BK7	#71-343	C\$101.50 Volume Pricing	1 In Stock
75.00	75.00	53.49	VIS 0° (425-675nm)	N-BK7	#86-907	C\$201.60 Volume Pricing	Contact Us
75.00	100.00	87.57	VIS 0° (425-675nm)	N-BK7	#71-846	C\$198.80 Volume Pricing	1 In Stock
75.00	125.00	115.99	VIS 0° (425-675nm)	N-BK7	#71-847	C\$198.80 Volume Pricing	Contact Us
75.00	150.00	142.45	VIS 0° (425-675nm)	N-BK7	#86-908	C\$198.80 Volume Pricing	20+ In Stock

75.00	175.00	168.68	VIS 0° (425-675nm)	N-BK7	#71-848	C\$198.80 Volume Pricing	1 In Stock
75.00	200.00	194.24	VIS 0° (425-675nm)	N-BK7	#86-909	C\$198.80 Volume Pricing	4 In Stock
75.00	250.00	244.73	VIS 0° (425-675nm)	N-BK7	#86-910	C\$198.80 Volume Pricing	10 In Stock
75.00	300.00	294.4	VIS 0° (425-675nm)	N-BK7	#71-849	C\$198.80 Volume Pricing	Contact Us
75.00	400.00	394.4	VIS 0° (425-675nm)	N-BK7	#71-850	C\$198.80 Volume Pricing	5 In Stock
75.00	500.00	494.73	VIS 0° (425-675nm)	N-BK7	#86-084	C\$198.80 Volume Pricing	Contact Us
75.00	750.00	745.35	VIS 0° (425-675nm)	N-BK7	#71-851	C\$198.80 Volume Pricing	4 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
Phone: 1-800-363-1992 :
www.edmundoptics.com