

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Achromatic Lenses](#)

TECHSPEC® VIS 0° Coated Achromatic Lenses



- Designed for 0° Angle of Incidence
- Less Than 0.4% Reflectance Per Surface from 425 - 675nm
- [MgF₂](#) and [VIS-NIR](#) Coated Achromats Also Available

Common Specifications

Physical & Mechanical Properties

Bevel: Protective as needed

Optical Properties

Focal Length
Specification
Wavelength (nm): 587.6

Coating: VIS 0° (425-675nm)


Coating Specification: $R_{avg} \leq 0.4\%$ @ 425 - 675nm

Power (P-V) @ 632.8nm: 1.5λ

Irregularity (P-V) @
632.8nm: $\lambda/4$

Wavelength Range (nm): 425 - 675

Technical Information

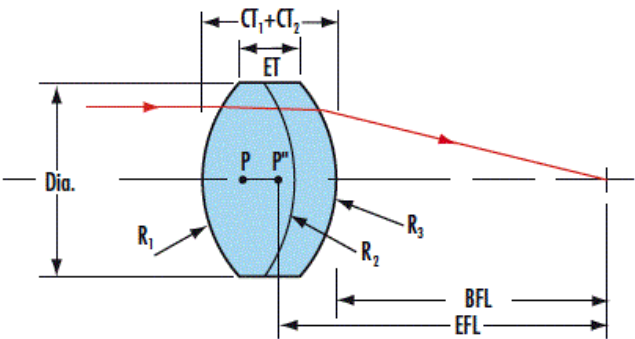

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Substrate	Coating	Stock Number	Price	Buy
#84-125 Clearance							
							
Clearance							
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
2.00	4.00	2.92	N-PSK53A / N-LASF9	VIS 0° (425-675nm)		C\$321.98	20+ In Stock
#83-978 Clearance							
							
Clearance							
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
2.00	9.00	8.00	N-PSK53A / N-LASF9	VIS 0° (425-675nm)		C\$321.98	20+ In Stock

[#83-979 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

2.00	12.00	11.00	N-PSK53A / N-LASF9	VIS 0° (425-675nm)		C\$321.98	20+ In Stock
------	-------	-------	------------------------------------	--------------------	--	-----------	--------------

3.00	4.50	2.99	N-LAK22 / N-SF6	VIS 0° (425-675nm)	#49-270	C\$182.95 Volume Pricing	20+ In Stock
------	------	------	---------------------------------	--------------------	-------------------------	---	--------------

3.00	6.00	4.33	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-271	C\$182.95 Volume Pricing	20+ In Stock
------	------	------	----------------------------------	--------------------	-------------------------	---	--------------

3.00	9.00	7.79	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-272	C\$182.95 Volume Pricing	20+ In Stock
------	------	------	-------------------------------	--------------------	-------------------------	---	--------------

3.00	12.00	10.77	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-273	C\$182.95 Volume Pricing	20+ In Stock
------	-------	-------	-------------------------------	--------------------	-------------------------	---	--------------

4.00	6.00	3.92	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#63-702	C\$163.30 Volume Pricing	20+ In Stock
------	------	------	----------------------------------	--------------------	-------------------------	---	--------------

4.00	8.00	6.69	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-274	C\$163.30 Volume Pricing	20+ In Stock
------	------	------	----------------------------------	--------------------	-------------------------	---	--------------

4.00	10.00	8.40	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#63-703	C\$163.30 Volume Pricing	20+ In Stock
------	-------	------	----------------------------------	--------------------	-------------------------	---	--------------

4.00	12.00	10.70	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-704	C\$163.30 Volume Pricing	20+ In Stock
------	-------	-------	-------------------------------	--------------------	-------------------------	---	--------------

5.00	7.50	5.01	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-275	C\$126.25 Volume Pricing	20+ In Stock
5.00	10.00	8.56	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-276	C\$126.25 Volume Pricing	14 In Stock
5.00	12.50	10.89	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-935	C\$126.25 Volume Pricing	20+ In Stock
5.00	15.00	13.64	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-277	C\$126.25 Volume Pricing	5 In Stock
5.00	20.00	18.60	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-278	C\$126.25 Volume Pricing	20+ In Stock
6.25	7.50	4.45	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-936	C\$103.57 Volume Pricing	20+ In Stock
6.25	10.00	7.83	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-689	C\$103.57 Volume Pricing	20+ In Stock
6.25	12.50	10.36	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-690	C\$103.57 Volume Pricing	20+ In Stock
6.25	15.00	12.73	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-691	C\$103.57 Volume Pricing	20+ In Stock
6.25	17.50	15.46	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-937	C\$103.57 Volume Pricing	20+ In Stock
6.25	20.00	18.23	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-692	C\$103.57 Volume Pricing	20+ In Stock
6.25	25.00	23.45	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-693	C\$103.57 Volume Pricing	14 In Stock
6.25	30.00	28.43	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-694	C\$103.57 Volume Pricing	20+ In Stock
6.25	35.00	33.59	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-695	C\$103.57 Volume Pricing	Contact Us

6.25	40.00	38.46	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-696	C\$103.57 Volume Pricing	20+ In Stock
6.25	50.00	48.61	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-697	C\$103.57 Volume Pricing	20+ In Stock
6.25	60.00	58.46	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-698	C\$103.57 Volume Pricing	20+ In Stock
9.00	12.00	8.33	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#47-652	C\$111.13 Volume Pricing	20+ In Stock
9.00	15.00	12.08	N-BAF10 / N-SF6	VIS 0° (425-675nm)	#49-938	C\$111.13 Volume Pricing	20+ In Stock
9.00	18.00	14.91	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-653	C\$111.13 Volume Pricing	20+ In Stock
9.00	22.50	20.21	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-939	C\$111.13 Volume Pricing	20+ In Stock
9.00	27.00	24.22	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-654	C\$111.13 Volume Pricing	20+ In Stock
9.00	36.00	34.17	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-655	C\$111.13 Volume Pricing	20+ In Stock
9.00	40.00	37.54	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-656	C\$111.13 Volume Pricing	20+ In Stock
9.00	45.00	42.97	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-657	C\$111.13 Volume Pricing	20+ In Stock
9.00	60.00	57.59	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-658	C\$111.13 Volume Pricing	3 In Stock
9.00	75.00	72.35	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-659	C\$111.13 Volume Pricing	20+ In Stock
10.00	15.00	10.66	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#63-705	C\$114.16 Volume Pricing	20+ In Stock

10.00	20.00	17.24	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#63-706	C\$114.16 Volume Pricing	20+ In Stock
10.00	25.00	22.60	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-707	C\$114.16 Volume Pricing	20+ In Stock
10.00	30.00	27.47	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-708	C\$114.16 Volume Pricing	20+ In Stock
10.00	40.00	37.79	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-709	C\$114.16 Volume Pricing	20+ In Stock
10.00	50.00	47.45	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-710	C\$114.16 Volume Pricing	16 In Stock
10.00	100.00	98.16	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-711	C\$114.16 Volume Pricing	20+ In Stock
12.50	15.00	10.82	N-LAK22 / N-SF6	VIS 0° (425-675nm)	#63-712	C\$125.50 Volume Pricing	20+ In Stock
12.50	14.00	9.92	N-BAF10 / N-SF5	VIS 0° (425-675nm)	#47-660	C\$125.50 Volume Pricing	20+ In Stock
12.50	17.50	13.59	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-940	C\$125.50 Volume Pricing	4 In Stock
12.50	20.00	16.45	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-661	C\$125.50 Volume Pricing	20+ In Stock
12.50	25.00	21.47	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-662	C\$125.50 Volume Pricing	20+ In Stock
12.50	30.00	26.12	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-663	C\$125.50 Volume Pricing	20+ In Stock
12.50	35.00	32.50	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-664	C\$125.50 Volume Pricing	20+ In Stock
12.50	40.00	37.54	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-665	C\$125.50 Volume Pricing	15 In Stock

12.50	45.00	42.52	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-666	C\$125.50 Volume Pricing	20+ In Stock
12.50	50.00	47.61	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-667	C\$125.50 Volume Pricing	20+ In Stock
12.50	60.00	57.59	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-668	C\$125.50 Volume Pricing	20+ In Stock
12.50	75.00	72.35	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-669	C\$125.50 Volume Pricing	20+ In Stock
12.50	80.00	78.40	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-670	C\$125.50 Volume Pricing	12 In Stock
12.50	90.00	88.47	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-671	C\$125.50 Volume Pricing	Contact Us
12.50	100.00	97.92	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-672	C\$125.50 Volume Pricing	20+ In Stock
12.70	15.00	10.56	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-771	C\$125.50 Volume Pricing	20+ In Stock
12.70	19.10	15.38	N-BAF10 / N-SF6	VIS 0° (425-675nm)	#49-772	C\$125.50 Volume Pricing	20+ In Stock
12.70	25.40	22.45	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-773	C\$125.50 Volume Pricing	20+ In Stock
12.70	31.75	28.83	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-774	C\$125.50 Volume Pricing	Contact Us
12.70	38.10	35.57	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-775	C\$125.50 Volume Pricing	20+ In Stock
12.70	44.45	41.98	N-BAK1 / N-SF8	VIS 0° (425-675nm)	#49-776	C\$125.50 Volume Pricing	20+ In Stock
12.70	50.80	48.86	N-BAK1 / N-SF15	VIS 0° (425-675nm)	#49-777	C\$125.50 Volume Pricing	20+ In Stock

12.70	125.00	121.95	N-BK7 / N-SF5	VIS 0° (425-675nm)	#69-922	C\$125.50 Volume Pricing	7 In Stock
15.00	20.00	15.34	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-941	C\$149.69 Volume Pricing	12 In Stock
15.00	25.00	20.98	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-699	C\$149.69 Volume Pricing	20+ In Stock
15.00	30.00	25.78	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-700	C\$149.69 Volume Pricing	20+ In Stock
15.00	40.00	35.63	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-701	C\$149.69 Volume Pricing	20+ In Stock
15.00	50.00	46.17	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-702	C\$149.69 Volume Pricing	20+ In Stock
15.00	60.00	57.48	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-942	C\$149.69 Volume Pricing	20+ In Stock
15.00	75.00	70.78	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-703	C\$149.69 Volume Pricing	20+ In Stock
18.00	22.50	16.39	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-943	C\$151.20 Volume Pricing	20+ In Stock
18.00	27.00	21.74	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-704	C\$151.20 Volume Pricing	15 In Stock
18.00	30.00	24.97	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-705	C\$151.20 Volume Pricing	20+ In Stock
18.00	35.00	30.72	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-706	C\$151.20 Volume Pricing	20+ In Stock
18.00	40.00	35.63	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-707	C\$151.20 Volume Pricing	20+ In Stock
18.00	50.00	45.24	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-708	C\$151.20 Volume Pricing	Contact Us

18.00	60.00	56.79	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-709	C\$151.20 Volume Pricing	20+ In Stock
18.00	75.00	72.15	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-710	C\$151.20 Volume Pricing	14 In Stock
18.00	80.00	76.52	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-711	C\$151.20 Volume Pricing	Contact Us
18.00	125.00	121.95	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-712	C\$151.20 Volume Pricing	16 In Stock
20.00	25.00	18.71	N-BAF10 / N-SF6	VIS 0° (425-675nm)	#49-944	C\$154.22 Volume Pricing	16 In Stock
20.00	30.00	24.70	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-733	C\$154.22 Volume Pricing	20+ In Stock
20.00	35.00	29.90	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-734	C\$154.22 Volume Pricing	17 In Stock
20.00	40.00	34.40	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-735	C\$154.22 Volume Pricing	14 In Stock
20.00	50.00	46.93	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-945	C\$154.22 Volume Pricing	11 In Stock
20.00	60.00	56.51	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-736	C\$154.22 Volume Pricing	20+ In Stock
20.00	80.00	77.26	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-946	C\$154.22 Volume Pricing	20+ In Stock
25.00	30.00	22.23	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-633	C\$175.39 Volume Pricing	20+ In Stock
25.00	35.00	27.55	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-634	C\$175.39 Volume Pricing	20+ In Stock
25.00	40.00	33.26	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-635	C\$172.37 Volume Pricing	20+ In Stock

25.00	45.00	39.28	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-636	C\$172.37 Volume Pricing	20+ In Stock
25.00	50.00	43.53	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-637	C\$172.37 Volume Pricing	20+ In Stock
25.00	60.00	52.23	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-638	C\$172.37 Volume Pricing	20+ In Stock
25.00	75.00	70.39	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-639	C\$172.37 Volume Pricing	20+ In Stock
25.00	85.00	81.21	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-640	C\$172.37 Volume Pricing	20+ In Stock
25.00	100.00	95.92	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-641	C\$172.37 Volume Pricing	20+ In Stock
25.00	125.00	120.89	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-642	C\$172.37 Volume Pricing	20+ In Stock
25.00	150.00	146.10	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-643	C\$172.37 Volume Pricing	Contact Us
25.00	160.00	157.87	N-BK7 / N-SF5	VIS 0° (425-675nm)	#67-331	C\$172.37 Volume Pricing	20+ In Stock
25.00	175.00	170.84	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-644	C\$172.37 Volume Pricing	20+ In Stock
25.00	200.00	194.14	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-645	C\$172.37 Volume Pricing	20+ In Stock
25.00	225.00	222.69	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-646	C\$172.37 Volume Pricing	20+ In Stock
25.00	250.00	246.63	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-647	C\$172.37 Volume Pricing	20+ In Stock
25.00	275.00	271.60	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-648	C\$172.37 Volume Pricing	20+ In Stock

25.00	300.00	297.73	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-649	C\$172.37 Volume Pricing	20+ In Stock
25.00	400.00	397.84	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-650	C\$172.37 Volume Pricing	20+ In Stock
25.00	500.00	497.57	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-651	C\$172.37 Volume Pricing	20+ In Stock
25.00	750.00	746.47	N-BK7 / N-SF5	VIS 0° (425-675nm)	#67-332	C\$172.37 Volume Pricing	20+ In Stock
25.40	38.10	30.77	N-BAF10 / N-SF6	VIS 0° (425-675nm)	#49-778	C\$172.37 Volume Pricing	20+ In Stock
25.40	50.80	44.90	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-779	C\$172.37 Volume Pricing	20+ In Stock
25.40	63.50	57.67	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-780	C\$172.37 Volume Pricing	20+ In Stock
25.40	76.20	71.14	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-781	C\$172.37 Volume Pricing	20+ In Stock
25.40	88.90	83.96	N-BAK1 / N-SF8	VIS 0° (425-675nm)	#49-782	C\$172.37 Volume Pricing	20+ In Stock
25.40	101.60	97.72	N-BAK1 / N-SF15	VIS 0° (425-675nm)	#49-783	C\$172.37 Volume Pricing	14 In Stock
30.00	40.00	31.14	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#33-920	C\$213.19 Volume Pricing	20+ In Stock
30.00	50.00	42.57	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-713	C\$213.19 Volume Pricing	20+ In Stock
30.00	60.00	52.50	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-714	C\$213.19 Volume Pricing	20+ In Stock
30.00	75.00	67.44	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-715	C\$213.19 Volume Pricing	20+ In Stock

30.00	100.00	94.54	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-716	C\$213.19 Volume Pricing	20+ In Stock
30.00	125.00	121.32	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-717	C\$213.19 Volume Pricing	20+ In Stock
30.00	150.00	144.63	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-718	C\$213.19 Volume Pricing	20+ In Stock
30.00	200.00	196.57	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-719	C\$213.19 Volume Pricing	20+ In Stock
40.00	50.00	34.46	N-SK11 / N-SF5	VIS 0° (425-675nm)	#89-682	C\$263.09 Volume Pricing	20+ In Stock
40.00	60.00	50.29	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-737	C\$263.09 Volume Pricing	20+ In Stock
40.00	80.00	70.75	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-738	C\$263.09 Volume Pricing	20+ In Stock
40.00	100.00	91.24	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-713	C\$263.09 Volume Pricing	20+ In Stock
40.00	120.00	111.00	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-739	C\$263.09 Volume Pricing	20+ In Stock
40.00	160.00	154.10	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-740	C\$263.09 Volume Pricing	20+ In Stock
40.00	200.00	194.21	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-741	C\$263.09 Volume Pricing	20+ In Stock
40.00	250.00	244.32	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-279	C\$263.09 Volume Pricing	20+ In Stock
40.00	300.00	293.63	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-280	C\$263.09 Volume Pricing	20+ In Stock
40.00	400.00	394.33	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-281	C\$263.09 Volume Pricing	20+ In Stock

40.00	450.00	445.69	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-282	C\$263.09 Volume Pricing	20+ In Stock
40.00	500.00	495.60	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-283	C\$263.09 Volume Pricing	20+ In Stock
40.00	750.00	744.37	N-BK7 / N-SF5	VIS 0° (425-675nm)	#67-333	C\$263.09 Volume Pricing	20+ In Stock
50.00	75.00	61.17	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-292	C\$291.82 Volume Pricing	20+ In Stock
50.00	100.00	89.94	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-284	C\$281.23 Volume Pricing	Contact Us
50.00	150.00	143.17	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-285	C\$281.23 Volume Pricing	Contact Us
50.00	200.00	194.45	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-286	C\$281.23 Volume Pricing	Contact Us
50.00	250.00	243.41	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-287	C\$281.23 Volume Pricing	20+ In Stock
50.00	300.00	292.91	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-288	C\$281.23 Volume Pricing	9 In Stock
50.00	350.00	344.32	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-289	C\$281.23 Volume Pricing	2 In Stock
50.00	500.00	494.50	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-290	C\$281.23 Volume Pricing	20+ In Stock
75.00	100.00	78.32	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#33-921	C\$532.22 Volume Pricing	20+ In Stock
75.00	150.00	126.46	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#33-922	C\$532.22 Volume Pricing	11 In Stock
75.00	200.00	187.69	N-BK7 / N-SF5	VIS 0° (425-675nm)	#88-593	C\$532.22 Volume Pricing	20+ In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com