

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Concave \(PCV\) Lenses](#)
TECHSPEC® VIS 0° Coated Plano-Concave (PCV) Lenses


- AR Coated to Provide <0.4% Reflectance per Surface for 425 - 675nm
- Designed for 0° Angle of Incidence
- Various Coating Options: [Uncoated](#), [VIS-EXT](#), [MgF₂](#), [VIS-NIR](#), [YAG-BBAR](#), [NIR-I](#), and [NIR-II](#)

Common Specifications

Physical & Mechanical Properties


Bevel: Protective as needed

Optical Properties


Coating: VIS 0° (425-675nm)

Wavelength Range (nm):	425 - 675	Coating Specification:	$R_{avg} \leq 0.4\% @ 425 - 675nm$
Focal Length Specification Wavelength (nm):	587.6	Focal Length Tolerance (%):	± 1
Power (P-V) @ 632.8nm:	1.5λ	Irregularity (P-V) @ 632.8nm:	$\lambda/4$

Technical Information

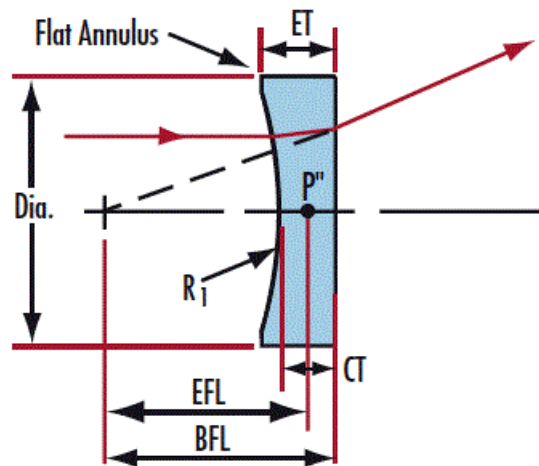

VIS 0° Coating
 $R_{avg} \leq 0.4\%$ @ 425 - 675nm
Typ. Energy Density Limit: 5 J/cm² @ 532nm, 10ns

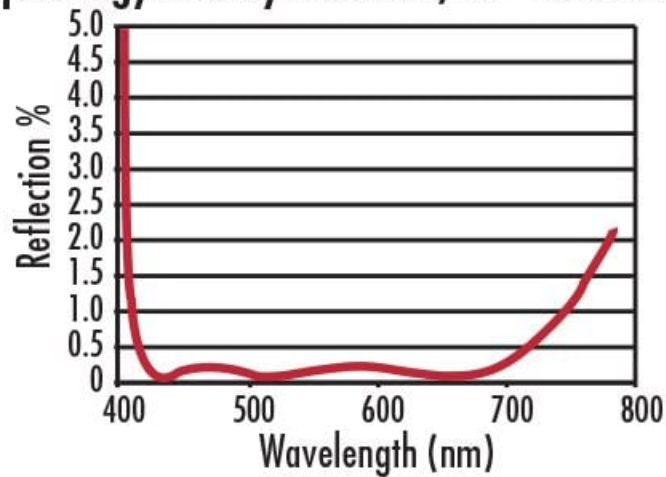

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
3.00	-6.00	-6.56	VIS 0° (425-675nm)	N-SF11	#84-377	C\$99.79 Volume Pricing	20+ In Stock
3.00	-9.00	-9.56	VIS 0° (425-675nm)	N-SF11	#84-378	C\$99.79 Volume Pricing	2 In Stock
6.00	-6.00	-6.84	VIS 0° (425-675nm)	N-SF11	#48-265	C\$61.24 Volume Pricing	20+ In Stock
6.00	-9.00	-9.84	VIS 0° (425-675nm)	N-SF11	#48-341	C\$61.24 Volume Pricing	12 In Stock
6.00	-12.00	-12.99	VIS 0° (425-675nm)	N-BK7	#48-266	C\$61.24 Volume Pricing	20+ In Stock
6.00	-15.00	-16.32	VIS 0° (425-675nm)	N-BK7	#48-690	C\$61.24 Volume Pricing	20+ In Stock
6.00	-18.00	-19.32	VIS 0° (425-675nm)	N-BK7	#48-267	C\$61.24 Volume Pricing	3 In Stock
9.00	-9.00	-10.21	VIS 0° (425-675nm)	N-SF11	#48-268	C\$62.75 Volume Pricing	20+ In Stock
9.00	-12.00	-13.26	VIS 0° (425-675nm)	N-SF11	#48-342	C\$62.75 Volume Pricing	10 In Stock
9.00	-18.00	-19.26	VIS 0° (425-675nm)	N-SF11	#48-269	C\$62.75 Volume Pricing	20+ In Stock
9.00	-27.00	-28.68	VIS 0° (425-675nm)	N-SF11	#48-270	C\$62.75 Volume Pricing	4 In Stock
12.00	-12.00	-13.23	VIS 0° (425-675nm)	N-SF11	#47-905	C\$65.77 Volume Pricing	20+ In Stock
12.00	-15.00	-16.68	VIS 0° (425-675nm)	N-SF11	#48-691	C\$65.77 Volume Pricing	20+ In Stock
12.00	-18.00	-19.95	VIS 0° (425-675nm)	N-SF11	#48-343	C\$65.77 Volume Pricing	20+ In Stock
12.00	-24.00	-26.32	VIS 0° (425-675nm)	N-BK7	#47-906	C\$65.77 Volume Pricing	Contact Us
12.00	-48.00	-50.31	VIS 0° (425-675nm)	N-BK7	#47-907	C\$65.77 Volume Pricing	20+ In Stock

20.00	-30.00	-31.96	VIS 0° (425-675nm)	N-SF11	#47-908	C\$68.04 Volume Pricing	20+ In Stock
20.00	-40.00	-42.31	VIS 0° (425-675nm)	N-BK7	#47-909	C\$68.04 Volume Pricing	6 In Stock
20.00	-50.00	-52.31	VIS 0° (425-675nm)	N-BK7	#47-910	C\$68.04 Volume Pricing	10 In Stock
20.00	-	-	VIS 0° (425-675nm)	N-BK7	#22-245	C\$68.04 Volume Pricing	6 In Stock
25.00	-25.00	-26.96	VIS 0° (425-675nm)	N-SF11	#47-911	C\$69.93 Volume Pricing	Contact Us
25.00	-35.00	-36.96	VIS 0° (425-675nm)	N-SF11	#48-692	C\$69.93 Volume Pricing	20+ In Stock
25.00	-50.00	-52.31	VIS 0° (425-675nm)	N-BK7	#47-912	C\$69.93 Volume Pricing	20+ In Stock
25.00	-	-	VIS 0° (425-675nm)	N-BK7	#47-913	C\$69.93 Volume Pricing	9 In Stock
50.00	-	-	VIS 0° (425-675nm)	N-BK7	#48-271	C\$101.30 Volume Pricing	15 In Stock
50.00	-	-	VIS 0° (425-675nm)	N-BK7	#48-272	C\$101.30 Volume Pricing	2 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com