

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® MgF₂ Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <1.75% Reflectance per Surface for 400 - 700nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), [VIS-EXT](#), and [YAG-BBAR](#)
- Also Available [Pre-Mounted in Engraved C-Mount Housings](#)

Common Specifications

Physical & Mechanical Properties



Bevel:	Protective as needed
--------	----------------------

Optical Properties

Focal Length Tolerance (%):	±1
-----------------------------	----

Wavelength Range (nm):	400 - 700
------------------------	-----------

Technical Information

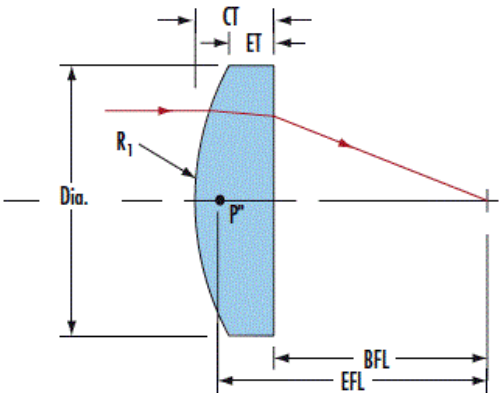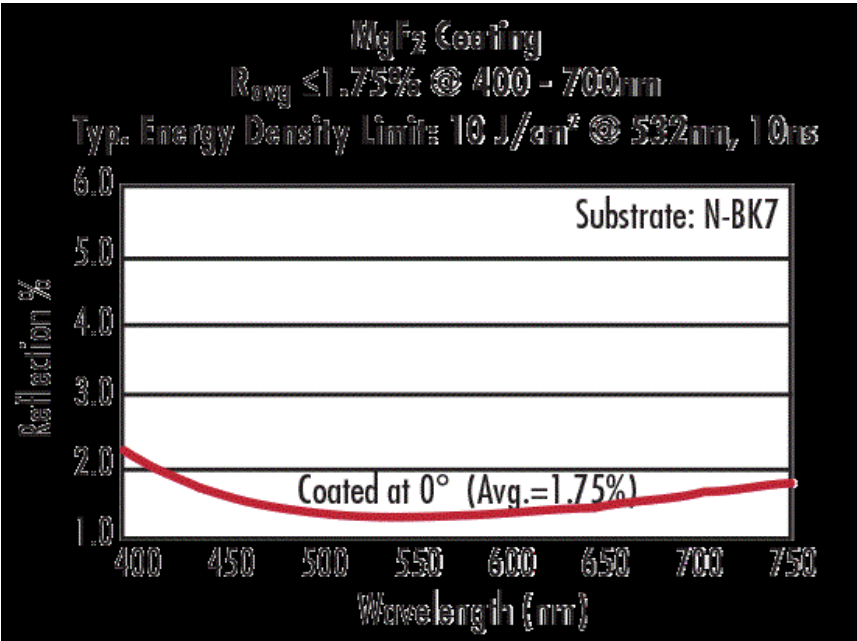

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	MgF ₂ (400-700nm)	N-LASF9	#65-257	C\$109.62 Volume Pricing	4 In Stock
1.00	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-258	C\$109.62 Volume Pricing	16 In Stock
1.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-259	C\$109.62 Volume Pricing	Contact Us
1.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-260	C\$109.62 Volume Pricing	1 In Stock
1.50	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-261	C\$109.62 Volume Pricing	2 In Stock
1.50	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-262	C\$109.62 Volume Pricing	1 In Stock
1.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-263	C\$109.62 Volume Pricing	14 In Stock
2.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-264	C\$108.11 Volume Pricing	6 In Stock
2.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-265	C\$108.11 Volume Pricing	9 In Stock
2.00	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-266	C\$108.11 Volume Pricing	2 In Stock
2.00	4.00	3.57	MgF ₂ (400-700nm)	N-LASF9	#65-267	C\$108.11 Volume Pricing	8 In Stock
2.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-268	C\$108.11 Volume Pricing	6 In Stock

2.50	2.50	2.05	MgF ₂ (400-700nm)	N-LASF9	#65-269	C\$108.11 Volume Pricing	7 In Stock
2.50	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-270	C\$108.11 Volume Pricing	7 In Stock
2.50	4.00	3.57	MgF ₂ (400-700nm)	N-LASF9	#65-271	C\$108.11 Volume Pricing	5 In Stock
2.50	5.00	4.57	MgF ₂ (400-700nm)	N-LASF9	#65-272	C\$108.11 Volume Pricing	5 In Stock
3.00	3.00	1.88	MgF ₂ (400-700nm)	N-SF11	#45-118	C\$89.21 Volume Pricing	20+ In Stock
3.00	4.50	3.50	MgF ₂ (400-700nm)	N-LASF44	#45-142	C\$89.21 Volume Pricing	Contact Us
3.00	6.00	4.81	MgF ₂ (400-700nm)	N-BK7	#32-953	C\$81.65 Volume Pricing	20+ In Stock
3.00	7.50	6.51	MgF ₂ (400-700nm)	N-BK7	#48-910	C\$81.65 Volume Pricing	5 In Stock
3.00	9.00	8.01	MgF ₂ (400-700nm)	N-BK7	#32-955	C\$81.65 Volume Pricing	10 In Stock
3.00	12.00	11.29	MgF ₂ (400-700nm)	N-BK7	#45-273	C\$81.65 Volume Pricing	14 In Stock
3.00	15.00	14.17	MgF ₂ (400-700nm)	N-BK7	#45-426	C\$81.65 Volume Pricing	12 In Stock
4.00	4.00	3.06	MgF ₂ (400-700nm)	N-LASF44	#45-224	C\$81.65 Volume Pricing	20+ In Stock
4.00	6.00	4.51	MgF ₂ (400-700nm)	N-BK7	#45-428	C\$81.65 Volume Pricing	20+ In Stock
4.00	8.00	7.17	MgF ₂ (400-700nm)	N-BAF10	#45-226	C\$75.22 Volume Pricing	20+ In Stock

4.00	10.00	8.92	MgF ₂ (400-700nm)	N-BK7	#45-430	C\$75.22 Volume Pricing	Contact Us
4.00	12.00	11.00	MgF ₂ (400-700nm)	N-BK7	#45-432	C\$75.22 Volume Pricing	20+ In Stock
4.50	4.50	3.05	MgF ₂ (400-700nm)	N-LASF44	#45-144	C\$81.65 Volume Pricing	20+ In Stock
4.50	9.00	7.41	MgF ₂ (400-700nm)	N-BK7	#45-148	C\$75.22 Volume Pricing	20+ In Stock
5.00	5.00	3.96	MgF ₂ (400-700nm)	N-LASF44	#45-228	C\$65.39 Volume Pricing	20+ In Stock
5.00	7.50	6.43	MgF ₂ (400-700nm)	N-SF11	#48-655	C\$64.64 Volume Pricing	15 In Stock
5.00	10.00	8.91	MgF ₂ (400-700nm)	N-BK7	#45-230	C\$64.64 Volume Pricing	20+ In Stock
5.00	12.00	10.83	MgF ₂ (400-700nm)	N-BK7	#45-434	C\$64.64 Volume Pricing	20+ In Stock
5.00	15.00	13.94	MgF ₂ (400-700nm)	N-BK7	#45-355	C\$64.64 Volume Pricing	5 In Stock
5.00	20.00	19.02	MgF ₂ (400-700nm)	N-BK7	#49-883	C\$64.64 Volume Pricing	20+ In Stock
5.00	25.00	23.95	MgF ₂ (400-700nm)	N-BK7	#87-913	C\$64.64 Volume Pricing	5 In Stock
5.00	30.00	28.95	MgF ₂ (400-700nm)	N-BK7	#87-914	C\$64.64 Volume Pricing	2 In Stock
6.00	6.00	4.60	MgF ₂ (400-700nm)	N-SF11	#45-078	C\$52.92 Volume Pricing	20+ In Stock
6.00	7.50	6.10	MgF ₂ (400-700nm)	N-SF11	#49-884	C\$52.16 Volume Pricing	20+ In Stock

6.00	9.00	7.95	MgF ₂ (400-700nm)	N-SF5	#32-470	C\$52.16 Volume Pricing	20+ In Stock
6.00	10.00	8.82	MgF ₂ (400-700nm)	N-BK7	#38-215	C\$52.16 Volume Pricing	7 In Stock
6.00	12.00	10.94	MgF ₂ (400-700nm)	N-BK7	#32-472	C\$50.65 Volume Pricing	20+ In Stock
6.00	15.00	13.68	MgF ₂ (400-700nm)	N-BK7	#45-080	C\$50.65 Volume Pricing	20+ In Stock
6.00	18.00	17.07	MgF ₂ (400-700nm)	N-BK7	#32-474	C\$50.65 Volume Pricing	20+ In Stock
6.00	20.00	19.04	MgF ₂ (400-700nm)	N-BK7	#38-216	C\$50.65 Volume Pricing	1 In Stock
6.00	21.00	20.06	MgF ₂ (400-700nm)	N-BK7	#45-232	C\$50.65 Volume Pricing	20+ In Stock
6.00	24.00	23.01	MgF ₂ (400-700nm)	N-BK7	#32-957	C\$50.65 Volume Pricing	20+ In Stock
6.00	25.00	24.04	MgF ₂ (400-700nm)	N-BK7	#38-217	C\$50.65 Volume Pricing	2 In Stock
6.00	30.00	29.14	MgF ₂ (400-700nm)	N-BK7	#45-120	C\$50.65 Volume Pricing	6 In Stock
6.00	36.00	34.95	MgF ₂ (400-700nm)	N-BK7	#32-849	C\$50.65 Volume Pricing	14 In Stock
6.00	48.00	46.95	MgF ₂ (400-700nm)	N-BK7	#45-234	C\$50.65 Volume Pricing	5 In Stock
6.00	60.00	58.95	MgF ₂ (400-700nm)	N-BK7	#67-154	C\$50.65 Volume Pricing	1 In Stock
6.00	72.00	70.97	MgF ₂ (400-700nm)	N-BK7	#32-851	C\$50.65 Volume Pricing	20+ In Stock

7.00	7.00	5.50	MgF ₂ (400-700nm)	N-SF11	#71-293	C\$52.92 Volume Pricing	3 In Stock
7.00	10.00	8.10	MgF ₂ (400-700nm)	N-BK7	#71-300	C\$52.16 Volume Pricing	5 In Stock
7.00	12.00	10.30	MgF ₂ (400-700nm)	N-BK7	#71-307	C\$52.16 Volume Pricing	3 In Stock
8.00	8.00	6.40	MgF ₂ (400-700nm)	N-SF11	#71-314	C\$52.92 Volume Pricing	20+ In Stock
8.00	10.00	7.60	MgF ₂ (400-700nm)	N-BK7	#71-321	C\$52.16 Volume Pricing	9 In Stock
8.00	12.00	10.00	MgF ₂ (400-700nm)	N-BK7	#71-328	C\$52.16 Volume Pricing	7 In Stock
9.00	9.00	7.32	MgF ₂ (400-700nm)	N-SF11	#45-082	C\$53.68 Volume Pricing	7 In Stock
9.00	10.00	8.49	MgF ₂ (400-700nm)	N-SF11	#38-218	C\$53.68 Volume Pricing	20+ In Stock
9.00	12.00	10.60	MgF ₂ (400-700nm)	N-SF11	#49-885	C\$53.68 Volume Pricing	20+ In Stock
9.00	13.50	11.94	MgF ₂ (400-700nm)	N-SF5	#32-010	C\$53.68 Volume Pricing	20+ In Stock
9.00	15.00	13.02	MgF ₂ (400-700nm)	N-BK7	#49-886	C\$53.68 Volume Pricing	20+ In Stock
9.00	18.00	16.41	MgF ₂ (400-700nm)	N-BK7	#31-854	C\$52.16 Volume Pricing	20+ In Stock
9.00	20.00	18.55	MgF ₂ (400-700nm)	N-BK7	#38-219	C\$52.16 Volume Pricing	1 In Stock
9.00	22.00	20.73	MgF ₂ (400-700nm)	N-BK7	#45-236	C\$52.16 Volume Pricing	11 In Stock

9.00	25.00	23.68	MgF ₂ (400-700nm)	N-BK7	#38-220	C\$52.16 Volume Pricing	3 In Stock
9.00	27.00	25.35	MgF ₂ (400-700nm)	N-BK7	#32-959	C\$52.16 Volume Pricing	20+ In Stock
9.00	36.00	34.48	MgF ₂ (400-700nm)	N-BK7	#45-122	C\$52.16 Volume Pricing	Contact Us
9.00	45.00	43.98	MgF ₂ (400-700nm)	N-BK7	#45-357	C\$52.16 Volume Pricing	7 In Stock
9.00	54.00	52.69	MgF ₂ (400-700nm)	N-BK7	#67-155	C\$52.16 Volume Pricing	6 In Stock
9.00	72.00	70.68	MgF ₂ (400-700nm)	N-BK7	#67-156	C\$52.16 Volume Pricing	20+ In Stock
9.00	90.00	88.68	MgF ₂ (400-700nm)	N-BK7	#67-157	C\$52.16 Volume Pricing	6 In Stock
10.00	10.00	8.18	MgF ₂ (400-700nm)	N-SF11	#63-484	C\$53.68 Volume Pricing	20+ In Stock
10.00	12.50	10.99	MgF ₂ (400-700nm)	N-SF11	#38-223	C\$53.68 Volume Pricing	20+ In Stock
10.00	15.00	13.32	MgF ₂ (400-700nm)	N-SF11	#63-485	C\$53.68 Volume Pricing	20+ In Stock
10.00	17.50	15.66	MgF ₂ (400-700nm)	N-BK7	#38-224	C\$52.16 Volume Pricing	20+ In Stock
10.00	20.00	18.03	MgF ₂ (400-700nm)	N-BK7	#63-486	C\$52.16 Volume Pricing	20+ In Stock
10.00	25.00	23.02	MgF ₂ (400-700nm)	N-BK7	#63-487	C\$52.16 Volume Pricing	20+ In Stock
10.00	30.00	28.01	MgF ₂ (400-700nm)	N-BK7	#63-488	C\$52.16 Volume Pricing	20+ In Stock

10.00	40.00	38.02	MgF ₂ (400-700nm)	N-BK7	#63-489	C\$52.16 Volume Pricing	Contact Us
10.00	50.00	48.02	MgF ₂ (400-700nm)	N-BK7	#63-490	C\$52.16 Volume Pricing	4 In Stock
10.00	75.00	73.02	MgF ₂ (400-700nm)	N-BK7	#63-491	C\$52.16 Volume Pricing	16 In Stock
10.00	100.00	98.02	MgF ₂ (400-700nm)	N-BK7	#63-492	C\$52.16 Volume Pricing	Contact Us
12.00	12.00	9.76	MgF ₂ (400-700nm)	N-SF11	#45-084	C\$56.70 Volume Pricing	20+ In Stock
12.00	15.00	12.03	MgF ₂ (400-700nm)	N-BK7	#45-303	C\$56.70 Volume Pricing	20+ In Stock
12.00	18.00	16.22	MgF ₂ (400-700nm)	N-SF5	#32-007	C\$56.70 Volume Pricing	20+ In Stock
12.00	20.00	17.69	MgF ₂ (400-700nm)	N-BK7	#49-887	C\$56.70 Volume Pricing	20+ In Stock
12.00	24.00	22.15	MgF ₂ (400-700nm)	N-BK7	#31-855	C\$55.19 Volume Pricing	20+ In Stock
12.00	25.00	23.22	MgF ₂ (400-700nm)	N-BK7	#38-226	C\$55.19 Volume Pricing	2 In Stock
12.00	30.00	28.02	MgF ₂ (400-700nm)	N-BK7	#45-086	C\$55.19 Volume Pricing	20+ In Stock
12.00	36.00	34.02	MgF ₂ (400-700nm)	N-BK7	#33-353	C\$55.19 Volume Pricing	20+ In Stock
12.00	42.00	40.22	MgF ₂ (400-700nm)	N-BK7	#45-124	C\$55.19 Volume Pricing	2 In Stock
12.00	48.00	46.36	MgF ₂ (400-700nm)	N-BK7	#32-853	C\$55.19 Volume Pricing	20+ In Stock

12.00	50.00	48.75	MgF ₂ (400-700nm)	N-BK7	#38-230	C\$55.19 Volume Pricing	4 In Stock
12.00	54.00	52.02	MgF ₂ (400-700nm)	N-BK7	#45-305	C\$55.19 Volume Pricing	20+ In Stock
12.00	60.00	58.37	MgF ₂ (400-700nm)	N-BK7	#32-855	C\$55.19 Volume Pricing	20+ In Stock
12.00	72.00	70.42	MgF ₂ (400-700nm)	N-BK7	#45-126	C\$55.19 Volume Pricing	14 In Stock
12.00	84.00	82.39	MgF ₂ (400-700nm)	N-BK7	#32-857	C\$55.19 Volume Pricing	20+ In Stock
12.00	100.00	98.35	MgF ₂ (400-700nm)	N-BK7	#45-275	C\$55.19 Volume Pricing	3 In Stock
12.50	12.50	10.40	MgF ₂ (400-700nm)	N-SF11	#38-231	C\$55.19 Volume Pricing	Contact Us
12.50	15.00	13.26	MgF ₂ (400-700nm)	N-SF11	#38-232	C\$55.19 Volume Pricing	13 In Stock
12.50	17.50	15.00	MgF ₂ (400-700nm)	N-BK7	#38-233	C\$55.19 Volume Pricing	2 In Stock
12.50	20.00	17.69	MgF ₂ (400-700nm)	N-BK7	#38-234	C\$55.19 Volume Pricing	8 In Stock
12.50	25.00	22.96	MgF ₂ (400-700nm)	N-BK7	#38-235	C\$53.68 Volume Pricing	1 In Stock
12.50	30.00	28.22	MgF ₂ (400-700nm)	N-BK7	#38-237	C\$53.68 Volume Pricing	1 In Stock
12.50	35.00	33.42	MgF ₂ (400-700nm)	N-BK7	#38-238	C\$53.68 Volume Pricing	6 In Stock
12.50	40.00	38.55	MgF ₂ (400-700nm)	N-BK7	#38-239	C\$53.68 Volume Pricing	4 In Stock

12.50	45.00	43.68	MgF ₂ (400-700nm)	N-BK7	#38-240	C\$53.68 Volume Pricing	1 In Stock
12.50	50.00	48.68	MgF ₂ (400-700nm)	N-BK7	#38-241	C\$53.68 Volume Pricing	4 In Stock
12.50	75.00	73.88	MgF ₂ (400-700nm)	N-BK7	#38-242	C\$53.68 Volume Pricing	5 In Stock
12.50	100.00	98.95	MgF ₂ (400-700nm)	N-BK7	#38-243	C\$53.68 Volume Pricing	3 In Stock
12.70	12.70	10.46	MgF ₂ (400-700nm)	N-SF11	#49-854	C\$55.19 Volume Pricing	8 In Stock
12.70	15.00	11.53	MgF ₂ (400-700nm)	N-BK7	#49-855	C\$55.19 Volume Pricing	20+ In Stock
12.70	19.10	16.46	MgF ₂ (400-700nm)	N-BK7	#49-856	C\$55.19 Volume Pricing	Contact Us
12.70	20.00	17.49	MgF ₂ (400-700nm)	N-BK7	#38-244	C\$55.19 Volume Pricing	4 In Stock
12.70	25.40	23.43	MgF ₂ (400-700nm)	N-BK7	#49-857	C\$53.68 Volume Pricing	20+ In Stock
12.70	30.00	28.22	MgF ₂ (400-700nm)	N-BK7	#38-245	C\$53.68 Volume Pricing	3 In Stock
12.70	31.80	29.81	MgF ₂ (400-700nm)	N-BK7	#49-858	C\$53.68 Volume Pricing	20+ In Stock
12.70	38.10	36.12	MgF ₂ (400-700nm)	N-BK7	#49-859	C\$53.68 Volume Pricing	20+ In Stock
12.70	40.00	38.48	MgF ₂ (400-700nm)	N-BK7	#38-246	C\$53.68 Volume Pricing	3 In Stock
12.70	44.50	42.69	MgF ₂ (400-700nm)	N-BK7	#49-860	C\$53.68 Volume Pricing	20+ In Stock

12.70	50.80	49.15	MgF ₂ (400-700nm)	N-BK7	#49-861	C\$53.68 Volume Pricing	20+ In Stock
12.70	100.00	98.88	MgF ₂ (400-700nm)	N-BK7	#38-247	C\$53.68 Volume Pricing	20+ In Stock
15.00	15.00	11.71	MgF ₂ (400-700nm)	N-SF5	#45-094	C\$56.70 Volume Pricing	Contact Us
15.00	18.00	15.61	MgF ₂ (400-700nm)	N-SF5	#49-888	C\$56.70 Volume Pricing	20+ In Stock
15.00	20.00	17.74	MgF ₂ (400-700nm)	N-SF5	#63-493	C\$56.70 Volume Pricing	20+ In Stock
15.00	22.50	20.50	MgF ₂ (400-700nm)	N-SF5	#32-005	C\$56.70 Volume Pricing	Contact Us
15.00	25.00	22.50	MgF ₂ (400-700nm)	N-BK7	#38-248	C\$55.19 Volume Pricing	Contact Us
15.00	30.00	27.90	MgF ₂ (400-700nm)	N-BK7	#31-856	C\$55.19 Volume Pricing	20+ In Stock
15.00	40.00	38.02	MgF ₂ (400-700nm)	N-BK7	#45-096	C\$55.19 Volume Pricing	20+ In Stock
15.00	45.00	43.35	MgF ₂ (400-700nm)	N-BK7	#49-889	C\$55.19 Volume Pricing	20+ In Stock
15.00	50.00	48.35	MgF ₂ (400-700nm)	N-BK7	#38-249	C\$55.19 Volume Pricing	20+ In Stock
15.00	60.00	58.65	MgF ₂ (400-700nm)	N-BK7	#45-436	C\$55.19 Volume Pricing	10 In Stock
15.00	75.00	73.79	MgF ₂ (400-700nm)	N-BK7	#45-359	C\$55.19 Volume Pricing	20+ In Stock
15.00	100.00	98.02	MgF ₂ (400-700nm)	N-BK7	#45-260	C\$55.19 Volume Pricing	7 In Stock

15.00	200.00	197.89	MgF ₂ (400-700nm)	N-BK7	#14-375	C\$55.19 Volume Pricing	Contact Us
15.00	250.00	248.02	MgF ₂ (400-700nm)	N-BK7	#14-383	C\$55.19 Volume Pricing	6 In Stock
#45-438 Clearance							
 Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
18.00	18.00	11.20	MgF ₂ (400-700nm)	N-BK7		C\$31.68	20+ In Stock
18.00	18.00	15.20	MgF ₂ (400-700nm)	N-SF11	#48-424	C\$57.46 Volume Pricing	13 In Stock
18.00	20.00	17.59	MgF ₂ (400-700nm)	N-SF11	#38-250	C\$56.70 Volume Pricing	1 In Stock
18.00	22.50	20.26	MgF ₂ (400-700nm)	N-SF11	#49-890	C\$56.70 Volume Pricing	20+ In Stock
18.00	25.00	21.51	MgF ₂ (400-700nm)	N-BK7	#38-251	C\$56.70 Volume Pricing	4 In Stock
18.00	27.00	24.73	MgF ₂ (400-700nm)	N-SF5	#32-002	C\$56.70 Volume Pricing	20+ In Stock
18.00	30.00	27.10	MgF ₂ (400-700nm)	N-BK7	#38-252	C\$54.43 Volume Pricing	5 In Stock

18.00	36.00	33.65	MgF ₂ (400-700nm)	N-BK7	#31-857	C\$54.43 Volume Pricing	20+ In Stock
18.00	50.00	48.09	MgF ₂ (400-700nm)	N-BK7	#38-253	C\$54.43 Volume Pricing	4 In Stock
18.00	54.00	52.02	MgF ₂ (400-700nm)	N-BK7	#45-307	C\$54.43 Volume Pricing	20+ In Stock
18.00	72.00	70.05	MgF ₂ (400-700nm)	N-BK7	#32-860	C\$54.43 Volume Pricing	6 In Stock
20.00	20.00	17.42	MgF ₂ (400-700nm)	N-SF11	#45-238	C\$58.21 Volume Pricing	20+ In Stock
20.00	25.00	22.76	MgF ₂ (400-700nm)	N-SF11	#49-891	C\$57.46 Volume Pricing	20+ In Stock
20.00	30.00	27.30	MgF ₂ (400-700nm)	N-BAF10	#45-240	C\$57.46 Volume Pricing	20+ In Stock
20.00	35.00	32.04	MgF ₂ (400-700nm)	N-BK7	#49-892	C\$57.46 Volume Pricing	20+ In Stock
20.00	40.00	36.77	MgF ₂ (400-700nm)	N-BK7	#32-961	C\$55.19 Volume Pricing	20+ In Stock
20.00	50.00	47.87	MgF ₂ (400-700nm)	N-BK7	#45-361	C\$55.19 Volume Pricing	20+ In Stock
20.00	60.00	57.03	MgF ₂ (400-700nm)	N-BK7	#32-963	C\$55.19 Volume Pricing	20+ In Stock
20.00	70.00	68.03	MgF ₂ (400-700nm)	N-BK7	#32-937	C\$55.19 Volume Pricing	5 In Stock
20.00	80.00	78.45	MgF ₂ (400-700nm)	N-BK7	#45-440	C\$55.19 Volume Pricing	20+ In Stock
20.00	100.00	97.13	MgF ₂ (400-700nm)	N-BK7	#32-476	C\$55.19 Volume Pricing	Contact Us

20.00	150.00	148.02	MgF ₂ (400-700nm)	N-BK7	#45-277	C\$55.19 Volume Pricing	11 In Stock
25.00	25.00	20.22	MgF ₂ (400-700nm)	N-SF5	#45-098	C\$58.21 Volume Pricing	20+ In Stock
25.00	30.00	24.69	MgF ₂ (400-700nm)	N-BK7	#45-363	C\$58.21 Volume Pricing	20+ In Stock
25.00	35.00	30.42	MgF ₂ (400-700nm)	N-BK7	#45-146	C\$58.21 Volume Pricing	20+ In Stock
25.00	40.00	36.31	MgF ₂ (400-700nm)	N-BK7	#45-279	C\$58.21 Volume Pricing	20+ In Stock
25.00	50.00	46.75	MgF ₂ (400-700nm)	N-BK7	#32-478	C\$55.19 Volume Pricing	20+ In Stock
25.00	60.00	56.90	MgF ₂ (400-700nm)	N-BK7	#45-128	C\$55.19 Volume Pricing	20+ In Stock
25.00	75.00	72.00	MgF ₂ (400-700nm)	N-BK7	#32-480	C\$55.19 Volume Pricing	20+ In Stock
25.00	85.00	82.17	MgF ₂ (400-700nm)	N-BK7	#45-365	C\$55.19 Volume Pricing	20+ In Stock
25.00	100.00	97.17	MgF ₂ (400-700nm)	N-BK7	#32-482	C\$55.19 Volume Pricing	20+ In Stock
25.00	125.00	122.70	MgF ₂ (400-700nm)	N-BK7	#32-862	C\$55.19 Volume Pricing	17 In Stock
25.00	150.00	147.81	MgF ₂ (400-700nm)	N-BK7	#32-864	C\$55.19 Volume Pricing	7 In Stock
25.00	175.00	172.85	MgF ₂ (400-700nm)	N-BK7	#32-866	C\$55.19 Volume Pricing	Contact Us
25.00	200.00	197.89	MgF ₂ (400-700nm)	N-BK7	#33-359	C\$55.19 Volume Pricing	7 In Stock

25.00	250.00	248.02	MgF ₂ (400-700nm)	N-BK7	#67-158	C\$55.19 Volume Pricing	5 In Stock
25.00	300.00	298.02	MgF ₂ (400-700nm)	N-BK7	#67-159	C\$55.19 Volume Pricing	17 In Stock
25.00	400.00	397.89	MgF ₂ (400-700nm)	N-BK7	#33-365	C\$55.19 Volume Pricing	4 In Stock
25.00	500.00	497.89	MgF ₂ (400-700nm)	N-BK7	#45-281	C\$55.19 Volume Pricing	20+ In Stock
25.00	750.00	747.89	MgF ₂ (400-700nm)	N-BK7	#45-283	C\$55.19 Volume Pricing	Contact Us
25.40	25.40	21.48	MgF ₂ (400-700nm)	N-SF11	#49-862	C\$58.21 Volume Pricing	20+ In Stock
25.40	35.00	30.46	MgF ₂ (400-700nm)	N-BK7	#38-254	C\$58.21 Volume Pricing	9 In Stock
25.40	38.10	33.48	MgF ₂ (400-700nm)	N-BK7	#49-863	C\$58.21 Volume Pricing	14 In Stock
25.40	40.00	36.11	MgF ₂ (400-700nm)	N-BK7	#38-255	C\$58.21 Volume Pricing	4 In Stock
25.40	50.80	47.50	MgF ₂ (400-700nm)	N-BK7	#49-864	C\$55.19 Volume Pricing	20+ In Stock
25.40	63.50	60.37	MgF ₂ (400-700nm)	N-BK7	#49-865	C\$55.19 Volume Pricing	20+ In Stock
25.40	75.00	72.69	MgF ₂ (400-700nm)	N-BK7	#38-262	C\$55.19 Volume Pricing	4 In Stock
25.40	76.20	73.56	MgF ₂ (400-700nm)	N-BK7	#49-866	C\$55.19 Volume Pricing	20+ In Stock
25.40	88.90	86.26	MgF ₂ (400-700nm)	N-BK7	#49-867	C\$55.19 Volume Pricing	20+ In Stock

25.40	100.00	98.02	MgF ₂ (400-700nm)	N-BK7	#38-264	C\$55.19 Volume Pricing	2 In Stock
25.40	101.60	98.97	MgF ₂ (400-700nm)	N-BK7	#49-868	C\$55.19 Volume Pricing	Contact Us
25.40	125.00	123.02	MgF ₂ (400-700nm)	N-BK7	#38-265	C\$55.19 Volume Pricing	3 In Stock
25.40	150.00	148.02	MgF ₂ (400-700nm)	N-BK7	#38-266	C\$55.19 Volume Pricing	20+ In Stock
30.00	30.00	26.13	MgF ₂ (400-700nm)	N-SF11	#48-656	C\$75.98 Volume Pricing	20+ In Stock
30.00	40.00	37.20	MgF ₂ (400-700nm)	N-SF11	#67-160	C\$73.71 Volume Pricing	14 In Stock
30.00	50.00	46.17	MgF ₂ (400-700nm)	N-SF5	#32-484	C\$73.71 Volume Pricing	20+ In Stock
30.00	60.00	56.03	MgF ₂ (400-700nm)	N-BK7	#45-242	C\$71.44 Volume Pricing	20+ In Stock
30.00	75.00	70.95	MgF ₂ (400-700nm)	N-BK7	#32-486	C\$71.44 Volume Pricing	20+ In Stock
30.00	100.00	96.01	MgF ₂ (400-700nm)	N-BK7	#32-488	C\$71.44 Volume Pricing	20+ In Stock
30.00	120.00	116.04	MgF ₂ (400-700nm)	N-BK7	#45-244	C\$71.44 Volume Pricing	10 In Stock
35.00	35.00	30.52	MgF ₂ (400-700nm)	N-SF11	#38-267	C\$78.62 Volume Pricing	4 In Stock
35.00	50.00	44.40	MgF ₂ (400-700nm)	N-BK7	#38-268	C\$75.98 Volume Pricing	5 In Stock
35.00	70.00	66.04	MgF ₂ (400-700nm)	N-BK7	#38-269	C\$75.98 Volume Pricing	20+ In Stock

35.00	100.00	97.03	MgF ₂ (400-700nm)	N-BK7	#38-270	C\$75.98 Volume Pricing	2 In Stock
40.00	40.00	35.13	MgF ₂ (400-700nm)	N-SF11	#48-657	C\$82.40 Volume Pricing	20+ In Stock
40.00	60.00	53.90	MgF ₂ (400-700nm)	N-BK7	#45-150	C\$82.40 Volume Pricing	16 In Stock
40.00	80.00	74.73	MgF ₂ (400-700nm)	N-BK7	#33-383	C\$80.89 Volume Pricing	20+ In Stock
40.00	100.00	95.39	MgF ₂ (400-700nm)	N-BK7	#33-371	C\$80.89 Volume Pricing	20+ In Stock
40.00	200.00	196.7	MgF ₂ (400-700nm)	N-BK7	#33-377	C\$80.89 Volume Pricing	5 In Stock
40.00	300.00	296.70	MgF ₂ (400-700nm)	N-BK7	#45-285	C\$80.89 Volume Pricing	20+ In Stock
40.00	400.00	396.70	MgF ₂ (400-700nm)	N-BK7	#45-287	C\$80.89 Volume Pricing	13 In Stock
50.00	50.00	43.28	MgF ₂ (400-700nm)	N-SF11	#32-971	C\$89.96 Volume Pricing	20+ In Stock
50.00	75.00	67.75	MgF ₂ (400-700nm)	N-BK7	#45-246	C\$86.94 Volume Pricing	20+ In Stock
50.00	100.00	93.41	MgF ₂ (400-700nm)	N-BK7	#32-973	C\$83.16 Volume Pricing	20+ In Stock
50.00	125.00	118.39	MgF ₂ (400-700nm)	N-BK7	#45-248	C\$83.16 Volume Pricing	9 In Stock
50.00	150.00	144.07	MgF ₂ (400-700nm)	N-BK7	#32-975	C\$83.16 Volume Pricing	20+ In Stock
50.00	175.00	169.05	MgF ₂ (400-700nm)	N-BK7	#45-250	C\$83.16 Volume Pricing	12 In Stock

50.00	200.00	196.66	MgF ₂ (400-700nm)	N-BK7	#45-152	C\$83.16 Volume Pricing	3 In Stock
50.00	250.00	246.74	MgF ₂ (400-700nm)	N-BK7	#45-154	C\$83.16 Volume Pricing	20+ In Stock
50.00	500.00	496.70	MgF ₂ (400-700nm)	N-BK7	#45-289	C\$83.16 Volume Pricing	20+ In Stock
50.80	50.81	44.08	MgF ₂ (400-700nm)	N-SF11	#71-335	C\$89.96 Volume Pricing	5 In Stock
50.80	76.20	68.95	MgF ₂ (400-700nm)	N-BK7	#71-342	C\$86.94 Volume Pricing	2 In Stock
75.00	75.00	53.49	MgF ₂ (400-700nm)	N-BK7	#45-368	C\$150.44 Volume Pricing	7 In Stock
75.00	100.00	87.57	MgF ₂ (400-700nm)	N-BK7	#71-840	C\$147.42 Volume Pricing	4 In Stock
75.00	125.00	115.99	MgF ₂ (400-700nm)	N-BK7	#71-841	C\$147.42 Volume Pricing	2 In Stock
75.00	150.00	142.45	MgF ₂ (400-700nm)	N-BK7	#45-370	C\$147.42 Volume Pricing	12 In Stock
75.00	175.00	168.68	MgF ₂ (400-700nm)	N-BK7	#71-842	C\$147.42 Volume Pricing	2 In Stock
75.00	200.00	194.24	MgF ₂ (400-700nm)	N-BK7	#45-372	C\$147.42 Volume Pricing	1 In Stock
75.00	250.00	244.73	MgF ₂ (400-700nm)	N-BK7	#63-495	C\$147.42 Volume Pricing	20+ In Stock
75.00	300.00	294.4	MgF ₂ (400-700nm)	N-BK7	#71-843	C\$147.42 Volume Pricing	5 In Stock
75.00	400.00	394.4	MgF ₂ (400-700nm)	N-BK7	#71-844	C\$147.42 Volume Pricing	2 In Stock

75.00	500.00	494.73	MgF ₂ (400-700nm)	N-BK7	#63-496	C\$147.42 Volume Pricing	20+ In Stock
75.00	750.00	745.35	MgF ₂ (400-700nm)	N-BK7	#71-845	C\$147.42 Volume Pricing	5 In Stock
100.00	200.00	190.77	MgF ₂ (400-700nm)	N-BK7	#17-900	C\$468.72 Volume Pricing	Contact Us
150.00	300.00	285.50	MgF ₂ (400-700nm)	N-BK7	#17-916	C\$861.84 Volume Pricing	Contact Us
200.00	400.00	381.54	MgF ₂ (400-700nm)	N-BK7	#17-932	C\$1,617.84 Volume Pricing	5 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com