


[All Products](#) / [Test Targets](#) / [Distortion Test Targets](#)

Diffuse Reflectance Grid Distortion Targets

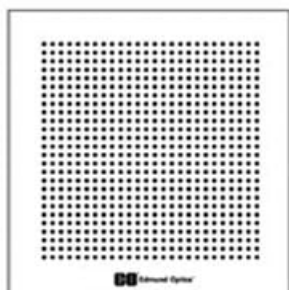

- Diffuse Reflectance Treatment Mimics Ceramic Targets
- Chrome Pattern on Substrate
- No Glare with On or Off Axis Lighting
- Perfect for Front Illuminated Measuring

Common Specifications

General

NIST Certification:	No
---------------------	----

Physical & Mechanical Properties

Thickness (mm):	2.00 ±0.2
-----------------	-----------

Center to Center Spacing Tolerance (μm):	± 1
--	-----

Dot Diameter Tolerance (μm):	±3
---------------------------------	----

Optical Properties

Coating:	Low Reflective Chrome
----------	-----------------------

Substrate:	Float Glass
------------	-------------

Technical Information

Products

Title	Stock Number	Price	Buy
2" x 2" 0.0625mm Dot, Low Reflect Grid Distortion Target	#62-949	C\$994.00 Volume Pricing	7 In Stock
2" x 2" 0.125mm Dot, Low Reflect Grid Distortion Target	#62-950	C\$959.00 Volume Pricing	5 In Stock
2" x 2" 0.25mm Dot, Low Reflect Grid Distortion Target	#62-951	C\$931.00 Volume Pricing	2 In Stock
3" x 3" 0.125mm Dot, Low Reflect Grid Distortion Target	#62-952	C\$1,197.00 Volume Pricing	2 In Stock
3" x 3" 0.25mm Dot, Low Reflect Grid Distortion Target	#62-953	C\$1,141.00 Volume Pricing	Contact Us
3" x 3" 0.5mm Dot, Low Reflect Grid Distortion Target	#62-954	C\$1,099.00 Volume Pricing	20+ In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com