

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Focusing \(Concave\) Mirrors](#)

Precision Parabolic Reflectors



- Precision Polished Substrate
- Protected Aluminum and Cold Mirror Coating Options
- Ideal for Highly Divergent Light Sources
- [Precision Ellipsoidal Reflectors](#) Also Available


Common Specifications

Optical Properties

Substrate: [BOROFLOAT®](#)

Coating Type: Metal

Technical Information

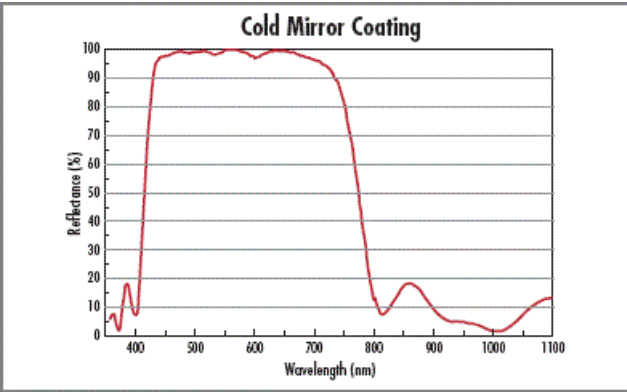

Products

Dia. (mm)	FL (mm)	Aperture (f/#)	Coating	Stock Number	Price	Buy
100.00	12.50	0.125	Protected Aluminum (400-700nm)	#90-964	C\$549.08 Volume Pricing	3 In Stock
100.00	19.00	0.190	Protected Aluminum (400-700nm)	#68-791	C\$549.08 Volume Pricing	6 In Stock
152.00	17.00	0.112	Protected Aluminum (400-700nm)	#68-792	C\$1,172.36 Volume Pricing	4 In Stock
152.00	30.00	0.197	Protected Aluminum (400-700nm)	#90-965	C\$1,038.80 Volume Pricing	3 In Stock
220.00	100.00	0.455	Protected Aluminum (400-700nm)	#68-793	C\$1,291.08 Volume Pricing	8 In Stock
300.00	42.00	0.140	Protected Aluminum (400-700nm)	#90-966	C\$2,151.80 Volume Pricing	3 In Stock
100.00	12.50	0.125	Cold Mirror, 0°	#90-967	C\$749.42 Volume Pricing	3 In Stock
100.00	19.00	0.190	Cold Mirror, 0°	#68-795	C\$749.42 Volume Pricing	3 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
Phone: 1-800-363-1992 :
www.edmundoptics.com