

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

Traditional Coated 700 – 1650nm Bandpass Interference Filters



- Available in UV, Visible, and IR Center Wavelengths
- 10 – 80nm Bandwidths Available
- Ideal for Biomedical Applications and Instrumentation Integration
- [193-399nm](#), [400-699nm](#), and 700-1650nm CWL Options Available

Common Specifications




Physical & Mechanical Properties

Thickness Tolerance (mm):	±0.1	Construction:	Mounted in Black Anodized Ring
---------------------------	------	---------------	--------------------------------

Optical Properties

Angle of Incidence (°):	0	Coating:	Traditional Coated
Surface Quality:	80-50		

Technical Information

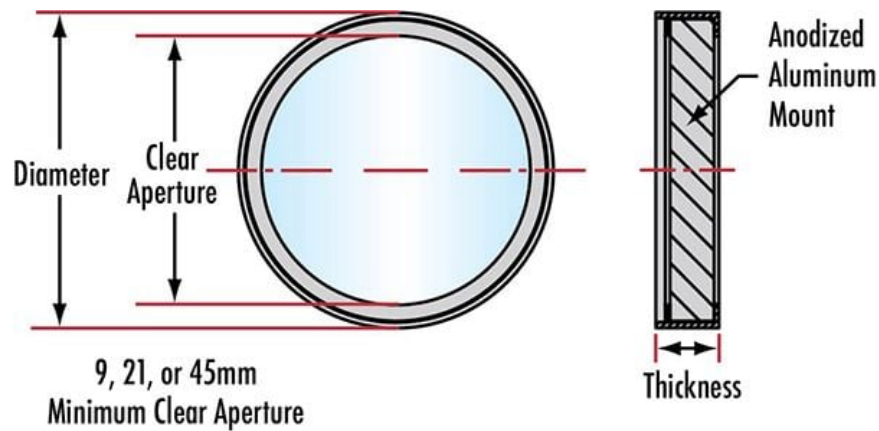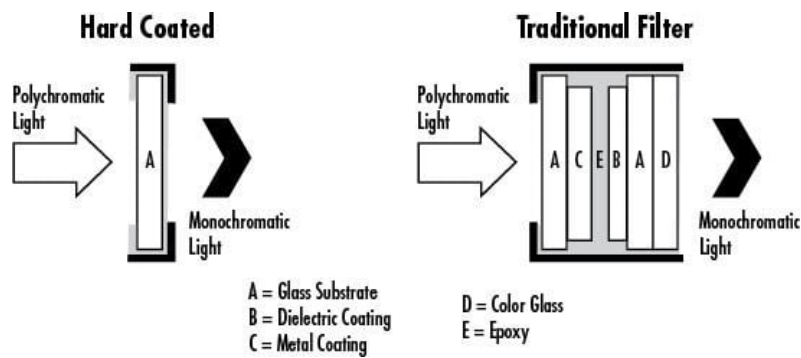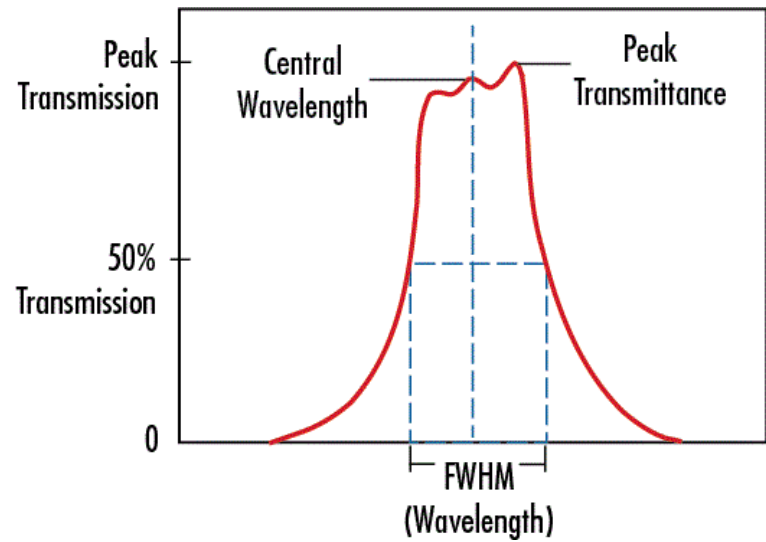

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Dimensions (mm)	Stock Number	Price	Buy
12.50	700.00	10.00	>55	200 - Far IR	-	#67-771	C\$138.01 Volume Pricing	5 In Stock
25.00	700.00	10.00	>55	200 - Far IR	-	#67-838	C\$255.25 Volume Pricing	1 In Stock
50.00	700.00	10.00	>55	200 - Far IR	-	#67-905	C\$688.58 Volume Pricing	2 In Stock
12.50	700.00	80.00	≥60	200 - 1200	-	#65-738	C\$138.01 Volume Pricing	5 In Stock
25.00	700.00	80.00	≥60	200 - 1200	-	#65-747	C\$255.25 Volume Pricing	3 In Stock
50.00	700.00	80.00	≥60	200 - 1200	-	#87-194	C\$688.58 Volume Pricing	3 In Stock
12.50	710.00	10.00	>55	200 - Far IR	-	#67-772	C\$138.01 Volume Pricing	4 In Stock
25.00	710.00	10.00	>55	200 - Far IR	-	#67-839	C\$255.25 Volume Pricing	4 In Stock
50.00	710.00	10.00	>55	200 - Far IR	-	#67-906	C\$737.55 Volume Pricing	1 In Stock
12.50	720.00	10.00	>55	200 - Far IR	-	#67-773	C\$138.01 Volume Pricing	4 In Stock
25.00	720.00	10.00	>55	200 - Far IR	-	#67-840	C\$255.25 Volume Pricing	1 In Stock
50.00	720.00	10.00	>55	200 - Far IR	-	#67-907	C\$737.55 Volume Pricing	3 In Stock
12.50	730.00	10.00	≥50	200 - 1200	-	#65-661	C\$138.01 Volume Pricing	5 In Stock
25.00	730.00	10.00	≥50	200 - 1200	-	#65-721	C\$255.25 Volume Pricing	5 In Stock
12.50	740.00	10.00	>55	200 - Far IR	-	#67-774	C\$138.01 Volume Pricing	4 In Stock
25.00	740.00	10.00	>55	200 - Far IR	-	#67-841	C\$255.25 Volume Pricing	2 In Stock
50.00	740.00	10.00	>55	200 - Far IR	-	#67-908	C\$737.55 Volume Pricing	1 In Stock
12.50	750.00	10.00	>50	200 - Far IR	-	#67-775	C\$138.01 Volume Pricing	1 In Stock
25.00	750.00	10.00	>50	200 - Far IR	-	#67-842	C\$255.25 Volume Pricing	4 In Stock

50.00	750.00	10.00	>50	200 - Far IR	-	#67-909	C\$737.55 Volume Pricing	2 In Stock
12.50	750.00	40.00	>40	200 - Far IR	-	#67-776	C\$138.01 Volume Pricing	6 In Stock
25.00	750.00	40.00	>40	200 - Far IR	-	#67-843	C\$255.25 Volume Pricing	5 In Stock
50.00	750.00	40.00	>40	200 - Far IR	-	#67-910	C\$737.55 Volume Pricing	3 In Stock
12.50	760.00	10.00	>50	200 - Far IR	-	#67-777	C\$138.01 Volume Pricing	6 In Stock
25.00	760.00	10.00	>50	200 - Far IR	-	#67-844	C\$255.25 Volume Pricing	4 In Stock
50.00	760.00	10.00	>50	200 - Far IR	-	#67-911	C\$737.55 Volume Pricing	1 In Stock
12.50	766.00	10.00	≥50	200 - 1200	-	#65-662	C\$138.01 Volume Pricing	7 In Stock
25.00	766.00	10.00	≥50	200 - 1200	-	#65-722	C\$255.25 Volume Pricing	5 In Stock
12.50	770.00	10.00	>50	200 - Far IR	-	#67-778	C\$138.01 Volume Pricing	2 In Stock
25.00	770.00	10.00	>50	200 - Far IR	-	#67-845	C\$255.25 Volume Pricing	2 In Stock
50.00	770.00	10.00	>50	200 - Far IR	-	#67-912	C\$737.55 Volume Pricing	1 In Stock
12.50	780.00	10.00	≥50	200 - 1200	-	#65-663	C\$138.01 Volume Pricing	20+ In Stock
25.00	780.00	10.00	≥50	200 - 1200	-	#65-723	C\$255.25 Volume Pricing	2 In Stock
50.00	780.00	10.00	≥50	200 - 1200	-	#86-637	C\$737.55 Volume Pricing	1 In Stock
12.50	790.00	10.00	>50	200 - Far IR	-	#67-779	C\$138.01 Volume Pricing	5 In Stock
25.00	790.00	10.00	>50	200 - Far IR	-	#67-846	C\$255.25 Volume Pricing	2 In Stock
50.00	790.00	10.00	>50	200 - Far IR	-	#67-913	C\$737.55 Volume Pricing	1 In Stock
12.50	795.00	10.00	>50	200 - Far IR	-	#67-780	C\$138.01 Volume Pricing	5 In Stock
25.00	795.00	10.00	>50	200 - Far IR	-	#67-847	C\$255.25 Volume Pricing	3 In Stock
50.00	795.00	10.00	>50	200 - Far IR	-	#67-914	C\$737.55 Volume Pricing	3 In Stock
12.50	800.00	10.00	≥50	200 - 1200	-	#65-664	C\$138.01 Volume Pricing	3 In Stock

25.00	800.00	10.00	≥50	200 - 1200	-	#65-724	C\$255.25 Volume Pricing	6 In Stock
12.50	800.00	40.00	>50	200 - Far IR	-	#67-781	C\$138.01 Volume Pricing	2 In Stock
25.00	800.00	40.00	>50	200 - Far IR	-	#67-848	C\$255.25 Volume Pricing	5 In Stock
50.00	800.00	40.00	>50	200 - Far IR	-	#67-915	C\$737.55 Volume Pricing	2 In Stock
12.50	810.00	10.00	>50	200 - Far IR	-	#67-782	C\$138.01 Volume Pricing	5 In Stock
25.00	810.00	10.00	>50	200 - Far IR	-	#67-849	C\$255.25 Volume Pricing	4 In Stock
50.00	810.00	10.00	>50	200 - Far IR	-	#67-916	C\$737.55 Volume Pricing	Contact Us
12.50	820.00	10.00	>50	200 - Far IR	-	#67-783	C\$138.01 Volume Pricing	4 In Stock
25.00	820.00	10.00	>50	200 - Far IR	-	#67-850	C\$255.25 Volume Pricing	5 In Stock
50.00	820.00	10.00	>50	200 - Far IR	-	#67-917	C\$737.55 Volume Pricing	1 In Stock
12.50	830.00	10.00	≥50	200 - 1200	-	#65-665	C\$138.01 Volume Pricing	5 In Stock
25.00	830.00	10.00	≥50	200 - 1200	-	#65-725	C\$255.25 Volume Pricing	5 In Stock
12.50	840.00	10.00	>50	200 - Far IR	-	#67-784	C\$138.01 Volume Pricing	3 In Stock
25.00	840.00	10.00	>50	200 - Far IR	-	#67-851	C\$255.25 Volume Pricing	5 In Stock
50.00	840.00	10.00	>50	200 - Far IR	-	#67-918	C\$737.55 Volume Pricing	2 In Stock
12.50	850.00	10.00	>50	200 - Far IR	-	#67-785	C\$138.01 Volume Pricing	7 In Stock
25.00	850.00	10.00	>50	200 - Far IR	-	#67-852	C\$255.25 Volume Pricing	8 In Stock
50.00	850.00	10.00	>50	200 - Far IR	-	#67-919	C\$737.55 Volume Pricing	1 In Stock
12.50	850.00	40.00	>50	200 - Far IR	-	#67-786	C\$138.01 Volume Pricing	7 In Stock
25.00	850.00	40.00	>50	200 - Far IR	-	#67-853	C\$255.25 Volume Pricing	5 In Stock
50.00	850.00	40.00	>50	200 - Far IR	-	#67-920	C\$737.55 Volume Pricing	1 In Stock
12.50	852.00	10.00	≥50	200 - 1200	-	#65-666	C\$138.01 Volume Pricing	1 In Stock

25.00	852.00	10.00	≥50	200 - 1200	-	#65-726	C\$255.25 Volume Pricing	4 In Stock
50.00	852.00	10.00	≥50	200 - 1200	-	#86-638	C\$737.55 Volume Pricing	3 In Stock
12.50	855.00	10.00	≥50	200 - 1200	-	#65-667	C\$138.01 Volume Pricing	2 In Stock
25.00	855.00	10.00	≥50	200 - 1200	-	#65-727	C\$255.25 Volume Pricing	3 In Stock
12.50	860.00	10.00	>50	200 - Far IR	-	#67-787	C\$138.01 Volume Pricing	Contact Us
25.00	860.00	10.00	>50	200 - Far IR	-	#67-854	C\$255.25 Volume Pricing	3 In Stock
50.00	860.00	10.00	>50	200 - Far IR	-	#67-921	C\$737.55 Volume Pricing	1 In Stock
12.50	870.00	10.00	>50	200 - Far IR	-	#67-788	C\$138.01 Volume Pricing	7 In Stock
25.00	870.00	10.00	>50	200 - Far IR	-	#67-855	C\$255.25 Volume Pricing	3 In Stock
50.00	870.00	10.00	>50	200 - Far IR	-	#67-922	C\$737.55 Volume Pricing	2 In Stock
12.50	880.00	10.00	≥50	200 - 1200	-	#65-668	C\$138.01 Volume Pricing	9 In Stock
25.00	880.00	10.00	≥50	200 - 1200	-	#65-728	C\$255.25 Volume Pricing	1 In Stock
12.50	880.00	50.00	≥55	200 - 1200	-	#65-739	C\$138.01 Volume Pricing	1 In Stock
25.00	880.00	50.00	≥55	200 - 1200	-	#65-748	C\$255.25 Volume Pricing	7 In Stock
50.00	880.00	50.00	≥55	200 - 1200	-	#87-195	C\$737.55 Volume Pricing	4 In Stock
12.50	890.00	10.00	>50	200 - Far IR	-	#67-789	C\$138.01 Volume Pricing	2 In Stock
25.00	890.00	10.00	>50	200 - Far IR	-	#67-856	C\$255.25 Volume Pricing	2 In Stock
50.00	890.00	10.00	>50	200 - Far IR	-	#67-923	C\$737.55 Volume Pricing	2 In Stock
12.50	900.00	10.00	>50	200 - Far IR	-	#67-790	C\$138.01 Volume Pricing	1 In Stock
25.00	900.00	10.00	>50	200 - Far IR	-	#67-857	C\$255.25 Volume Pricing	5 In Stock
50.00	900.00	10.00	>50	200 - Far IR	-	#67-924	C\$737.55 Volume Pricing	3 In Stock
12.50	900.00	40.00	>50	200 - Far IR	-	#67-791	C\$138.01 Volume Pricing	Contact Us

25.00	900.00	40.00	>50	200 - Far IR	-	#67-858	C\$255.25 Volume Pricing	3 In Stock
50.00	900.00	40.00	>50	200 - Far IR	-	#67-925	C\$737.55 Volume Pricing	2 In Stock
12.50	905.00	10.00	≥50	200 - 1200	-	#65-669	C\$138.01 Volume Pricing	5 In Stock
25.00	905.00	10.00	≥50	200 - 1200	-	#65-729	C\$255.25 Volume Pricing	5 In Stock
12.50	910.00	10.00	>50	200 - Far IR	-	#67-792	C\$138.01 Volume Pricing	12 In Stock
25.00	910.00	10.00	>50	200 - Far IR	-	#67-859	C\$255.25 Volume Pricing	4 In Stock
50.00	910.00	10.00	>50	200 - Far IR	-	#67-926	C\$737.55 Volume Pricing	1 In Stock
12.50	920.00	10.00	>50	200 - Far IR	-	#67-793	C\$138.01 Volume Pricing	5 In Stock
25.00	920.00	10.00	>50	200 - Far IR	-	#67-860	C\$255.25 Volume Pricing	2 In Stock
50.00	920.00	10.00	>50	200 - Far IR	-	#67-927	C\$737.55 Volume Pricing	2 In Stock
12.50	930.00	10.00	>50	200 - Far IR	-	#67-794	C\$138.01 Volume Pricing	1 In Stock
25.00	930.00	10.00	>50	200 - Far IR	-	#67-861	C\$255.25 Volume Pricing	1 In Stock
50.00	930.00	10.00	>50	200 - Far IR	-	#67-928	C\$737.55 Volume Pricing	1 In Stock
12.50	940.00	10.00	≥50	200 - 1200	-	#65-670	C\$138.01 Volume Pricing	4 In Stock
25.00	940.00	10.00	≥50	200 - 1200	-	#65-730	C\$255.25 Volume Pricing	5 In Stock
50.00	940.00	10.00	≥50	200 - 1200	-	#86-639	C\$737.55 Volume Pricing	1 In Stock
12.50	950.00	10.00	>50	200 - Far IR	-	#67-795	C\$138.01 Volume Pricing	1 In Stock
25.00	950.00	10.00	>50	200 - Far IR	-	#67-862	C\$255.25 Volume Pricing	20+ In Stock
50.00	950.00	10.00	>50	200 - Far IR	-	#67-929	C\$737.55 Volume Pricing	1 In Stock
12.50	950.00	50.00	≥55	200 - 1200	-	#65-740	C\$138.01 Volume Pricing	5 In Stock
25.00	950.00	50.00	≥55	200 - 1200	-	#65-749	C\$255.25 Volume Pricing	5 In Stock
50.00	950.00	50.00	≥55	200 - 1200	-	#87-196	C\$737.55 Volume Pricing	2 In Stock

12.50	960.00	10.00	>50	200 - Far IR	-	#67-796	C\$138.01 Volume Pricing	5 In Stock
25.00	960.00	10.00	>50	200 - Far IR	-	#67-863	C\$255.25 Volume Pricing	3 In Stock
50.00	960.00	10.00	>50	200 - Far IR	-	#67-930	C\$737.55 Volume Pricing	1 In Stock
12.50	970.00	10.00	>50	200 - Far IR	-	#67-797	C\$138.01 Volume Pricing	1 In Stock
25.00	970.00	10.00	>50	200 - Far IR	-	#67-864	C\$255.25 Volume Pricing	5 In Stock
50.00	970.00	10.00	>50	200 - Far IR	-	#67-931	C\$737.55 Volume Pricing	1 In Stock
12.50	990.00	10.00	>50	200 - Far IR	-	#67-798	C\$138.01 Volume Pricing	1 In Stock
25.00	990.00	10.00	>50	200 - Far IR	-	#67-865	C\$255.25 Volume Pricing	5 In Stock
50.00	990.00	10.00	>50	200 - Far IR	-	#67-932	C\$737.55 Volume Pricing	1 In Stock
12.50	1,000.00	10.00	>70	200 - 1200	-	#65-768	C\$138.01 Volume Pricing	5 In Stock
25.00	1,000.00	10.00	>70	200 - 1200	-	#65-782	C\$255.25 Volume Pricing	5 In Stock
12.50	1,050.00	10.00	>70	200 - 1200	-	#65-769	C\$138.01 Volume Pricing	5 In Stock
25.00	1,050.00	10.00	>70	200 - 1200	-	#65-783	C\$255.25 Volume Pricing	3 In Stock
12.50	1,064.00	10.00	≥50	200 - 1200	-	#65-671	C\$138.01 Volume Pricing	2 In Stock
25.00	1,064.00	10.00	≥50	200 - 1200	-	#65-731	C\$255.25 Volume Pricing	5 In Stock
50.00	1,064.00	10.00	≥50	200 - 1200	-	#87-006	C\$737.55 Volume Pricing	1 In Stock
12.50	1,100.00	10.00	>70	200 - 1200	-	#65-770	C\$138.01 Volume Pricing	3 In Stock
25.00	1,100.00	10.00	>70	200 - 1200	-	#65-784	C\$311.64 Volume Pricing	Contact Us
12.50	1,150.00	10.00	>70	200 - 1350	-	#65-771	C\$138.01 Volume Pricing	8 In Stock
25.00	1,150.00	10.00	>70	200 - 1350	-	#65-785	C\$311.64 Volume Pricing	2 In Stock
12.50	1,200.00	10.00	>70	200 - 1350	-	#65-772	C\$138.01 Volume Pricing	2 In Stock
25.00	1,200.00	10.00	>70	200 - 1350	-	#65-786	C\$311.64 Volume Pricing	4 In Stock

12.50	1,250.00	10.00	>70	200 - 1500	-	#65-773	C\$138.01 Volume Pricing	5 In Stock
25.00	1,250.00	10.00	>70	200 - 1500	-	#65-787	C\$311.64 Volume Pricing	6 In Stock
12.50	1,300.00	12.00	>70	200 - 1500	-	#65-774	C\$138.01 Volume Pricing	7 In Stock
25.00	1,300.00	12.00	>70	200 - 1500	-	#65-788	C\$311.64 Volume Pricing	1 In Stock
12.50	1,350.00	12.00	>70	200 - 1500	-	#65-775	C\$138.01 Volume Pricing	7 In Stock
25.00	1,350.00	12.00	>70	200 - 1500	-	#65-789	C\$311.64 Volume Pricing	3 In Stock
12.50	1,400.00	12.00	>70	200 - 1800	-	#65-776	C\$138.01 Volume Pricing	8 In Stock
25.00	1,400.00	12.00	>70	200 - 1800	-	#65-790	C\$311.64 Volume Pricing	2 In Stock
12.50	1,450.00	12.00	>70	200 - 1800	-	#65-777	C\$138.01 Volume Pricing	5 In Stock
25.00	1,450.00	12.00	>70	200 - 1800	-	#65-791	C\$311.64 Volume Pricing	8 In Stock
12.50	1,500.00	12.00	>70	200 - 1800	-	#65-778	C\$138.01 Volume Pricing	4 In Stock
25.00	1,500.00	12.00	>70	200 - 1800	-	#65-792	C\$311.64 Volume Pricing	4 In Stock
12.50	1,550.00	12.00	>70	200 - 1800	-	#65-779	C\$138.01 Volume Pricing	5 In Stock
25.00	1,550.00	12.00	>70	200 - 1800	-	#65-793	C\$311.64 Volume Pricing	5 In Stock
12.50	1,600.00	12.00	>65	200 - 1800	-	#65-780	C\$138.01 Volume Pricing	5 In Stock
25.00	1,600.00	12.00	>65	200 - 1800	-	#65-794	C\$311.64 Volume Pricing	3 In Stock
12.50	1,650.00	12.00	>65	200 - 1800	-	#65-781	C\$138.01 Volume Pricing	5 In Stock
25.00	1,650.00	12.00	>65	200 - 1800	-	#65-795	C\$311.64 Volume Pricing	5 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
 Phone: 1-800-363-1992 :
www.edmundoptics.com