


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [UV Lenses](#)

TECHSPEC® Laser Grade Plano-Convex (PCX) Lenses

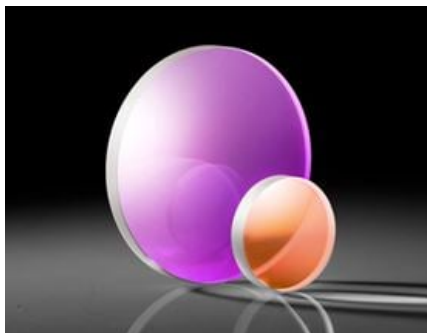

- Guaranteed Laser Damage Threshold
- 10-5 Surface Quality
- $\lambda/10$ Surface Accuracy

Common Specifications

Physical & Mechanical Properties




Bevel: Protective as needed

Optical Properties


Substrate: [Fused Silica](#) (Corning 7980)

Power (P-V) @ 632.8nm: λ

Technical Information

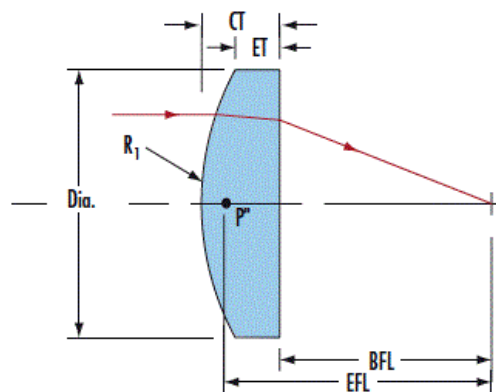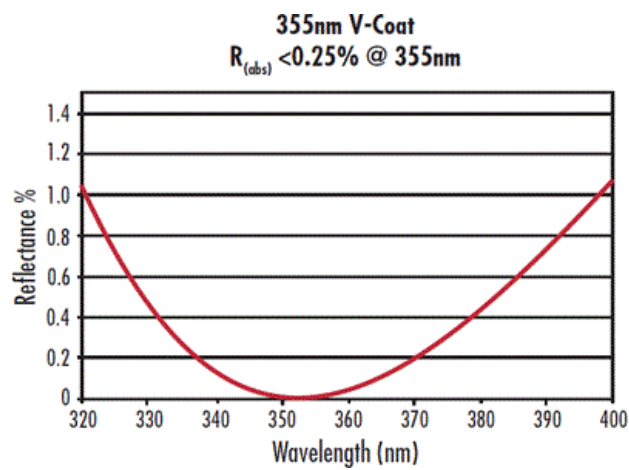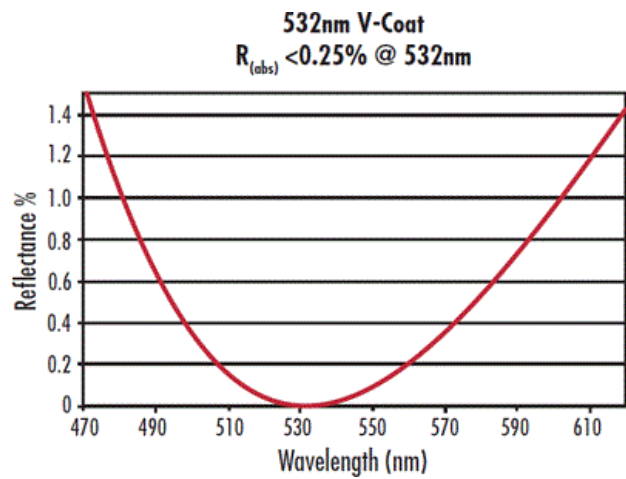

1064nm V-Coat
 $R_{(obs)} < 0.25\%$ @ 1064nm

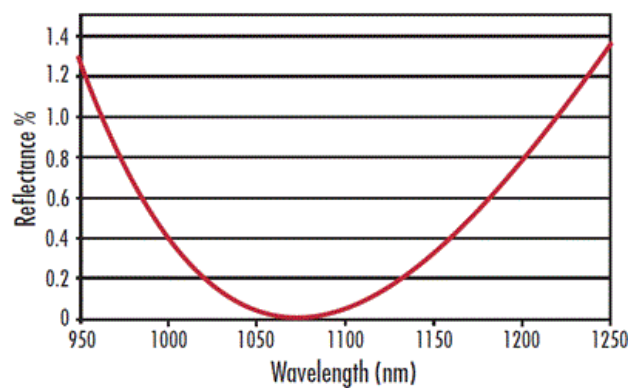

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	12.00	10.63	Uncoated	Fused Silica	#87-924	C\$206.28 Volume Pricing	20+ In Stock
6.00	12.00	10.63	Laser V-Coat (266nm)	Fused Silica	#87-928	C\$258.55 Volume Pricing	11 In Stock
6.00	12.00	10.63	Laser V-Coat (355nm)	Fused Silica	#87-932	C\$258.55 Volume Pricing	7 In Stock
6.00	12.00	10.63	Laser V-Coat (532nm)	Fused Silica	#87-936	C\$258.55 Volume Pricing	20+ In Stock
6.00	12.00	10.63	Laser V-Coat (1064nm)	Fused Silica	#87-940	C\$258.55 Volume Pricing	20+ In Stock
6.00	18.00	16.62	Uncoated	Fused Silica	#87-925	C\$206.28 Volume Pricing	20+ In Stock
6.00	18.00	16.62	Laser V-Coat (266nm)	Fused Silica	#87-929	C\$258.55 Volume Pricing	11 In Stock
6.00	18.00	16.62	Laser V-Coat (355nm)	Fused Silica	#87-933	C\$258.55 Volume Pricing	13 In Stock
6.00	18.00	16.62	Laser V-Coat (532nm)	Fused Silica	#87-937	C\$258.55 Volume Pricing	13 In Stock
6.00	18.00	16.62	Laser V-Coat (1064nm)	Fused Silica	#87-941	C\$258.55 Volume Pricing	5 In Stock
6.00	24.00	22.63	Uncoated	Fused Silica	#87-926	C\$206.28 Volume Pricing	20+ In Stock
6.00	24.00	22.63	Laser V-Coat (266nm)	Fused Silica	#87-930	C\$258.55 Volume Pricing	14 In Stock
6.00	24.00	22.63	Laser V-Coat (355nm)	Fused Silica	#87-934	C\$258.55 Volume Pricing	13 In Stock

6.00	24.00	22.63	Laser V-Coat (532nm)	Fused Silica	#87-938	C\$258.55 Volume Pricing	12 In Stock
6.00	24.00	22.63	Laser V-Coat (1064nm)	Fused Silica	#87-942	C\$258.55 Volume Pricing	5 In Stock
12.00	18.00	15.23	Uncoated	Fused Silica	#67-090	C\$221.12 Volume Pricing	5 In Stock
12.00	18.00	15.23	Laser V-Coat (266nm)	Fused Silica	#67-939	C\$284.26 Volume Pricing	6 In Stock
12.00	18.00	15.23	Laser V-Coat (355nm)	Fused Silica	#67-949	C\$284.26 Volume Pricing	7 In Stock
12.00	18.00	15.23	Laser V-Coat (532nm)	Fused Silica	#67-959	C\$284.26 Volume Pricing	7 In Stock
12.00	18.00	15.23	Laser V-Coat (1064nm)	Fused Silica	#67-969	C\$284.26 Volume Pricing	20+ In Stock
12.00	25.00	22.31	Uncoated	Fused Silica	#67-091	C\$221.12 Volume Pricing	20+ In Stock
12.00	25.00	22.31	Laser V-Coat (266nm)	Fused Silica	#67-940	C\$284.26 Volume Pricing	3 In Stock
12.00	25.00	22.31	Laser V-Coat (355nm)	Fused Silica	#67-950	C\$284.26 Volume Pricing	4 In Stock
12.00	25.00	22.31	Laser V-Coat (532nm)	Fused Silica	#67-960	C\$284.26 Volume Pricing	Contact Us
12.00	25.00	22.31	Laser V-Coat (1064nm)	Fused Silica	#67-970	C\$284.26 Volume Pricing	8 In Stock
12.00	36.00	34.29	Uncoated	Fused Silica	#67-092	C\$221.12 Volume Pricing	20+ In Stock
12.00	36.00	34.29	Laser V-Coat (266nm)	Fused Silica	#67-941	C\$284.26 Volume Pricing	8 In Stock
12.00	36.00	34.29	Laser V-Coat (355nm)	Fused Silica	#67-951	C\$284.26 Volume Pricing	1 In Stock

12.00	36.00	34.29	Laser V-Coat (532nm)	Fused Silica	#67-961	C\$284.26 Volume Pricing	3 In Stock
12.00	36.00	34.29	Laser V-Coat (1064nm)	Fused Silica	#67-971	C\$284.26 Volume Pricing	1 In Stock
12.00	50.00	48.01	Uncoated	Fused Silica	#67-093	C\$221.12 Volume Pricing	20+ In Stock
12.00	50.00	48.01	Laser V-Coat (266nm)	Fused Silica	#67-942	C\$284.26 Volume Pricing	9 In Stock
12.00	50.00	48.01	Laser V-Coat (355nm)	Fused Silica	#67-952	C\$284.26 Volume Pricing	3 In Stock
12.00	50.00	48.01	Laser V-Coat (532nm)	Fused Silica	#67-962	C\$284.26 Volume Pricing	8 In Stock
12.00	50.00	48.01	Laser V-Coat (1064nm)	Fused Silica	#67-972	C\$284.26 Volume Pricing	2 In Stock
12.70	25.00	21.62	Uncoated	Fused Silica	#38-634	C\$221.12 Volume Pricing	6 In Stock
12.70	25.00	21.62	Laser V-Coat (266nm)	Fused Silica	#38-656	C\$284.26 Volume Pricing	6 In Stock
12.70	25.00	21.62	Laser V-Coat (355nm)	Fused Silica	#38-681	C\$284.26 Volume Pricing	Contact Us
12.70	25.00	21.62	Laser V-Coat (532nm)	Fused Silica	#38-707	C\$284.26 Volume Pricing	3 In Stock
12.70	25.00	21.62	Laser V-Coat (1064nm)	Fused Silica	#38-733	C\$284.26 Volume Pricing	6 In Stock
12.70	35.00	32.30	Uncoated	Fused Silica	#38-635	C\$221.12 Volume Pricing	4 In Stock
12.70	35.00	32.30	Laser V-Coat (266nm)	Fused Silica	#38-658	C\$284.26 Volume Pricing	7 In Stock
12.70	35.00	32.30	Laser V-Coat (355nm)	Fused Silica	#38-684	C\$284.26 Volume Pricing	5 In Stock

12.70	35.00	32.30	Laser V-Coat (532nm)	Fused Silica	#38-708	C\$284.26 Volume Pricing	13 In Stock
12.70	35.00	32.30	Laser V-Coat (1064nm)	Fused Silica	#38-734	C\$284.26 Volume Pricing	2 In Stock
12.70	50.00	47.30	Uncoated	Fused Silica	#38-636	C\$221.12 Volume Pricing	14 In Stock
12.70	50.00	47.30	Laser V-Coat (266nm)	Fused Silica	#38-660	C\$284.26 Volume Pricing	5 In Stock
12.70	50.00	47.30	Laser V-Coat (355nm)	Fused Silica	#38-685	C\$284.26 Volume Pricing	3 In Stock
12.70	50.00	47.30	Laser V-Coat (532nm)	Fused Silica	#38-709	C\$284.26 Volume Pricing	20+ In Stock
12.70	50.00	47.30	Laser V-Coat (1064nm)	Fused Silica	#38-735	C\$284.26 Volume Pricing	2 In Stock
12.70	75.00	72.31	Uncoated	Fused Silica	#38-637	C\$221.12 Volume Pricing	20+ In Stock
12.70	75.00	72.31	Laser V-Coat (266nm)	Fused Silica	#38-661	C\$284.26 Volume Pricing	4 In Stock
12.70	75.00	72.31	Laser V-Coat (355nm)	Fused Silica	#38-686	C\$284.26 Volume Pricing	4 In Stock
12.70	75.00	72.31	Laser V-Coat (532nm)	Fused Silica	#38-711	C\$284.26 Volume Pricing	2 In Stock
12.70	75.00	72.31	Laser V-Coat (1064nm)	Fused Silica	#38-736	C\$284.26 Volume Pricing	16 In Stock
12.70	100.00	97.32	Uncoated	Fused Silica	#38-638	C\$221.12 Volume Pricing	6 In Stock
12.70	100.00	97.32	Laser V-Coat (266nm)	Fused Silica	#38-662	C\$284.26 Volume Pricing	3 In Stock
12.70	100.00	97.32	Laser V-Coat (355nm)	Fused Silica	#38-687	C\$284.26 Volume Pricing	6 In Stock

12.70	100.00	97.32	Laser V-Coat (532nm)	Fused Silica	#38-712	C\$284.26 Volume Pricing	5 In Stock
12.70	100.00	97.32	Laser V-Coat (1064nm)	Fused Silica	#38-737	C\$284.26 Volume Pricing	5 In Stock
12.70	150.00	147.33	Uncoated	Fused Silica	#38-639	C\$221.12 Volume Pricing	20+ In Stock
12.70	150.00	147.33	Laser V-Coat (266nm)	Fused Silica	#38-665	C\$284.26 Volume Pricing	7 In Stock
12.70	150.00	147.33	Laser V-Coat (355nm)	Fused Silica	#38-688	C\$284.26 Volume Pricing	17 In Stock
12.70	150.00	147.33	Laser V-Coat (532nm)	Fused Silica	#38-715	C\$284.26 Volume Pricing	5 In Stock
12.70	150.00	147.33	Laser V-Coat (1064nm)	Fused Silica	#38-738	C\$284.26 Volume Pricing	20+ In Stock
12.70	200.00	197.35	Uncoated	Fused Silica	#38-640	C\$221.12 Volume Pricing	20+ In Stock
12.70	200.00	197.35	Laser V-Coat (266nm)	Fused Silica	#38-666	C\$284.26 Volume Pricing	4 In Stock
12.70	200.00	197.35	Laser V-Coat (355nm)	Fused Silica	#38-689	C\$284.26 Volume Pricing	6 In Stock
12.70	200.00	197.35	Laser V-Coat (532nm)	Fused Silica	#38-716	C\$284.26 Volume Pricing	5 In Stock
12.70	200.00	197.35	Laser V-Coat (1064nm)	Fused Silica	#38-739	C\$284.26 Volume Pricing	11 In Stock
12.70	250.00	247.36	Uncoated	Fused Silica	#38-641	C\$221.12 Volume Pricing	20+ In Stock
12.70	250.00	247.36	Laser V-Coat (266nm)	Fused Silica	#38-667	C\$284.26 Volume Pricing	3 In Stock
12.70	250.00	247.36	Laser V-Coat (355nm)	Fused Silica	#38-690	C\$284.26 Volume Pricing	5 In Stock

12.70	250.00	247.36	Laser V-Coat (532nm)	Fused Silica	#38-717	C\$284.26 Volume Pricing	4 In Stock
12.70	250.00	247.36	Laser V-Coat (1064nm)	Fused Silica	#38-740	C\$284.26 Volume Pricing	6 In Stock
12.70	300.00	297.38	Uncoated	Fused Silica	#38-643	C\$221.12 Volume Pricing	20+ In Stock
12.70	300.00	297.38	Laser V-Coat (266nm)	Fused Silica	#38-668	C\$284.26 Volume Pricing	3 In Stock
12.70	300.00	297.38	Laser V-Coat (355nm)	Fused Silica	#38-691	C\$284.26 Volume Pricing	7 In Stock
12.70	300.00	297.38	Laser V-Coat (532nm)	Fused Silica	#38-718	C\$284.26 Volume Pricing	4 In Stock
12.70	300.00	297.38	Laser V-Coat (1064nm)	Fused Silica	#38-741	C\$284.26 Volume Pricing	1 In Stock
12.70	500.00	497.44	Uncoated	Fused Silica	#38-644	C\$221.12 Volume Pricing	20+ In Stock
12.70	500.00	497.44	Laser V-Coat (266nm)	Fused Silica	#38-669	C\$284.26 Volume Pricing	3 In Stock
12.70	500.00	497.44	Laser V-Coat (355nm)	Fused Silica	#38-692	C\$284.26 Volume Pricing	9 In Stock
12.70	500.00	497.44	Laser V-Coat (532nm)	Fused Silica	#38-719	C\$284.26 Volume Pricing	14 In Stock
12.70	500.00	497.44	Laser V-Coat (1064nm)	Fused Silica	#38-742	C\$284.26 Volume Pricing	3 In Stock
12.70	1,000.00	997.59	Uncoated	Fused Silica	#38-645	C\$221.12 Volume Pricing	20+ In Stock
12.70	1,000.00	997.59	Laser V-Coat (266nm)	Fused Silica	#38-670	C\$284.26 Volume Pricing	1 In Stock
12.70	1,000.00	997.59	Laser V-Coat (355nm)	Fused Silica	#38-693	C\$284.26 Volume Pricing	3 In Stock

12.70	1,000.00	997.59	Laser V-Coat (532nm)	Fused Silica	#38-720	C\$284.26 Volume Pricing	8 In Stock
12.70	1,000.00	997.59	Laser V-Coat (1064nm)	Fused Silica	#38-743	C\$284.26 Volume Pricing	5 In Stock
25.00	38.00	33.03	Uncoated	Fused Silica	#67-094	C\$276.02 Volume Pricing	20+ In Stock
25.00	38.00	33.03	Laser V-Coat (266nm)	Fused Silica	#67-943	C\$316.01 Volume Pricing	17 In Stock
25.00	38.00	33.03	Laser V-Coat (355nm)	Fused Silica	#67-953	C\$316.01 Volume Pricing	8 In Stock
25.00	38.00	33.03	Laser V-Coat (532nm)	Fused Silica	#67-963	C\$316.01 Volume Pricing	5 In Stock
25.00	38.00	33.03	Laser V-Coat (1064nm)	Fused Silica	#67-973	C\$316.01 Volume Pricing	2 In Stock
25.00	50.00	46.00	Uncoated	Fused Silica	#67-095	C\$276.02 Volume Pricing	7 In Stock
25.00	50.00	46.00	Laser V-Coat (266nm)	Fused Silica	#67-944	C\$316.01 Volume Pricing	7 In Stock
25.00	50.00	46.00	Laser V-Coat (355nm)	Fused Silica	#67-954	C\$316.01 Volume Pricing	5 In Stock
25.00	50.00	46.00	Laser V-Coat (532nm)	Fused Silica	#67-964	C\$316.01 Volume Pricing	9 In Stock
25.00	50.00	46.00	Laser V-Coat (1064nm)	Fused Silica	#67-974	C\$316.01 Volume Pricing	6 In Stock
25.00	75.00	71.96	Uncoated	Fused Silica	#67-096	C\$276.02 Volume Pricing	13 In Stock
25.00	75.00	71.96	Laser V-Coat (266nm)	Fused Silica	#67-945	C\$316.01 Volume Pricing	Contact Us
25.00	75.00	71.96	Laser V-Coat (355nm)	Fused Silica	#67-955	C\$316.01 Volume Pricing	5 In Stock

25.00	75.00	71.96	Laser V-Coat (532nm)	Fused Silica	#67-965	C\$316.01 Volume Pricing	20+ In Stock
25.00	75.00	71.96	Laser V-Coat (1064nm)	Fused Silica	#67-975	C\$316.01 Volume Pricing	7 In Stock
25.00	100.00	97.40	Uncoated	Fused Silica	#67-097	C\$276.02 Volume Pricing	2 In Stock
25.00	100.00	97.4	Laser V-Coat (266nm)	Fused Silica	#67-946	C\$316.01 Volume Pricing	17 In Stock
25.00	100.00	97.40	Laser V-Coat (355nm)	Fused Silica	#67-956	C\$316.01 Volume Pricing	5 In Stock
25.00	100.00	97.40	Laser V-Coat (532nm)	Fused Silica	#67-966	C\$316.01 Volume Pricing	10 In Stock
25.00	100.00	97.40	Laser V-Coat (1064nm)	Fused Silica	#67-976	C\$316.01 Volume Pricing	9 In Stock
25.00	150.00	147.82	Uncoated	Fused Silica	#67-098	C\$276.02 Volume Pricing	20+ In Stock
25.00	150.00	147.86	Laser V-Coat (266nm)	Fused Silica	#67-947	C\$316.01 Volume Pricing	3 In Stock
25.00	150.00	147.82	Laser V-Coat (355nm)	Fused Silica	#67-957	C\$316.01 Volume Pricing	20+ In Stock
25.00	150.00	147.82	Laser V-Coat (532nm)	Fused Silica	#67-967	C\$316.01 Volume Pricing	Contact Us
25.00	150.00	147.82	Laser V-Coat (1064nm)	Fused Silica	#67-977	C\$316.01 Volume Pricing	Contact Us
25.00	250.00	248.14	Uncoated	Fused Silica	#67-099	C\$276.02 Volume Pricing	1 In Stock
25.00	250.00	248.14	Laser V-Coat (266nm)	Fused Silica	#67-948	C\$316.01 Volume Pricing	15 In Stock
25.00	250.00	248.14	Laser V-Coat (355nm)	Fused Silica	#67-958	C\$316.01 Volume Pricing	6 In Stock

25.00	250.00	248.14	Laser V-Coat (532nm)	Fused Silica	#67-968	C\$316.01 Volume Pricing	5 In Stock
25.00	250.00	248.14	Laser V-Coat (1064nm)	Fused Silica	#67-978	C\$316.01 Volume Pricing	6 In Stock
25.40	35.00	28.55	Uncoated	Fused Silica	#38-624	C\$276.02 Volume Pricing	9 In Stock
25.40	35.00	28.55	Laser V-Coat (266nm)	Fused Silica	#38-646	C\$316.01 Volume Pricing	7 In Stock
25.40	35.00	28.55	Laser V-Coat (355nm)	Fused Silica	#38-671	C\$316.01 Volume Pricing	16 In Stock
25.40	35.00	28.55	Laser V-Coat (532nm)	Fused Silica	#38-694	C\$316.01 Volume Pricing	1 In Stock
25.40	35.00	28.55	Laser V-Coat (1064nm)	Fused Silica	#38-721	C\$316.01 Volume Pricing	2 In Stock
25.40	50.00	45.71	Uncoated	Fused Silica	#38-625	C\$276.02 Volume Pricing	12 In Stock
25.40	50.00	45.71	Laser V-Coat (266nm)	Fused Silica	#38-647	C\$316.01 Volume Pricing	3 In Stock
25.40	50.00	45.71	Laser V-Coat (355nm)	Fused Silica	#38-672	C\$316.01 Volume Pricing	5 In Stock
25.40	50.00	45.71	Laser V-Coat (532nm)	Fused Silica	#38-695	C\$316.01 Volume Pricing	7 In Stock
25.40	50.00	45.71	Laser V-Coat (1064nm)	Fused Silica	#38-722	C\$316.01 Volume Pricing	3 In Stock
25.40	75.00	71.63	Uncoated	Fused Silica	#38-626	C\$276.02 Volume Pricing	6 In Stock
25.40	75.00	71.63	Laser V-Coat (266nm)	Fused Silica	#38-648	C\$316.01 Volume Pricing	5 In Stock
25.40	75.00	71.63	Laser V-Coat (355nm)	Fused Silica	#38-673	C\$316.01 Volume Pricing	4 In Stock

25.40	75.00	71.63	Laser V-Coat (532nm)	Fused Silica	#38-699	C\$316.01 Volume Pricing	4 In Stock
25.40	75.00	71.63	Laser V-Coat (1064nm)	Fused Silica	#38-723	C\$316.01 Volume Pricing	2 In Stock
25.40	100.00	97.32	Uncoated	Fused Silica	#38-627	C\$276.02 Volume Pricing	Contact Us
25.40	100.00	97.32	Laser V-Coat (266nm)	Fused Silica	#38-649	C\$316.01 Volume Pricing	Contact Us
25.40	100.00	97.32	Laser V-Coat (355nm)	Fused Silica	#38-674	C\$316.01 Volume Pricing	10 In Stock
25.40	100.00	97.32	Laser V-Coat (532nm)	Fused Silica	#38-700	C\$316.01 Volume Pricing	3 In Stock
25.40	100.00	97.32	Laser V-Coat (1064nm)	Fused Silica	#38-724	C\$316.01 Volume Pricing	14 In Stock
25.40	150.00	147.33	Uncoated	Fused Silica	#38-628	C\$276.02 Volume Pricing	16 In Stock
25.40	150.00	147.33	Laser V-Coat (266nm)	Fused Silica	#38-650	C\$316.01 Volume Pricing	3 In Stock
25.40	150.00	147.33	Laser V-Coat (355nm)	Fused Silica	#38-675	C\$316.01 Volume Pricing	12 In Stock
25.40	150.00	147.33	Laser V-Coat (532nm)	Fused Silica	#38-701	C\$316.01 Volume Pricing	3 In Stock
25.40	150.00	147.33	Laser V-Coat (1064nm)	Fused Silica	#38-725	C\$316.01 Volume Pricing	5 In Stock
25.40	200.00	197.35	Uncoated	Fused Silica	#38-629	C\$276.02 Volume Pricing	20+ In Stock
25.40	200.00	197.35	Laser V-Coat (266nm)	Fused Silica	#38-651	C\$316.01 Volume Pricing	4 In Stock
25.40	200.00	197.35	Laser V-Coat (355nm)	Fused Silica	#38-676	C\$316.01 Volume Pricing	9 In Stock

25.40	200.00	197.35	Laser V-Coat (532nm)	Fused Silica	#38-702	C\$316.01 Volume Pricing	10 In Stock
25.40	200.00	197.35	Laser V-Coat (1064nm)	Fused Silica	#38-726	C\$316.01 Volume Pricing	Contact Us
25.40	250.00	247.36	Uncoated	Fused Silica	#38-630	C\$276.02 Volume Pricing	20+ In Stock
25.40	250.00	247.36	Laser V-Coat (266nm)	Fused Silica	#38-652	C\$316.01 Volume Pricing	4 In Stock
25.40	250.00	247.36	Laser V-Coat (355nm)	Fused Silica	#38-677	C\$316.01 Volume Pricing	7 In Stock
25.40	250.00	247.36	Laser V-Coat (532nm)	Fused Silica	#38-703	C\$316.01 Volume Pricing	7 In Stock
25.40	250.00	247.36	Laser V-Coat (1064nm)	Fused Silica	#38-727	C\$316.01 Volume Pricing	2 In Stock
25.40	300.00	297.38	Uncoated	Fused Silica	#38-631	C\$276.02 Volume Pricing	20+ In Stock
25.40	300.00	297.38	Laser V-Coat (266nm)	Fused Silica	#38-653	C\$316.01 Volume Pricing	5 In Stock
25.40	300.00	297.38	Laser V-Coat (355nm)	Fused Silica	#38-678	C\$316.01 Volume Pricing	4 In Stock
25.40	300.00	297.38	Laser V-Coat (532nm)	Fused Silica	#38-704	C\$316.01 Volume Pricing	5 In Stock
25.40	300.00	297.38	Laser V-Coat (1064nm)	Fused Silica	#38-729	C\$316.01 Volume Pricing	4 In Stock
25.40	500.00	497.44	Uncoated	Fused Silica	#38-632	C\$276.02 Volume Pricing	9 In Stock
25.40	500.00	497.44	Laser V-Coat (266nm)	Fused Silica	#38-654	C\$316.01 Volume Pricing	6 In Stock
25.40	500.00	497.44	Laser V-Coat (355nm)	Fused Silica	#38-679	C\$316.01 Volume Pricing	Contact Us

25.40	500.00	497.44	Laser V-Coat (532nm)	Fused Silica	#38-705	C\$316.01 Volume Pricing	3 In Stock
25.40	500.00	497.44	Laser V-Coat (1064nm)	Fused Silica	#38-731	C\$316.01 Volume Pricing	6 In Stock
25.40	1,000.00	997.59	Uncoated	Fused Silica	#38-633	C\$276.02 Volume Pricing	20+ In Stock
25.40	1,000.00	997.59	Laser V-Coat (266nm)	Fused Silica	#38-655	C\$316.01 Volume Pricing	4 In Stock
25.40	1,000.00	997.59	Laser V-Coat (355nm)	Fused Silica	#38-680	C\$316.01 Volume Pricing	3 In Stock
25.40	1,000.00	997.59	Laser V-Coat (532nm)	Fused Silica	#38-706	C\$316.01 Volume Pricing	13 In Stock
25.40	1,000.00	997.59	Laser V-Coat (1064nm)	Fused Silica	#38-732	C\$316.01 Volume Pricing	7 In Stock

[#70-003 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80	100.00	91.773	Uncoated	Fused Silica		C\$556.50 Volume Pricing	20+ In Stock
-------	--------	--------	----------	------------------------------	--	---	--------------

[#70-004 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144 Uncoated

[Fused Silica](#)

C\$556.50
[Volume Pricing](#)

20+ In Stock

[#70-005 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515 Uncoated

[Fused Silica](#)

C\$556.50
[Volume Pricing](#)

6 In Stock

[#70-006 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

50.80 250.00 244.514 Uncoated

[Fused
Silica](#)

C\$556.50
[Volume Pricing](#)

20+ In Stock

[#70-007 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

50.80 300.00 294.516 Uncoated

[Fused
Silica](#)

C\$556.50
[Volume Pricing](#)

15 In Stock

[#70-013 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

C\$598.75
[Volume Pricing](#)

4 In Stock

50.80 100.00 91.773 Laser V-Coat (266nm) [Fused Silica](#)

[#70-014 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

C\$598.75
[Volume Pricing](#)

4 In Stock

50.80 150.00 143.144 Laser V-Coat (266nm) [Fused Silica](#)

[#70-015 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515

Laser V-Coat
(266nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

3 In Stock

[#70-016 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 250.00 244.514

Laser V-Coat
(266nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

5 In Stock

[#70-017 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 300.00 294.516

Laser V-Coat
(266nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

9 In Stock

[#70-023 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 100.00 91.773

Laser V-Coat
(355nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

5 In Stock

[#70-024 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144

Laser V-Coat (355nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

5 In Stock

[#70-025 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515

Laser V-Coat (355nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

5 In Stock

[#70-026 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 250.00 244.514

Laser V-Coat (355nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

5 In Stock

[#70-027 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 300.00 294.516

Laser V-Coat (355nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

5 In Stock

[#70-033 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 100.00 91.773

Laser V-Coat (532nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

2 In Stock

[#70-034 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144

Laser V-Coat (532nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

1 In Stock

[#70-035 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515

Laser V-Coat (532nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

13 In Stock

[#70-036 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 250.00 244.514

Laser V-Coat (532nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

1 In Stock

[#70-037 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 300.00 294.516

Laser V-Coat
(532nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

7 In Stock

[#70-043 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 100.00 91.773

Laser V-Coat
(1064nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

2 In Stock

[#70-044 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144

Laser V-Coat
(1064nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

7 In Stock

[#70-045 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515

Laser V-Coat
(1064nm)

[Fused Silica](#)

C\$598.75
[Volume Pricing](#)

2 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com