

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

TECHSPEC® Fluorescence Bandpass Filters



- Common Wavelengths for Popular Fluorophores
- Excitation Filters and Emission Filters Available
- >93% Transmission
- >OD 6 Blocking, <3% from Edge of Bandwidth
- [Fluorescence Filter Sets](#) and [Pre-Mounted Fluorescence Filter Cube Sets](#) Also Available

Common Specifications

Physical & Mechanical Properties

Thickness Tolerance (mm):	±0.1	Construction:	Mounted in Black Anodized Ring
Physical Durability:	Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2	Substrate Thickness (mm):	2.00 ±0.25

Optical Properties

Angle of Incidence (°):	0 ±5	Optical Density OD (Average):	≥6.0
Coating:	Hard Coated	Surface Quality:	60-40
Transmitted Wavefront, RMS:	λ/4 (prior to coating)		


Threading & Mounting

Mount Thickness (mm):	3.5 ±0.1
------------------------------	----------

Environmental & Durability Factors

Environmental Durability:	Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7
----------------------------------	---

Technical Information

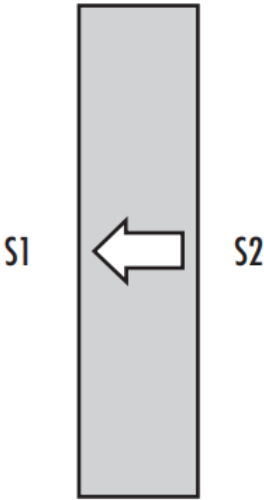

All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is applied to S2.

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Average Transmission (%)	Compatible Fluorophore	Blocking Wavelength Range (nm)	Stock Number	Price	Buy
12.50	340.00	29.00	>75	FURA2 Excitation	250 -925	#84-076	C\$385.84 Volume Pricing	4 In Stock
25.00	340.00	29.00	>75	FURA2 Excitation	250 -925	#84-092	C\$485.27 Volume Pricing	4 In Stock
50.00	340.00	29.00	>75	FURA2 Excitation	250 -925	#84-108	C\$1,314.82 Volume Pricing	1 In Stock
12.50	357.00	48.00	>75	Tryptophan Emission	250 - 1100	#86-973	C\$385.84 Volume Pricing	9 In Stock
25.00	357.00	48.00	>75	Tryptophan Emission	250 - 1100	#86-981	C\$485.27 Volume Pricing	3 In Stock
50.00	357.00	48.00	>75	Tryptophan Emission	250 - 1100	#86-989	C\$1,314.82 Volume Pricing	1 In Stock
12.50	370.00	40.00	>85	Sirius Excitation	250 - 1100	#86-974	C\$385.84 Volume Pricing	9 In Stock
25.00	370.00	40.00	>85	Sirius Excitation	250 - 1100	#86-982	C\$485.27 Volume Pricing	12 In Stock
50.00	370.00	40.00	>85	Sirius Excitation	250 - 1100	#86-990	C\$1,314.82 Volume Pricing	2 In Stock
12.50	377.00	54.00	>85	DAPI Excitation	250 - 1100	#84-077	C\$385.84 Volume Pricing	2 In Stock
25.00	377.00	54.00	>85	DAPI Excitation	250 - 1100	#84-093	C\$485.27 Volume Pricing	15 In Stock
50.00	377.00	54.00	>85	DAPI Excitation	250 - 1100	#84-109	C\$1,314.82 Volume Pricing	5 In Stock
12.50	386.00	27.00	>90	DAPI Excitation	250 - 1100	#33-320	C\$385.84 Volume Pricing	3 In Stock
25.00	386.00	27.00	>90	DAPI Excitation	250 - 1100	#33-321	C\$485.27 Volume Pricing	6 In Stock
50.00	386.00	27.00	>90	DAPI Excitation	250 - 1100	#33-322	C\$1,314.82 Volume Pricing	6 In Stock
12.50	387.00	15.00	>90	DAPI Excitation / BFP & GFP Excitation	250 -1050	#84-078	C\$385.84 Volume Pricing	20+ In Stock
25.00	387.00	15.00	>90	DAPI Excitation / BFP & GFP Excitation	250 -1050	#84-094	C\$485.27 Volume Pricing	4 In Stock
50.00	387.00	15.00	>90	DAPI Excitation / BFP & GFP Excitation	250 -1050	#84-110	C\$1,314.82 Volume Pricing	1 In Stock

12.50	390.00	45.00	>90	405nm Laser Excitation	250 - 1100	#86-337	C\$385.84 Volume Pricing	3 In Stock
25.00	390.00	45.00	>90	405nm Laser Excitation	250 - 1100	#86-348	C\$485.27 Volume Pricing	14 In Stock
50.00	390.00	45.00	>90	405nm Laser Excitation	250 - 1100	#86-359	C\$1,314.82 Volume Pricing	1 In Stock
12.50	435.00	48.00	>93	Qdot® Excitation	250 - 1100	#86-338	C\$385.84 Volume Pricing	20+ In Stock
25.00	435.00	48.00	>93	Qdot® Excitation	250 - 1100	#86-349	C\$485.27 Volume Pricing	12 In Stock
50.00	435.00	48.00	>93	Qdot® Excitation	250 - 1100	#86-360	C\$1,314.82 Volume Pricing	4 In Stock
12.50	438.00	28.00	>93	CFP Excitation	250 - 1100	#67-012	C\$385.84 Volume Pricing	9 In Stock
25.00	438.00	28.00	>93	CFP Excitation	250 - 1100	#67-026	C\$485.27 Volume Pricing	4 In Stock
50.00	438.00	28.00	>93	CFP Excitation	250 - 1100	#67-040	C\$1,314.82 Volume Pricing	1 In Stock
12.50	440.00	46.00	>93	Sirius Emission	250 - 1100	#86-339	C\$385.84 Volume Pricing	1 In Stock
25.00	440.00	46.00	>93	Sirius Emission	250 - 1100	#86-350	C\$485.27 Volume Pricing	3 In Stock
50.00	440.00	46.00	>93	Sirius Emission	250 - 1100	#86-361	C\$1,314.82 Volume Pricing	2 In Stock
12.50	447.00	65.00	>93	DAPI Emission / BFP & GFP Emission	250 - 1100	#84-079	C\$385.84 Volume Pricing	4 In Stock
25.00	447.00	65.00	>93	DAPI Emission / BFP & GFP Emission	250 - 1100	#84-095	C\$485.27 Volume Pricing	3 In Stock
50.00	447.00	65.00	>93	DAPI Emission / BFP & GFP Emission	250 - 1100	#84-111	C\$1,314.82 Volume Pricing	5 In Stock
12.50	448.00	25.00	>93	442nm Laser Excitation	250 - 1100	#86-975	C\$385.84 Volume Pricing	8 In Stock
25.00	448.00	25.00	>93	442nm Laser Excitation	250 - 1100	#86-983	C\$485.27 Volume Pricing	2 In Stock
50.00	448.00	25.00	>93	442nm Laser Excitation	250 - 1100	#86-991	C\$1,314.82 Volume Pricing	2 In Stock
12.50	452.00	51.00	>93	DiA Excitation	250 - 1100	#86-340	C\$385.84 Volume Pricing	5 In Stock
25.00	452.00	51.00	>93	DiA Excitation	250 - 1100	#86-351	C\$485.27 Volume Pricing	16 In Stock
50.00	452.00	51.00	>93	DiA Excitation	250 - 1100	#86-362	C\$1,314.82 Volume Pricing	5 In Stock

12.50	466.00	45.00	>93	GFP Excitation	250 - 1100	#86-341	C\$385.84 Volume Pricing	4 In Stock
25.00	466.00	45.00	>93	GFP Excitation	250 - 1100	#86-352	C\$485.27 Volume Pricing	1 In Stock
50.00	466.00	45.00	>93	GFP Excitation	250 - 1100	#86-363	C\$1,314.82 Volume Pricing	1 In Stock
12.50	472.00	35.00	>93	GFP Excitation	250 - 1100	#67-013	C\$385.84 Volume Pricing	20+ In Stock
25.00	472.00	35.00	>93	GFP Excitation	250 - 1100	#67-027	C\$485.27 Volume Pricing	15 In Stock
50.00	472.00	35.00	>93	GFP Excitation	250 - 1100	#67-041	C\$1,314.82 Volume Pricing	1 In Stock
12.50	475.00	56.00	>93	FITC Excitation	250 - 1100	#86-342	C\$385.84 Volume Pricing	1 In Stock
25.00	475.00	56.00	>93	FITC Excitation	250 - 1100	#86-353	C\$485.27 Volume Pricing	20+ In Stock
50.00	475.00	56.00	>93	FITC Excitation	250 - 1100	#86-364	C\$1,314.82 Volume Pricing	1 In Stock
12.50	482.50	36.00	>93	FITC Excitation / CFP Emission	250 - 1100	#67-014	C\$385.84 Volume Pricing	20+ In Stock
25.00	482.50	36.00	>93	FITC Excitation / CFP Emission	250 - 1100	#67-028	C\$485.27 Volume Pricing	7 In Stock
50.00	482.50	36.00	>93	FITC Excitation / CFP Emission	250 - 1100	#67-042	C\$1,314.82 Volume Pricing	3 In Stock
12.50	494.00	25.00	>93	SpectrumGreen™ Excitation	300 - 1150	#84-080	C\$385.84 Volume Pricing	20+ In Stock
25.00	494.00	25.00	>93	SpectrumGreen™ Excitation	300 - 1150	#84-096	C\$485.27 Volume Pricing	13 In Stock
50.00	494.00	25.00	>93	SpectrumGreen™ Excitation	300 - 1150	#84-112	C\$1,314.82 Volume Pricing	7 In Stock
12.50	500.00	29.00	>93	YFP Excitation	250 - 1100	#67-015	C\$385.84 Volume Pricing	3 In Stock
25.00	500.00	29.00	>93	YFP Excitation	250 - 1100	#67-029	C\$485.27 Volume Pricing	5 In Stock
50.00	500.00	29.00	>93	YFP Excitation	250 - 1100	#67-043	C\$1,314.82 Volume Pricing	2 In Stock
12.50	510.00	25.00	>93	Cy2 Emission / Cy3 Excitation	250 - 1100	#87-734	C\$385.84 Volume Pricing	20+ In Stock
25.00	510.00	25.00	>93	Cy2 Emission / Cy3 Excitation	250 - 1100	#87-748	C\$485.27 Volume Pricing	1 In Stock
50.00	510.00	25.00	>93	Cy2 Emission / Cy3 Excitation	250 - 1100	#87-762	C\$1,314.82 Volume Pricing	6 In Stock
12.50	510.00	89.00	>93	FURA2 Emission	250 - 1100	#84-081	C\$385.84 Volume Pricing	11 In Stock

25.00	510.00	89.00	>93	FURA2 Emission	250 - 1100	#84-097	C\$485.27 Volume Pricing	5 In Stock
50.00	510.00	89.00	>93	FURA2 Emission	250 - 1100	#84-113	C\$1,314.82 Volume Pricing	1 In Stock
12.50	512.00	30.00	>93	Fluorescein Emission	250 - 1100	#33-323	C\$385.84 Volume Pricing	20+ In Stock
25.00	512.00	30.00	>93	Fluorescein Emission	250 - 1100	#33-324	C\$485.27 Volume Pricing	20+ In Stock
50.00	512.00	30.00	>93	Fluorescein Emission	250 - 1100	#33-325	C\$1,314.82 Volume Pricing	5 In Stock
12.50	520.00	41.00	>93	GFP Emission	250 -1025	#67-016	C\$385.84 Volume Pricing	20+ In Stock
25.00	520.00	41.00	>93	GFP Emission	250 -1025	#67-030	C\$485.27 Volume Pricing	20+ In Stock
50.00	520.00	41.00	>93	GFP Emission	250 -1025	#67-044	C\$1,314.82 Volume Pricing	1 In Stock
12.50	520.00	77.00	>93	Alexa Fluor® 488 Emission/ GFP Emission	250 -1200	#87-735	C\$385.84 Volume Pricing	8 In Stock
25.00	520.00	77.00	>93	Alexa Fluor® 488 Emission/ GFP Emission	250 -1200	#87-749	C\$485.27 Volume Pricing	20+ In Stock
50.00	520.00	77.00	>93	Alexa Fluor® 488 Emission/ GFP Emission	250 -1200	#87-763	C\$1,314.82 Volume Pricing	4 In Stock
12.50	525.00	18.00	>93	Qdot® 525 Emission	250 - 1100	#86-343	C\$385.84 Volume Pricing	3 In Stock
25.00	525.00	18.00	>93	Qdot® 525 Emission	250 - 1100	#86-354	C\$485.27 Volume Pricing	3 In Stock
50.00	525.00	18.00	>93	Qdot® 525 Emission	250 - 1100	#86-365	C\$1,314.82 Volume Pricing	1 In Stock
12.50	525.00	51.00	>93	GPF/FITC Emission	250 - 1100	#86-976	C\$385.84 Volume Pricing	2 In Stock
25.00	525.00	51.00	>93	GPF/FITC Emission	250 - 1100	#86-984	C\$485.27 Volume Pricing	13 In Stock
50.00	525.00	51.00	>93	GPF/FITC Emission	250 - 1100	#86-992	C\$1,314.82 Volume Pricing	5 In Stock
12.50	527.00	22.00	>93	SpectrumGreen™ Emission	250 - 1100	#84-082	C\$385.84 Volume Pricing	5 In Stock
25.00	527.00	22.00	>93	SpectrumGreen™ Emission	250 - 1100	#84-098	C\$485.27 Volume Pricing	3 In Stock
50.00	527.00	22.00	>93	SpectrumGreen™ Emission	250 - 1100	#84-114	C\$1,314.82 Volume Pricing	5 In Stock

12.50	530.00	62.00	>93	Alexa Fluor® 532 Excitation / Thiazole Orange Emission	250 - 1100	#87-736	C\$385.84 Volume Pricing	3 In Stock
25.00	530.00	62.00	>93	Alexa Fluor® 532 Excitation / Thiazole Orange Emission	250 - 1100	#87-750	C\$485.27 Volume Pricing	4 In Stock
50.00	530.00	62.00	>93	Alexa Fluor® 532 Excitation / Thiazole Orange Emission	250 - 1100	#87-764	C\$1,314.82 Volume Pricing	2 In Stock
12.50	534.00	25.00	>93	SpectrumGold™ Excitation	250 - 1100	#84-083	C\$385.84 Volume Pricing	20+ In Stock
25.00	534.00	25.00	>93	SpectrumGold™ Excitation	250 - 1100	#84-099	C\$485.27 Volume Pricing	17 In Stock
50.00	534.00	25.00	>93	SpectrumGold™ Excitation	250 - 1100	#84-115	C\$1,314.82 Volume Pricing	9 In Stock
12.50	534.50	48.00	>93	Cy3 Excitation / FITC Emission	250 - 1100	#67-017	C\$385.84 Volume Pricing	20+ In Stock
25.00	534.50	48.00	>93	Cy3 Excitation / FITC Emission	250 - 1100	#67-031	C\$485.27 Volume Pricing	20+ In Stock
50.00	534.50	48.00	>93	Cy3 Excitation / FITC Emission	250 - 1100	#67-045	C\$1,314.82 Volume Pricing	1 In Stock
12.50	540.00	56.00	>93	FITC Emission	250 - 1100	#86-344	C\$385.84 Volume Pricing	3 In Stock
25.00	540.00	56.00	>93	FITC Emission	250 - 1100	#86-355	C\$485.27 Volume Pricing	14 In Stock
50.00	540.00	56.00	>93	FITC Emission	250 - 1100	#86-366	C\$1,314.82 Volume Pricing	3 In Stock
12.50	543.00	27.00	>93	YFP Emission / TRITC Excitation	250 - 1100	#67-018	C\$385.84 Volume Pricing	3 In Stock
25.00	543.00	27.00	>93	YFP Emission / TRITC Excitation	250 - 1100	#67-032	C\$485.27 Volume Pricing	20+ In Stock
50.00	543.00	27.00	>93	YFP Emission / TRITC Excitation	250 - 1100	#67-046	C\$1,314.82 Volume Pricing	7 In Stock
12.50	549.00	21.00	>93	Alexa Fluor® 532 Emission / DyLight™ Excitation	250 - 1100	#87-737	C\$385.84 Volume Pricing	4 In Stock
25.00	549.00	21.00	>93	Alexa Fluor® 532 Emission / DyLight™ Excitation	250 - 1100	#87-751	C\$485.27 Volume Pricing	2 In Stock
50.00	549.00	21.00	>93	Alexa Fluor® 532 Emission / DyLight™ Excitation	250 - 1100	#87-765	C\$1,314.82 Volume Pricing	2 In Stock

12.50	550.00	100.00	>93	Broadband Green Fluorescence	250 - 1100	#33-329	C\$385.84 Volume Pricing	20+ In Stock
25.00	550.00	100.00	>93	Broadband Green Fluorescence	250 - 1100	#33-330	C\$485.27 Volume Pricing	4 In Stock
50.00	550.00	100.00	>93	Broadband Green Fluorescence	250 - 1100	#33-331	C\$1,314.82 Volume Pricing	6 In Stock
12.50	560.00	32.00	>93	561nm Laser Emission	250 - 1100	#86-977	C\$385.84 Volume Pricing	1 In Stock
25.00	560.00	32.00	>93	561nm Laser Emission	250 - 1100	#86-985	C\$485.27 Volume Pricing	4 In Stock
50.00	560.00	32.00	>93	561nm Laser Emission	250 - 1100	#86-993	C\$1,314.82 Volume Pricing	1 In Stock
12.50	561.00	21.00	>93	Keima Red Excitation	250 - 1100	#86-978	C\$385.84 Volume Pricing	Contact Us
25.00	561.00	21.00	>93	Keima Red Excitation	250 - 1100	#86-986	C\$485.27 Volume Pricing	10 In Stock
50.00	561.00	21.00	>93	Keima Red Excitation	250 - 1100	#86-994	C\$1,314.82 Volume Pricing	1 In Stock
12.50	562.00	46.00	>93	Texas Red Excitation / mCherry Excitation	250 -1000	#67-019	C\$385.84 Volume Pricing	20+ In Stock
25.00	562.00	46.00	>93	Texas Red Excitation / mCherry Excitation	250 -1000	#67-033	C\$485.27 Volume Pricing	16 In Stock
50.00	562.00	46.00	>93	Texas Red Excitation / mCherry Excitation	250 -1000	#67-047	C\$1,314.82 Volume Pricing	1 In Stock
12.50	572.00	33.00	>93	SpectrumGold™ Emission	250 -1120	#84-084	C\$385.84 Volume Pricing	20+ In Stock
25.00	572.00	33.00	>93	SpectrumGold™ Emission	250 -1120	#84-100	C\$485.27 Volume Pricing	4 In Stock
50.00	572.00	33.00	>93	SpectrumGold™ Emission	250 -1120	#84-116	C\$1,314.82 Volume Pricing	Contact Us
12.50	575.00	35.00	>93	Alexa Fluor® 568 Excitation	250 - 1100	#33-332	C\$385.84 Volume Pricing	4 In Stock
25.00	575.00	35.00	>93	Alexa Fluor® 568 Excitation	250 - 1100	#33-333	C\$485.27 Volume Pricing	5 In Stock
50.00	575.00	35.00	>93	Alexa Fluor® 568 Excitation	250 - 1100	#33-334	C\$1,314.82 Volume Pricing	2 In Stock
12.50	578.00	22.00	>93	Alexa Fluor® 568 Excitation / Cy3.5 Emission	250 - 1100	#87-738	C\$385.84 Volume Pricing	3 In Stock
25.00	578.00	22.00	>93	Alexa Fluor® 568 Excitation / Cy3.5 Emission	250 - 1100	#87-752	C\$485.27 Volume Pricing	6 In Stock

50.00	578.00	22.00	>93	Alexa Fluor® 568 Excitation / Cy3.5 Emission	250 - 1100	#87-766	C\$1,314.82 Volume Pricing	4 In Stock
12.50	585.00	40.00	>93	-	250 -1100	#33-906	C\$385.84 Volume Pricing	3 In Stock
25.00	585.00	40.00	>93	-	250 -1100	#33-907	C\$485.27 Volume Pricing	5 In Stock
50.00	585.00	40.00	>93	-	250 -1100	#33-908	C\$1,314.82 Volume Pricing	3 In Stock
12.50	586.00	26.00	>93	SpectrumOrange™ Emission / SpectrumRed™ Excitation	250 -1120	#84-085	C\$385.84 Volume Pricing	20+ In Stock
25.00	586.00	26.00	>93	SpectrumOrange™ Emission / SpectrumRed™ Excitation	250 -1120	#84-101	C\$485.27 Volume Pricing	3 In Stock
50.00	586.00	26.00	>93	SpectrumOrange™ Emission / SpectrumRed™ Excitation	250 -1120	#84-117	C\$1,314.82 Volume Pricing	3 In Stock
12.50	591.50	49.00	>93	Cy3 Emission / TRITC Emission	250 - 1100	#67-020	C\$385.84 Volume Pricing	20+ In Stock
25.00	591.50	49.00	>93	Cy3 Emission / TRITC Emission	250 - 1100	#67-034	C\$485.27 Volume Pricing	10 In Stock
50.00	591.50	49.00	>93	Cy3 Emission / TRITC Emission	250 - 1100	#67-048	C\$1,314.82 Volume Pricing	6 In Stock
12.50	605.00	22.00	>93	Qdot® 605 Emission	250 - 1100	#86-345	C\$385.84 Volume Pricing	20+ In Stock
25.00	605.00	22.00	>93	Qdot® 605 Emission	250 - 1100	#86-356	C\$485.27 Volume Pricing	3 In Stock
50.00	605.00	22.00	>93	Qdot® 605 Emission	250 - 1100	#86-367	C\$1,314.82 Volume Pricing	3 In Stock
12.50	607.00	42.00	>93	GFP Emission / RFP Emission	250 -1000	#84-086	C\$385.84 Volume Pricing	15 In Stock
25.00	607.00	42.00	>93	GFP Emission / RFP Emission	250 -1000	#84-102	C\$485.27 Volume Pricing	5 In Stock
50.00	607.00	42.00	>93	GFP Emission / RFP Emission	250 -1000	#84-118	C\$1,314.82 Volume Pricing	3 In Stock
12.50	615.00	26.00	>93	Alexa Fluor® 594 Emission / Cy3 Emission	250 - 1100	#87-739	C\$385.84 Volume Pricing	20+ In Stock
25.00	615.00	26.00	>93	Alexa Fluor® 594 Emission / Cy3™ Emission	250 - 1100	#87-753	C\$485.27 Volume Pricing	8 In Stock

50.00	615.00	26.00	>93	Alexa Fluor® 594 Emission / Cy3™ Emission	250 - 1100	#87-767	C\$1,314.82 Volume Pricing	7 In Stock
12.50	620.00	60.00	>93	-	250 - 1100	#33-909	C\$385.84 Volume Pricing	3 In Stock
25.00	620.00	60.00	>93	-	250 - 1100	#33-910	C\$485.27 Volume Pricing	Contact Us
50.00	620.00	60.00	>93	-	250 - 1100	#33-911	C\$1,314.82 Volume Pricing	5 In Stock
12.50	623.00	30.00	>93	Cy5 Excitation / Texas Red® Emission	250 - 1100	#87-740	C\$385.84 Volume Pricing	20+ In Stock
25.00	623.00	30.00	>93	Cy5 Excitation / Texas Red® Emission	250 - 1100	#87-754	C\$485.27 Volume Pricing	5 In Stock
50.00	623.00	30.00	>93	Cy5 Excitation / Texas Red® Emission	250 - 1100	#87-768	C\$1,314.82 Volume Pricing	5 In Stock
12.50	624.00	46.00	>93	Texas Red Emission / Cy5 Excitation	250 -1000	#67-021	C\$385.84 Volume Pricing	Contact Us
25.00	624.00	46.00	>93	Texas Red Emission / Cy5 Excitation	250 -1000	#67-035	C\$485.27 Volume Pricing	20+ In Stock
50.00	624.00	46.00	>93	Texas Red Emission / Cy5 Excitation	250 -1000	#67-049	C\$1,314.82 Volume Pricing	Contact Us
12.50	625.00	25.00	>93	Qdot® 625 Emission	250 - 1100	#86-346	C\$385.84 Volume Pricing	12 In Stock
25.00	625.00	25.00	>93	Qdot® 625 Emission	250 - 1100	#86-357	C\$485.27 Volume Pricing	1 In Stock
50.00	625.00	25.00	>93	Qdot® 625 Emission	250 - 1100	#86-368	C\$1,314.82 Volume Pricing	1 In Stock
12.50	628.00	38.00	>93	SpectrumRed™ Emission / Cy5 Excitation	250 - 1100	#84-087	C\$385.84 Volume Pricing	20+ In Stock
25.00	628.00	38.00	>93	SpectrumRed™ Emission / Cy5 Excitation	250 - 1100	#84-103	C\$485.27 Volume Pricing	Contact Us
50.00	628.00	38.00	>93	SpectrumRed™ Emission / Cy5 Excitation	250 - 1100	#84-119	C\$1,314.82 Volume Pricing	2 In Stock
12.50	631.00	28.00	>93	Alexa Fluor® 633 Excitation	250 - 1100	#33-326	C\$385.84 Volume Pricing	2 In Stock
25.00	631.00	28.00	>93	Alexa Fluor® 633 Excitation	250 - 1100	#33-327	C\$485.27 Volume Pricing	1 In Stock

50.00	631.00	28.00	>93	Alexa Fluor® 633 Excitation	250 - 1100	#33-328	C\$1,314.82 Volume Pricing	4 In Stock
12.50	640.00	20.00	>93	635nm Laser Excitation	250 - 1100	#86-979	C\$385.84 Volume Pricing	5 In Stock
25.00	640.00	20.00	>93	635nm Laser Excitation	250 - 1100	#86-987	C\$485.27 Volume Pricing	2 In Stock
50.00	640.00	20.00	>93	635nm Laser Excitation	250 - 1100	#86-995	C\$1,314.82 Volume Pricing	1 In Stock
12.50	640.50	81.00	>93	mCherry Emission	250 - 1100	#67-022	C\$385.84 Volume Pricing	20+ In Stock
25.00	640.50	81.00	>93	mcherry Emission	250 - 1100	#67-036	C\$485.27 Volume Pricing	6 In Stock
50.00	640.50	81.00	>93	mCherry Emission	250 - 1100	#67-050	C\$1,314.82 Volume Pricing	Contact Us
12.50	648.00	20.00	>93	FITC Emission	250 - 1100	#33-335	C\$385.84 Volume Pricing	1 In Stock
25.00	648.00	20.00	>93	FITC Emission	250 - 1100	#33-336	C\$485.27 Volume Pricing	2 In Stock
50.00	648.00	20.00	>93	FITC Emission	250 - 1100	#33-337	C\$1,314.82 Volume Pricing	2 In Stock
12.50	655.00	24.00	>93	Qdot® 655 Emission	250 - 1100	#86-347	C\$385.84 Volume Pricing	20+ In Stock
25.00	655.00	24.00	>93	Qdot® 655 Emission	250 - 1100	#86-358	C\$485.27 Volume Pricing	1 In Stock
50.00	655.00	24.00	>93	Qdot® 655 Emission	250 - 1100	#86-369	C\$1,314.82 Volume Pricing	Contact Us
12.50	655.00	47.00	>93	Cy5.5 Excitation	250 - 1100	#67-023	C\$385.84 Volume Pricing	13 In Stock
25.00	655.00	47.00	>93	Cy5.5 Excitation	250 - 1100	#67-037	C\$485.27 Volume Pricing	2 In Stock
50.00	655.00	47.00	>93	Cy5.5 Excitation	250 - 1100	#67-051	C\$1,314.82 Volume Pricing	1 In Stock
12.50	661.00	26.00	>93	Alexa Fluor®647 Excitation / TO- PRO®-3 Iodide Emission	250 - 1100	#87-741	C\$385.84 Volume Pricing	20+ In Stock
25.00	661.00	26.00	>93	Alexa Fluor®647 Excitation / TO- PRO®-3 Iodide Emission	250 - 1100	#87-755	C\$485.27 Volume Pricing	Contact Us
50.00	661.00	26.00	>93	Alexa Fluor®647 Excitation / TO- PRO®-3 Iodide Emission	250 - 1100	#87-769	C\$1,314.82 Volume Pricing	11 In Stock
12.50	676.00	36.00	>93	Cy5 Emission	250 - 1100	#86-980	C\$385.84 Volume Pricing	9 In Stock

25.00	676.00	36.00	>93	Cy5 Emission	250 - 1100	#86-988	C\$485.27 Volume Pricing	4 In Stock
50.00	676.00	36.00	>93	Cy5 Emission	250 - 1100	#86-996	C\$1,314.82 Volume Pricing	5 In Stock
12.50	692.00	47.00	>93	Cy5 Emission	250 - 1100	#67-024	C\$385.84 Volume Pricing	20+ In Stock
25.00	692.00	47.00	>93	Cy5 Emission	250 - 1100	#67-038	C\$485.27 Volume Pricing	20+ In Stock
50.00	692.00	47.00	>93	Cy5 Emission	250 - 1100	#67-052	C\$1,314.82 Volume Pricing	6 In Stock
12.50	697.00	91.00	>93	Alexa Fluor® 680 Emission / Cy5.5™ Emission	250 - 1100	#87-743	C\$385.84 Volume Pricing	5 In Stock
25.00	697.00	91.00	>93	Alexa Fluor® 680 Emission / Cy5.5™ Emission	250 - 1100	#87-757	C\$485.27 Volume Pricing	4 In Stock
50.00	697.00	91.00	>93	Alexa Fluor® 680 Emission / Cy5.5™ Emission	250 - 1100	#87-771	C\$1,314.82 Volume Pricing	8 In Stock
12.50	710.00	47.00	>93	Cy7 Excitation	250 - 1100	#84-088	C\$403.65 Volume Pricing	5 In Stock
25.00	710.00	47.00	>93	Cy7 Excitation	250 - 1100	#84-104	C\$501.59 Volume Pricing	6 In Stock
50.00	710.00	47.00	>93	Cy7 Excitation	250 - 1100	#84-120	C\$1,347.47 Volume Pricing	Contact Us
12.50	716.00	47.00	>93	Cy5 Emission	250 - 1100	#67-025	C\$403.65 Volume Pricing	20+ In Stock
25.00	716.00	47.00	>93	Cy5 Emission	250 - 1100	#67-039	C\$501.59 Volume Pricing	2 In Stock
50.00	716.00	47.00	>93	Cy5 Emission	250 - 1100	#67-053	C\$1,347.47 Volume Pricing	1 In Stock
12.50	732.00	76.00	>93	Cy7 Excitation / DY-732 Excitation	250 - 1100	#87-744	C\$403.65 Volume Pricing	2 In Stock
25.00	732.00	76.00	>93	Cy7 Excitation / DY-732 Excitation	250 - 1100	#87-758	C\$501.59 Volume Pricing	20+ In Stock
50.00	732.00	76.00	>93	Cy7 Excitation / DY-732 Excitation	250 - 1100	#87-772	C\$1,347.47 Volume Pricing	9 In Stock
12.50	769.00	48.00	>93	ICG-A Excitation	250 -1150	#84-089	C\$403.65 Volume Pricing	6 In Stock
25.00	769.00	48.00	>93	ICG-A Excitation	250 -1150	#84-105	C\$501.59 Volume Pricing	20+ In Stock
50.00	769.00	48.00	>93	ICG-A Excitation	250 -1150	#84-121	C\$1,347.47 Volume Pricing	4 In Stock
12.50	775.00	54.00	>93	Cy7 Emission	250 - 1100	#84-090	C\$403.65 Volume Pricing	3 In Stock

25.00	775.00	54.00	>93	Cy7 Excitation	250 - 1100	#84-106	C\$501.59 Volume Pricing	12 In Stock
50.00	775.00	54.00	>93	Cy7 Excitation	250 - 1100	#84-122	C\$1,347.47 Volume Pricing	8 In Stock
12.50	785.00	71.00	>93	Alexa Fluor® 790 Excitation / IRDye 800RS Emission	250 - 1100	#87-745	C\$403.65 Volume Pricing	3 In Stock
25.00	785.00	71.00	>93	Alexa Fluor® 790 Excitation / IRDye 800RS Emission	250 - 1100	#87-759	C\$501.59 Volume Pricing	20+ In Stock
50.00	785.00	71.00	>93	Alexa Fluor® 790 Excitation / IRDye 800RS Emission	250 - 1100	#87-773	C\$1,347.47 Volume Pricing	8 In Stock
12.50	832.00	45.00	>93	ICG-A Excitation	250 - 1100	#84-091	C\$403.65 Volume Pricing	20+ In Stock
25.00	832.00	45.00	>93	ICG-A Excitation	250 - 1100	#84-107	C\$501.59 Volume Pricing	9 In Stock
50.00	832.00	45.00	>93	ICG-A Excitation	250 - 1100	#84-123	C\$1,347.47 Volume Pricing	6 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
 Phone: 1-800-363-1992 :
www.edmundoptics.com