

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® NIR II Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <0.7% Reflectance per Surface for 750 - 1550nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [VIS-EXT](#), and [YAG-BBAR](#)

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed
--------	----------------------



Optical Properties

Coating:	NIR II (750-1550nm)
----------	---------------------

Focal Length Tolerance (%):	±1
-----------------------------	----

Wavelength Range (nm):	750 - 1550
------------------------	------------

Technical Information

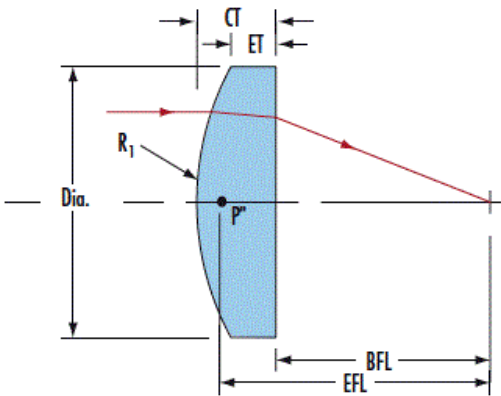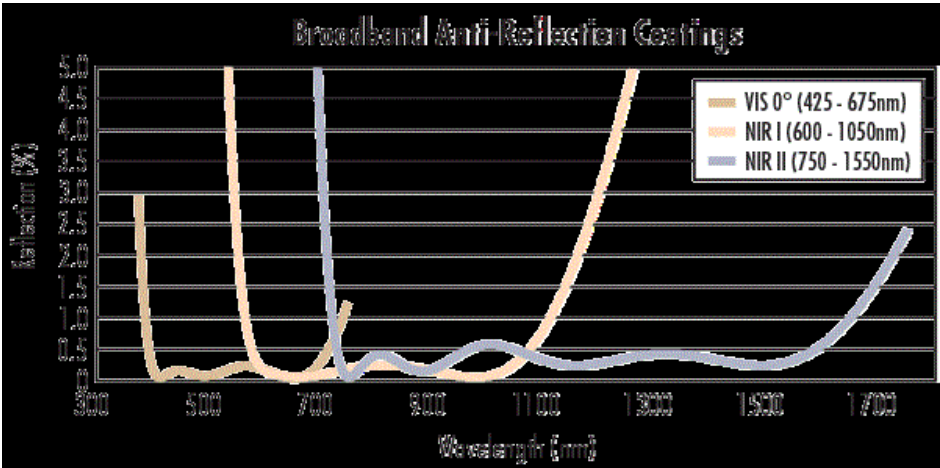

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	NIR II (750-1550nm)	N-LASF9	#67-423	C\$120.96 Volume Pricing	Contact Us
1.00	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-424	C\$120.96 Volume Pricing	2 In Stock
1.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-425	C\$120.96 Volume Pricing	7 In Stock
1.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-426	C\$120.96 Volume Pricing	20+ In Stock
1.50	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-427	C\$120.96 Volume Pricing	20+ In Stock
1.50	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-428	C\$120.96 Volume Pricing	9 In Stock
1.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-429	C\$120.96 Volume Pricing	9 In Stock
2.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-430	C\$119.45 Volume Pricing	20+ In Stock
2.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-431	C\$119.45 Volume Pricing	9 In Stock
2.00	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-432	C\$119.45 Volume Pricing	14 In Stock
2.00	4.00	3.57	NIR II (750-1550nm)	N-LASF9	#67-433	C\$119.45 Volume Pricing	12 In Stock
2.00	4.00	3.46	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-256	C\$157.25 Volume Pricing	5 In Stock

2.00	6.00	5.45	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-264	C\$148.93 Volume Pricing	5 In Stock
2.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-434	C\$119.45 Volume Pricing	20+ In Stock
2.50	2.50	2.07	NIR II (750-1550nm)	N-LASF9	#67-435	C\$119.45 Volume Pricing	7 In Stock
2.50	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-436	C\$119.45 Volume Pricing	4 In Stock
2.50	4.00	3.57	NIR II (750-1550nm)	N-LASF9	#67-437	C\$119.45 Volume Pricing	Contact Us
2.50	5.00	4.57	NIR II (750-1550nm)	N-LASF9	#67-438	C\$119.45 Volume Pricing	5 In Stock
3.00	3.00	1.88	NIR II (750-1550nm)	N-SF11	#67-439	C\$100.55 Volume Pricing	13 In Stock
3.00	4.50	3.50	NIR II (750-1550nm)	N-LASF44	#67-440	C\$100.55 Volume Pricing	20+ In Stock
3.00	6.00	4.81	NIR II (750-1550nm)	N-BK7	#67-441	C\$92.99 Volume Pricing	20+ In Stock
3.00	6.00	5.01	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-272	C\$157.25 Volume Pricing	5 In Stock
3.00	7.50	6.51	NIR II (750-1550nm)	N-BK7	#67-442	C\$92.99 Volume Pricing	15 In Stock
3.00	9.00	8.01	NIR II (750-1550nm)	N-BK7	#67-443	C\$92.99 Volume Pricing	3 In Stock
3.00	9.00	8.11	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-281	C\$148.93 Volume Pricing	5 In Stock
3.00	12.00	11.29	NIR II (750-1550nm)	N-BK7	#67-444	C\$92.99 Volume Pricing	10 In Stock

3.00	15.00	14.22	NIR II (750-1550nm)	N-BK7	#67-445	C\$92.99 Volume Pricing	1 In Stock
4.00	4.00	3.06	NIR II (750-1550nm)	N-LASF44	#67-446	C\$96.77 Volume Pricing	12 In Stock
4.00	6.00	4.51	NIR II (750-1550nm)	N-BK7	#67-447	C\$96.77 Volume Pricing	20+ In Stock
4.00	8.00	7.17	NIR II (750-1550nm)	N-BAF10	#67-448	C\$90.72 Volume Pricing	13 In Stock
4.00	8.00	6.91	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-289	C\$187.49 Volume Pricing	5 In Stock
4.00	10.00	8.96	NIR II (750-1550nm)	N-BK7	#67-449	C\$90.72 Volume Pricing	16 In Stock
4.00	12.00	11	NIR II (750-1550nm)	N-BK7	#67-450	C\$90.72 Volume Pricing	1 In Stock
4.00	12.00	11.04	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-297	C\$179.93 Volume Pricing	5 In Stock
4.50	4.50	3.05	NIR II (750-1550nm)	N-LASF44	#67-451	C\$96.77 Volume Pricing	17 In Stock
4.50	9.00	7.41	NIR II (750-1550nm)	N-BK7	#67-452	C\$90.72 Volume Pricing	2 In Stock
5.00	5.00	3.96	NIR II (750-1550nm)	N-LASF44	#67-453	C\$72.95 Volume Pricing	14 In Stock
5.00	7.50	6.43	NIR II (750-1550nm)	N-SF11	#67-454	C\$72.20 Volume Pricing	Contact Us
5.00	10.00	8.91	NIR II (750-1550nm)	N-BK7	#67-455	C\$72.20 Volume Pricing	3 In Stock
5.00	12.00	10.83	NIR II (750-1550nm)	N-BK7	#67-456	C\$72.20 Volume Pricing	9 In Stock

5.00	15.00	13.94	NIR II (750-1550nm)	N-BK7	#67-457	C\$72.20 Volume Pricing	8 In Stock
5.00	20.00	19.02	NIR II (750-1550nm)	N-BK7	#67-458	C\$72.20 Volume Pricing	3 In Stock
5.00	25.00	23.95	NIR II (750-1550nm)	N-BK7	#87-921	C\$72.20 Volume Pricing	5 In Stock
5.00	30.00	28.95	NIR II (750-1550nm)	N-BK7	#87-922	C\$72.20 Volume Pricing	20+ In Stock
6.00	6.00	4.60	NIR II (750-1550nm)	N-SF11	#67-459	C\$60.48 Volume Pricing	12 In Stock
6.00	7.50	6.10	NIR II (750-1550nm)	N-SF11	#67-460	C\$59.72 Volume Pricing	20+ In Stock
6.00	9.00	7.95	NIR II (750-1550nm)	N-SF5	#67-461	C\$59.72 Volume Pricing	20+ In Stock
6.00	10.00	8.82	NIR II (750-1550nm)	N-BK7	#38-386	C\$59.72 Volume Pricing	Contact Us
6.00	12.00	10.94	NIR II (750-1550nm)	N-BK7	#67-462	C\$58.21 Volume Pricing	20+ In Stock
6.00	15.00	13.68	NIR II (750-1550nm)	N-BK7	#67-463	C\$58.21 Volume Pricing	3 In Stock
6.00	18.00	17.07	NIR II (750-1550nm)	N-BK7	#67-464	C\$58.21 Volume Pricing	4 In Stock
6.00	20.00	19.04	NIR II (750-1550nm)	N-BK7	#38-387	C\$58.21 Volume Pricing	Contact Us
6.00	21.00	20.06	NIR II (750-1550nm)	N-BK7	#67-465	C\$58.21 Volume Pricing	9 In Stock
6.00	24.00	23.01	NIR II (750-1550nm)	N-BK7	#67-466	C\$58.21 Volume Pricing	15 In Stock

6.00	25.00	24.04	NIR II (750-1550nm)	N-BK7	#38-388	C\$58.21 Volume Pricing	3 In Stock
6.00	30.00	29.14	NIR II (750-1550nm)	N-BK7	#67-467	C\$58.21 Volume Pricing	20+ In Stock
6.00	36.00	34.95	NIR II (750-1550nm)	N-BK7	#67-468	C\$58.21 Volume Pricing	7 In Stock
6.00	48.00	46.95	NIR II (750-1550nm)	N-BK7	#67-469	C\$58.21 Volume Pricing	Contact Us
6.00	60.00	58.95	NIR II (750-1550nm)	N-BK7	#67-470	C\$58.21 Volume Pricing	20+ In Stock
6.00	72.00	70.97	NIR II (750-1550nm)	N-BK7	#67-471	C\$58.21 Volume Pricing	5 In Stock
7.00	7.00	5.50	NIR II (750-1550nm)	N-SF11	#71-296	C\$60.48 Volume Pricing	3 In Stock
7.00	10.00	8.10	NIR II (750-1550nm)	N-BK7	#71-303	C\$59.72 Volume Pricing	3 In Stock
7.00	12.00	10.30	NIR II (750-1550nm)	N-BK7	#71-310	C\$59.72 Volume Pricing	5 In Stock
8.00	8.00	6.40	NIR II (750-1550nm)	N-SF11	#71-317	C\$60.48 Volume Pricing	5 In Stock
8.00	10.00	7.60	NIR II (750-1550nm)	N-BK7	#71-324	C\$59.72 Volume Pricing	9 In Stock
8.00	12.00	10.00	NIR II (750-1550nm)	N-BK7	#71-331	C\$59.72 Volume Pricing	5 In Stock
9.00	9.00	7.32	NIR II (750-1550nm)	N-SF11	#67-472	C\$61.24 Volume Pricing	17 In Stock
9.00	10.00	8.49	NIR II (750-1550nm)	N-SF11	#38-389	C\$61.24 Volume Pricing	20+ In Stock

9.00	12.00	10.60	NIR II (750-1550nm)	N-SF11	#67-473	C\$61.24 Volume Pricing	20+ In Stock
9.00	13.50	11.94	NIR II (750-1550nm)	N-SF5	#67-474	C\$61.24 Volume Pricing	6 In Stock
9.00	15.00	13.02	NIR II (750-1550nm)	N-BK7	#67-475	C\$61.24 Volume Pricing	20+ In Stock
9.00	18.00	16.41	NIR II (750-1550nm)	N-BK7	#67-476	C\$59.72 Volume Pricing	11 In Stock
9.00	20.00	18.55	NIR II (750-1550nm)	N-BK7	#38-390	C\$59.72 Volume Pricing	Contact Us
9.00	22.00	20.73	NIR II (750-1550nm)	N-BK7	#67-477	C\$59.72 Volume Pricing	3 In Stock
9.00	25.00	23.68	NIR II (750-1550nm)	N-BK7	#38-391	C\$59.72 Volume Pricing	20+ In Stock
9.00	27.00	25.34	NIR II (750-1550nm)	N-BK7	#67-478	C\$59.72 Volume Pricing	20+ In Stock
9.00	36.00	34.48	NIR II (750-1550nm)	N-BK7	#67-479	C\$59.72 Volume Pricing	3 In Stock
9.00	45.00	43.98	NIR II (750-1550nm)	N-BK7	#67-480	C\$59.72 Volume Pricing	13 In Stock
9.00	54.00	52.69	NIR II (750-1550nm)	N-BK7	#67-481	C\$59.72 Volume Pricing	7 In Stock
9.00	72.00	70.68	NIR II (750-1550nm)	N-BK7	#67-482	C\$59.72 Volume Pricing	14 In Stock
9.00	90.00	88.68	NIR II (750-1550nm)	N-BK7	#67-483	C\$59.72 Volume Pricing	2 In Stock
10.00	10.00	8.18	NIR II (750-1550nm)	N-SF11	#67-484	C\$61.24 Volume Pricing	20+ In Stock

10.00	12.50	10.99	NIR II (750-1550nm)	N-SF11	#38-392	C\$61.24 Volume Pricing	3 In Stock
10.00	15.00	13.32	NIR II (750-1550nm)	N-SF11	#67-485	C\$61.24 Volume Pricing	4 In Stock
10.00	17.50	15.66	NIR II (750-1550nm)	N-BK7	#38-393	C\$59.72 Volume Pricing	5 In Stock
10.00	20.00	18.03	NIR II (750-1550nm)	N-BK7	#67-486	C\$59.72 Volume Pricing	20+ In Stock
10.00	25.00	23.02	NIR II (750-1550nm)	N-BK7	#67-487	C\$59.72 Volume Pricing	Contact Us
10.00	30.00	28.01	NIR II (750-1550nm)	N-BK7	#67-488	C\$59.72 Volume Pricing	Contact Us
10.00	40.00	38.02	NIR II (750-1550nm)	N-BK7	#67-489	C\$59.72 Volume Pricing	7 In Stock
10.00	50.00	48.02	NIR II (750-1550nm)	N-BK7	#67-490	C\$59.72 Volume Pricing	20+ In Stock
10.00	75.00	73.02	NIR II (750-1550nm)	N-BK7	#67-491	C\$59.72 Volume Pricing	Contact Us
10.00	100.00	98.02	NIR II (750-1550nm)	N-BK7	#67-492	C\$59.72 Volume Pricing	15 In Stock
12.00	12.00	9.76	NIR II (750-1550nm)	N-SF11	#67-493	C\$66.53 Volume Pricing	20+ In Stock
12.00	15.00	12.03	NIR II (750-1550nm)	N-BK7	#67-494	C\$66.53 Volume Pricing	14 In Stock
12.00	18.00	16.22	NIR II (750-1550nm)	N-SF5	#67-495	C\$66.53 Volume Pricing	1 In Stock
12.00	20.00	17.69	NIR II (750-1550nm)	N-BK7	#67-496	C\$66.53 Volume Pricing	5 In Stock

12.00	24.00	22.15	NIR II (750-1550nm)	N-BK7	#67-497	C\$65.02 Volume Pricing	1 In Stock
12.00	25.00	23.22	NIR II (750-1550nm)	N-BK7	#38-394	C\$65.02 Volume Pricing	7 In Stock
12.00	30.00	28.02	NIR II (750-1550nm)	N-BK7	#67-498	C\$65.02 Volume Pricing	20+ In Stock
12.00	36.00	34.02	NIR II (750-1550nm)	N-BK7	#33-357	C\$65.02 Volume Pricing	20+ In Stock
12.00	42.00	40.22	NIR II (750-1550nm)	N-BK7	#67-500	C\$65.02 Volume Pricing	Contact Us
12.00	48.00	46.36	NIR II (750-1550nm)	N-BK7	#67-501	C\$65.02 Volume Pricing	Contact Us
12.00	50.00	48.75	NIR II (750-1550nm)	N-BK7	#38-395	C\$65.02 Volume Pricing	7 In Stock
12.00	54.00	52.02	NIR II (750-1550nm)	N-BK7	#67-502	C\$65.02 Volume Pricing	Contact Us
12.00	60.00	58.37	NIR II (750-1550nm)	N-BK7	#67-503	C\$65.02 Volume Pricing	13 In Stock
12.00	72.00	70.42	NIR II (750-1550nm)	N-BK7	#67-504	C\$65.02 Volume Pricing	6 In Stock
12.00	84.00	82.39	NIR II (750-1550nm)	N-BK7	#67-505	C\$65.02 Volume Pricing	Contact Us
12.00	100.00	98.35	NIR II (750-1550nm)	N-BK7	#67-506	C\$65.02 Volume Pricing	14 In Stock
12.50	12.50	10.40	NIR II (750-1550nm)	N-SF11	#38-397	C\$65.02 Volume Pricing	15 In Stock
12.50	15.00	13.26	NIR II (750-1550nm)	N-SF11	#38-398	C\$65.02 Volume Pricing	2 In Stock

12.50	17.50	15.00	NIR II (750-1550nm)	N-BK7	#38-399	C\$65.02 Volume Pricing	1 In Stock
12.50	20.00	17.69	NIR II (750-1550nm)	N-BK7	#38-400	C\$65.02 Volume Pricing	6 In Stock
12.50	25.00	22.96	NIR II (750-1550nm)	N-BK7	#38-401	C\$63.50 Volume Pricing	Contact Us
12.50	30.00	28.22	NIR II (750-1550nm)	N-BK7	#38-402	C\$63.50 Volume Pricing	2 In Stock
12.50	35.00	33.42	NIR II (750-1550nm)	N-BK7	#38-403	C\$63.50 Volume Pricing	3 In Stock
12.50	40.00	38.55	NIR II (750-1550nm)	N-BK7	#38-404	C\$63.50 Volume Pricing	20+ In Stock
12.50	45.00	43.68	NIR II (750-1550nm)	N-BK7	#38-405	C\$63.50 Volume Pricing	6 In Stock
12.50	50.00	48.68	NIR II (750-1550nm)	N-BK7	#38-406	C\$63.50 Volume Pricing	5 In Stock
12.50	75.00	73.88	NIR II (750-1550nm)	N-BK7	#38-407	C\$63.50 Volume Pricing	14 In Stock
12.50	100.00	98.95	NIR II (750-1550nm)	N-BK7	#38-408	C\$63.50 Volume Pricing	5 In Stock
12.70	12.70	10.46	NIR II (750-1550nm)	N-SF11	#67-507	C\$65.02 Volume Pricing	20+ In Stock
12.70	15.00	11.53	NIR II (750-1550nm)	N-BK7	#67-508	C\$65.02 Volume Pricing	Contact Us
12.70	19.10	16.46	NIR II (750-1550nm)	N-BK7	#67-509	C\$65.02 Volume Pricing	14 In Stock
12.70	20.00	17.49	NIR II (750-1550nm)	N-BK7	#38-409	C\$65.02 Volume Pricing	Contact Us

12.70	25.40	23.43	NIR II (750-1550nm)	N-BK7	#67-510	C\$63.50 Volume Pricing	20+ In Stock
12.70	30.00	28.22	NIR II (750-1550nm)	N-BK7	#38-410	C\$63.50 Volume Pricing	7 In Stock
12.70	31.80	29.81	NIR II (750-1550nm)	N-BK7	#67-511	C\$63.50 Volume Pricing	7 In Stock
12.70	38.10	36.12	NIR II (750-1550nm)	N-BK7	#67-512	C\$63.50 Volume Pricing	5 In Stock
12.70	40.00	38.48	NIR II (750-1550nm)	N-BK7	#38-411	C\$63.50 Volume Pricing	1 In Stock
12.70	44.50	42.69	NIR II (750-1550nm)	N-BK7	#67-513	C\$63.50 Volume Pricing	1 In Stock
12.70	50.80	49.15	NIR II (750-1550nm)	N-BK7	#67-514	C\$63.50 Volume Pricing	Contact Us
12.70	100.00	98.88	NIR II (750-1550nm)	N-BK7	#38-412	C\$63.50 Volume Pricing	9 In Stock
15.00	15.00	11.71	NIR II (750-1550nm)	N-SF5	#67-515	C\$66.53 Volume Pricing	20+ In Stock
15.00	18.00	15.61	NIR II (750-1550nm)	N-SF5	#67-516	C\$66.53 Volume Pricing	Contact Us
15.00	20.00	17.74	NIR II (750-1550nm)	N-SF5	#67-517	C\$66.53 Volume Pricing	5 In Stock
15.00	22.50	20.50	NIR II (750-1550nm)	N-SF5	#67-518	C\$66.53 Volume Pricing	5 In Stock
15.00	25.00	22.50	NIR II (750-1550nm)	N-BK7	#38-413	C\$65.02 Volume Pricing	1 In Stock
15.00	30.00	27.90	NIR II (750-1550nm)	N-BK7	#67-519	C\$65.02 Volume Pricing	9 In Stock

15.00	40.00	38.02	NIR II (750-1550nm)	N-BK7	#67-520	C\$65.02 Volume Pricing	20+ In Stock
15.00	45.00	43.35	NIR II (750-1550nm)	N-BK7	#67-521	C\$65.02 Volume Pricing	20+ In Stock
15.00	50.00	48.35	NIR II (750-1550nm)	N-BK7	#38-414	C\$65.02 Volume Pricing	2 In Stock
15.00	60.00	58.65	NIR II (750-1550nm)	N-BK7	#67-522	C\$65.02 Volume Pricing	5 In Stock
15.00	75.00	73.79	NIR II (750-1550nm)	N-BK7	#67-523	C\$65.02 Volume Pricing	10 In Stock
15.00	100.00	98.02	NIR II (750-1550nm)	N-BK7	#67-524	C\$65.02 Volume Pricing	2 In Stock
15.00	200.00	197.89	NIR II (750-1550nm)	N-BK7	#14-378	C\$65.02 Volume Pricing	5 In Stock
15.00	250.00	248.02	NIR II (750-1550nm)	N-BK7	#14-386	C\$65.02 Volume Pricing	Contact Us
18.00	18.00	15.20	NIR II (750-1550nm)	N-SF11	#67-525	C\$67.28 Volume Pricing	12 In Stock
18.00	20.00	17.59	NIR II (750-1550nm)	N-SF11	#38-415	C\$66.53 Volume Pricing	2 In Stock
18.00	22.50	20.26	NIR II (750-1550nm)	N-SF11	#67-526	C\$66.53 Volume Pricing	4 In Stock
18.00	25.00	21.51	NIR II (750-1550nm)	N-BK7	#38-416	C\$66.53 Volume Pricing	1 In Stock
18.00	27.00	24.73	NIR II (750-1550nm)	N-SF5	#67-527	C\$66.53 Volume Pricing	20+ In Stock
18.00	30.00	27.10	NIR II (750-1550nm)	N-BK7	#38-419	C\$64.26 Volume Pricing	5 In Stock

18.00	36.00	33.65	NIR II (750-1550nm)	N-BK7	#67-528	C\$64.26 Volume Pricing	20+ In Stock
18.00	50.00	48.09	NIR II (750-1550nm)	N-BK7	#38-420	C\$64.26 Volume Pricing	3 In Stock
18.00	54.00	52.02	NIR II (750-1550nm)	N-BK7	#67-529	C\$64.26 Volume Pricing	20+ In Stock
18.00	72.00	70.05	NIR II (750-1550nm)	N-BK7	#67-530	C\$64.26 Volume Pricing	20+ In Stock
20.00	20.00	17.42	NIR II (750-1550nm)	N-SF11	#67-531	C\$68.04 Volume Pricing	20+ In Stock
20.00	25.00	22.76	NIR II (750-1550nm)	N-SF11	#67-532	C\$67.28 Volume Pricing	14 In Stock
20.00	30.00	27.30	NIR II (750-1550nm)	N-BAF10	#67-533	C\$67.28 Volume Pricing	2 In Stock
20.00	35.00	32.04	NIR II (750-1550nm)	N-BK7	#67-534	C\$67.28 Volume Pricing	Contact Us
20.00	40.00	36.77	NIR II (750-1550nm)	N-BK7	#67-535	C\$65.02 Volume Pricing	17 In Stock
20.00	50.00	47.87	NIR II (750-1550nm)	N-BK7	#67-536	C\$65.02 Volume Pricing	20+ In Stock
20.00	60.00	57.03	NIR II (750-1550nm)	N-BK7	#67-537	C\$65.02 Volume Pricing	2 In Stock
20.00	70.00	68.03	NIR II (750-1550nm)	N-BK7	#67-538	C\$65.02 Volume Pricing	2 In Stock
20.00	80.00	78.45	NIR II (750-1550nm)	N-BK7	#67-539	C\$65.02 Volume Pricing	10 In Stock
20.00	100.00	97.13	NIR II (750-1550nm)	N-BK7	#67-540	C\$65.02 Volume Pricing	9 In Stock

20.00	150.00	148.02	NIR II (750-1550nm)	N-BK7	#67-541	C\$65.02 Volume Pricing	4 In Stock
25.00	25.00	20.22	NIR II (750-1550nm)	N-SF5	#67-542	C\$68.04 Volume Pricing	20+ In Stock
25.00	30.00	24.69	NIR II (750-1550nm)	N-BK7	#67-543	C\$68.04 Volume Pricing	20+ In Stock
25.00	35.00	30.42	NIR II (750-1550nm)	N-BK7	#67-544	C\$68.04 Volume Pricing	13 In Stock
25.00	40.00	36.31	NIR II (750-1550nm)	N-BK7	#67-545	C\$68.04 Volume Pricing	20+ In Stock
25.00	50.00	46.75	NIR II (750-1550nm)	N-BK7	#67-546	C\$65.02 Volume Pricing	20+ In Stock
25.00	60.00	56.90	NIR II (750-1550nm)	N-BK7	#67-547	C\$65.02 Volume Pricing	20+ In Stock
25.00	75.00	72.00	NIR II (750-1550nm)	N-BK7	#67-548	C\$65.02 Volume Pricing	10 In Stock
25.00	85.00	82.17	NIR II (750-1550nm)	N-BK7	#67-549	C\$65.02 Volume Pricing	1 In Stock
25.00	100.00	97.17	NIR II (750-1550nm)	N-BK7	#67-550	C\$65.02 Volume Pricing	13 In Stock
25.00	125.00	122.70	NIR II (750-1550nm)	N-BK7	#67-551	C\$65.02 Volume Pricing	4 In Stock
25.00	150.00	147.81	NIR II (750-1550nm)	N-BK7	#67-552	C\$65.02 Volume Pricing	20+ In Stock
25.00	175.00	172.85	NIR II (750-1550nm)	N-BK7	#67-553	C\$65.02 Volume Pricing	6 In Stock
25.00	200.00	197.89	NIR II (750-1550nm)	N-BK7	#33-363	C\$65.02 Volume Pricing	10 In Stock

25.00	250.00	248.02	NIR II (750-1550nm)	N-BK7	#67-555	C\$65.02 Volume Pricing	4 In Stock
25.00	300.00	298.02	NIR II (750-1550nm)	N-BK7	#67-556	C\$65.02 Volume Pricing	2 In Stock
25.00	400.00	397.89	NIR II (750-1550nm)	N-BK7	#33-369	C\$65.02 Volume Pricing	8 In Stock
25.00	500.00	497.89	NIR II (750-1550nm)	N-BK7	#67-558	C\$65.02 Volume Pricing	4 In Stock
25.00	750.00	747.89	NIR II (750-1550nm)	N-BK7	#67-559	C\$65.02 Volume Pricing	12 In Stock
25.40	25.40	21.48	NIR II (750-1550nm)	N-SF11	#67-560	C\$68.04 Volume Pricing	5 In Stock
25.40	35.00	30.46	NIR II (750-1550nm)	N-BK7	#38-421	C\$68.04 Volume Pricing	2 In Stock
25.40	38.10	33.48	NIR II (750-1550nm)	N-BK7	#67-561	C\$68.04 Volume Pricing	Contact Us
25.40	40.00	36.11	NIR II (750-1550nm)	N-BK7	#38-422	C\$68.04 Volume Pricing	15 In Stock
25.40	50.80	47.5	NIR II (750-1550nm)	N-BK7	#67-562	C\$65.02 Volume Pricing	7 In Stock
25.40	63.50	60.37	NIR II (750-1550nm)	N-BK7	#67-563	C\$65.02 Volume Pricing	5 In Stock
25.40	75.00	72.69	NIR II (750-1550nm)	N-BK7	#38-424	C\$65.02 Volume Pricing	5 In Stock
25.40	76.20	73.56	NIR II (750-1550nm)	N-BK7	#67-564	C\$65.02 Volume Pricing	7 In Stock
25.40	88.90	86.26	NIR II (750-1550nm)	N-BK7	#67-565	C\$65.02 Volume Pricing	5 In Stock

25.40	100.00	98.02	NIR II (750-1550nm)	N-BK7	#38-425	C\$65.02 Volume Pricing	5 In Stock
25.40	101.60	98.97	NIR II (750-1550nm)	N-BK7	#67-566	C\$65.02 Volume Pricing	8 In Stock
25.40	125.00	123.02	NIR II (750-1550nm)	N-BK7	#38-431	C\$65.02 Volume Pricing	Contact Us
25.40	150.00	148.02	NIR II (750-1550nm)	N-BK7	#38-432	C\$65.02 Volume Pricing	5 In Stock
30.00	30.00	26.13	NIR II (750-1550nm)	N-SF11	#67-567	C\$83.92 Volume Pricing	20+ In Stock
30.00	40.00	37.20	NIR II (750-1550nm)	N-SF11	#67-568	C\$80.89 Volume Pricing	3 In Stock
30.00	50.00	46.17	NIR II (750-1550nm)	N-SF5	#67-569	C\$80.89 Volume Pricing	4 In Stock
30.00	60.00	56.03	NIR II (750-1550nm)	N-BK7	#67-570	C\$78.62 Volume Pricing	7 In Stock
30.00	75.00	70.95	NIR II (750-1550nm)	N-BK7	#67-571	C\$78.62 Volume Pricing	6 In Stock
30.00	100.00	96.01	NIR II (750-1550nm)	N-BK7	#67-572	C\$78.62 Volume Pricing	Contact Us
30.00	120.00	116.04	NIR II (750-1550nm)	N-BK7	#67-573	C\$78.62 Volume Pricing	20+ In Stock
35.00	35.00	30.52	NIR II (750-1550nm)	N-SF11	#38-433	C\$86.18 Volume Pricing	11 In Stock
35.00	50.00	44.40	NIR II (750-1550nm)	N-BK7	#38-434	C\$83.92 Volume Pricing	1 In Stock
35.00	70.00	66.04	NIR II (750-1550nm)	N-BK7	#38-435	C\$83.92 Volume Pricing	1 In Stock

35.00	100.00	97.03	NIR II (750-1550nm)	N-BK7	#38-436	C\$83.92 Volume Pricing	12 In Stock
40.00	40.00	35.13	NIR II (750-1550nm)	N-SF11	#67-574	C\$93.74 Volume Pricing	20+ In Stock
40.00	60.00	53.9	NIR II (750-1550nm)	N-BK7	#67-575	C\$93.74 Volume Pricing	1 In Stock
40.00	80.00	74.73	NIR II (750-1550nm)	N-BK7	#33-387	C\$92.23 Volume Pricing	5 In Stock
40.00	100.00	95.39	NIR II (750-1550nm)	N-BK7	#33-375	C\$92.23 Volume Pricing	5 In Stock
40.00	200.00	196.7	NIR II (750-1550nm)	N-BK7	#33-381	C\$92.23 Volume Pricing	9 In Stock
40.00	300.00	296.7	NIR II (750-1550nm)	N-BK7	#67-579	C\$92.23 Volume Pricing	Contact Us
40.00	400.00	396.7	NIR II (750-1550nm)	N-BK7	#67-580	C\$92.23 Volume Pricing	Contact Us
50.00	50.00	43.28	NIR II (750-1550nm)	N-SF11	#67-581	C\$101.30 Volume Pricing	3 In Stock
50.00	75.00	67.75	NIR II (750-1550nm)	N-BK7	#67-582	C\$98.28 Volume Pricing	20+ In Stock
50.00	100.00	93.41	NIR II (750-1550nm)	N-BK7	#67-583	C\$94.50 Volume Pricing	2 In Stock
50.00	125.00	117.479	NIR II (750-1550nm)	N-BK7	#67-584	C\$94.50 Volume Pricing	4 In Stock
50.00	150.00	144.07	NIR II (750-1550nm)	N-BK7	#67-585	C\$94.50 Volume Pricing	16 In Stock
50.00	175.00	169.05	NIR II (750-1550nm)	N-BK7	#67-586	C\$94.50 Volume Pricing	5 In Stock

50.00	200.00	196.66	NIR II (750-1550nm)	N-BK7	#67-587	C\$94.50 Volume Pricing	2 In Stock
50.00	250.00	246.74	NIR II (750-1550nm)	N-BK7	#67-588	C\$94.50 Volume Pricing	5 In Stock
50.00	500.00	496.70	NIR II (750-1550nm)	N-BK7	#67-589	C\$94.50 Volume Pricing	1 In Stock
50.80	50.81	44.08	NIR II (750-1550nm)	N-SF11	#71-338	C\$101.30 Volume Pricing	3 In Stock
50.80	76.20	68.95	NIR II (750-1550nm)	N-BK7	#71-345	C\$98.28 Volume Pricing	2 In Stock
75.00	75.00	53.49	NIR II (750-1550nm)	N-BK7	#86-921	C\$196.56 Volume Pricing	4 In Stock
#71-858 New							
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
75.00	100.00	87.57	NIR II (750-1550nm)	N-BK7		C\$193.54 Volume Pricing	4 In Stock
75.00	100.00	85.61	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-305	C\$990.36 Volume Pricing	2 In Stock
75.00	125.00	112.66	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-313	C\$960.12 Volume Pricing	1 In Stock

[#71-859 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 125.00 115.99

NIR II
(750-1550nm)

[N-BK7](#)

C\$193.54
[Volume Pricing](#)

5 In Stock

75.00 150.00 142.45

NIR II
(750-1550nm)

[N-BK7](#)

[#86-922](#)

C\$193.54
[Volume Pricing](#)

4 In Stock

75.00 150.00 136.31

NIR II
(750-1550nm)

Fused
Silica
(Corning
7980)

[#72-321](#)

C\$929.88
[Volume Pricing](#)

1 In Stock

[#71-860 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 175.00 168.68

NIR II
(750-1550nm)

[N-BK7](#)

C\$193.54
[Volume Pricing](#)

3 In Stock

75.00 200.00 194.24

NIR II
(750-1550nm)

[N-BK7](#)

[#86-923](#)

C\$193.54
[Volume Pricing](#)

4 In Stock

75.00	200.00	187.18	NIR II (750-1550nm)	Fused Silica (Corning 7980)	#72-329	C\$899.64 Volume Pricing	1 In Stock
75.00	250.00	244.73	NIR II (750-1550nm)	N-BK7	#86-924	C\$193.54 Volume Pricing	3 In Stock
#71-861 New							
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
75.00	300.00	294.4	NIR II (750-1550nm)	N-BK7		C\$193.54 Volume Pricing	11 In Stock
#71-862 New							
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
75.00	400.00	394.4	NIR II (750-1550nm)	N-BK7		C\$193.54 Volume Pricing	5 In Stock
75.00	500.00	494.73	NIR II (750-1550nm)	N-BK7	#86-925	C\$193.54 Volume Pricing	5 In Stock

[#71-863 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00 750.00 745.35

NIR II
(750-
1550nm)

[N-BK7](#)

C\$193.54
[Volume Pricing](#)

7 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com