

[All Products](#) / [Microscopy](#) / [Infinity Corrected Objectives](#)

Nikon CFI Plan Fluor Objectives

See More by [Nikon](#)



- Provide High Contrast Fluorescence Observation
- Ideal for Multiple Microscopy Techniques
- High Transmission from UV to the IR

Common Specifications

General

Compatible Tube Lens Focal Length (mm):	Focal Length: 200mm	Manufacturer:	Nikon
--	---------------------	---------------	-------


Sensor

Maximum Sensor Format:	2/3"
------------------------	------


Threading & Mounting

Mounting Threads:	M25 x 0.75
-------------------	------------

Technical Information

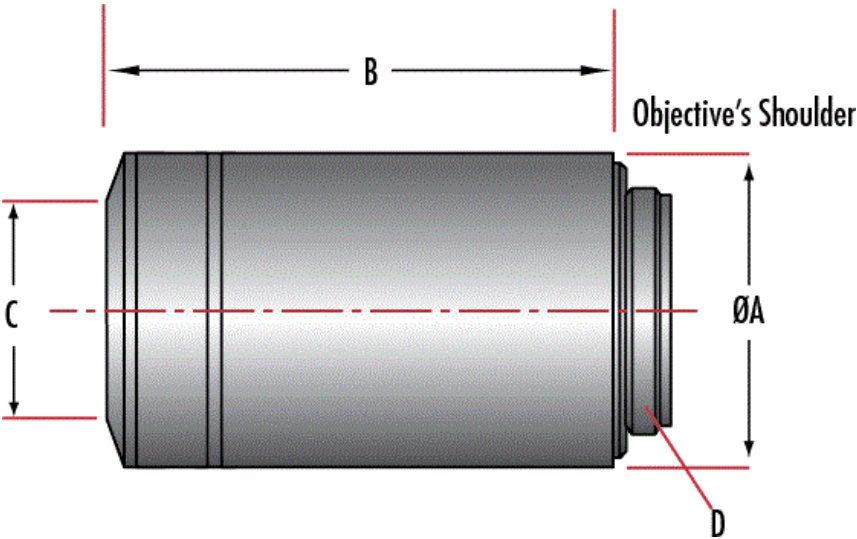

Products

Magnification	NA	Field Number (mm)	Model Number	WD (mm)	Stock Number	Price	Buy
4X	0.13	25	MRH00045	17.2	#88-378	C\$777.73	1 In Stock
10X	0.30	25	MRH00105	16.0	#88-379	C\$1,411.20	1 In Stock
20X	0.50	25	MRH00205	2.1	#88-380	C\$1,568.00	Contact Us
40X	0.75	25.2	MRH00405	0.66	#88-381	C\$3,057.60	3 In Stock
60X	0.85	25.2	MRH00602	0.3	#88-382	C\$4,704.00	Contact Us
#75-343 New							
							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
40X	1.3	25	MRH01401	0.24		C\$10,632.61	1 In Stock

[#75-344 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

100X

1.3

25

MRH01902

0.16

C\$4,189.70

1 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
Phone: 1-800-363-1992 :
www.edmundoptics.com