


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® YAG-BBAR Coated Plano-Convex (PCX) Lenses

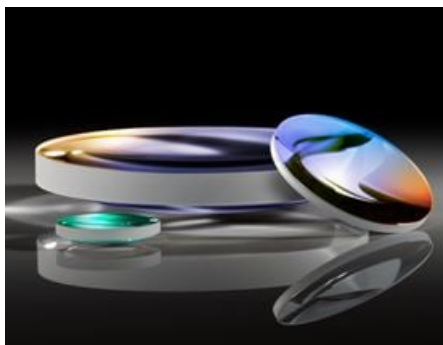

- Optimized for $R < 0.25\%$ @ Both 532nm and 1064nm
- AR Coated to Provide $< 1.0\%$ Reflectance per Surface for 500 - 1100nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), and [VIS-EXT](#)

Common Specifications

Physical & Mechanical Properties


Bevel:	Protective as needed
--------	----------------------

Optical Properties

Coating:	YAG-BBAR (500-1100nm)
----------	-----------------------

Focal Length Tolerance (%):	± 1
-----------------------------	---------

Technical Information

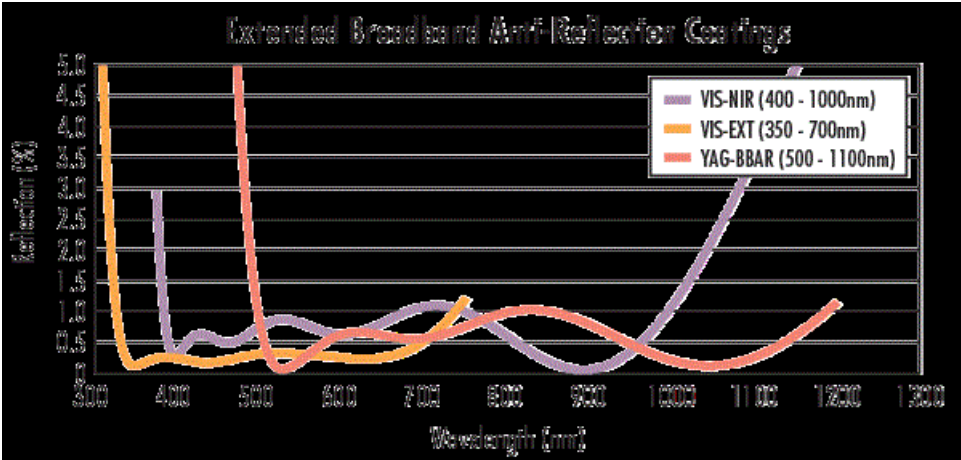

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	YAG-BBAR (500-1100nm)	N-LASF9	#35-710	C\$123.23 Volume Pricing	3 In Stock
1.00	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-711	C\$123.23 Volume Pricing	Contact Us
1.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-712	C\$123.23 Volume Pricing	11 In Stock
1.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-713	C\$123.23 Volume Pricing	5 In Stock
1.50	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-714	C\$123.23 Volume Pricing	9 In Stock
1.50	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-715	C\$123.23 Volume Pricing	4 In Stock
1.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-716	C\$123.23 Volume Pricing	5 In Stock
2.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-717	C\$121.72 Volume Pricing	4 In Stock
2.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-718	C\$121.72 Volume Pricing	3 In Stock
2.00	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-719	C\$121.72 Volume Pricing	3 In Stock
2.00	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-720	C\$121.72 Volume Pricing	10 In Stock
2.00	4.00	3.46	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-259	C\$164.81 Volume Pricing	5 In Stock

2.00	6.00	5.45	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-267	C\$157.25 Volume Pricing	4 In Stock
2.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-721	C\$121.72 Volume Pricing	5 In Stock
2.50	2.50	2.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-722	C\$121.72 Volume Pricing	Contact Us
2.50	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-723	C\$121.72 Volume Pricing	20+ In Stock
2.50	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-724	C\$121.72 Volume Pricing	10 In Stock
2.50	5.00	4.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-725	C\$121.72 Volume Pricing	3 In Stock
3.00	3.00	1.88	YAG-BBAR (500-1100nm)	N-SF11	#88-774	C\$104.33 Volume Pricing	16 In Stock
3.00	4.50	3.5	YAG-BBAR (500-1100nm)	N-LASF44	#88-775	C\$104.33 Volume Pricing	15 In Stock
3.00	6.00	4.81	YAG-BBAR (500-1100nm)	N-BK7	#88-776	C\$96.77 Volume Pricing	20+ In Stock
3.00	6.00	5.01	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-276	C\$164.81 Volume Pricing	5 In Stock
3.00	7.50	6.51	YAG-BBAR (500-1100nm)	N-BK7	#88-777	C\$96.77 Volume Pricing	20+ In Stock
3.00	9.00	8.01	YAG-BBAR (500-1100nm)	N-BK7	#88-778	C\$96.77 Volume Pricing	6 In Stock
3.00	9.00	8.11	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-284	C\$157.25 Volume Pricing	5 In Stock
3.00	12.00	11.29	YAG-BBAR (500-1100nm)	N-BK7	#88-779	C\$96.77 Volume Pricing	8 In Stock

3.00	15.00	14.22	YAG-BBAR (500-1100nm)	N-BK7	#88-780	C\$96.77 Volume Pricing	17 In Stock
4.00	4.00	3.06	YAG-BBAR (500-1100nm)	N-LASF44	#88-781	C\$104.33 Volume Pricing	20+ In Stock
4.00	6.00	4.51	YAG-BBAR (500-1100nm)	N-BK7	#88-782	C\$104.33 Volume Pricing	1 In Stock
4.00	8.00	6.91	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-292	C\$195.05 Volume Pricing	5 In Stock
4.00	10.00	8.92	YAG-BBAR (500-1100nm)	N-BK7	#88-784	C\$98.28 Volume Pricing	7 In Stock
4.00	12.00	11.00	YAG-BBAR (500-1100nm)	N-BK7	#88-785	C\$98.28 Volume Pricing	10 In Stock
4.00	12.00	11.04	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-300	C\$187.49 Volume Pricing	4 In Stock
4.50	4.50	3.05	YAG-BBAR (500-1100nm)	N-LASF44	#88-786	C\$104.33 Volume Pricing	7 In Stock
4.50	9.00	7.41	YAG-BBAR (500-1100nm)	N-BK7	#88-787	C\$98.28 Volume Pricing	3 In Stock
5.00	5.00	3.96	YAG-BBAR (500-1100nm)	N-LASF44	#88-788	C\$76.73 Volume Pricing	1 In Stock
5.00	7.50	6.43	YAG-BBAR (500-1100nm)	N-SF11	#88-789	C\$75.98 Volume Pricing	2 In Stock
5.00	10.00	8.91	YAG-BBAR (500-1100nm)	N-BK7	#88-790	C\$75.98 Volume Pricing	5 In Stock
5.00	12.00	10.83	YAG-BBAR (500-1100nm)	N-BK7	#88-791	C\$75.98 Volume Pricing	1 In Stock
5.00	15.00	13.94	YAG-BBAR (500-1100nm)	N-BK7	#88-792	C\$75.98 Volume Pricing	20+ In Stock

5.00	20.00	19.02	YAG-BBAR (500-1100nm)	N-BK7	#88-793	C\$75.98 Volume Pricing	5 In Stock
5.00	25.00	23.95	YAG-BBAR (500-1100nm)	N-BK7	#88-794	C\$75.98 Volume Pricing	10 In Stock
5.00	30.00	28.95	YAG-BBAR (500-1100nm)	N-BK7	#88-795	C\$75.98 Volume Pricing	12 In Stock
6.00	6.00	4.60	YAG-BBAR (500-1100nm)	N-SF11	#88-796	C\$64.26 Volume Pricing	14 In Stock
6.00	7.50	6.10	YAG-BBAR (500-1100nm)	N-SF11	#88-797	C\$63.50 Volume Pricing	11 In Stock
6.00	9.00	7.95	YAG-BBAR (500-1100nm)	N-SF5	#88-798	C\$63.50 Volume Pricing	Contact Us
6.00	10.00	8.82	YAG-BBAR (500-1100nm)	N-BK7	#38-568	C\$63.50 Volume Pricing	3 In Stock
6.00	12.00	10.94	YAG-BBAR (500-1100nm)	N-BK7	#88-799	C\$61.99 Volume Pricing	10 In Stock
6.00	15.00	13.68	YAG-BBAR (500-1100nm)	N-BK7	#88-800	C\$61.99 Volume Pricing	12 In Stock
6.00	18.00	17.07	YAG-BBAR (500-1100nm)	N-BK7	#88-801	C\$61.99 Volume Pricing	5 In Stock
6.00	20.00	19.04	YAG-BBAR (500-1100nm)	N-BK7	#38-569	C\$61.99 Volume Pricing	20+ In Stock
6.00	21.00	20.06	YAG-BBAR (500-1100nm)	N-BK7	#88-802	C\$61.99 Volume Pricing	1 In Stock
6.00	24.00	23.01	YAG-BBAR (500-1100nm)	N-BK7	#88-803	C\$61.99 Volume Pricing	Contact Us
6.00	25.00	24.04	YAG-BBAR (500-1100nm)	N-BK7	#38-570	C\$61.99 Volume Pricing	7 In Stock

6.00	30.00	29.14	YAG-BBAR (500-1100nm)	N-BK7	#88-804	C\$61.99 Volume Pricing	Contact Us
6.00	36.00	34.95	YAG-BBAR (500-1100nm)	N-BK7	#88-805	C\$61.99 Volume Pricing	1 In Stock
6.00	48.00	46.95	YAG-BBAR (500-1100nm)	N-BK7	#88-806	C\$61.99 Volume Pricing	5 In Stock
6.00	60.00	58.95	YAG-BBAR (500-1100nm)	N-BK7	#88-807	C\$61.99 Volume Pricing	3 In Stock
6.00	72.00	70.97	YAG-BBAR (500-1100nm)	N-BK7	#88-808	C\$61.99 Volume Pricing	5 In Stock
7.00	7.00	5.50	YAG-BBAR (500-1100nm)	N-LASF9	#71-299	C\$63.50 Volume Pricing	8 In Stock
7.00	10.00	8.10	YAG-BBAR (500-1100nm)	N-LASF9	#71-306	C\$62.75 Volume Pricing	5 In Stock
7.00	12.00	10.30	YAG-BBAR (500-1100nm)	N-LASF9	#71-313	C\$62.75 Volume Pricing	4 In Stock
8.00	8.00	6.40	YAG-BBAR (500-1100nm)	N-LASF9	#71-320	C\$63.50 Volume Pricing	8 In Stock
8.00	10.00	7.60	YAG-BBAR (500-1100nm)	N-LASF9	#71-327	C\$62.75 Volume Pricing	4 In Stock
8.00	12.00	10.00	YAG-BBAR (500-1100nm)	N-LASF9	#71-334	C\$62.75 Volume Pricing	9 In Stock
9.00	9.00	7.32	YAG-BBAR (500-1100nm)	N-SF11	#88-809	C\$65.02 Volume Pricing	3 In Stock
9.00	10.00	8.49	YAG-BBAR (500-1100nm)	N-SF11	#38-571	C\$65.02 Volume Pricing	2 In Stock
9.00	12.00	10.60	YAG-BBAR (500-1100nm)	N-SF11	#88-810	C\$65.02 Volume Pricing	20+ In Stock

9.00	13.50	11.94	YAG-BBAR (500-1100nm)	N-SF5	#88-811	C\$65.02 Volume Pricing	11 In Stock
9.00	15.00	13.02	YAG-BBAR (500-1100nm)	N-BK7	#88-812	C\$65.02 Volume Pricing	1 In Stock
9.00	18.00	16.41	YAG-BBAR (500-1100nm)	N-BK7	#88-813	C\$63.50 Volume Pricing	8 In Stock
9.00	20.00	18.55	YAG-BBAR (500-1100nm)	N-BK7	#38-572	C\$63.50 Volume Pricing	5 In Stock
9.00	22.00	20.73	YAG-BBAR (500-1100nm)	N-BK7	#88-814	C\$63.50 Volume Pricing	14 In Stock
9.00	25.00	23.68	YAG-BBAR (500-1100nm)	N-BK7	#38-573	C\$63.50 Volume Pricing	5 In Stock
9.00	27.00	25.34	YAG-BBAR (500-1100nm)	N-BK7	#88-815	C\$63.50 Volume Pricing	10 In Stock
9.00	36.00	34.48	YAG-BBAR (500-1100nm)	N-BK7	#88-816	C\$63.50 Volume Pricing	Contact Us
9.00	45.00	43.98	YAG-BBAR (500-1100nm)	N-BK7	#88-817	C\$63.50 Volume Pricing	14 In Stock
9.00	54.00	52.69	YAG-BBAR (500-1100nm)	N-BK7	#88-818	C\$63.50 Volume Pricing	5 In Stock
9.00	72.00	70.68	YAG-BBAR (500-1100nm)	N-BK7	#88-819	C\$63.50 Volume Pricing	11 In Stock
9.00	90.00	88.68	YAG-BBAR (500-1100nm)	N-BK7	#88-820	C\$63.50 Volume Pricing	5 In Stock
10.00	10.00	8.18	YAG-BBAR (500-1100nm)	N-SF11	#88-821	C\$65.02 Volume Pricing	20+ In Stock
10.00	12.50	10.99	YAG-BBAR (500-1100nm)	N-SF11	#38-574	C\$65.02 Volume Pricing	6 In Stock

10.00	15.00	13.32	YAG-BBAR (500-1100nm)	N-SF11	#88-822	C\$65.02 Volume Pricing	7 In Stock
10.00	17.50	15.66	YAG-BBAR (500-1100nm)	N-BK7	#38-575	C\$63.50 Volume Pricing	1 In Stock
10.00	20.00	18.03	YAG-BBAR (500-1100nm)	N-BK7	#88-823	C\$63.50 Volume Pricing	20+ In Stock
10.00	25.00	23.02	YAG-BBAR (500-1100nm)	N-BK7	#88-824	C\$63.50 Volume Pricing	5 In Stock
10.00	30.00	28.01	YAG-BBAR (500-1100nm)	N-BK7	#88-825	C\$63.50 Volume Pricing	17 In Stock
10.00	40.00	38.02	YAG-BBAR (500-1100nm)	N-BK7	#88-826	C\$63.50 Volume Pricing	3 In Stock
10.00	50.00	48.02	YAG-BBAR (500-1100nm)	N-BK7	#88-827	C\$63.50 Volume Pricing	13 In Stock
10.00	75.00	73.02	YAG-BBAR (500-1100nm)	N-BK7	#88-828	C\$63.50 Volume Pricing	3 In Stock
10.00	100.00	98.02	YAG-BBAR (500-1100nm)	N-BK7	#88-829	C\$63.50 Volume Pricing	10 In Stock
12.00	12.00	9.76	YAG-BBAR (500-1100nm)	N-SF11	#88-830	C\$70.31 Volume Pricing	20+ In Stock
12.00	15.00	12.03	YAG-BBAR (500-1100nm)	N-BK7	#88-831	C\$70.31 Volume Pricing	12 In Stock
12.00	18.00	16.22	YAG-BBAR (500-1100nm)	N-SF5	#88-832	C\$70.31 Volume Pricing	Contact Us
12.00	20.00	17.69	YAG-BBAR (500-1100nm)	N-BK7	#88-833	C\$70.31 Volume Pricing	5 In Stock
12.00	24.00	22.15	YAG-BBAR (500-1100nm)	N-BK7	#88-834	C\$68.80 Volume Pricing	20+ In Stock

12.00	25.00	23.22	YAG-BBAR (500-1100nm)	N-BK7	#38-576	C\$68.80 Volume Pricing	20+ In Stock
12.00	30.00	28.02	YAG-BBAR (500-1100nm)	N-BK7	#88-835	C\$68.80 Volume Pricing	2 In Stock
12.00	36.00	34.02	YAG-BBAR (500-1100nm)	N-BK7	#34-183	C\$68.80 Volume Pricing	3 In Stock
12.00	42.00	40.22	YAG-BBAR (500-1100nm)	N-BK7	#88-837	C\$68.80 Volume Pricing	16 In Stock
12.00	48.00	46.36	YAG-BBAR (500-1100nm)	N-BK7	#88-838	C\$68.80 Volume Pricing	5 In Stock
12.00	50.00	48.75	YAG-BBAR (500-1100nm)	N-BK7	#38-577	C\$68.80 Volume Pricing	4 In Stock
12.00	54.00	52.02	YAG-BBAR (500-1100nm)	N-BK7	#88-839	C\$68.80 Volume Pricing	8 In Stock
12.00	60.00	58.37	YAG-BBAR (500-1100nm)	N-BK7	#88-840	C\$68.80 Volume Pricing	Contact Us
12.00	72.00	70.42	YAG-BBAR (500-1100nm)	N-BK7	#88-841	C\$68.80 Volume Pricing	6 In Stock
12.00	84.00	82.39	YAG-BBAR (500-1100nm)	N-BK7	#88-842	C\$68.80 Volume Pricing	4 In Stock
12.00	100.00	98.35	YAG-BBAR (500-1100nm)	N-BK7	#88-843	C\$68.80 Volume Pricing	1 In Stock
12.50	12.50	10.40	YAG-BBAR (500-1100nm)	N-SF11	#38-578	C\$68.80 Volume Pricing	14 In Stock
12.50	15.00	13.26	YAG-BBAR (500-1100nm)	N-SF11	#38-579	C\$68.80 Volume Pricing	20+ In Stock
12.50	17.50	15.00	YAG-BBAR (500-1100nm)	N-BK7	#38-580	C\$68.80 Volume Pricing	Contact Us

12.50	20.00	17.69	YAG-BBAR (500-1100nm)	N-BK7	#38-581	C\$68.80 Volume Pricing	15 In Stock
12.50	25.00	22.96	YAG-BBAR (500-1100nm)	N-BK7	#38-584	C\$67.28 Volume Pricing	4 In Stock
12.50	30.00	28.22	YAG-BBAR (500-1100nm)	N-BK7	#38-585	C\$67.28 Volume Pricing	13 In Stock
12.50	35.00	33.42	YAG-BBAR (500-1100nm)	N-BK7	#38-586	C\$67.28 Volume Pricing	3 In Stock
12.50	40.00	38.55	YAG-BBAR (500-1100nm)	N-BK7	#38-587	C\$67.28 Volume Pricing	7 In Stock
12.50	45.00	43.68	YAG-BBAR (500-1100nm)	N-BK7	#38-588	C\$67.28 Volume Pricing	13 In Stock
12.50	50.00	48.68	YAG-BBAR (500-1100nm)	N-BK7	#38-589	C\$67.28 Volume Pricing	2 In Stock
12.50	75.00	73.88	YAG-BBAR (500-1100nm)	N-BK7	#38-591	C\$67.28 Volume Pricing	9 In Stock
12.50	100.00	98.95	YAG-BBAR (500-1100nm)	N-BK7	#38-593	C\$67.28 Volume Pricing	3 In Stock
12.70	12.70	10.46	YAG-BBAR (500-1100nm)	N-SF11	#88-844	C\$68.80 Volume Pricing	3 In Stock
12.70	15.00	11.53	YAG-BBAR (500-1100nm)	N-BK7	#88-845	C\$68.80 Volume Pricing	6 In Stock
12.70	19.10	16.46	YAG-BBAR (500-1100nm)	N-BK7	#88-846	C\$68.80 Volume Pricing	9 In Stock
12.70	20.00	17.49	YAG-BBAR (500-1100nm)	N-BK7	#38-594	C\$68.80 Volume Pricing	9 In Stock
12.70	25.40	23.43	YAG-BBAR (500-1100nm)	N-BK7	#88-847	C\$67.28 Volume Pricing	6 In Stock

12.70	30.00	28.22	YAG-BBAR (500-1100nm)	N-BK7	#38-595	C\$67.28 Volume Pricing	10 In Stock
12.70	31.80	29.81	YAG-BBAR (500-1100nm)	N-BK7	#88-848	C\$67.28 Volume Pricing	3 In Stock
12.70	38.10	36.12	YAG-BBAR (500-1100nm)	N-BK7	#88-849	C\$67.28 Volume Pricing	5 In Stock
12.70	40.00	38.48	YAG-BBAR (500-1100nm)	N-BK7	#38-596	C\$67.28 Volume Pricing	1 In Stock
12.70	44.50	42.69	YAG-BBAR (500-1100nm)	N-BK7	#88-850	C\$67.28 Volume Pricing	2 In Stock
12.70	50.80	49.15	YAG-BBAR (500-1100nm)	N-BK7	#88-851	C\$67.28 Volume Pricing	Contact Us
12.70	100.00	98.88	YAG-BBAR (500-1100nm)	N-BK7	#38-597	C\$67.28 Volume Pricing	Contact Us
15.00	15.00	11.71	YAG-BBAR (500-1100nm)	N-SF5	#88-852	C\$70.31 Volume Pricing	13 In Stock
15.00	18.00	15.61	YAG-BBAR (500-1100nm)	N-SF5	#88-853	C\$70.31 Volume Pricing	6 In Stock
15.00	20.00	17.74	YAG-BBAR (500-1100nm)	N-SF5	#88-854	C\$70.31 Volume Pricing	20+ In Stock
15.00	22.50	20.50	YAG-BBAR (500-1100nm)	N-SF5	#88-855	C\$70.31 Volume Pricing	5 In Stock
15.00	25.00	22.50	YAG-BBAR (500-1100nm)	N-BK7	#38-598	C\$68.80 Volume Pricing	5 In Stock
15.00	30.00	27.90	YAG-BBAR (500-1100nm)	N-BK7	#88-856	C\$68.80 Volume Pricing	20+ In Stock
15.00	40.00	38.02	YAG-BBAR (500-1100nm)	N-BK7	#88-857	C\$68.80 Volume Pricing	20+ In Stock

15.00	45.00	43.35	YAG-BBAR (500-1100nm)	N-BK7	#88-858	C\$68.80 Volume Pricing	8 In Stock
15.00	50.00	48.35	YAG-BBAR (500-1100nm)	N-BK7	#38-599	C\$68.80 Volume Pricing	14 In Stock
15.00	60.00	58.65	YAG-BBAR (500-1100nm)	N-BK7	#88-859	C\$68.80 Volume Pricing	7 In Stock
15.00	75.00	73.79	YAG-BBAR (500-1100nm)	N-BK7	#88-860	C\$68.80 Volume Pricing	5 In Stock
15.00	100.00	98.02	YAG-BBAR (500-1100nm)	N-BK7	#88-861	C\$68.80 Volume Pricing	14 In Stock
15.00	200.00	197.89	YAG-BBAR (500-1100nm)	N-BK7	#14-381	C\$68.80 Volume Pricing	6 In Stock
15.00	250.00	248.02	YAG-BBAR (500-1100nm)	N-BK7	#14-389	C\$68.80 Volume Pricing	Contact Us
18.00	18.00	15.20	YAG-BBAR (500-1100nm)	N-SF11	#88-862	C\$72.58 Volume Pricing	9 In Stock
18.00	20.00	17.59	YAG-BBAR (500-1100nm)	N-SF11	#38-600	C\$71.82 Volume Pricing	7 In Stock
18.00	22.50	20.26	YAG-BBAR (500-1100nm)	N-SF11	#88-863	C\$71.82 Volume Pricing	6 In Stock
18.00	25.00	21.51	YAG-BBAR (500-1100nm)	N-BK7	#38-601	C\$71.82 Volume Pricing	4 In Stock
18.00	27.00	24.73	YAG-BBAR (500-1100nm)	N-SF5	#88-864	C\$71.82 Volume Pricing	7 In Stock
18.00	30.00	27.10	YAG-BBAR (500-1100nm)	N-BK7	#38-602	C\$69.55 Volume Pricing	3 In Stock
18.00	36.00	33.65	YAG-BBAR (500-1100nm)	N-BK7	#88-865	C\$69.55 Volume Pricing	Contact Us

18.00	50.00	48.09	YAG-BBAR (500-1100nm)	N-BK7	#38-603	C\$69.55 Volume Pricing	20+ In Stock
18.00	54.00	52.02	YAG-BBAR (500-1100nm)	N-BK7	#88-866	C\$69.55 Volume Pricing	3 In Stock
18.00	72.00	70.05	YAG-BBAR (500-1100nm)	N-BK7	#88-867	C\$69.55 Volume Pricing	6 In Stock
20.00	20.00	17.42	YAG-BBAR (500-1100nm)	N-SF11	#88-868	C\$73.33 Volume Pricing	14 In Stock
20.00	25.00	22.76	YAG-BBAR (500-1100nm)	N-SF11	#88-869	C\$72.58 Volume Pricing	7 In Stock
20.00	35.00	32.04	YAG-BBAR (500-1100nm)	N-BK7	#88-871	C\$72.58 Volume Pricing	4 In Stock
20.00	40.00	36.77	YAG-BBAR (500-1100nm)	N-BK7	#88-872	C\$70.31 Volume Pricing	8 In Stock
20.00	50.00	47.87	YAG-BBAR (500-1100nm)	N-BK7	#88-873	C\$70.31 Volume Pricing	8 In Stock
20.00	60.00	57.03	YAG-BBAR (500-1100nm)	N-BK7	#88-874	C\$70.31 Volume Pricing	4 In Stock
20.00	70.00	68.03	YAG-BBAR (500-1100nm)	N-BK7	#88-875	C\$70.31 Volume Pricing	20+ In Stock
20.00	80.00	78.45	YAG-BBAR (500-1100nm)	N-BK7	#88-876	C\$70.31 Volume Pricing	20+ In Stock
20.00	100.00	97.13	YAG-BBAR (500-1100nm)	N-BK7	#88-877	C\$70.31 Volume Pricing	4 In Stock
20.00	150.00	148.02	YAG-BBAR (500-1100nm)	N-BK7	#88-878	C\$70.31 Volume Pricing	6 In Stock
25.00	25.00	20.22	YAG-BBAR (500-1100nm)	N-SF5	#88-879	C\$77.11 Volume Pricing	17 In Stock

25.00	30.00	24.69	YAG-BBAR (500-1100nm)	N-BK7	#88-880	C\$77.11 Volume Pricing	11 In Stock
25.00	35.00	30.42	YAG-BBAR (500-1100nm)	N-BK7	#88-881	C\$77.11 Volume Pricing	5 In Stock
25.00	40.00	36.31	YAG-BBAR (500-1100nm)	N-BK7	#88-882	C\$77.11 Volume Pricing	2 In Stock
25.00	50.00	46.75	YAG-BBAR (500-1100nm)	N-BK7	#88-883	C\$74.09 Volume Pricing	4 In Stock
25.00	60.00	56.90	YAG-BBAR (500-1100nm)	N-BK7	#88-884	C\$74.09 Volume Pricing	1 In Stock
25.00	75.00	72.00	YAG-BBAR (500-1100nm)	N-BK7	#88-885	C\$74.09 Volume Pricing	5 In Stock
25.00	85.00	82.17	YAG-BBAR (500-1100nm)	N-BK7	#88-886	C\$74.09 Volume Pricing	5 In Stock
25.00	100.00	97.17	YAG-BBAR (500-1100nm)	N-BK7	#88-887	C\$74.09 Volume Pricing	5 In Stock
25.00	125.00	122.70	YAG-BBAR (500-1100nm)	N-BK7	#88-888	C\$74.09 Volume Pricing	12 In Stock
25.00	150.00	147.81	YAG-BBAR (500-1100nm)	N-BK7	#88-889	C\$74.09 Volume Pricing	3 In Stock
25.00	175.00	172.85	YAG-BBAR (500-1100nm)	N-BK7	#88-890	C\$74.09 Volume Pricing	5 In Stock
25.00	200.00	197.89	YAG-BBAR (500-1100nm)	N-BK7	#34-184	C\$74.09 Volume Pricing	5 In Stock
25.00	250.00	248.02	YAG-BBAR (500-1100nm)	N-BK7	#88-892	C\$74.09 Volume Pricing	6 In Stock
25.00	300.00	298.02	YAG-BBAR (500-1100nm)	N-BK7	#88-893	C\$74.09 Volume Pricing	Contact Us

25.00	400.00	397.89	YAG-BBAR (500-1100nm)	N-BK7	#34-185	C\$74.09 Volume Pricing	14 In Stock
25.00	500.00	497.89	YAG-BBAR (500-1100nm)	N-BK7	#88-895	C\$74.09 Volume Pricing	2 In Stock
25.00	750.00	747.89	YAG-BBAR (500-1100nm)	N-BK7	#88-896	C\$74.09 Volume Pricing	4 In Stock
25.40	25.40	21.48	YAG-BBAR (500-1100nm)	N-SF11	#88-897	C\$77.11 Volume Pricing	11 In Stock
25.40	35.00	30.46	YAG-BBAR (500-1100nm)	N-BK7	#38-604	C\$77.11 Volume Pricing	1 In Stock
25.40	38.10	33.48	YAG-BBAR (500-1100nm)	N-BK7	#88-898	C\$77.11 Volume Pricing	9 In Stock
25.40	40.00	36.11	YAG-BBAR (500-1100nm)	N-BK7	#38-605	C\$77.11 Volume Pricing	5 In Stock
25.40	50.80	47.50	YAG-BBAR (500-1100nm)	N-BK7	#88-899	C\$74.09 Volume Pricing	3 In Stock
25.40	63.50	60.37	YAG-BBAR (500-1100nm)	N-BK7	#88-900	C\$74.09 Volume Pricing	Contact Us
25.40	75.00	72.69	YAG-BBAR (500-1100nm)	N-BK7	#38-607	C\$74.09 Volume Pricing	Contact Us
25.40	76.20	73.56	YAG-BBAR (500-1100nm)	N-BK7	#88-901	C\$74.09 Volume Pricing	10 In Stock
25.40	88.90	86.26	YAG-BBAR (500-1100nm)	N-BK7	#88-902	C\$74.09 Volume Pricing	Contact Us
25.40	100.00	98.02	YAG-BBAR (500-1100nm)	N-BK7	#38-608	C\$74.09 Volume Pricing	5 In Stock
25.40	101.60	98.97	YAG-BBAR (500-1100nm)	N-BK7	#88-903	C\$74.09 Volume Pricing	1 In Stock

25.40	125.00	123.02	YAG-BBAR (500-1100nm)	N-BK7	#38-609	C\$74.09 Volume Pricing	20+ In Stock
25.40	150.00	148.02	YAG-BBAR (500-1100nm)	N-BK7	#38-610	C\$74.09 Volume Pricing	13 In Stock
30.00	30.00	26.13	YAG-BBAR (500-1100nm)	N-SF11	#88-904	C\$87.70 Volume Pricing	7 In Stock
30.00	40.00	37.20	YAG-BBAR (500-1100nm)	N-SF11	#88-905	C\$84.67 Volume Pricing	Contact Us
30.00	50.00	46.17	YAG-BBAR (500-1100nm)	N-SF5	#88-906	C\$84.67 Volume Pricing	20+ In Stock
30.00	60.00	56.03	YAG-BBAR (500-1100nm)	N-BK7	#88-907	C\$82.40 Volume Pricing	14 In Stock
30.00	75.00	70.95	YAG-BBAR (500-1100nm)	N-BK7	#88-908	C\$82.40 Volume Pricing	5 In Stock
30.00	100.00	96.01	YAG-BBAR (500-1100nm)	N-BK7	#88-909	C\$82.40 Volume Pricing	4 In Stock
30.00	120.00	116.04	YAG-BBAR (500-1100nm)	N-BK7	#88-910	C\$82.40 Volume Pricing	Contact Us
35.00	35.00	30.52	YAG-BBAR (500-1100nm)	N-SF11	#38-611	C\$89.96 Volume Pricing	7 In Stock
35.00	50.00	44.40	YAG-BBAR (500-1100nm)	N-BK7	#38-612	C\$87.70 Volume Pricing	4 In Stock
35.00	70.00	66.04	YAG-BBAR (500-1100nm)	N-BK7	#38-613	C\$87.70 Volume Pricing	4 In Stock
35.00	100.00	97.03	YAG-BBAR (500-1100nm)	N-BK7	#38-614	C\$87.70 Volume Pricing	4 In Stock
40.00	40.00	35.13	YAG-BBAR (500-1100nm)	N-SF11	#88-911	C\$105.08 Volume Pricing	11 In Stock

40.00	60.00	53.90	YAG-BBAR (500-1100nm)	N-BK7	#88-912	C\$105.08 Volume Pricing	16 In Stock
40.00	80.00	74.73	YAG-BBAR (500-1100nm)	N-BK7	#34-186	C\$103.57 Volume Pricing	Contact Us
40.00	100.00	95.39	YAG-BBAR (500-1100nm)	N-BK7	#34-187	C\$103.57 Volume Pricing	5 In Stock
40.00	200.00	196.70	YAG-BBAR (500-1100nm)	N-BK7	#34-188	C\$103.57 Volume Pricing	4 In Stock
40.00	300.00	296.70	YAG-BBAR (500-1100nm)	N-BK7	#88-916	C\$103.57 Volume Pricing	9 In Stock
40.00	400.00	396.70	YAG-BBAR (500-1100nm)	N-BK7	#88-917	C\$103.57 Volume Pricing	5 In Stock
50.00	50.00	43.28	YAG-BBAR (500-1100nm)	N-SF11	#88-918	C\$112.64 Volume Pricing	15 In Stock
50.00	75.00	67.75	YAG-BBAR (500-1100nm)	N-BK7	#88-919	C\$109.62 Volume Pricing	6 In Stock
50.00	100.00	93.41	YAG-BBAR (500-1100nm)	N-BK7	#88-920	C\$105.84 Volume Pricing	5 In Stock
50.00	125.00	118.39	YAG-BBAR (500-1100nm)	N-BK7	#88-921	C\$105.84 Volume Pricing	Contact Us
50.00	150.00	144.07	YAG-BBAR (500-1100nm)	N-BK7	#88-922	C\$105.84 Volume Pricing	6 In Stock
50.00	175.00	169.05	YAG-BBAR (500-1100nm)	N-BK7	#88-923	C\$105.84 Volume Pricing	7 In Stock
50.00	200.00	196.66	YAG-BBAR (500-1100nm)	N-BK7	#88-924	C\$105.84 Volume Pricing	2 In Stock
50.00	250.00	246.74	YAG-BBAR (500-1100nm)	N-BK7	#88-925	C\$105.84 Volume Pricing	3 In Stock

50.00	500.00	496.70	YAG-BBAR (500-1100nm)	N-BK7	#88-926	C\$105.84 Volume Pricing	4 In Stock
50.80	50.81	44.08	YAG-BBAR (500-1100nm)	N-SF11	#71-341	C\$112.64 Volume Pricing	7 In Stock
50.80	76.20	68.95	YAG-BBAR (500-1100nm)	N-BK7	#71-348	C\$109.62 Volume Pricing	4 In Stock
75.00	75.00	53.49	YAG-BBAR (500-1100nm)	N-BK7	#26-114	C\$219.24 Volume Pricing	Contact Us
75.00	100.00	85.61	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-308	C\$1,005.48 Volume Pricing	5 In Stock
75.00	125.00	112.66	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-316	C\$975.24 Volume Pricing	5 In Stock
75.00	150.00	142.45	YAG-BBAR (500-1100nm)	N-BK7	#26-115	C\$216.22 Volume Pricing	8 In Stock
75.00	150.00	136.31	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-324	C\$945.00 Volume Pricing	5 In Stock
75.00	200.00	194.24	YAG-BBAR (500-1100nm)	N-BK7	#26-116	C\$216.22 Volume Pricing	8 In Stock
75.00	200.00	187.18	YAG-BBAR (500-1100nm)	Fused Silica (Corning 7980)	#72-332	C\$914.76 Volume Pricing	5 In Stock
75.00	250.00	244.73	YAG-BBAR (500-1100nm)	N-BK7	#26-117	C\$216.22 Volume Pricing	9 In Stock
75.00	500.00	494.73	YAG-BBAR (500-1100nm)	N-BK7	#26-118	C\$216.22 Volume Pricing	5 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
Phone: 1-800-363-1992 :
www.edmundoptics.com