

[All Products](#) /
 [Laser Optics](#) /
 [Laser Windows](#) /
 [Laser Line Windows](#)

TECHSPEC® $\lambda/10$ Laser Line Coated Windows



- 10-5 Surface Quality
- Damage Thresholds at Design Wavelengths
- Diameters from 12.5 to 76.2mm Available
- [Uncoated Substrates Available](#)

Common Specifications



Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	90
Edges:	Fine Ground		


Optical Properties

Angle of Incidence (°):	0
Surface Quality:	10-5

Technical Information

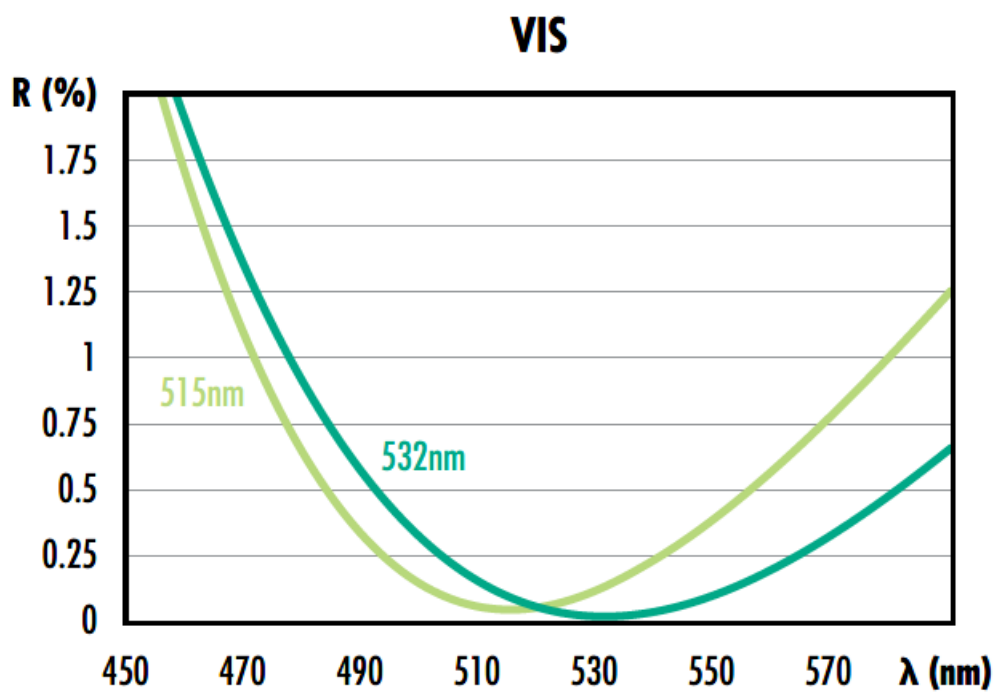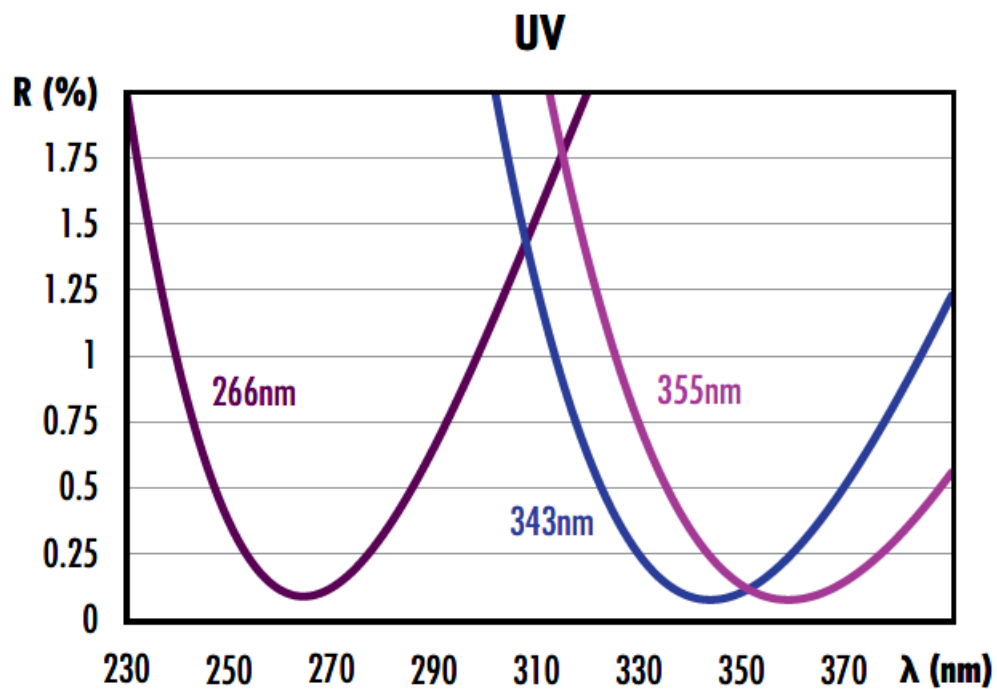

NIR

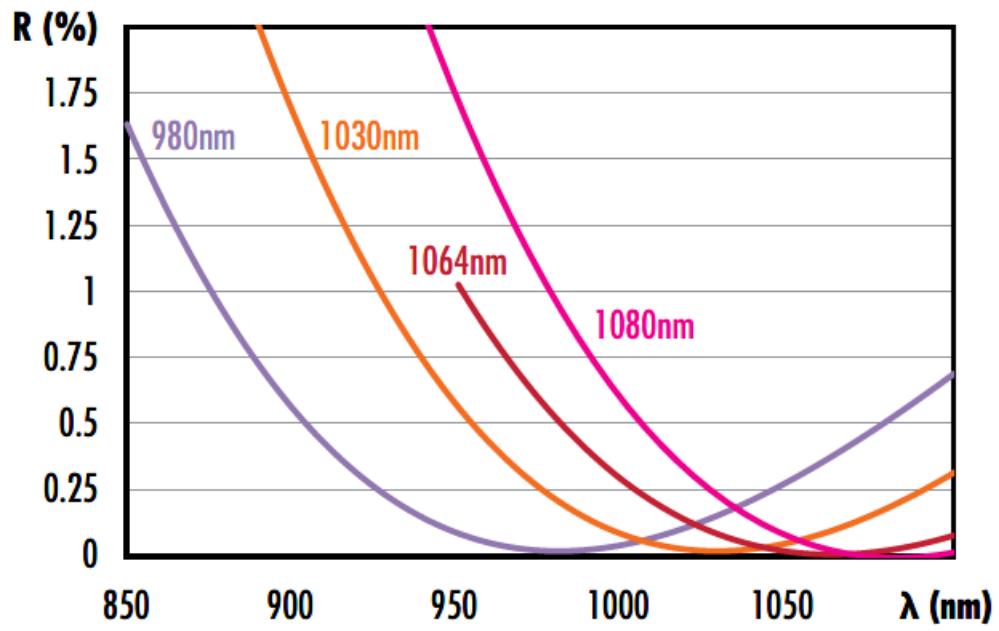

Products

Coating	Substrate	Dia. (mm)	Thickness (mm)	Stock Number	Price	Buy
Laser V-Coat (266nm)	Fused Silica	12.50	3.00	#48-204	C\$200.34 Volume Pricing	7 In Stock
Laser V-Coat (266nm)	Fused Silica	12.70	6.35	#38-918	C\$200.34 Volume Pricing	16 In Stock
Laser V-Coat (266nm)	Fused Silica	19.10	6.35	#38-921	C\$215.18 Volume Pricing	11 In Stock
Laser V-Coat (266nm)	Fused Silica	25.00	3.00	#48-205	C\$234.47 Volume Pricing	7 In Stock
Laser V-Coat (266nm)	Fused Silica	25.40	6.35	#38-923	C\$234.47 Volume Pricing	20+ In Stock
Laser V-Coat (266nm)	Fused Silica	38.10	6.35	#38-925	C\$329.45 Volume Pricing	5 In Stock
Laser V-Coat (266nm)	Fused Silica	50.80	9.53	#38-928	C\$400.68 Volume Pricing	6 In Stock
Laser V-Coat (343nm)	Fused Silica	12.70	6.35	#39-668	C\$200.34 Volume Pricing	6 In Stock
Laser V-Coat (343nm)	Fused Silica	19.10	6.35	#39-670	C\$215.18 Volume Pricing	15 In Stock
Laser V-Coat (343nm)	Fused Silica	25.40	6.35	#39-671	C\$234.47 Volume Pricing	Contact Us
Laser V-Coat (343nm)	Fused Silica	38.10	6.35	#39-673	C\$329.45 Volume Pricing	13 In Stock
Laser V-Coat (343nm)	Fused Silica	50.80	9.53	#39-675	C\$400.68 Volume Pricing	Contact Us

Laser V-Coat (343nm)	Fused Silica	76.20	12.70	#27-040	C\$1,187.20 Volume Pricing	Contact Us
Laser V-Coat (355nm)	Fused Silica	12.50	3.00	#48-206	C\$200.34 Volume Pricing	14 In Stock
Laser V-Coat (355nm)	Fused Silica	12.70	6.35	#38-936	C\$200.34 Volume Pricing	20+ In Stock
Laser V-Coat (355nm)	Fused Silica	19.10	6.35	#38-938	C\$215.18 Volume Pricing	6 In Stock
Laser V-Coat (355nm)	Fused Silica	25.00	3.00	#48-207	C\$234.47 Volume Pricing	12 In Stock
Laser V-Coat (355nm)	Fused Silica	25.40	6.35	#38-942	C\$234.47 Volume Pricing	20+ In Stock
Laser V-Coat (355nm)	Fused Silica	38.10	6.35	#38-949	C\$329.45 Volume Pricing	3 In Stock
Laser V-Coat (355nm)	Fused Silica	50.80	9.53	#38-951	C\$400.68 Volume Pricing	4 In Stock
Laser V-Coat (515nm)	Fused Silica	12.70	6.35	#39-681	C\$200.34 Volume Pricing	20+ In Stock
Laser V-Coat (515nm)	Fused Silica	19.10	6.35	#39-683	C\$215.18 Volume Pricing	13 In Stock
Laser V-Coat (515nm)	Fused Silica	25.40	6.35	#39-684	C\$234.47 Volume Pricing	Contact Us
Laser V-Coat (515nm)	Fused Silica	38.10	6.35	#39-688	C\$329.45 Volume Pricing	16 In Stock
Laser V-Coat (515nm)	Fused Silica	50.80	9.53	#39-690	C\$400.68 Volume Pricing	12 In Stock
Laser V-Coat (515nm)	Fused Silica	76.20	12.70	#27-041	C\$1,187.20 Volume Pricing	20+ In Stock

Laser V-Coat (532nm)	Fused Silica	12.50	3.00	#48-208	C\$200.34 Volume Pricing	7 In Stock
Laser V-Coat (532nm)	Fused Silica	12.70	6.35	#38-966	C\$200.34 Volume Pricing	20+ In Stock
Laser V-Coat (532nm)	Fused Silica	19.10	6.35	#38-968	C\$215.18 Volume Pricing	8 In Stock
Laser V-Coat (532nm)	Fused Silica	25.00	3.00	#48-209	C\$234.47 Volume Pricing	13 In Stock
Laser V-Coat (532nm)	Fused Silica	25.40	6.35	#38-969	C\$234.47 Volume Pricing	15 In Stock
Laser V-Coat (532nm)	Fused Silica	38.10	6.35	#38-973	C\$329.45 Volume Pricing	8 In Stock
Laser V-Coat (532nm)	Fused Silica	50.80	9.53	#38-975	C\$400.68 Volume Pricing	5 In Stock
Laser V-Coat (980nm)	Fused Silica	12.70	6.35	#39-702	C\$200.34 Volume Pricing	7 In Stock
Laser V-Coat (980nm)	Fused Silica	19.10	6.35	#39-704	C\$215.18 Volume Pricing	6 In Stock
Laser V-Coat (980nm)	Fused Silica	25.40	6.35	#39-705	C\$234.47 Volume Pricing	1 In Stock
Laser V-Coat (980nm)	Fused Silica	38.10	6.35	#39-707	C\$329.45 Volume Pricing	6 In Stock
Laser V-Coat (980nm)	Fused Silica	50.80	9.53	#39-710	C\$400.68 Volume Pricing	3 In Stock
Laser V-Coat (1030nm)	Fused Silica	12.70	6.35	#39-717	C\$200.34 Volume Pricing	20+ In Stock
Laser V-Coat (1030nm)	Fused Silica	19.10	6.35	#39-719	C\$215.18 Volume Pricing	10 In Stock

Laser V-Coat (1030nm)	Fused Silica	25.40	6.35	#39-720	C\$234.47 Volume Pricing	14 In Stock
Laser V-Coat (1030nm)	Fused Silica	38.10	6.35	#39-722	C\$329.45 Volume Pricing	14 In Stock
Laser V-Coat (1030nm)	Fused Silica	50.80	9.53	#39-724	C\$400.68 Volume Pricing	20+ In Stock
Laser V-Coat (1030nm)	Fused Silica	76.20	12.70	#27-042	C\$1,187.20 Volume Pricing	20+ In Stock
Laser V-Coat (1064nm)	Fused Silica	12.50	3.00	#48-210	C\$200.34 Volume Pricing	8 In Stock
Laser V-Coat (1064nm)	Fused Silica	12.70	6.35	#38-982	C\$200.34 Volume Pricing	8 In Stock
Laser V-Coat (1064nm)	Fused Silica	19.10	6.35	#38-984	C\$215.18 Volume Pricing	9 In Stock
Laser V-Coat (1064nm)	Fused Silica	25.00	3.00	#48-211	C\$234.47 Volume Pricing	20+ In Stock
Laser V-Coat (1064nm)	Fused Silica	25.40	6.35	#38-985	C\$234.47 Volume Pricing	14 In Stock
Laser V-Coat (1064nm)	Fused Silica	38.10	6.35	#38-988	C\$329.45 Volume Pricing	5 In Stock
Laser V-Coat (1064nm)	Fused Silica	50.80	9.53	#38-990	C\$400.68 Volume Pricing	Contact Us
Laser V-Coat (1080nm)	Fused Silica	12.70	6.35	#11-397	C\$200.34 Volume Pricing	17 In Stock
Laser V-Coat (1080nm)	Fused Silica	19.10	6.35	#11-399	C\$215.18 Volume Pricing	9 In Stock
Laser V-Coat (1080nm)	Fused Silica	25.40	6.35	#11-400	C\$234.47 Volume Pricing	17 In Stock

Laser V-Coat (1080nm)	Fused Silica	38.10	6.35	#11-402	C\$329.45 Volume Pricing	9 In Stock
--------------------------	------------------------------	-------	------	-------------------------	---	------------

Laser V-Coat (1080nm)	Fused Silica	50.80	9.53	#11-404	C\$400.68 Volume Pricing	14 In Stock
--------------------------	------------------------------	-------	------	-------------------------	---	-------------

[#38-933 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat (355nm)	N-BK7	25.40	6.35		C\$166.21	4 In Stock
-------------------------	-----------------------	-------	------	--	-----------	------------

[#38-963 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

Laser V-
Coat
(532nm)

[N-BK7](#)

25.40

6.35

C\$151.37

14 In Stock

[#39-699 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

Laser V-
Coat
(980nm)

[N-BK7](#)

25.40

6.35

C\$105.36

8 In Stock

[#38-977 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

Laser V-
Coat
(1064nm)

[N-BK7](#)

12.70

6.35

C\$151.37

3 In Stock

[#11-453 Clearance](#)



Clearance

Availability
is limited,
so buy
before
these
products
disappear.
Sorry, we
cannot
accept
returns.
Receive
up to 80%
off select
products.

Laser V-
Coat
(1064nm)

[N-BK7](#)

38.10

6.35

C\$148.33

1 In Stock

Laser V-
Coat
(266nm)

[Fused
Silica](#)

76.20

12.70

[#20-437](#)

C\$1,187.20
[Volume Pricing](#)

3 In Stock

Laser V-Coat (355nm)	Fused Silica	76.20	12.70	#20-444	C\$1,187.20 Volume Pricing	2 In Stock
Laser V-Coat (532nm)	Fused Silica	76.20	12.70	#20-449	C\$1,187.20 Volume Pricing	5 In Stock
Laser V-Coat (1064nm)	Fused Silica	76.20	12.70	#20-450	C\$1,187.20 Volume Pricing	4 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
 Phone: 1-800-363-1992 :
www.edmundoptics.com