

[All Products](#) / [Laser Optics](#) / [Laser Mirrors](#) / [Laser Line Mirrors](#)

TECHSPEC® Concave Laser Line Mirrors



- Ideal for Focusing Laser Light
- >99.8% Reflectivity at Center Wavelength
- High Thermal Stability Fused Silica Substrates

Common Specifications

Physical & Mechanical Properties

Back Surface: Fine Grind



Clear Aperture (%): 90

Optical Properties

Substrate: [Fused Silica](#) (Corning 7980)

Surface Quality: 20-10

Technical Information

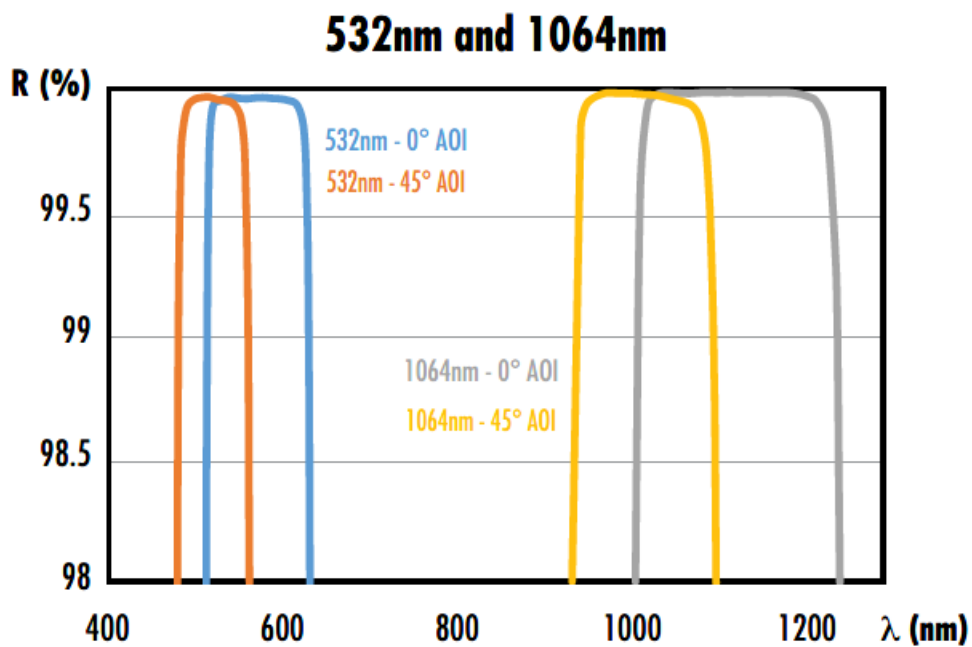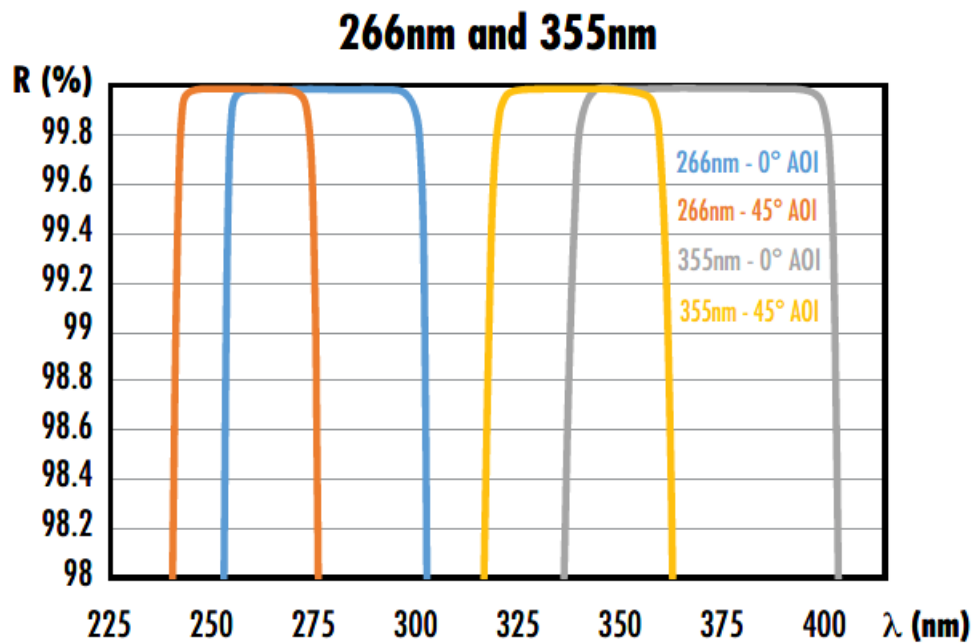

Products

DWL (nm)	Dia. (mm)	EFL (mm)	Coating	Stock Number	Price	Buy
266	25.40	25.00	Laser Mirror (266nm)	#39-947	C\$244.86 Volume Pricing	10 In Stock
266	25.40	50.00	Laser Mirror (266nm)	#39-948	C\$244.86 Volume Pricing	10 In Stock
266	25.40	75.00	Laser Mirror (266nm)	#39-949	C\$244.86 Volume Pricing	12 In Stock
266	25.40	100.00	Laser Mirror (266nm)	#39-950	C\$244.86 Volume Pricing	5 In Stock
266	25.40	200.00	Laser Mirror (266nm)	#39-951	C\$244.86 Volume Pricing	2 In Stock
266	25.40	500.00	Laser Mirror (266nm)	#39-952	C\$244.86 Volume Pricing	8 In Stock
355	25.40	25.00	Laser Mirror (355nm)	#39-954	C\$244.86 Volume Pricing	13 In Stock
355	25.40	50.00	Laser Mirror (355nm)	#39-955	C\$244.86 Volume Pricing	20+ In Stock
355	25.40	75.00	Laser Mirror (355nm)	#39-956	C\$244.86 Volume Pricing	17 In Stock
355	25.40	100.00	Laser Mirror (355nm)	#39-957	C\$244.86 Volume Pricing	14 In Stock
355	25.40	200.00	Laser Mirror (355nm)	#39-958	C\$244.86 Volume Pricing	20+ In Stock
355	25.40	500.00	Laser Mirror (355nm)	#39-959	C\$244.86 Volume Pricing	10 In Stock
532	25.40	25.00	Laser Mirror (532nm)	#39-960	C\$244.86 Volume Pricing	2 In Stock
532	25.40	50.00	Laser Mirror (532nm)	#39-961	C\$244.86 Volume Pricing	4 In Stock
532	25.40	75.00	Laser Mirror (532nm)	#39-962	C\$244.86 Volume Pricing	3 In Stock
532	25.40	100.00	Laser Mirror (532nm)	#39-963	C\$244.86 Volume Pricing	6 In Stock

532	25.40	200.00	Laser Mirror (532nm)	#39-964	C\$244.86 Volume Pricing	5 In Stock
532	25.40	500.00	Laser Mirror (532nm)	#39-965	C\$244.86 Volume Pricing	5 In Stock
1064	25.40	25.00	Laser Mirror (1064nm)	#39-966	C\$244.86 Volume Pricing	11 In Stock
1064	25.40	50.00	Laser Mirror (1064nm)	#39-967	C\$244.86 Volume Pricing	4 In Stock
1064	25.40	75.00	Laser Mirror (1064nm)	#39-968	C\$244.86 Volume Pricing	10 In Stock
1064	25.40	100.00	Laser Mirror (1064nm)	#39-969	C\$244.86 Volume Pricing	10 In Stock
1064	25.40	200.00	Laser Mirror (1064nm)	#39-970	C\$244.86 Volume Pricing	1 In Stock
1064	25.40	500.00	Laser Mirror (1064nm)	#39-971	C\$244.86 Volume Pricing	1 In Stock
266	50.80	50.00	Laser Mirror (266nm)	#11-327	C\$356.16 Volume Pricing	1 In Stock
266	50.80	100.00	Laser Mirror (266nm)	#11-328	C\$356.16 Volume Pricing	4 In Stock
266	50.80	150.00	Laser Mirror (266nm)	#11-329	C\$356.16 Volume Pricing	5 In Stock
266	50.80	250.00	Laser Mirror (266nm)	#11-330	C\$356.16 Volume Pricing	5 In Stock
266	50.80	500.00	Laser Mirror (266nm)	#11-331	C\$356.16 Volume Pricing	4 In Stock
355	50.80	50.00	Laser Mirror (355nm)	#11-332	C\$356.16 Volume Pricing	2 In Stock
355	50.80	100.00	Laser Mirror (355nm)	#11-333	C\$356.16 Volume Pricing	6 In Stock
355	50.80	150.00	Laser Mirror (355nm)	#11-334	C\$356.16 Volume Pricing	9 In Stock
355	50.80	250.00	Laser Mirror (355nm)	#11-335	C\$356.16 Volume Pricing	5 In Stock
355	50.80	500.00	Laser Mirror (355nm)	#11-336	C\$356.16 Volume Pricing	14 In Stock
532	50.80	50.00	Laser Mirror (532nm)	#11-337	C\$356.16 Volume Pricing	3 In Stock

532	50.80	100.00	Laser Mirror (532nm)	#11-338	C\$356.16 Volume Pricing	3 In Stock
532	50.80	150.00	Laser Mirror (532nm)	#11-339	C\$356.16 Volume Pricing	1 In Stock
532	50.80	250.00	Laser Mirror (532nm)	#11-340	C\$356.16 Volume Pricing	5 In Stock
532	50.80	500.00	Laser Mirror (532nm)	#11-341	C\$356.16 Volume Pricing	5 In Stock
1064	50.80	50.00	Laser Mirror (1064nm)	#11-342	C\$356.16 Volume Pricing	2 In Stock
1064	50.80	100.00	Laser Mirror (1064nm)	#11-343	C\$356.16 Volume Pricing	Contact Us
1064	50.80	150.00	Laser Mirror (1064nm)	#11-344	C\$356.16 Volume Pricing	2 In Stock
1064	50.80	250.00	Laser Mirror (1064nm)	#11-345	C\$356.16 Volume Pricing	8 In Stock
1064	50.80	500.00	Laser Mirror (1064nm)	#11-346	C\$356.16 Volume Pricing	4 In Stock
-	25.40	25.00	Uncoated	#39-973	C\$164.72 Volume Pricing	20+ In Stock
-	25.40	50.00	Uncoated	#39-974	C\$164.72 Volume Pricing	16 In Stock
-	25.40	100.00	Uncoated	#39-977	C\$164.72 Volume Pricing	20+ In Stock
-	25.40	75.00	Uncoated	#39-975	C\$164.72 Volume Pricing	15 In Stock
-	25.40	200.00	Uncoated	#39-978	C\$164.72 Volume Pricing	20+ In Stock
-	25.40	500.00	Uncoated	#39-979	C\$164.72 Volume Pricing	20+ In Stock
-	50.80	50.00	Uncoated	#11-347	C\$305.70 Volume Pricing	20+ In Stock
-	50.80	100.00	Uncoated	#11-348	C\$304.22 Volume Pricing	13 In Stock
-	50.80	150.00	Uncoated	#11-349	C\$305.70 Volume Pricing	20+ In Stock
-	50.80	250.00	Uncoated	#11-350	C\$305.70 Volume Pricing	20+ In Stock

-	50.80	500.00	Uncoated	#11-352	C\$305.70 Volume Pricing	20+ In Stock
---	-------	--------	----------	-------------------------	---	--------------



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com