


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

Micro Plano-Convex (PCX) Lenses

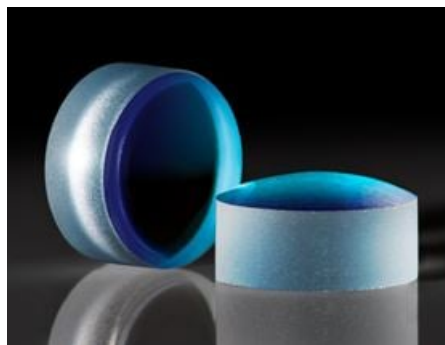

- Diameters as Small as 1mm
- Short Focal Lengths for Integration into Compact Devices
- Broadband Antireflection Coating Options Available

Common Specifications

Physical & Mechanical Properties

Bevel:

Protective as needed

Optical Properties

Focal Length Tolerance (%):

± 1

Technical Information

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	NIR I (600-1050nm)	N-LASF9	#45-951	C\$120.96 Volume Pricing	Contact Us
1.00	0.60	0.17	Uncoated	N-LASF9	#45-588	C\$100.55 Volume Pricing	11 In Stock
1.00	1.00	0.57	NIR I (600-1050nm)	N-LASF9	#45-952	C\$120.96 Volume Pricing	5 In Stock
1.00	1.00	0.57	Uncoated	N-LASF9	#45-589	C\$100.55 Volume Pricing	20+ In Stock
1.00	0.60	0.17	MgF ₂ (400-700nm)	N-LASF9	#65-257	C\$109.62 Volume Pricing	4 In Stock
1.00	0.60	0.17	NIR II (750-1550nm)	N-LASF9	#67-423	C\$120.96 Volume Pricing	Contact Us
1.00	0.60	0.17	VIS 0° (425-675nm)	N-LASF9	#65-273	C\$120.96 Volume Pricing	5 In Stock
1.00	0.60	0.17	VIS-EXT (350-700nm)	N-LASF9	#35-694	C\$123.23 Volume Pricing	5 In Stock
1.00	0.60	0.17	VIS-NIR (400-1000nm)	N-LASF9	#65-289	C\$123.23 Volume Pricing	5 In Stock
1.00	0.60	0.17	YAG-BBAR (500-1100nm)	N-LASF9	#35-710	C\$123.23 Volume Pricing	3 In Stock
1.00	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-258	C\$109.62 Volume Pricing	16 In Stock
1.00	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-424	C\$120.96 Volume Pricing	2 In Stock
1.00	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-274	C\$120.96 Volume Pricing	Contact Us
1.00	1.00	0.57	VIS-EXT (350-700nm)	N-LASF9	#35-695	C\$123.23 Volume Pricing	14 In Stock
1.00	1.00	0.57	VIS-NIR (400-1000nm)	N-LASF9	#65-290	C\$123.23 Volume Pricing	5 In Stock
1.00	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-711	C\$123.23 Volume Pricing	Contact Us

1.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-259	C\$109.62 Volume Pricing	Contact Us
1.00	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#65-305	C\$120.96 Volume Pricing	Contact Us
1.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-425	C\$120.96 Volume Pricing	7 In Stock
1.00	1.50	1.07	Uncoated	N-LASF9	#65-252	C\$100.55 Volume Pricing	20+ In Stock
1.00	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-275	C\$120.96 Volume Pricing	3 In Stock
1.00	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-696	C\$123.23 Volume Pricing	7 In Stock
1.00	1.50	1.07	VIS-NIR (400-1000nm)	N-LASF9	#65-291	C\$123.23 Volume Pricing	Contact Us
1.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-712	C\$123.23 Volume Pricing	11 In Stock
1.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-260	C\$109.62 Volume Pricing	1 In Stock
1.00	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#65-306	C\$120.96 Volume Pricing	6 In Stock
1.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-426	C\$120.96 Volume Pricing	20+ In Stock
1.00	2.00	1.57	Uncoated	N-LASF9	#65-253	C\$100.55 Volume Pricing	20+ In Stock
1.00	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-276	C\$120.96 Volume Pricing	Contact Us
1.00	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-697	C\$123.23 Volume Pricing	11 In Stock
1.00	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-292	C\$123.23 Volume Pricing	6 In Stock
1.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-713	C\$123.23 Volume Pricing	5 In Stock
1.50	1.00	0.57	NIR I (600-1050nm)	N-LASF9	#45-953	C\$120.96 Volume Pricing	8 In Stock
1.50	1.00	0.57	Uncoated	N-LASF9	#43-394	C\$100.55 Volume Pricing	20+ In Stock
1.50	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-261	C\$109.62 Volume Pricing	2 In Stock

1.50	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-427	C\$120.96 Volume Pricing	20+ In Stock
1.50	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-277	C\$120.96 Volume Pricing	14 In Stock
1.50	1.00	0.57	VIS-EXT (350-700nm)	N-LASF9	#35-698	C\$123.23 Volume Pricing	Contact Us
1.50	1.00	0.57	VIS-NIR (400-1000nm)	N-LASF9	#65-293	C\$123.23 Volume Pricing	5 In Stock
1.50	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-714	C\$123.23 Volume Pricing	9 In Stock
1.50	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-262	C\$109.62 Volume Pricing	1 In Stock
1.50	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-428	C\$120.96 Volume Pricing	9 In Stock
1.50	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#45-954	C\$120.96 Volume Pricing	20+ In Stock
1.50	1.50	1.07	Uncoated	N-LASF9	#43-395	C\$100.55 Volume Pricing	4 In Stock
1.50	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-278	C\$120.96 Volume Pricing	6 In Stock
1.50	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-699	C\$123.23 Volume Pricing	Contact Us
1.50	1.50	1.07	VIS-NIR (400-1000nm)	N-LASF9	#65-294	C\$123.23 Volume Pricing	3 In Stock
1.50	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-715	C\$123.23 Volume Pricing	4 In Stock
1.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-263	C\$109.62 Volume Pricing	14 In Stock
1.50	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#65-307	C\$120.96 Volume Pricing	5 In Stock
1.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-429	C\$120.96 Volume Pricing	9 In Stock
1.50	2.00	1.57	Uncoated	N-LASF9	#65-254	C\$100.55 Volume Pricing	20+ In Stock
1.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-279	C\$120.96 Volume Pricing	12 In Stock
1.50	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-700	C\$123.23 Volume Pricing	10 In Stock

1.50	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-295	C\$123.23 Volume Pricing	17 In Stock
1.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-716	C\$123.23 Volume Pricing	5 In Stock
2.00	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#45-955	C\$119.45 Volume Pricing	10 In Stock
2.00	1.50	1.07	Uncoated	N-LASF9	#43-396	C\$99.04 Volume Pricing	20+ In Stock
2.00	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#45-956	C\$119.45 Volume Pricing	8 In Stock
2.00	2.00	1.57	Uncoated	N-LASF9	#43-397	C\$99.04 Volume Pricing	20+ In Stock
2.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-264	C\$108.11 Volume Pricing	6 In Stock
2.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-430	C\$119.45 Volume Pricing	20+ In Stock
2.00	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-280	C\$119.45 Volume Pricing	5 In Stock
2.00	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-701	C\$121.72 Volume Pricing	20+ In Stock
2.00	1.50	1.07	VIS-NIR (400-1000nm)	N-LASF9	#65-296	C\$121.72 Volume Pricing	20+ In Stock
2.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-717	C\$121.72 Volume Pricing	4 In Stock
2.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-265	C\$108.11 Volume Pricing	9 In Stock
2.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-431	C\$119.45 Volume Pricing	9 In Stock
2.00	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-281	C\$119.45 Volume Pricing	Contact Us
2.00	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-702	C\$121.72 Volume Pricing	20+ In Stock
2.00	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-297	C\$121.72 Volume Pricing	20+ In Stock
2.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-718	C\$121.72 Volume Pricing	3 In Stock
2.00	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-266	C\$108.11 Volume Pricing	2 In Stock

2.00	3.00	2.57	NIR I (600-1050nm)	N-LASF9	#65-308	C\$119.45 Volume Pricing	20+ In Stock
2.00	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-432	C\$119.45 Volume Pricing	14 In Stock
2.00	3.00	2.57	Uncoated	N-LASF9	#65-255	C\$99.04 Volume Pricing	20+ In Stock
2.00	3.00	2.57	VIS 0° (425-675nm)	N-LASF9	#65-282	C\$119.45 Volume Pricing	14 In Stock
2.00	3.00	2.57	VIS-EXT (350-700nm)	N-LASF9	#35-703	C\$121.72 Volume Pricing	20+ In Stock
2.00	3.00	2.57	VIS-NIR (400-1000nm)	N-LASF9	#65-298	C\$121.72 Volume Pricing	5 In Stock
2.00	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-719	C\$121.72 Volume Pricing	3 In Stock
2.00	4.00	3.57	MgF ₂ (400-700nm)	N-LASF9	#65-267	C\$108.11 Volume Pricing	8 In Stock
2.00	4.00	3.57	NIR I (600-1050nm)	N-LASF9	#65-309	C\$119.45 Volume Pricing	7 In Stock
2.00	4.00	3.57	NIR II (750-1550nm)	N-LASF9	#67-433	C\$119.45 Volume Pricing	12 In Stock
2.00	4.00	3.57	Uncoated	N-LASF9	#65-256	C\$99.04 Volume Pricing	20+ In Stock
2.00	4.00	3.57	VIS 0° (425-675nm)	N-LASF9	#65-283	C\$119.45 Volume Pricing	8 In Stock
2.00	4.00	3.57	VIS-EXT (350-700nm)	N-LASF9	#35-704	C\$121.72 Volume Pricing	10 In Stock
2.00	4.00	3.57	VIS-NIR (400-1000nm)	N-LASF9	#65-299	C\$121.72 Volume Pricing	4 In Stock
2.00	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-720	C\$121.72 Volume Pricing	10 In Stock
2.50	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#45-957	C\$119.45 Volume Pricing	20+ In Stock
2.50	2.00	1.57	Uncoated	N-LASF9	#43-398	C\$99.04 Volume Pricing	20+ In Stock
2.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-268	C\$108.11 Volume Pricing	6 In Stock
2.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-434	C\$119.45 Volume Pricing	20+ In Stock

2.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-284	C\$119.45 Volume Pricing	17 In Stock
2.50	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-705	C\$121.72 Volume Pricing	4 In Stock
2.50	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-300	C\$121.72 Volume Pricing	2 In Stock
2.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-721	C\$121.72 Volume Pricing	5 In Stock
2.50	2.50	2.05	MgF ₂ (400-700nm)	N-LASF9	#65-269	C\$108.11 Volume Pricing	7 In Stock
2.50	2.50	2.07	NIR II (750-1550nm)	N-LASF9	#67-435	C\$119.45 Volume Pricing	7 In Stock
2.50	2.50	2.07	NIR I (600-1050nm)	N-LASF9	#45-958	C\$119.45 Volume Pricing	9 In Stock
2.50	2.50	2.07	Uncoated	N-LASF9	#43-399	C\$99.04 Volume Pricing	20+ In Stock
2.50	2.50	2.05	VIS 0° (425-675nm)	N-LASF9	#65-285	C\$119.45 Volume Pricing	3 In Stock
2.50	2.50	2.07	VIS-EXT (350-700nm)	N-LASF9	#35-706	C\$121.72 Volume Pricing	Contact Us
2.50	2.50	2.05	VIS-NIR (400-1000nm)	N-LASF9	#65-301	C\$121.72 Volume Pricing	10 In Stock
2.50	2.50	2.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-722	C\$121.72 Volume Pricing	Contact Us
2.50	3.00	2.57	Uncoated	N-LASF9	#45-590	C\$99.04 Volume Pricing	20+ In Stock
2.50	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-270	C\$108.11 Volume Pricing	7 In Stock
2.50	3.00	2.57	NIR I (600-1050nm)	N-LASF9	#45-959	C\$119.45 Volume Pricing	9 In Stock
2.50	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-436	C\$119.45 Volume Pricing	4 In Stock
2.50	3.00	2.57	VIS 0° (425-675nm)	N-LASF9	#65-286	C\$119.45 Volume Pricing	20+ In Stock
2.50	3.00	2.57	VIS-EXT (350-700nm)	N-LASF9	#35-707	C\$121.72 Volume Pricing	13 In Stock
2.50	3.00	2.57	VIS-NIR (400-1000nm)	N-LASF9	#65-302	C\$121.72 Volume Pricing	20+ In Stock

2.50	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-723	C\$121.72 Volume Pricing	20+ In Stock
2.50	4.00	3.57	MgF ₂ (400-700nm)	N-LASF9	#65-271	C\$108.11 Volume Pricing	5 In Stock
2.50	4.00	3.57	NIR I (600-1050nm)	N-LASF9	#48-646	C\$119.45 Volume Pricing	2 In Stock
2.50	4.00	3.57	NIR II (750-1550nm)	N-LASF9	#67-437	C\$119.45 Volume Pricing	Contact Us
2.50	4.00	3.57	Uncoated	N-LASF9	#48-643	C\$99.04 Volume Pricing	20+ In Stock
2.50	4.00	3.57	VIS 0° (425-675nm)	N-LASF9	#65-287	C\$119.45 Volume Pricing	5 In Stock
2.50	4.00	3.57	VIS-EXT (350-700nm)	N-LASF9	#35-708	C\$121.72 Volume Pricing	14 In Stock
2.50	4.00	3.57	VIS-NIR (400-1000nm)	N-LASF9	#65-303	C\$121.72 Volume Pricing	10 In Stock
2.50	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-724	C\$121.72 Volume Pricing	10 In Stock
2.50	5.00	4.57	MgF ₂ (400-700nm)	N-LASF9	#65-272	C\$108.11 Volume Pricing	5 In Stock
2.50	5.00	4.57	NIR I (600-1050nm)	N-LASF9	#48-647	C\$119.45 Volume Pricing	20+ In Stock
2.50	5.00	4.57	NIR II (750-1550nm)	N-LASF9	#67-438	C\$119.45 Volume Pricing	5 In Stock
2.50	5.00	4.57	Uncoated	N-LASF9	#48-644	C\$99.04 Volume Pricing	20+ In Stock
2.50	5.00	4.57	VIS 0° (425-675nm)	N-LASF9	#65-288	C\$119.45 Volume Pricing	20+ In Stock
2.50	5.00	4.57	VIS-EXT (350-700nm)	N-LASF9	#35-709	C\$121.72 Volume Pricing	3 In Stock
2.50	5.00	4.57	VIS-NIR (400-1000nm)	N-LASF9	#65-304	C\$121.72 Volume Pricing	13 In Stock
2.50	5.00	4.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-725	C\$121.72 Volume Pricing	3 In Stock
3.00	3.00	1.88	VIS-EXT (350-700nm)	N-SF11	#88-615	C\$104.33 Volume Pricing	Contact Us
3.00	3.00	1.88	YAG-BBAR (500-1100nm)	N-SF11	#88-774	C\$104.33 Volume Pricing	16 In Stock

3.00	12.00	11.29	MgF ₂ (400-700nm)	N-BK7	#45-273	C\$81.65 Volume Pricing	14 In Stock
3.00	12.00	11.29	NIR I (600-1050nm)	N-BK7	#45-964	C\$92.99 Volume Pricing	4 In Stock
3.00	12.00	11.29	Uncoated	N-BK7	#45-272	C\$72.58 Volume Pricing	20+ In Stock
3.00	12.00	11.29	VIS 0° (425-675nm)	N-BK7	#49-172	C\$92.99 Volume Pricing	11 In Stock
3.00	12.00	11.29	VIS-EXT (350-700nm)	N-BK7	#88-620	C\$96.77 Volume Pricing	12 In Stock
3.00	12.00	11.29	VIS-NIR (400-1000nm)	N-BK7	#49-179	C\$96.77 Volume Pricing	10 In Stock
3.00	12.00	11.29	YAG-BBAR (500-1100nm)	N-BK7	#88-779	C\$96.77 Volume Pricing	8 In Stock
3.00	15.00	14.17	MgF ₂ (400-700nm)	N-BK7	#45-426	C\$81.65 Volume Pricing	12 In Stock
3.00	15.00	14.22	NIR I (600-1050nm)	N-BK7	#45-965	C\$92.99 Volume Pricing	20+ In Stock
3.00	15.00	14.22	Uncoated	N-BK7	#45-425	C\$72.58 Volume Pricing	20+ In Stock
3.00	15.00	14.17	VIS 0° (425-675nm)	N-BK7	#49-173	C\$92.99 Volume Pricing	10 In Stock
3.00	15.00	14.22	VIS-EXT (350-700nm)	N-BK7	#88-621	C\$96.77 Volume Pricing	Contact Us
3.00	15.00	14.17	VIS-NIR (400-1000nm)	N-BK7	#49-180	C\$96.77 Volume Pricing	5 In Stock
3.00	15.00	14.22	YAG-BBAR (500-1100nm)	N-BK7	#88-780	C\$96.77 Volume Pricing	17 In Stock
3.00	3.00	1.88	MgF ₂ (400-700nm)	N-SF11	#45-118	C\$89.21 Volume Pricing	20+ In Stock
3.00	3.00	1.88	NIR I (600-1050nm)	N-SF11	#45-960	C\$100.55 Volume Pricing	10 In Stock
3.00	3.00	1.88	Uncoated	N-SF11	#45-117	C\$80.14 Volume Pricing	20+ In Stock
3.00	3.00	1.88	VIS 0° (425-675nm)	N-SF11	#49-167	C\$100.55 Volume Pricing	20+ In Stock
3.00	3.00	1.88	VIS-NIR (400-1000nm)	N-SF11	#49-174	C\$104.33 Volume Pricing	7 In Stock

3.00	4.50	3.50	MgF ₂ (400-700nm)	N-LASF44	#45-142	C\$89.21 Volume Pricing	Contact Us
3.00	4.50	3.50	NIR I (600-1050nm)	N-LASF44	#45-961	C\$100.55 Volume Pricing	14 In Stock
3.00	4.50	3.50	Uncoated	N-LASF44	#45-141	C\$80.14 Volume Pricing	20+ In Stock
3.00	4.50	3.50	VIS 0° (425-675nm)	N-LASF44	#49-168	C\$100.55 Volume Pricing	4 In Stock
3.00	4.50	3.50	VIS-NIR (400-1000nm)	N-LASF44	#49-175	C\$104.33 Volume Pricing	20+ In Stock
3.00	6.00	4.81	MgF ₂ (400-700nm)	N-BK7	#32-953	C\$81.65 Volume Pricing	20+ In Stock
3.00	6.00	4.81	NIR I (600-1050nm)	N-BK7	#45-962	C\$92.99 Volume Pricing	20+ In Stock
3.00	6.00	4.81	Uncoated	N-BK7	#32-952	C\$72.58 Volume Pricing	20+ In Stock
3.00	6.00	4.81	VIS 0° (425-675nm)	N-BK7	#49-169	C\$92.99 Volume Pricing	20+ In Stock
3.00	6.00	4.81	VIS-EXT (350-700nm)	N-BK7	#88-617	C\$96.77 Volume Pricing	10 In Stock
3.00	6.00	4.81	VIS-NIR (400-1000nm)	N-BK7	#49-176	C\$96.77 Volume Pricing	3 In Stock
3.00	6.00	4.81	YAG-BBAR (500-1100nm)	N-BK7	#88-776	C\$96.77 Volume Pricing	20+ In Stock
3.00	7.50	6.51	Uncoated	N-BK7	#48-645	C\$72.58 Volume Pricing	20+ In Stock
3.00	7.50	6.51	VIS 0° (425-675nm)	N-BK7	#49-170	C\$92.99 Volume Pricing	5 In Stock
3.00	7.50	6.51	VIS-EXT (350-700nm)	N-BK7	#88-618	C\$96.77 Volume Pricing	Contact Us
3.00	7.50	6.51	VIS-NIR (400-1000nm)	N-BK7	#49-177	C\$96.77 Volume Pricing	20+ In Stock
3.00	7.50	6.51	YAG-BBAR (500-1100nm)	N-BK7	#88-777	C\$96.77 Volume Pricing	20+ In Stock
3.00	9.00	8.01	MgF ₂ (400-700nm)	N-BK7	#32-955	C\$81.65 Volume Pricing	10 In Stock
3.00	9.00	8.01	NIR I (600-1050nm)	N-BK7	#45-963	C\$92.99 Volume Pricing	14 In Stock

3.00	9.00	8.01	Uncoated	N-BK7	#32-954	C\$72.58 Volume Pricing	20+ In Stock
3.00	9.00	8.01	VIS 0° (425-675nm)	N-BK7	#49-171	C\$92.99 Volume Pricing	14 In Stock
3.00	9.00	8.01	VIS-EXT (350-700nm)	N-BK7	#88-619	C\$96.77 Volume Pricing	2 In Stock
3.00	9.00	8.01	VIS-NIR (400-1000nm)	N-BK7	#49-178	C\$96.77 Volume Pricing	20+ In Stock
3.00	9.00	8.01	YAG-BBAR (500-1100nm)	N-BK7	#88-778	C\$96.77 Volume Pricing	6 In Stock
3.00	12.00	11.29	NIR II (750-1550nm)	N-BK7	#67-444	C\$92.99 Volume Pricing	10 In Stock
3.00	15.00	14.22	NIR II (750-1550nm)	N-BK7	#67-445	C\$92.99 Volume Pricing	1 In Stock
3.00	3.00	1.88	NIR II (750-1550nm)	N-SF11	#67-439	C\$100.55 Volume Pricing	13 In Stock
3.00	4.50	3.50	NIR II (750-1550nm)	N-LASF44	#67-440	C\$100.55 Volume Pricing	20+ In Stock
3.00	4.50	3.50	VIS-EXT (350-700nm)	N-LASF44	#88-616	C\$104.33 Volume Pricing	20+ In Stock
3.00	4.50	3.5	YAG-BBAR (500-1100nm)	N-LASF44	#88-775	C\$104.33 Volume Pricing	15 In Stock
3.00	6.00	4.81	NIR II (750-1550nm)	N-BK7	#67-441	C\$92.99 Volume Pricing	20+ In Stock
3.00	7.50	6.51	MgF ₂ (400-700nm)	N-BK7	#48-910	C\$81.65 Volume Pricing	5 In Stock
3.00	7.50	6.51	NIR I (600-1050nm)	N-BK7	#48-648	C\$92.99 Volume Pricing	20+ In Stock
3.00	7.50	6.51	NIR II (750-1550nm)	N-BK7	#67-442	C\$92.99 Volume Pricing	15 In Stock
3.00	9.00	8.01	NIR II (750-1550nm)	N-BK7	#67-443	C\$92.99 Volume Pricing	3 In Stock
4.00	10.00	8.92	MgF ₂ (400-700nm)	N-BK7	#45-430	C\$75.22 Volume Pricing	Contact Us
4.00	10.00	8.92	NIR I (600-1050nm)	N-BK7	#48-705	C\$90.72 Volume Pricing	20+ In Stock
4.00	10.00	8.92	Uncoated	N-BK7	#45-429	C\$66.15 Volume Pricing	20+ In Stock

4.00	10.00	8.92	VIS 0° (425-675nm)	N-BK7	#47-864	C\$90.72 Volume Pricing	5 In Stock
4.00	10.00	8.92	VIS-EXT (350-700nm)	N-BK7	#88-625	C\$98.28 Volume Pricing	17 In Stock
4.00	10.00	8.92	VIS-NIR (400-1000nm)	N-BK7	#47-853	C\$98.28 Volume Pricing	20+ In Stock
4.00	10.00	8.92	YAG-BBAR (500-1100nm)	N-BK7	#88-784	C\$98.28 Volume Pricing	7 In Stock
4.00	12.00	11.00	MgF ₂ (400-700nm)	N-BK7	#45-432	C\$75.22 Volume Pricing	20+ In Stock
4.00	12.00	11.00	NIR I (600-1050nm)	N-BK7	#48-706	C\$90.72 Volume Pricing	3 In Stock
4.00	12.00	11.00	Uncoated	N-BK7	#45-431	C\$66.15 Volume Pricing	20+ In Stock
4.00	12.00	11.00	VIS 0° (425-675nm)	N-BK7	#47-865	C\$90.72 Volume Pricing	2 In Stock
4.00	12.00	11.00	VIS-EXT (350-700nm)	N-BK7	#88-626	C\$98.28 Volume Pricing	3 In Stock
4.00	12.00	11.00	VIS-NIR (400-1000nm)	N-BK7	#47-854	C\$98.28 Volume Pricing	Contact Us
4.00	12.00	11.00	YAG-BBAR (500-1100nm)	N-BK7	#88-785	C\$98.28 Volume Pricing	10 In Stock
4.00	4.00	3.06	MgF ₂ (400-700nm)	N-LASF44	#45-224	C\$81.65 Volume Pricing	20+ In Stock
4.00	4.00	3.06	NIR I (600-1050nm)	N-LASF44	#48-702	C\$96.77 Volume Pricing	20+ In Stock
4.00	4.00	3.06	Uncoated	N-LASF44	#45-223	C\$72.58 Volume Pricing	20+ In Stock
4.00	4.00	3.06	VIS 0° (425-675nm)	N-LASF44	#47-861	C\$96.77 Volume Pricing	20+ In Stock
4.00	4.00	3.06	VIS-NIR (400-1000nm)	N-LASF44	#47-850	C\$104.33 Volume Pricing	8 In Stock
4.00	6.00	4.51	MgF ₂ (400-700nm)	N-BK7	#45-428	C\$81.65 Volume Pricing	20+ In Stock
4.00	6.00	4.51	NIR I (600-1050nm)	N-BK7	#48-703	C\$96.77 Volume Pricing	14 In Stock
4.00	6.00	4.51	Uncoated	N-BK7	#45-427	C\$72.58 Volume Pricing	20+ In Stock

4.00	6.00	4.51	VIS 0° (425-675nm)	N-BK7	#47-862	C\$96.77 Volume Pricing	5 In Stock
4.00	6.00	4.51	VIS-EXT (350-700nm)	N-BK7	#88-623	C\$104.33 Volume Pricing	14 In Stock
4.00	6.00	4.51	VIS-NIR (400-1000nm)	N-BK7	#47-851	C\$104.33 Volume Pricing	20+ In Stock
4.00	6.00	4.51	YAG-BBAR (500-1100nm)	N-BK7	#88-782	C\$104.33 Volume Pricing	1 In Stock
4.00	8.00	7.17	MgF ₂ (400-700nm)	N-BAF10	#45-226	C\$75.22 Volume Pricing	20+ In Stock
4.00	8.00	7.17	NIR I (600-1050nm)	N-BAF10	#48-704	C\$90.72 Volume Pricing	10 In Stock
4.00	8.00	7.17	Uncoated	N-BAF10	#45-225	C\$66.15 Volume Pricing	20+ In Stock
4.00	8.00	7.17	VIS 0° (425-675nm)	N-BAF10	#47-863	C\$90.72 Volume Pricing	11 In Stock
4.00	8.00	7.17	VIS-NIR (400-1000nm)	N-BAF10	#47-852	C\$98.28 Volume Pricing	Contact Us
4.00	10.00	8.96	NIR II (750-1550nm)	N-BK7	#67-449	C\$90.72 Volume Pricing	16 In Stock
4.00	12.00	11	NIR II (750-1550nm)	N-BK7	#67-450	C\$90.72 Volume Pricing	1 In Stock
4.00	4.00	3.06	NIR II (750-1550nm)	N-LASF44	#67-446	C\$96.77 Volume Pricing	12 In Stock
4.00	4.00	3.06	VIS-EXT (350-700nm)	N-LASF44	#88-622	C\$104.33 Volume Pricing	20+ In Stock
4.00	4.00	3.06	YAG-BBAR (500-1100nm)	N-LASF44	#88-781	C\$104.33 Volume Pricing	20+ In Stock
4.00	6.00	4.51	NIR II (750-1550nm)	N-BK7	#67-447	C\$96.77 Volume Pricing	20+ In Stock
4.00	8.00	7.17	NIR II (750-1550nm)	N-BAF10	#67-448	C\$90.72 Volume Pricing	13 In Stock
4.50	4.50	3.05	MgF ₂ (400-700nm)	N-LASF44	#45-144	C\$81.65 Volume Pricing	20+ In Stock
4.50	4.50	3.05	NIR I (600-1050nm)	N-LASF44	#48-707	C\$96.77 Volume Pricing	20+ In Stock
4.50	4.50	3.05	NIR II (750-1550nm)	N-LASF44	#67-451	C\$96.77 Volume Pricing	17 In Stock

4.50	4.50	3.05	Uncoated	N-LASF44	#45-143	C\$72.58 Volume Pricing	20+ In Stock
4.50	4.50	3.05	VIS 0° (425-675nm)	N-LASF44	#47-866	C\$96.77 Volume Pricing	20+ In Stock
4.50	4.50	3.05	VIS-EXT (350-700nm)	N-LASF44	#88-627	C\$104.33 Volume Pricing	17 In Stock
4.50	4.50	3.05	VIS-NIR (400-1000nm)	N-LASF44	#47-855	C\$104.33 Volume Pricing	20+ In Stock
4.50	4.50	3.05	YAG-BBAR (500-1100nm)	N-LASF44	#88-786	C\$104.33 Volume Pricing	7 In Stock
4.50	9.00	7.41	MgF ₂ (400-700nm)	N-BK7	#45-148	C\$75.22 Volume Pricing	20+ In Stock
4.50	9.00	7.41	NIR I (600-1050nm)	N-BK7	#48-708	C\$90.72 Volume Pricing	8 In Stock
4.50	9.00	7.41	Uncoated	N-BK7	#45-147	C\$66.15 Volume Pricing	20+ In Stock
4.50	9.00	7.41	VIS 0° (425-675nm)	N-BK7	#47-867	C\$90.72 Volume Pricing	20+ In Stock
4.50	9.00	7.41	VIS-EXT (350-700nm)	N-BK7	#88-628	C\$98.28 Volume Pricing	3 In Stock
4.50	9.00	7.41	VIS-NIR (400-1000nm)	N-BK7	#47-856	C\$98.28 Volume Pricing	7 In Stock
4.50	9.00	7.41	YAG-BBAR (500-1100nm)	N-BK7	#88-787	C\$98.28 Volume Pricing	3 In Stock
4.50	9.00	7.41	NIR II (750-1550nm)	N-BK7	#67-452	C\$90.72 Volume Pricing	2 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
Phone: 1-800-363-1992 :
www.edmundoptics.com