

[All Products](#) / [Optomechanics](#) / [Tube System](#) / [C, S, and T-Mount Components](#)

TECHSPEC®

C, S, and T-Mount Circular Optic Mounts





- Mounts for Simple Lenses, Achromats, Filters, or Reticles
- Designed to Integrate with Any C, S, or T-Mount Components
- Optic is Held in Place with Included Retaining Ring

Common Specifications


General

Type of Optics:	Circular	Function:	Optic Mount (Fixed)
-----------------	----------	-----------	---------------------


Technical Information

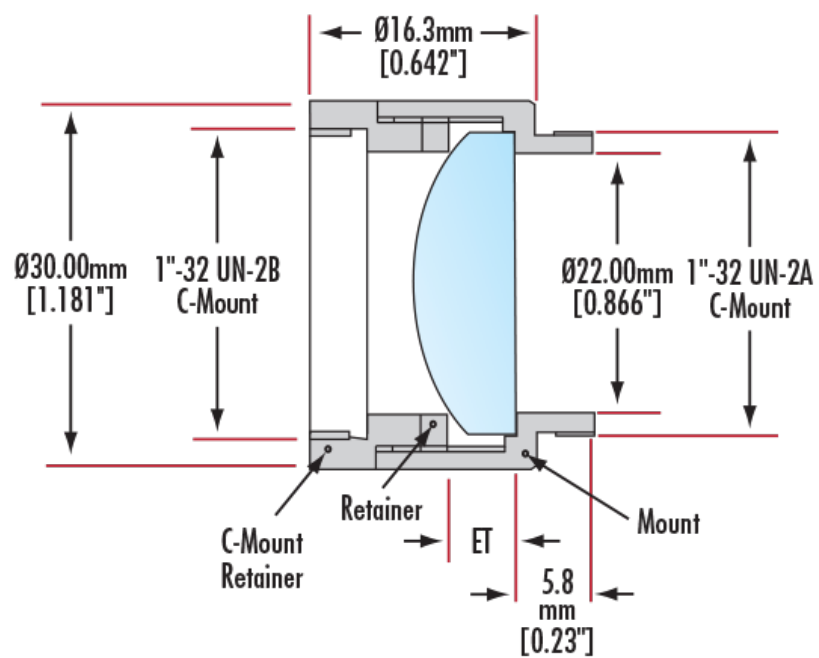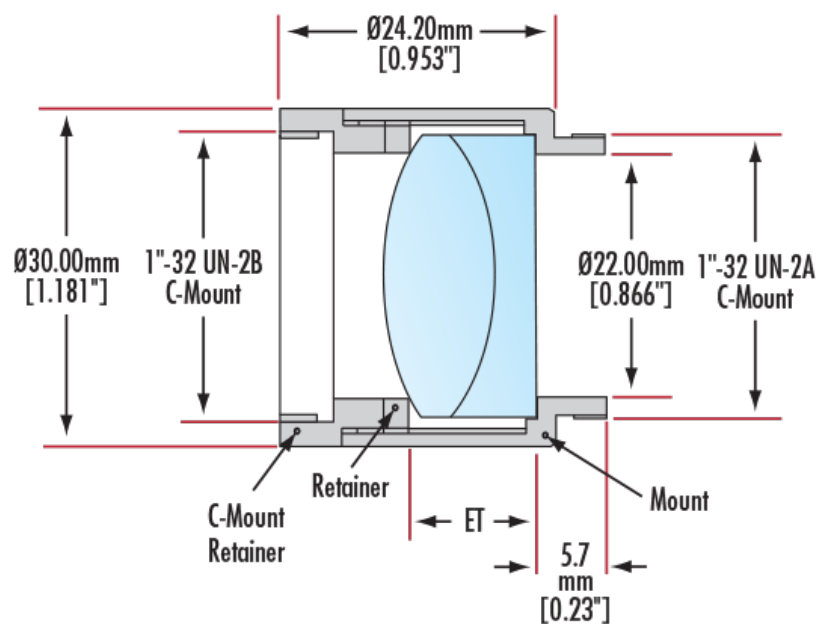


C-Mount Achromat/Thick Lens Mounts

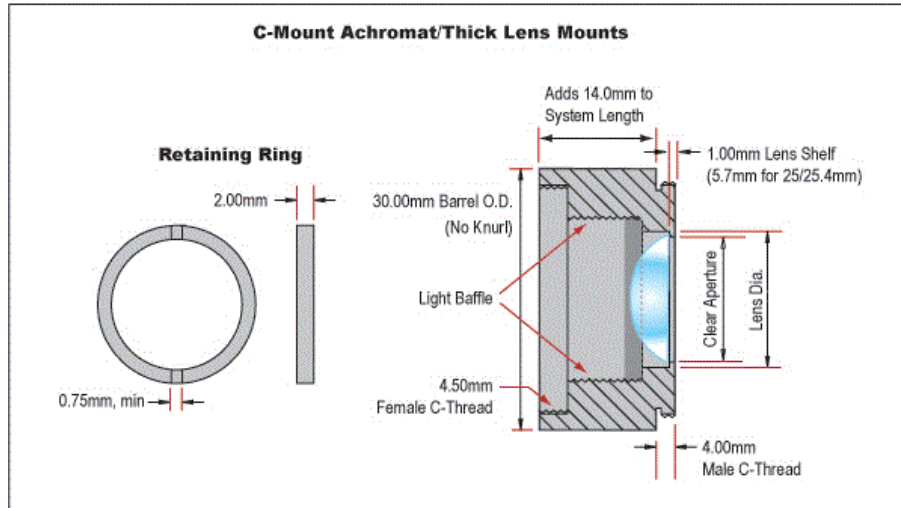


C-Thread Simple / Thin Lens Mount

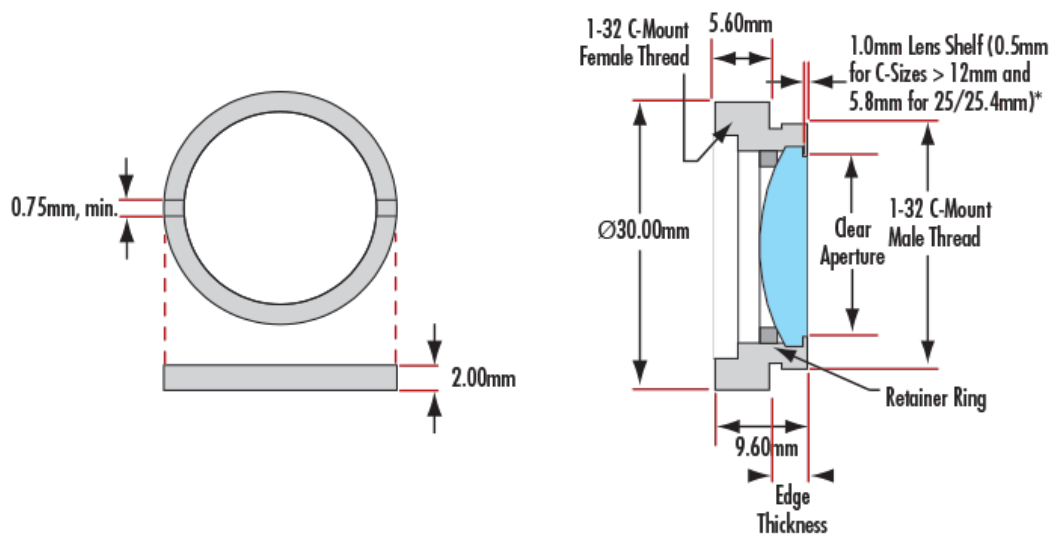


C-Thread Achromat / Thick Lens Mount

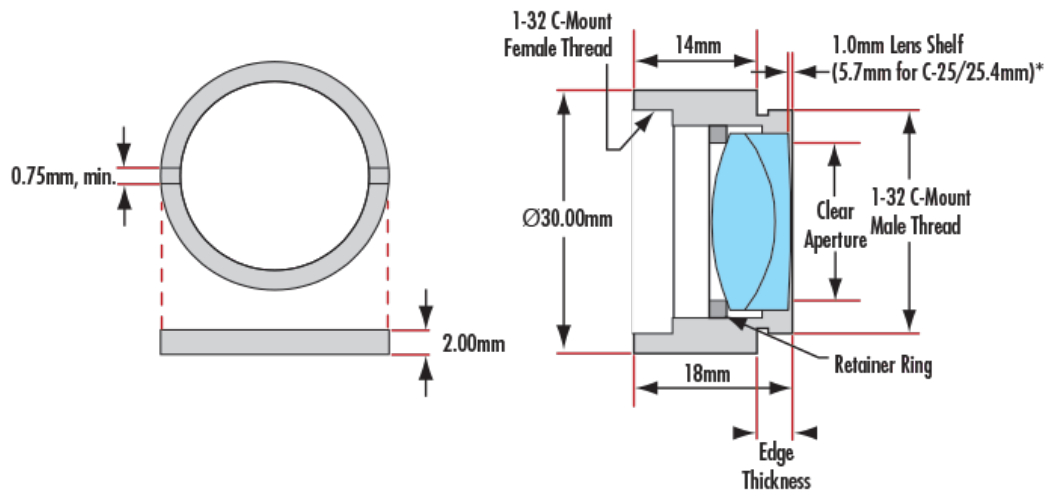


S-Thread Simple / Thin Lens Mount

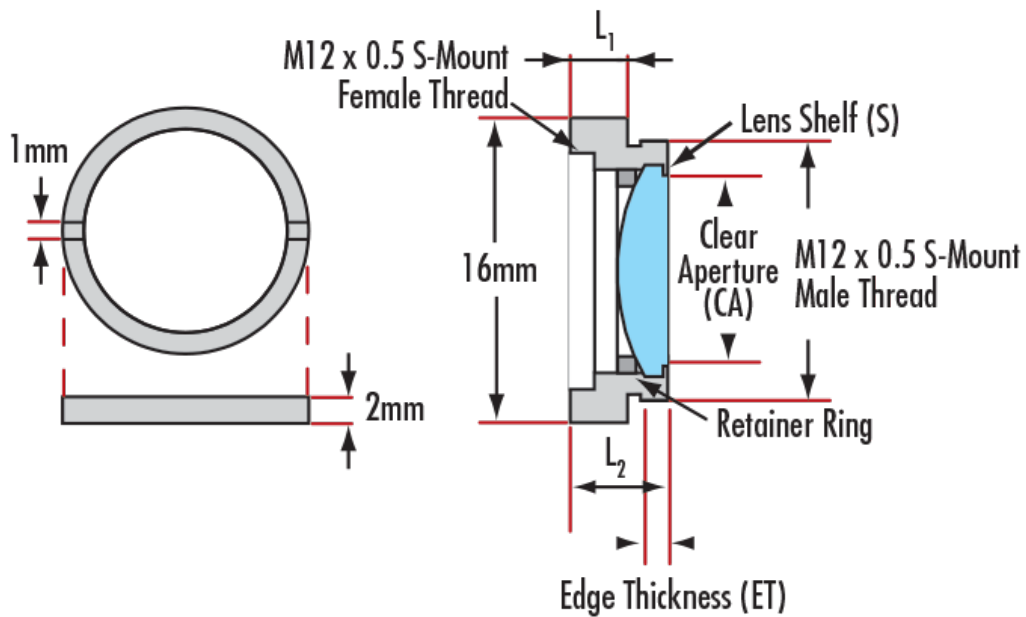


C-Thread Achromat / Thick Lens Mount

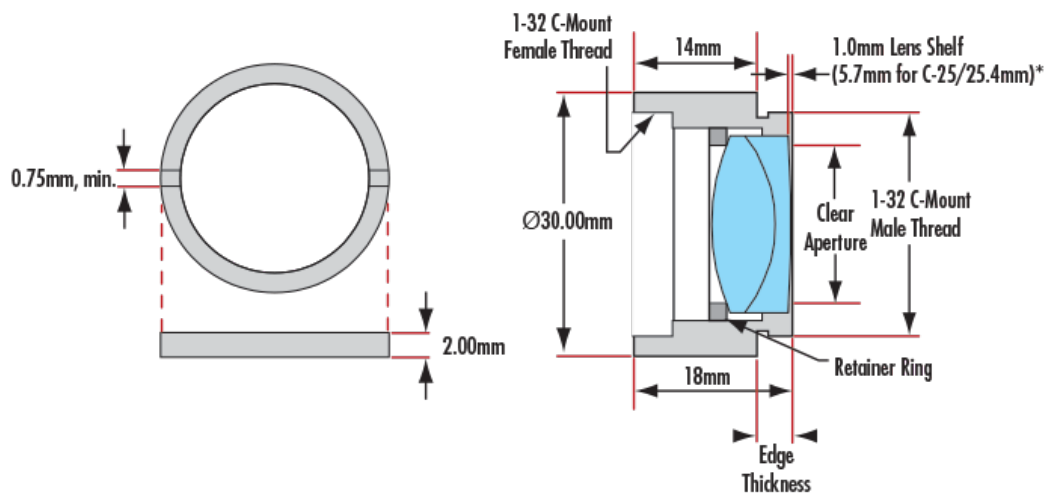


S-Thread Simple /Thin Lens Mount

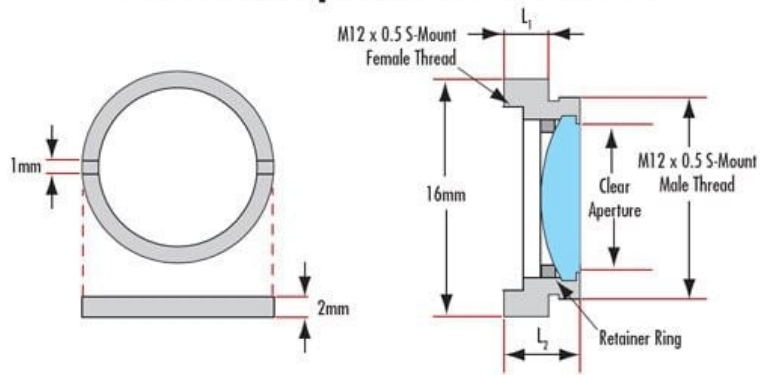


S-Thread Achromat / Thick Lens Mount

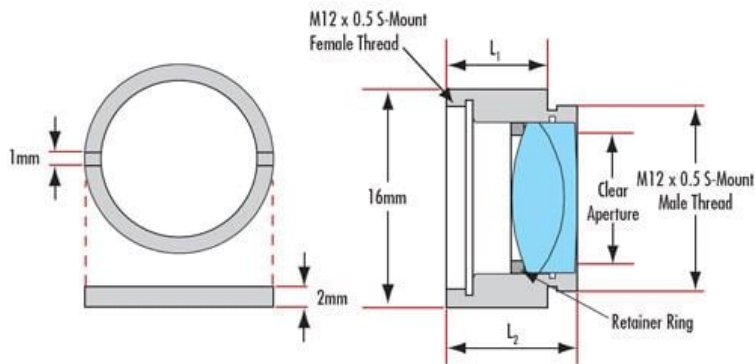

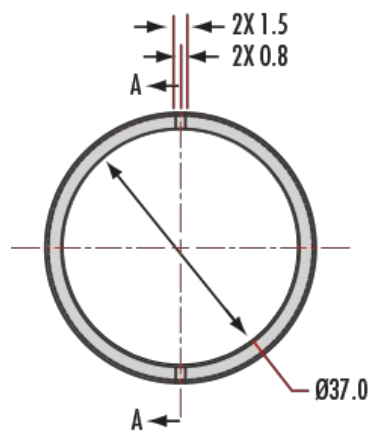

Section A-A

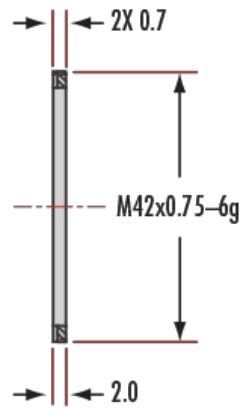

#58-741

Products

Thread Type	Diameter of Compatible Optics (mm)	Max. Thickness of Compatible Optics (mm)	Min. Thickness of Compatible Optics (mm)	Extension Length (mm)	Stock Number	Price	Buy
C-Mount	25.0 - 25.4	3.75	1.0	16.3	#56-353	C\$144.06 Volume Pricing	20+ In Stock
C-Mount	21.0	3.0	1.0	5.6	#53-860	C\$79.38 Volume Pricing	12 In Stock
C-Mount	20.0	2.90	1.00	5.6	#54-618	C\$79.38 Volume Pricing	20+ In Stock
C-Mount	18.0	3.0	1.0	5.6	#54-617	C\$79.38 Volume Pricing	5 In Stock
C-Mount	15.0	3.0	1.0	5.6	#54-616	C\$79.38 Volume Pricing	5 In Stock
C-Mount	12.5	3.0	1.0	5.6	#55-246	C\$79.38 Volume Pricing	20+ In Stock
C-Mount	12.0	3.0	1.0	5.6	#54-615	C\$79.38 Volume Pricing	3 In Stock
C-Mount	10.0	3.0	1.0	5.6	#63-979	C\$75.60 Volume Pricing	16 In Stock
C-Mount	9.0	3.0	1.0	5.6	#54-614	C\$79.38 Volume Pricing	20+ In Stock
C-Mount	6.5	3.0	1.0	5.6	#57-973	C\$79.38 Volume Pricing	4 In Stock
C-Mount	6.0	3.0	1.0	5.6	#54-613	C\$79.38 Volume Pricing	9 In Stock
C-Mount	5.0	3.0	1.0	5.6	#54-612	C\$79.38 Volume Pricing	1 In Stock
C-Mount	4.0	3.0	1.0	5.6	#57-972	C\$79.38 Volume Pricing	3 In Stock
C-Mount	3.0	3.0	1.0	5.6	#54-611	C\$79.38 Volume Pricing	16 In Stock
C-Mount	3.0	11.0	1.5	14.0	#54-620	C\$79.38 Volume Pricing	5 In Stock
C-Mount	5.0	6.5	1.0	14.0	#57-974	C\$79.38 Volume Pricing	6 In Stock

C-Mount	6.25	11.0	2.5	14.0	#54-621	C\$79.38 Volume Pricing	Contact Us
C-Mount	9.0	11.0	2.5	14.0	#54-622	C\$79.38 Volume Pricing	Contact Us
C-Mount	10.0	10.5	2.0	14.0	#63-980	C\$75.60 Volume Pricing	20+ In Stock
C-Mount	12.5	11.0	2.5	14.0	#54-623	C\$79.38 Volume Pricing	9 In Stock
C-Mount	15.0	11.0	3.0	14.0	#54-624	C\$79.38 Volume Pricing	13 In Stock
C-Mount	18.0	11.0	3.0	14.0	#54-625	C\$79.38 Volume Pricing	3 In Stock
C-Mount	20.0	11.0	3.5	14.0	#54-626	C\$79.38 Volume Pricing	13 In Stock
C-Mount	25.0 - 25.4	11.5	3.3	24.2	#56-354	C\$144.06 Volume Pricing	20+ In Stock
S-Mount	3.0	3.0	1.0	6.2	#63-938	C\$51.80 Volume Pricing	20+ In Stock
S-Mount	4.0	3.0	1.0	6.2	#63-939	C\$54.39 Volume Pricing	14 In Stock
S-Mount	5.0	3.0	1.0	5.6	#63-940	C\$54.39 Volume Pricing	20+ In Stock
S-Mount	6.0	3.0	1.0	5.6	#63-941	C\$54.39 Volume Pricing	20+ In Stock
S-Mount	9.0	3.0	1.0	5.6	#63-942	C\$54.39 Volume Pricing	20+ In Stock
S-Mount	10.0	2.5	1.0	8.6	#63-943	C\$54.39 Volume Pricing	20+ In Stock
S-Mount	12.5 - 12.7	2.5	1.0	13.6	#63-944	C\$89.67 Volume Pricing	20+ In Stock
S-Mount	5.0	6.5	1.0	9.7	#63-948	C\$51.80 Volume Pricing	8 In Stock
S-Mount	6.25	6.5	2.0	9.7	#63-949	C\$54.39 Volume Pricing	20+ In Stock
S-Mount	9.0	6.5	2.0	9.7	#63-950	C\$54.39 Volume Pricing	5 In Stock
S-Mount	10.0	6.5	2.0	12.7	#63-951	C\$54.39 Volume Pricing	4 In Stock
S-Mount	12.5 - 12.7	6.5	2.0	20.5	#63-952	C\$89.67 Volume Pricing	20+ In Stock
T-Mount	12.5 - 12.7	5.50	2.00	11.5	#52-933	C\$96.29 Volume Pricing	Contact Us

T-Mount	25.0 - 25.4	5.50	2.00	11.5	#52-292	C\$96.29 Volume Pricing	11 In Stock
T-Mount	27.0	5.5	2.0	11.5	#53-861	C\$96.29 Volume Pricing	3 In Stock
T-Mount	30.0	5.5	2.5	11.5	#57-975	C\$96.29 Volume Pricing	3 In Stock
T-Mount	40.0	10.95	2.0	15.0	#57-976	C\$96.29 Volume Pricing	7 In Stock
T-Mount	12.5 - 12.7	15.50	5.00	21.5	#52-954	C\$96.29 Volume Pricing	4 In Stock
T-Mount	25.0 - 25.4	15.50	5.00	21.5	#52-293	C\$96.29 Volume Pricing	3 In Stock
T-Mount	30.0	15.5	5.0	21.5	#57-977	C\$96.29 Volume Pricing	Contact Us
T-Mount	40.0	20.95	5.0	25.0	#57-978	C\$96.29 Volume Pricing	15 In Stock
T-Mount	50.0	10.0	2.0	22.0	#88-943	C\$137.20 Volume Pricing	20+ In Stock
T-Mount	50.0	18.5	5.0	32.5	#88-944	C\$144.06 Volume Pricing	11 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com