


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Concave \(PCV\) Lenses](#)

TECHSPEC® YAG-BBAR Coated Plano-Concave (PCV) Lenses

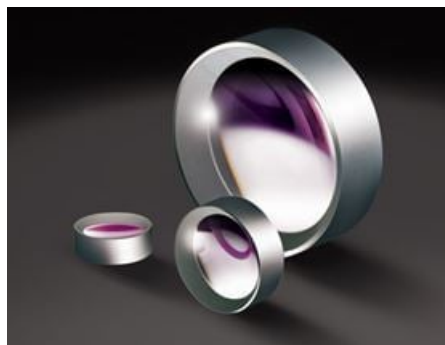

- Negative Focal Lengths for Beam Expansion or Light Projection Applications
- Optimized for $R < 0.25\%$ at both 532nm and 1064nm
- AR Coated to Provide $< 1.0\%$ Reflectance per Surface for 500 - 1100nm
- Various Coating Options: [Uncoated](#), [VIS-EXT](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), and [1064nm V-Coat](#)

Common Specifications

Physical & Mechanical Properties

Bevel: Protective as needed

Optical Properties

Coating: YAG-BBAR (500-1100nm)

Wavelength Range (nm):	500 - 1100	Focal Length Specification Wavelength (nm):	587.6
Focal Length Tolerance (%):	± 1	Damage Threshold, By Design:	5 J/cm ² @ 532nm, 10ns
Power (P-V) @ 632.8nm:	1.5 λ	Irregularity (P-V) @ 632.8nm:	$\lambda/4$

Technical Information

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
3.00	-6.00	-6.56	YAG-BBAR (500- 1100nm)	N-SF11	#21-299	C\$107.35 Volume Pricing	10 In Stock
3.00	-9.00	-9.56	YAG-BBAR (500- 1100nm)	N-SF11	#21-300	C\$107.35 Volume Pricing	5 In Stock
6.00	-6.00	-6.84	YAG-BBAR (500- 1100nm)	N-SF11	#21-301	C\$65.02 Volume Pricing	Contact Us
6.00	-9.00	-9.84	YAG-BBAR (500- 1100nm)	N-SF11	#21-302	C\$65.02 Volume Pricing	9 In Stock
6.00	-12.00	-12.99	YAG-BBAR (500- 1100nm)	N-BK7	#21-303	C\$65.02 Volume Pricing	3 In Stock
6.00	-15.00	-16.32	YAG-BBAR (500- 1100nm)	N-BK7	#21-304	C\$65.02 Volume Pricing	4 In Stock
6.00	-18.00	-19.32	YAG-BBAR (500- 1100nm)	N-BK7	#21-305	C\$65.02 Volume Pricing	7 In Stock
9.00	-9.00	-10.21	YAG-BBAR (500- 1100nm)	N-SF11	#21-306	C\$66.53 Volume Pricing	7 In Stock
9.00	-12.00	-13.26	YAG-BBAR (500- 1100nm)	N-SF11	#21-307	C\$66.53 Volume Pricing	15 In Stock
9.00	-18.00	-19.26	YAG-BBAR (500- 1100nm)	N-SF11	#21-308	C\$66.53 Volume Pricing	14 In Stock
9.00	-27.00	-28.68	YAG-BBAR (500- 1100nm)	N-SF11	#21-309	C\$66.53 Volume Pricing	20+ In Stock
12.00	-12.00	-13.23	YAG-BBAR (500- 1100nm)	N-SF11	#21-310	C\$69.55 Volume Pricing	Contact Us

12.00	-15.00	-16.68	YAG-BBAR (500-1100nm)	N-SF11	#21-311	C\$69.55 Volume Pricing	2 In Stock
12.00	-18.00	-19.95	YAG-BBAR (500-1100nm)	N-SF11	#21-312	C\$69.55 Volume Pricing	2 In Stock
12.00	-24.00	-26.32	YAG-BBAR (500-1100nm)	N-BK7	#21-313	C\$69.55 Volume Pricing	10 In Stock
12.00	-48.00	-50.31	YAG-BBAR (500-1100nm)	N-BK7	#21-314	C\$69.55 Volume Pricing	6 In Stock
20.00	-30.00	-31.96	YAG-BBAR (500-1100nm)	N-SF11	#21-315	C\$73.33 Volume Pricing	3 In Stock
20.00	-40.00	-42.31	YAG-BBAR (500-1100nm)	N-BK7	#21-316	C\$73.33 Volume Pricing	1 In Stock
20.00	-50.00	-52.31	YAG-BBAR (500-1100nm)	N-BK7	#21-317	C\$73.33 Volume Pricing	1 In Stock
20.00	-	-	YAG-BBAR (500-1100nm)	N-BK7	#21-335	C\$73.33 Volume Pricing	5 In Stock
25.00	-25.00	-26.96	YAG-BBAR (500-1100nm)	N-SF11	#21-318	C\$77.11 Volume Pricing	15 In Stock
25.00	-35.00	-36.96	YAG-BBAR (500-1100nm)	N-SF11	#21-319	C\$77.11 Volume Pricing	10 In Stock
25.00	-50.00	-52.31	YAG-BBAR (500-1100nm)	N-BK7	#21-320	C\$77.11 Volume Pricing	7 In Stock
25.00	-	-	YAG-BBAR (500-1100nm)	N-BK7	#21-321	C\$77.11 Volume Pricing	5 In Stock
50.00	-	-	YAG-BBAR (500-1100nm)	N-BK7	#21-322	C\$112.64 Volume Pricing	3 In Stock
50.00	-	-	YAG-BBAR (500-1100nm)	N-BK7	#21-323	C\$112.64 Volume Pricing	1 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com