

[All Products](#) /
 [Optics](#) /
 [Optical Mirrors](#) /
 [Focusing \(Concave\) Mirrors](#)

TECHSPEC® Broadband Dielectric Spherical Mirrors






- Ideal for Multispectral Focusing Applications
- Average Reflectivity >99% Over Broad UV, Visible, and NIR Wavelengths
- Multiple Sizes Available


Common Specifications

Physical & Mechanical Properties

Back Surface: Ground	Edge Thickness Tolerance (%): +0.0/-15
Optical Properties	
Coating Type: Dielectric	Focal Length Tolerance (%): ±2
Surface Accuracy: $\lambda/4$	Surface Quality: 60-40

Technical Information

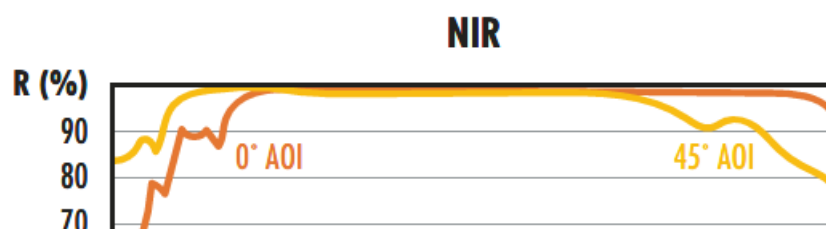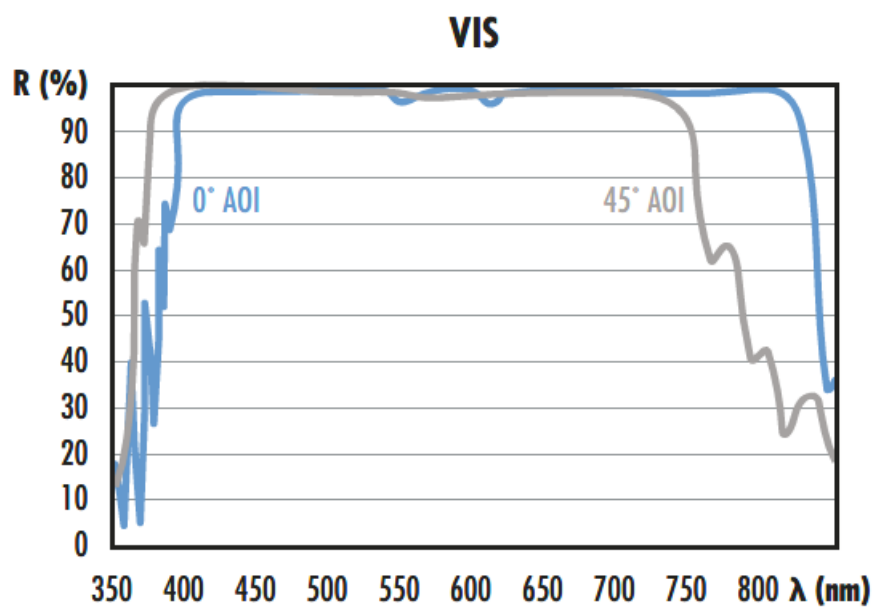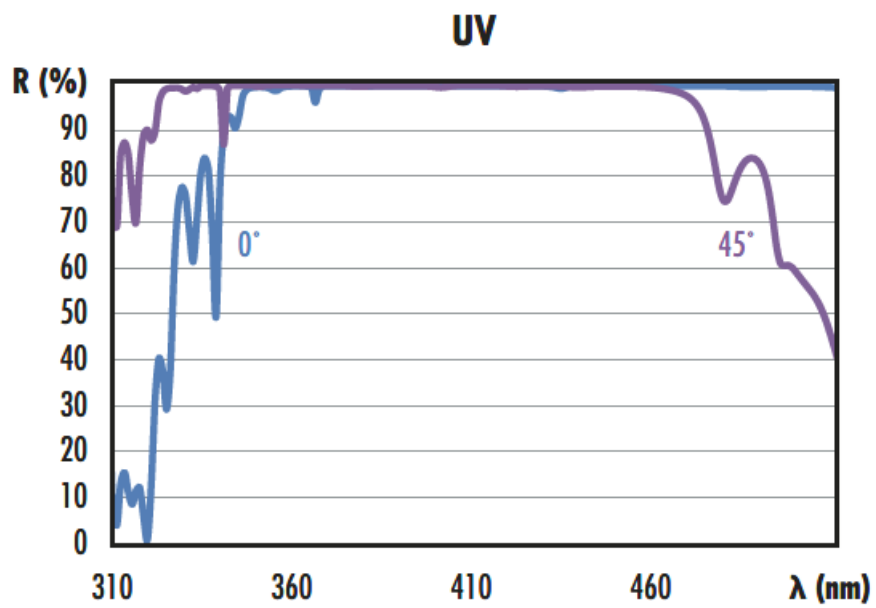

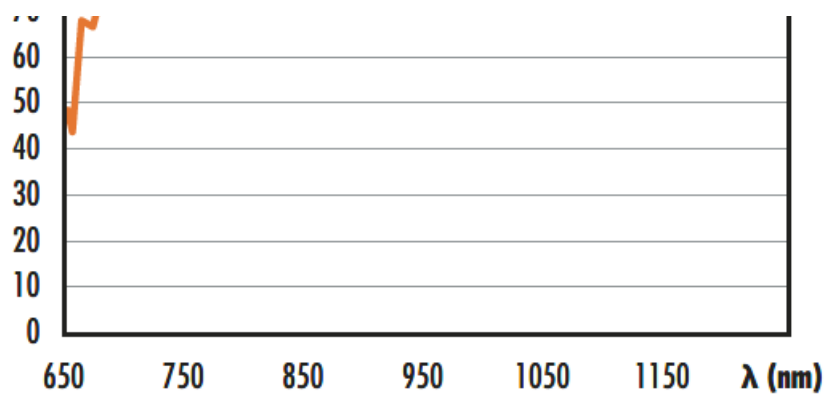

Products

Dia. (mm)	Wavelength Range (nm)	EFL (mm)	ET (mm)	Stock Number	Price	Buy
25.40	320 - 450	25.40	6.35	#72-960	C\$252.28 Volume Pricing	9 In Stock
25.40	320 - 450	50.80	6.35	#72-961	C\$252.28 Volume Pricing	14 In Stock
25.40	320 - 450	76.20	6.35	#72-962	C\$252.28 Volume Pricing	8 In Stock
25.40	320 - 450	101.60	6.35	#72-963	C\$252.28 Volume Pricing	9 In Stock
25.40	320 - 450	152.40	6.35	#72-964	C\$252.28 Volume Pricing	8 In Stock
25.40	320 - 450	203.20	6.35	#72-965	C\$252.28 Volume Pricing	Contact Us
50.80	320 - 450	50.80	12.70	#72-966	C\$408.10 Volume Pricing	10 In Stock
50.80	320 - 450	101.60	12.70	#72-967	C\$408.10 Volume Pricing	10 In Stock
50.80	320 - 450	152.40	12.70	#72-968	C\$408.10 Volume Pricing	4 In Stock
50.80	320 - 450	203.20	12.70	#72-969	C\$408.10 Volume Pricing	7 In Stock
50.80	320 - 450	304.80	12.70	#72-970	C\$408.10 Volume Pricing	4 In Stock
50.80	320 - 450	508.00	12.70	#72-971	C\$408.10 Volume Pricing	4 In Stock
50.80	320 - 450	1,016.00	12.70	#72-972	C\$408.10 Volume Pricing	5 In Stock
76.20	320 - 450	76.20	12.70	#72-973	C\$630.70 Volume Pricing	3 In Stock
76.20	320 - 450	152.40	12.70	#72-974	C\$630.70 Volume Pricing	3 In Stock
76.20	320 - 450	203.20	12.70	#72-975	C\$630.70 Volume Pricing	3 In Stock
76.20	320 - 450	304.80	12.70	#72-976	C\$630.70 Volume Pricing	3 In Stock

76.20	320 - 450	457.20	12.70	#72-977	C\$630.70 Volume Pricing	3 In Stock
76.20	320 - 450	762.00	12.70	#72-978	C\$630.70 Volume Pricing	3 In Stock
152.40	320 - 450	609.60	25.40	#72-979	C\$1,780.80 Volume Pricing	1 In Stock
25.40	400 - 750	25.40	6.35	#72-980	C\$222.60 Volume Pricing	13 In Stock
25.40	400 - 750	50.80	6.35	#72-981	C\$222.60 Volume Pricing	12 In Stock
25.40	400 - 750	76.20	6.35	#72-982	C\$222.60 Volume Pricing	14 In Stock
25.40	400 - 750	101.60	6.35	#72-983	C\$222.60 Volume Pricing	14 In Stock
25.40	400 - 750	152.40	6.35	#72-984	C\$222.60 Volume Pricing	16 In Stock
25.40	400 - 750	203.20	6.35	#72-985	C\$222.60 Volume Pricing	14 In Stock
50.80	400 - 750	50.80	12.70	#72-986	C\$371.00 Volume Pricing	5 In Stock
50.80	400 - 750	101.60	12.70	#72-987	C\$371.00 Volume Pricing	5 In Stock
50.80	400 - 750	152.40	12.70	#72-988	C\$371.00 Volume Pricing	9 In Stock
50.80	400 - 750	203.20	12.70	#72-989	C\$371.00 Volume Pricing	10 In Stock
50.80	400 - 750	304.80	12.70	#72-990	C\$371.00 Volume Pricing	11 In Stock
50.80	400 - 750	508.00	12.70	#72-991	C\$371.00 Volume Pricing	9 In Stock
50.80	400 - 750	1,016.00	12.70	#72-992	C\$371.00 Volume Pricing	4 In Stock
76.20	400 - 750	76.20	12.70	#72-993	C\$586.18 Volume Pricing	3 In Stock
76.20	400 - 750	152.40	12.70	#72-994	C\$586.18 Volume Pricing	Contact Us
76.20	400 - 750	203.20	12.70	#72-995	C\$586.18 Volume Pricing	1 In Stock
76.20	400 - 750	304.80	12.70	#72-996	C\$586.18 Volume Pricing	3 In Stock

76.20	400 - 750	457.20	12.70	#72-997	C\$586.18 Volume Pricing	1 In Stock
76.20	400 - 750	762.00	12.70	#72-998	C\$586.18 Volume Pricing	2 In Stock
152.40	400 - 750	609.60	25.40	#72-999	C\$1,669.50 Volume Pricing	1 In Stock
25.40	750 - 1100	25.40	6.35	#73-000	C\$222.60 Volume Pricing	12 In Stock
25.40	750 - 1100	50.80	6.35	#73-001	C\$222.60 Volume Pricing	7 In Stock
25.40	750 - 1100	76.20	6.35	#73-002	C\$222.60 Volume Pricing	8 In Stock
25.40	750 - 1100	101.60	6.35	#73-003	C\$222.60 Volume Pricing	5 In Stock
25.40	750 - 1100	152.40	6.35	#73-006	C\$222.60 Volume Pricing	11 In Stock
25.40	750 - 1100	203.20	6.35	#73-007	C\$222.60 Volume Pricing	Contact Us
50.80	750 - 1100	50.80	12.70	#73-008	C\$371.00 Volume Pricing	5 In Stock
50.80	750 - 1100	101.60	12.70	#73-009	C\$371.00 Volume Pricing	7 In Stock
50.80	750 - 1100	152.40	12.70	#73-010	C\$371.00 Volume Pricing	4 In Stock
50.80	750 - 1100	203.20	12.70	#73-011	C\$371.00 Volume Pricing	5 In Stock
50.80	750 - 1100	304.80	12.70	#73-015	C\$371.00 Volume Pricing	3 In Stock
50.80	750 - 1100	508.00	12.70	#73-020	C\$371.00 Volume Pricing	5 In Stock
50.80	750 - 1100	1,016.00	12.70	#73-021	C\$371.00 Volume Pricing	5 In Stock
76.20	750 - 1100	76.20	12.70	#73-024	C\$586.18 Volume Pricing	5 In Stock
76.20	750 - 1100	152.40	12.70	#73-025	C\$586.18 Volume Pricing	2 In Stock
76.20	750 - 1100	203.20	12.70	#73-026	C\$586.18 Volume Pricing	2 In Stock
76.20	750 - 1100	304.80	12.70	#73-027	C\$586.18 Volume Pricing	3 In Stock

76.20	750 - 1100	457.20	12.70	#73-030	C\$586.18 Volume Pricing	2 In Stock
76.20	750 - 1100	762.00	12.70	#73-034	C\$586.18 Volume Pricing	3 In Stock
152.40	750 - 1100	609.60	25.40	#73-036	C\$1,669.50 Volume Pricing	Contact Us



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com