

Iris Mount for 22mm Outer Diameter Irises



Iris Mount for 70mm Outer Diameter Irises, #53-921



Stock **#23-123** **20+ In Stock**

-

1

+

C\$69^{.93}

ADD TO CART

Volume Pricing	
Qty 1-4	C\$69.93 each
Qty 5-9	C\$63.05 each
Qty 10-25	C\$56.85 each
Need More?	Request Quote

Product Downloads

SPECIFICATIONS

Physical & Mechanical Properties

Compatible Iris Diameter (mm):

22.0	Outer Diameter (mm):
39.0	
6.00	Thickness (mm):
19.05	Optical Axis Height (mm):

Threading & Mounting

M4 x0.7 and 8-32	Mounting Threads:
4-40	Set Screw Thread:

Regulatory Compliance


Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 235:

PRODUCT DETAILS

- Multiple Iris Diameter Options Available
- Durable Anodized Aluminum Construction
- Set Screw Included

Iris Diaphragm Mounts fit our most popular sizes of [Iris Diaphragms](#) and are constructed from durable black anodized aluminum. These mounts feature a variety of different English post mounting options, and each utilize an included set screw to ensure a secure fit.

TECHNICAL INFORMATION

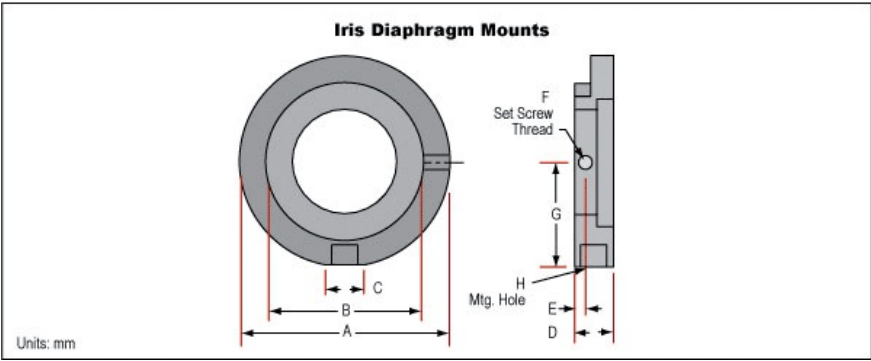

Iris Diameter	A	B	C	D	E	F	G	H	Stock No.
19.8	30.8	19.8	6.1	6.35	2.5	4-40	15.1	8-32	#53-918
37.0	50.8	37.0	9.0	9.5	2.8	6-32	25.0	1/4-20	#53-919
53.0	66.0	53.0	9.9	9.5	3.0	6-32	32.7	1/4-20	#53-920
70.0	86.0	70.0	10.1	9.5	3.8	6-32	42.7	1/4-20	#53-921
21.0	32.0	21.0	6.2	9.5	3.2	4-40	15.7	8-32	#54-862
38.0	52.0	38.0	9.1	9.5	3.2	6-32	25.6	1/4-20	#54-863
54.0	67.0	54.0	8.9	9.5	3.8	6-32	33.2	1/4-20	#54-864
72.0	88.0	72.0	10.3	11.5	3.8	6-32	43.7	1/4-20	#54-865

